
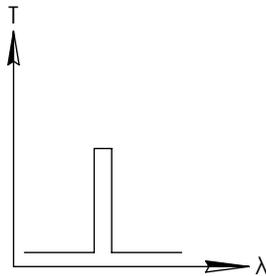
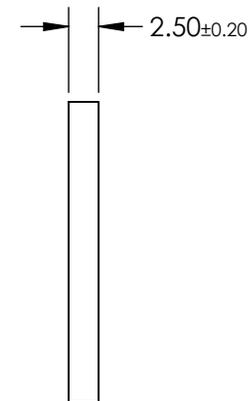
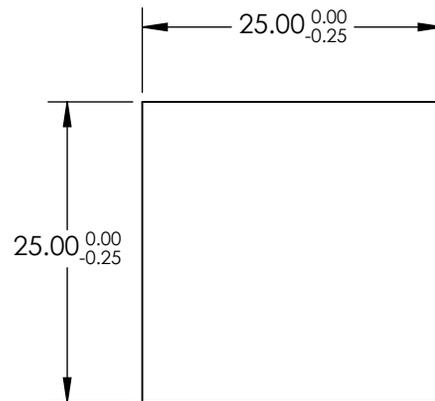


**FOR INFORMATION ONLY:  
DO NOT MANUFACTURE  
PARTS TO THIS DRAWING**

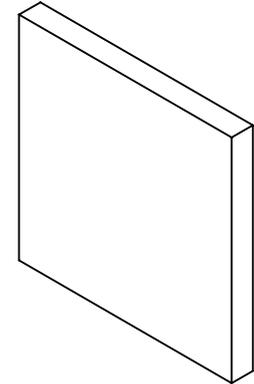


BANDPASS FILTER

SPECIFICATIONS SUBJECT TO CHANGE WITHOUT NOTICE  
DIMENSIONS ARE FOR REFERENCE ONLY

	VALUE
SHAPE	PLANO
CENTER WAVELENGTH (nm)	830
FULL WIDTH HALF MAX (FWHM) (nm)	260
SURFACE QUALITY	80-50
CAOTING TYPE	Uncoated
BEVEL	PROTECTIVE AS NEEDED



THIRD ANGLE PROJECTION

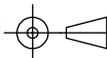

TITLE

HOYA RT-830 (IR) 25mm Square, Colored  
Glass Bandpass Filter

ALL DIMS IN

mm

DWG NO

46086

SHEET  
1 OF 1