

NOTES:

1. SUBSTRATE MATERIAL:  
BOROFLOAT®




2. COATING (APPLY ACROSS CLEAR APERTURE)

S1: R(avg) <0.5% @ 425 - 675nm  
HYDROPHOBIC COATING - REPELS WATER, OIL AND  
DEBRIS

S2:NONE

3. FINE GRIND SURFACE

4. ROHS COMPLIANT

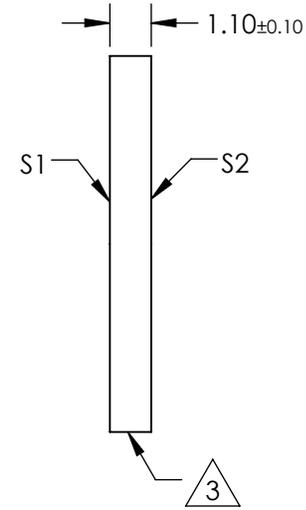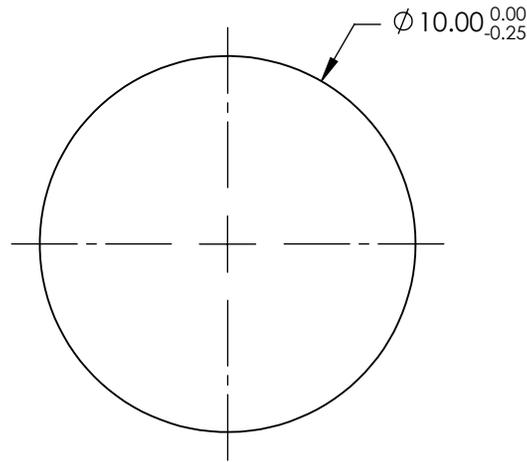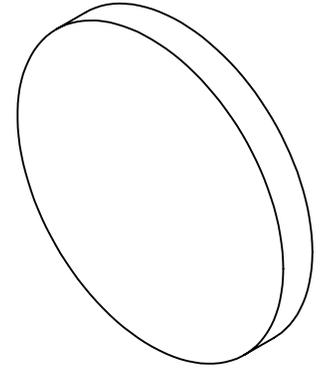

**FOR INFORMATION ONLY:  
DO NOT MANUFACTURE  
PARTS TO THIS DRAWING**

SPECIFICATIONS SUBJECT TO CHANGE WITHOUT NOTICE  
DIMENSIONS ARE FOR REFERENCE ONLY

	S1	S2
SHAPE	PLANO	PLANO
SURFACE QUALITY	80 - 50	80 - 50
CLEAR APERTURE	Ø9.00	Ø9.00
BEVEL	PROTECTIVE AS NEEDED	PROTECTIVE AS NEEDED

THIRD ANGLE  
PROJECTION

ALL DIMS IN mm

**EO**® **Edmund Optics**®

TITLE

WINDOW BORO HYDRO & OLEO 10MM TS  
Indoor

DWG NO

36069

SHEET  
1 OF 1