

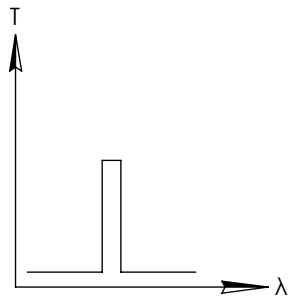
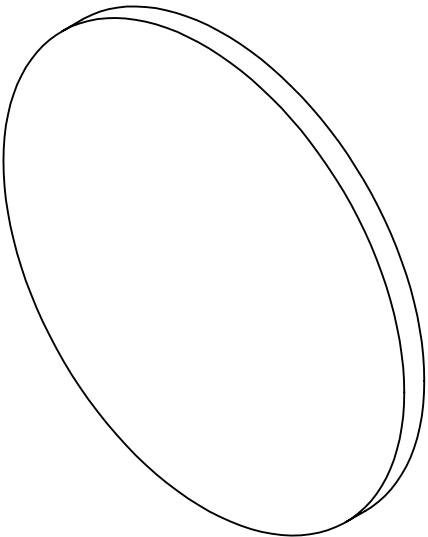


NOTES:

1. SUBSTRATE: COLORED GLASS

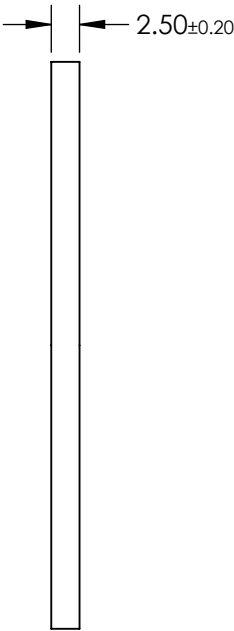

BANDPASS FILTER

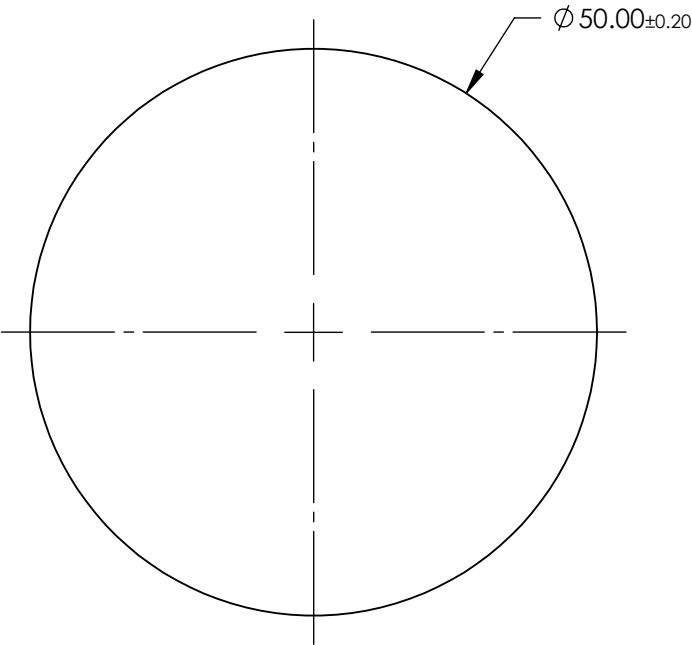

**FOR INFORMATION ONLY:
DO NOT MANUFACTURE
PARTS TO THIS DRAWING**

SPECIFICATIONS SUBJECT TO CHANGE WITHOUT NOTICE
DIMENSIONS ARE FOR REFERENCE ONLY

| | VALUE |
|---------------------------------|----------------------|
| SHAPE | PLANO |
| CENTER WAVELENGTH (nm) | 330.00 |
| FULL WIDTH HALF MAX (FWHM) (nm) | 140.00 |
| SURFACE QUALITY | 60-40 |
| COATING TYPE | UNCOATED |
| BEVEL | PROTECTIVE AS NEEDED |

THIRD ANGLE
PROJECTION

ALL DIMS IN

mm

 **Edmund Optics®**

| | | | |
|--------|---|-----------------|--|
| TITLE | Hoya U330 (UV) 50mm Dia., 2.5mm Thick, Colored Glass Bandpass Filter | | |
| DWG NO | 18764 | SHEET 1 OF 1 | |