



NOTES:

1. SUBSTRATE: COLORED GLASS

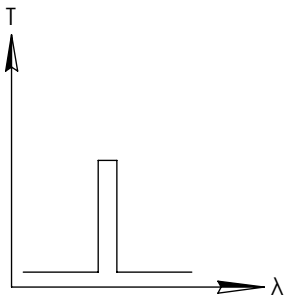

BANDPASS FILTER

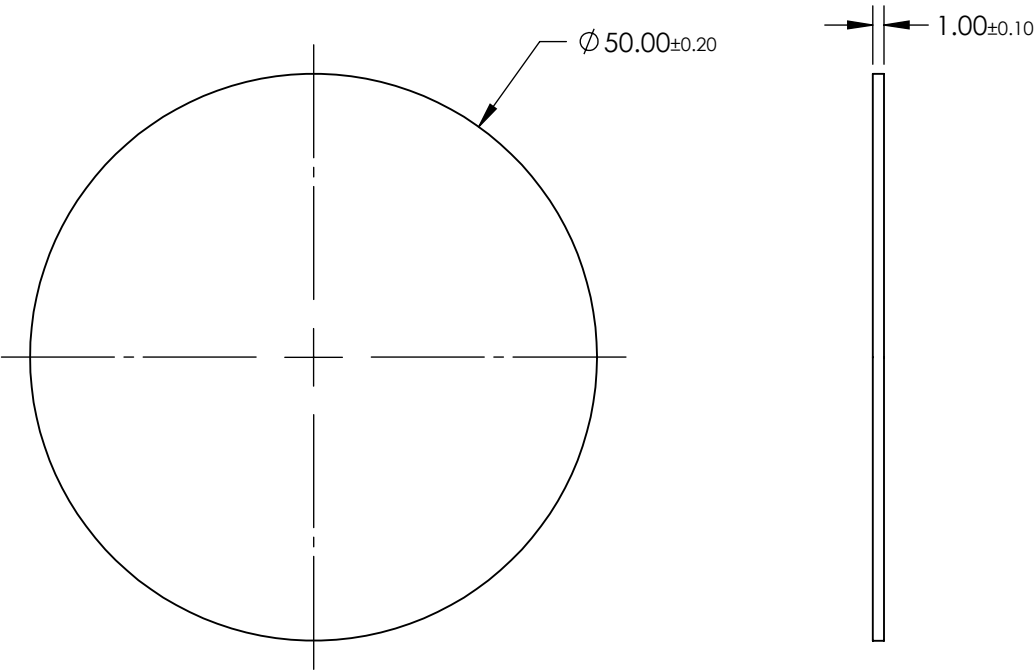

**FOR INFORMATION ONLY:
DO NOT MANUFACTURE
PARTS TO THIS DRAWING**

SPECIFICATIONS SUBJECT TO CHANGE WITHOUT NOTICE
DIMENSIONS ARE FOR REFERENCE ONLY

	VALUE
SHAPE	PLANO
CENTER WAVELENGTH (nm)	340.00
FULL WIDTH HALF MAX (FWHM) (nm)	85.00
SURFACE QUALITY	60-40
COATING TYPE	UNCOATED
BEVEL	PROTECTIVE AS NEEDED

THIRD ANGLE
PROJECTION

ALL DIMS IN

mm

 **Edmund Optics®**

TITLE

Hoya U340 (UV) 50mm Dia., 1mm Thick,
Colored Glass Bandpass Filter

DWG NO

18768

SHEET
1 OF 1