

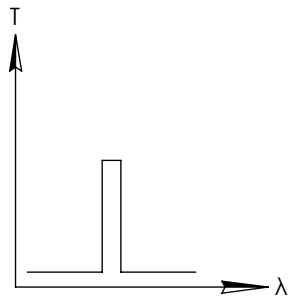
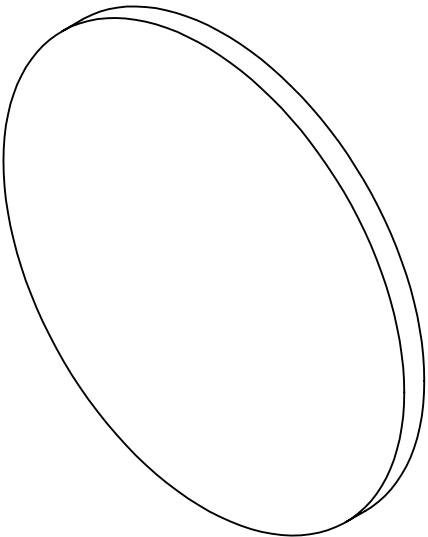


NOTES:

1. SUBSTRATE: COLORED GLASS

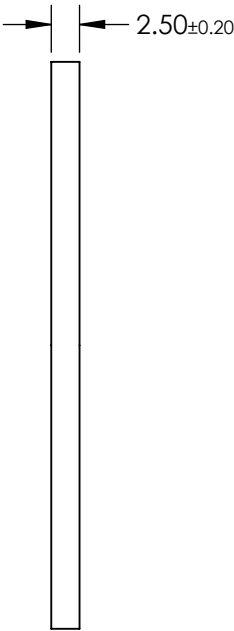

BANDPASS FILTER

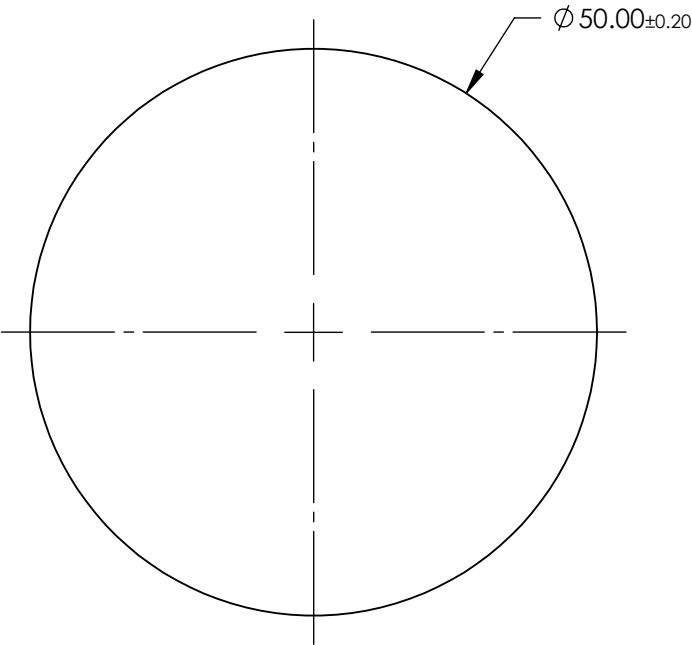

**FOR INFORMATION ONLY:
DO NOT MANUFACTURE
PARTS TO THIS DRAWING**


SPECIFICATIONS SUBJECT TO CHANGE WITHOUT NOTICE
DIMENSIONS ARE FOR REFERENCE ONLY

	VALUE
SHAPE	PLANO
CENTER WAVELENGTH (nm)	390.00
FULL WIDTH HALF MAX (FWHM) (nm)	125.00
SURFACE QUALITY	60-40
COATING TYPE	UNCOATED
BEVEL	PROTECTIVE AS NEEDED

THIRD ANGLE
PROJECTION

ALL DIMS IN

mm

 **Edmund Optics®**

TITLE

Hoya B390 (UVVIS) 50mm Dia., 2.5mm Thick,
Colored Glass Bandpass Filter

DWG NO

18784

SHEET
1 OF 1