


NOTES:

- 1. LASER CLASS:  
IIIb
- 2. OPERATING TEMPERATURE: 15 to 30 °C  
OPERATING VOLTAGE: 5V
- 3. OUTPUT POWER: 15mW
- 4. WAVELENGTH RANGE: 445±10 nm

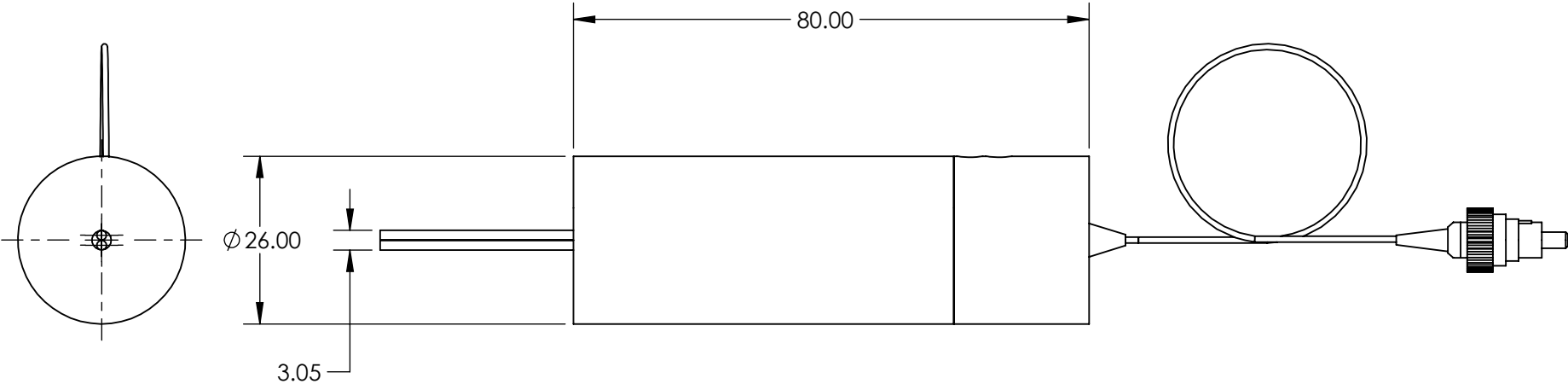

**FOR INFORMATION ONLY:  
DO NOT MANUFACTURE  
PARTS TO THIS DRAWING**

SPECIFICATIONS SUBJECT TO CHANGE WITHOUT NOTICE  
DIMENSIONS ARE FOR REFERENCE ONLY

**EO**® Edmund Optics®

THIRD ANGLE PROJECTION		TITLE	445nm 15mW Pigtailed Laser Diode	
ALL DIMS IN	mm	DWG NO	23755	SHEET 1 OF 1