
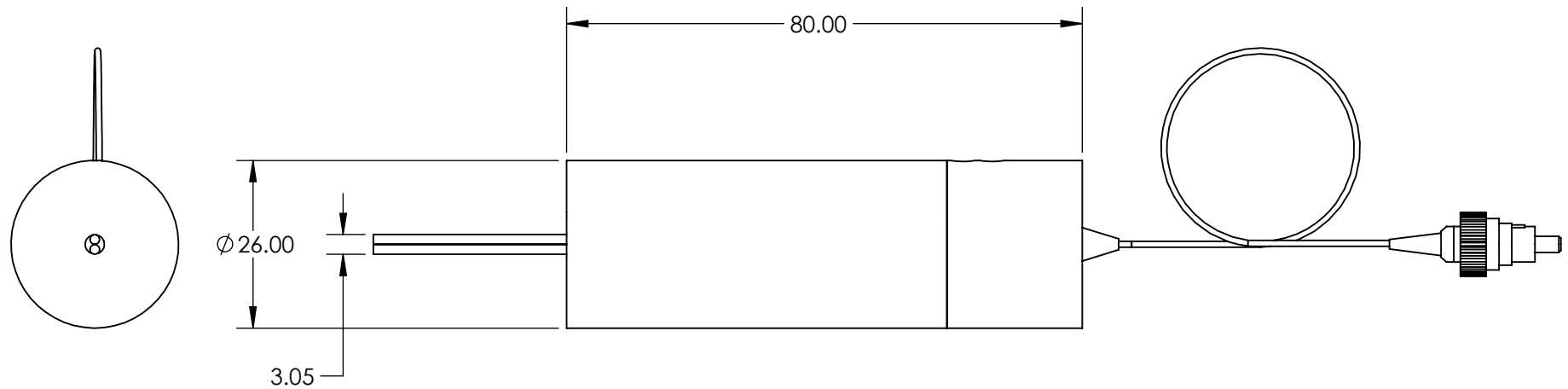


NOTES:

1. LASER CLASS:  
IIIb
2. OPERATING TEMPERATURE: 15 to 30 °C  
OPERATING VOLTAGE: 5V
3. OUTPUT POWER: 50mW
4. WAVELENGTH RANGE: 520±10 nm

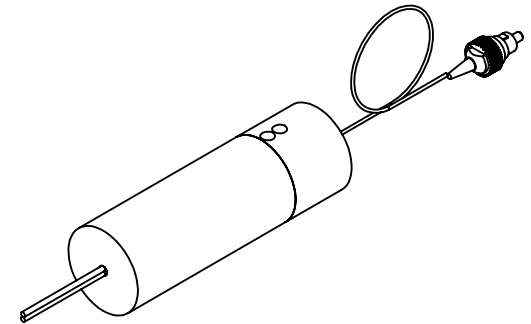

**FOR INFORMATION ONLY:  
DO NOT MANUFACTURE  
PARTS TO THIS DRAWING**

SPECIFICATIONS SUBJECT TO CHANGE WITHOUT NOTICE  
DIMENSIONS ARE FOR REFERENCE ONLY

**EO**® Edmund Optics®

THIRD ANGLE PROJECTION		TITLE	520nm 50mW Pigtailed Laser Diode	
ALL DIMS IN	mm	DWG NO	23769	SHEET 1 OF 1