

NOTES:

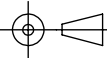
- 1. LASER CLASS:  
IIIb
- 2. OPERATING TEMPERATURE: 15 to 30 °C  
OPERATING VOLTAGE: 5V
- 3. OUTPUT POWER: 100mW
- 4. WAVELENGTH RANGE: 658±10 nm



**FOR INFORMATION ONLY:  
DO NOT MANUFACTURE  
PARTS TO THIS DRAWING**

SPECIFICATIONS SUBJECT TO CHANGE WITHOUT NOTICE  
DIMENSIONS ARE FOR REFERENCE ONLY

**EO**® Edmund Optics®

|  |    |        |                                   |              |
|--|----|--------|-----------------------------------|--------------|
| THIRD ANGLE PROJECTION  |    | TITLE  | 658nm 100mW Pigtailed Laser Diode |              |
| ALL DIMS IN  | mm | DWG NO | 23780                             | SHEET 1 OF 1 |