
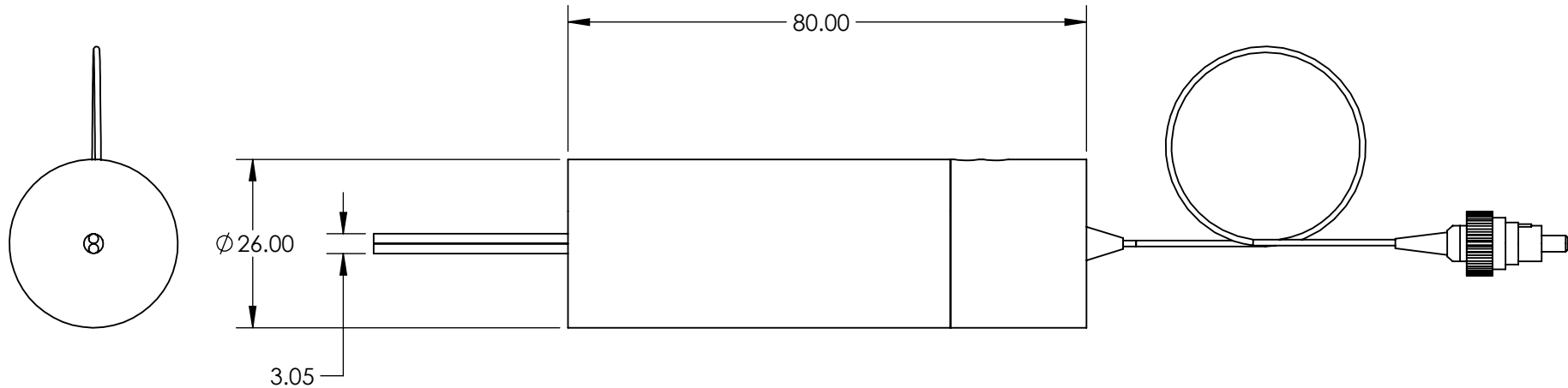


NOTES:

- 1. LASER CLASS:
IIIb
- 2. OPERATING TEMPERATURE: 15 to 30 °C
OPERATING VOLTAGE: 5V
- 3. OUTPUT POWER: 1mW
- 4. WAVELENGTH RANGE: 880±0 nm

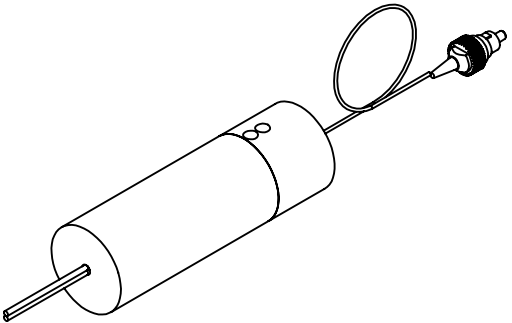

**FOR INFORMATION ONLY:
DO NOT MANUFACTURE
PARTS TO THIS DRAWING**

SPECIFICATIONS SUBJECT TO CHANGE WITHOUT NOTICE
DIMENSIONS ARE FOR REFERENCE ONLY

EO[®] Edmund Optics[®]

THIRD ANGLE PROJECTION		TITLE	880nm 1mW Pigtailed Laser Diode	
ALL DIMS IN	mm	DWG NO	23793	SHEET 1 OF 1