
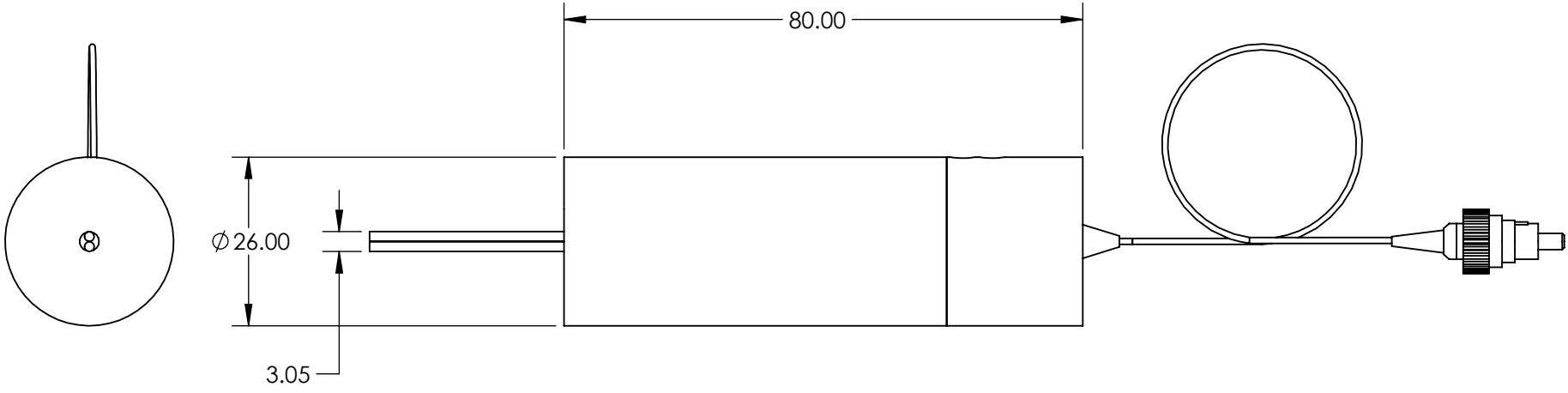


NOTES:

- 1. LASER CLASS:
IIIb
- 2. OPERATING TEMPERATURE: 15 to 30 °C
OPERATING VOLTAGE: 5V
- 3. OUTPUT POWER: 10mW
- 4. WAVELENGTH RANGE: 1310±10nm

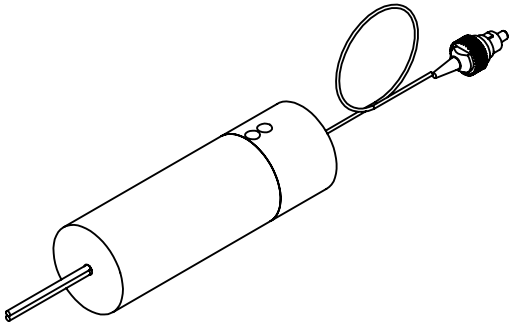

**FOR INFORMATION ONLY:
DO NOT MANUFACTURE
PARTS TO THIS DRAWING**

SPECIFICATIONS SUBJECT TO CHANGE WITHOUT NOTICE
DIMENSIONS ARE FOR REFERENCE ONLY

THIRD ANGLE PROJECTION		Edmund Optics®		
ALL DIMS IN		TITLE	1310nm 10mW Pigtailed Laser Diode	SHEET 1 OF 1
mm		DWG NO	23802	