

NOTES:

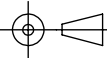
- 1. LASER CLASS:  
IIIb
- 2. OPERATING TEMPERATURE: 15 to 30 °C  
OPERATING VOLTAGE: 5V
- 3. OUTPUT POWER: 10mW
- 4. WAVELENGTH RANGE: 1550±10nm



**FOR INFORMATION ONLY:**  
**DO NOT MANUFACTURE**  
**PARTS TO THIS DRAWING**

SPECIFICATIONS SUBJECT TO CHANGE WITHOUT NOTICE  
DIMENSIONS ARE FOR REFERENCE ONLY

**EO**® Edmund Optics®

THIRD ANGLE PROJECTION 		TITLE	1550nm 10mW Pigtailed Laser Diode	
ALL DIMS IN	mm	DWG NO	23804	SHEET 1 OF 1