


Imaging Module profile M

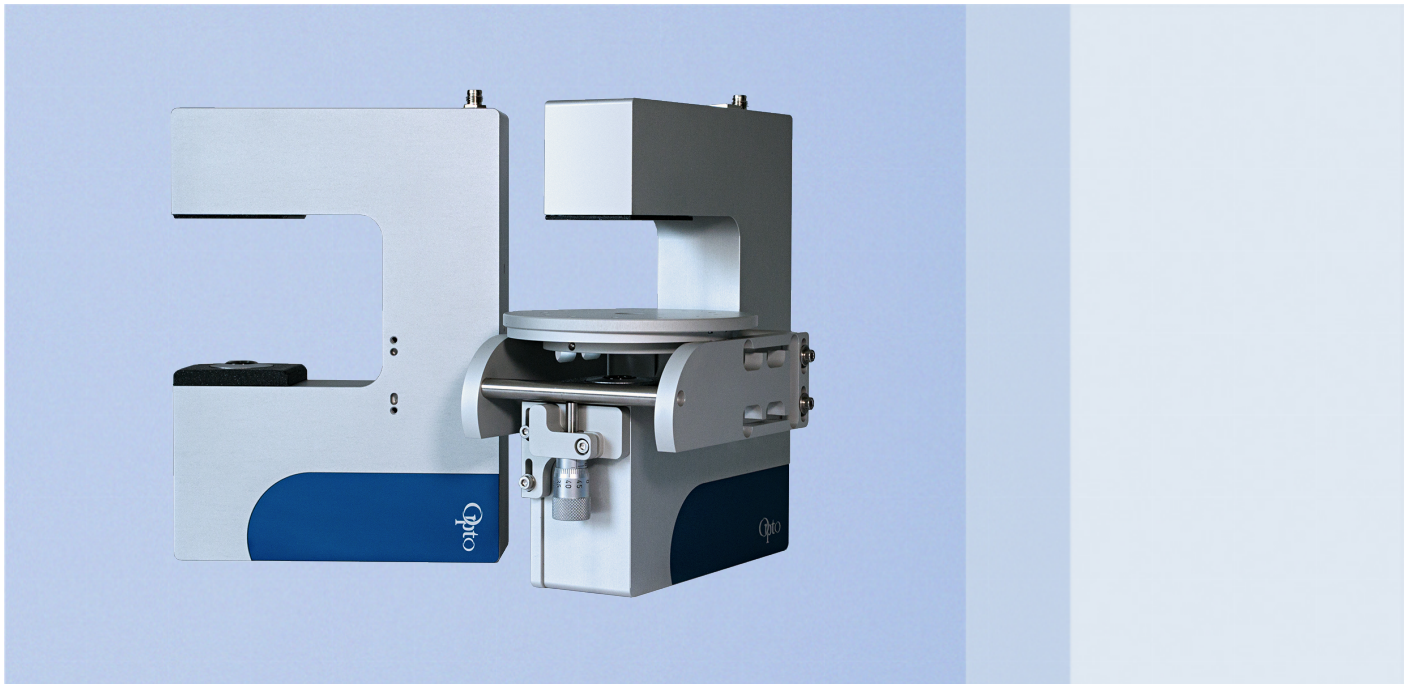

Item.Nr.	IP10-08x03MU5201
Typ	profile M
FoV [mm]	0.42 x 0.35
WD [mm]	3.60
Resolution [LP/mm]	810
Object space [μ /pixel]	3.45
Image	Mono
Sensor [MP]	5.01
Frames [fps]	36
Interface	USB3.1 Gen 1 Type C
Light	transm
Dimension [mm]	W140 x L193 x H40
Weight [g]	1400
Conformity	CE, RoHS, WEEE

- High performance imaging with simple plug-and-play functionality
- Optimized image, thanks to perfectly matched component selection
- Robust aluminum block design with various mounting options
- Includes OptoViewer application
- Software integration tools: C/C++ Opto-SDK

