

[All Products](#) / [Lasers](#) / [Laser Sources](#) / [Industrial and Pointing Lasers](#)

# Compact LDM Focusable Laser Diode Modules




- Circular and Elliptical Beam Options
- Bare Leads for Instrument Integration
- Focusable from 20mm to Infinity



## Common Specifications

General			
Drive Circuitry:		Fully shielded, reverse polarity protected	Note: Includes: Users Manual, Warning Label, and Focus Key
Type of Laser:		Diode	
Physical & Mechanical Properties			
Weight (g):		22.00	0.25
Optical Properties			
Wavelength Stability (nm/°C):			
Electrical			
Output Power Tolerance (%):			±5
Hardware & Interface Connectivity			
Electrical Leads/ Pin Connections:		red (+), black (-)	Output Type: Free Space

Technical Information

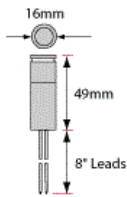

Products

Wavelength (nm)	Output Power (mW)	Beam Size at Nearest Focus (μm)	Beam Diameter (mm)	Beam Divergence (mrad)	Stock Number	Price	Buy
635.00	0.9 (Maximum)	<0.550	5.00	<0.5	<a href="#">#53-228</a>	₹15,750	10 to 12 days
670.00	0.9 (Maximum)	<0.550	5.00	<0.2	<a href="#">#38-920</a>	₹17,100	10 to 12 days
<a href="#">#72-817 New</a>							
<div><div></div><div>New</div><div>Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!</div></div>							
520.00	1 (Maximum)	<50	5 at Aperture	<0.5		₹19,800	10 to 12 days
<a href="#">#72-819 New</a>							
<div><div></div><div>New</div><div>Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!</div></div>							
780.00	1 (Maximum)	<50	5 at Aperture	<0.5		₹16,200	10 to 12 days

[#72-820 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

850.00

1  
(Maximum)

<50

5 at  
Aperture

<0.5

₹16,200

10 to 12 days

---

[#72-818 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

520.00

3  
(Maximum)

<50

5 at  
Aperture

<0.5

₹20,700

10 to 12 days

---

670.00

3  
(Maximum)

<0.525

4 x 2

<0.5

[#38-922](#)

₹18,000

10 to 12 days

---

635.00

4.5  
(Maximum)

<0.525

4 x 2

<0.5

[#53-756](#)

₹22,500

10 to 12 days

---

670.00

4.5  
(Maximum)

<0.525

4 x 2

<0.5

[#52-094](#)

₹22,500

10 to 12 days

---



Copyright 2023, Edmund Optics India Private Limited, #267, Greystone Building, Second Floor, 6th Cross Rd, Binnamangala, Stage 1, Indiranagar, Bengaluru, Karnataka, India 560038

Phone: 1-800-363-1992 :

[www.edmundoptics.com](http://www.edmundoptics.com)