


[All Products](#) / [Optics](#) / [Optical Mirrors](#) / [Flat Mirrors](#) / [Precision Polished Metal Coatings](#)

TECHSPEC®

Precision Optical Flat Mirrors

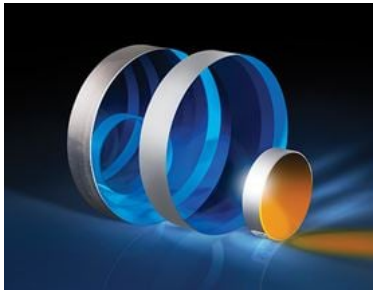

- Fused Silica and ZERODUR® Substrates
- $\lambda/10$ and $\lambda/20$ Surface Flatness
- Variety of Coating Options Offered

Common Specifications

General	
Note: Flatness is specified as Peak to Valley	
Physical & Mechanical Properties	
Back Surface: Commercial Polish	
Optical Properties	
Surface Quality: 60-40	Coating Type: Metal

Technical Information

Products

Surface Flatness (P-V)	Dia. (mm)	Substrate	Coating Specification	Coating	Thickness (mm)	Stock Number	Price	Buy
λ/10	12.70	Fused Silica	R _{avg} >85% @ 400 - 700nm R _{avg} >90% @ 400 - 2000nm	Protected Aluminum (400-2000nm)	3.20	#43-319-522	₹7,551 Volume Pricing	1 In Stock
λ/20	12.70	Fused Silica	R _{avg} >85% @ 400 - 700nm R _{avg} >90% @ 400 - 2000nm	Protected Aluminum (400-2000nm)	3.20	#43-400-522	₹10,276 Volume Pricing	4 In Stock
λ/10	12.70	ZERODUR®	R _{avg} >85% @ 400 - 700nm R _{avg} >90% @ 400 - 2000nm	Protected Aluminum (400-2000nm)	3.20	#43-327-522	₹8,252 Volume Pricing	1 In Stock
λ/20	12.70	ZERODUR®	R _{avg} >85% @ 400 - 700nm R _{avg} >90% @ 400 - 2000nm	Protected Aluminum (400-2000nm)	3.20	#43-404-522	₹11,755 Volume Pricing	4 In Stock
λ/10	12.70	Fused Silica	R _{avg} >95% @ 450 - 650nm	Enhanced Aluminum (450-650nm)	3.20	#43-319-533	₹7,941 Volume Pricing	5 In Stock
λ/20	12.70	Fused Silica	R _{avg} >95% @ 450 - 650nm	Enhanced Aluminum (450-650nm)	3.20	#43-400-533	₹10,665 Volume Pricing	20+ In Stock
λ/10	12.70	ZERODUR®	R _{avg} >95% @ 450 - 650nm	Enhanced Aluminum (450-650nm)	3.20	#43-327-533	₹8,641 Volume Pricing	1 In Stock
λ/20	12.70	ZERODUR®	R _{avg} >95% @ 450 - 650nm	Enhanced Aluminum (450-650nm)	3.20	#43-404-533	₹12,145 Volume Pricing	2 In Stock
λ/10	12.70	Fused Silica	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	Protected Gold (700-10000nm)	3.20	#43-319-566	₹9,108 Volume Pricing	20+ In Stock
λ/20	12.70	Fused Silica	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	Protected Gold (700-10000nm)	3.20	#43-400-566	₹11,833 Volume Pricing	Contact Us
λ/10	12.70	ZERODUR®	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	Protected Gold (700-10000nm)	3.20	#43-327-566	₹9,809 Volume Pricing	Contact Us

$\lambda/20$	12.70	ZERODUR®	$R_{avg} > 96\% @ 700 - 2000nm$ $R_{avg} > 96\% @ 2000 - 10,000nm$	Protected Gold (700-10000nm)	3.20	#43-404-566	₹13,312 Volume Pricing	2 In Stock
$\lambda/10$	12.70	Fused Silica	$R_{avg} > 98\% @ 450 - 2000nm$ $R_{avg} > 98\% @ 2000 - 10,000nm$	Protected Silver (450-10000nm)	3.20	#43-319-577	₹8,719 Volume Pricing	20+ In Stock
$\lambda/20$	12.70	Fused Silica	$R_{avg} > 98\% @ 450 - 2000nm$ $R_{avg} > 98\% @ 2000 - 10,000nm$	Protected Silver (450-10000nm)	3.20	#43-400-577	₹11,444 Volume Pricing	5 In Stock
$\lambda/10$	12.70	ZERODUR®	$R_{avg} > 98\% @ 450 - 2000nm$ $R_{avg} > 98\% @ 2000 - 10,000nm$	Protected Silver (450-10000nm)	3.20	#43-327-577	₹9,420 Volume Pricing	Contact Us
$\lambda/20$	12.70	ZERODUR®	$R_{avg} > 98\% @ 450 - 2000nm$ $R_{avg} > 98\% @ 2000 - 10,000nm$	Protected Silver (450-10000nm)	3.20	#43-404-577	₹12,923 Volume Pricing	2 In Stock
$\lambda/10$	25.40	Fused Silica	$R_{avg} > 85\% @ 400 - 700nm$ $R_{avg} > 90\% @ 400 - 2000nm$	Protected Aluminum (400-2000nm)	12.70	#01-913-522	₹11,133 Volume Pricing	5 In Stock
$\lambda/20$	25.40	Fused Silica	$R_{avg} > 85\% @ 400 - 700nm$ $R_{avg} > 90\% @ 400 - 2000nm$	Protected Aluminum (400-2000nm)	12.70	#43-408-522	₹16,115 Volume Pricing	8 In Stock
$\lambda/10$	25.40	ZERODUR®	$R_{avg} > 85\% @ 400 - 700nm$ $R_{avg} > 90\% @ 400 - 2000nm$	Protected Aluminum (400-2000nm)	12.70	#32-195-522	₹12,534 Volume Pricing	3 In Stock
$\lambda/20$	25.40	ZERODUR®	$R_{avg} > 85\% @ 400 - 700nm$ $R_{avg} > 90\% @ 400 - 2000nm$	Protected Aluminum (400-2000nm)	12.70	#43-412-522	₹16,738 Volume Pricing	Contact Us
$\lambda/10$	25.40	Fused Silica	$R_{avg} > 95\% @ 450 - 650nm$	Enhanced Aluminum (450-650nm)	12.70	#01-913-533	₹11,522 Volume Pricing	3 In Stock
$\lambda/20$	25.40	Fused Silica	$R_{avg} > 95\% @ 450 - 650nm$	Enhanced Aluminum (450-650nm)	12.70	#43-408-533	₹16,504 Volume Pricing	20+ In Stock
$\lambda/10$	25.40	ZERODUR®	$R_{avg} > 95\% @ 450 - 650nm$	Enhanced Aluminum (450-650nm)	12.70	#32-195-533	₹12,923 Volume Pricing	2 In Stock

$\lambda/20$	25.40	ZERODUR®	$R_{avg} > 95\% @ 450 - 650nm$	Enhanced Aluminum (450-650nm)	12.70	#43-412-533	₹17,127 Volume Pricing	1 In Stock
$\lambda/10$	25.40	Fused Silica	$R_{avg} > 96\% @ 700 - 2000nm$ $R_{avg} > 96\% @ 2000 - 10,000nm$	Protected Gold (700-10000nm)	12.70	#01-913-566	₹13,079 Volume Pricing	Contact Us
$\lambda/20$	25.40	Fused Silica	$R_{avg} > 96\% @ 700 - 2000nm$ $R_{avg} > 96\% @ 2000 - 10,000nm$	Protected Gold (700-10000nm)	12.70	#43-408-566	₹18,061 Volume Pricing	1 In Stock
$\lambda/10$	25.40	ZERODUR®	$R_{avg} > 96\% @ 700 - 2000nm$ $R_{avg} > 96\% @ 2000 - 10,000nm$	Protected Gold (700-10000nm)	12.70	#32-195-566	₹14,480 Volume Pricing	6 In Stock
$\lambda/20$	25.40	ZERODUR®	$R_{avg} > 96\% @ 700 - 2000nm$ $R_{avg} > 96\% @ 2000 - 10,000nm$	Protected Gold (700-10000nm)	12.70	#43-412-566	₹18,684 Volume Pricing	6 In Stock
$\lambda/10$	25.40	Fused Silica	$R_{avg} > 98\% @ 450 - 2000nm$ $R_{avg} > 98\% @ 2000 - 10,000nm$	Protected Silver (450-10000nm)	12.70	#01-913-577	₹14,636 Volume Pricing	4 In Stock
$\lambda/20$	25.40	Fused Silica	$R_{avg} > 98\% @ 450 - 2000nm$ $R_{avg} > 98\% @ 2000 - 10,000nm$	Protected Silver (450-10000nm)	12.70	#43-408-577	₹19,618 Volume Pricing	Contact Us
$\lambda/10$	25.40	ZERODUR®	$R_{avg} > 98\% @ 450 - 2000nm$ $R_{avg} > 98\% @ 2000 - 10,000nm$	Protected Silver (450-10000nm)	12.70	#32-195-577	₹16,037 Volume Pricing	6 In Stock
$\lambda/20$	25.40	ZERODUR®	$R_{avg} > 98\% @ 450 - 2000nm$ $R_{avg} > 98\% @ 2000 - 10,000nm$	Protected Silver (450-10000nm)	12.70	#43-412-577	₹20,241 Volume Pricing	4 In Stock
$\lambda/10$	50.80	Fused Silica	$R_{avg} > 85\% @ 400 - 700nm$ $R_{avg} > 90\% @ 400 - 2000nm$	Protected Aluminum (400-2000nm)	12.70	#01-914-522	₹18,606 Volume Pricing	3 In Stock
$\lambda/20$	50.80	Fused Silica	$R_{avg} > 85\% @ 400 - 700nm$ $R_{avg} > 90\% @ 400 - 2000nm$	Protected Aluminum (400-2000nm)	12.70	#43-416-522	₹24,289 Volume Pricing	6 In Stock

$\lambda/10$	50.80	ZERODUR®	$R_{avg} > 85\% @ 400 - 700nm$ $R_{avg} > 90\% @ 400 - 2000nm$	Protected Aluminum (400-2000nm)	12.70	#32-199-522	₹20,552 Volume Pricing	Contact Us
$\lambda/20$	50.80	ZERODUR®	$R_{avg} > 85\% @ 400 - 700nm$ $R_{avg} > 90\% @ 400 - 2000nm$	Protected Aluminum (400-2000nm)	12.70	#43-420-522	₹28,026 Volume Pricing	4 In Stock
$\lambda/10$	50.80	Fused Silica	$R_{avg} > 95\% @ 450 - 650nm$	Enhanced Aluminum (450-650nm)	12.70	#01-914-533	₹20,552 Volume Pricing	4 In Stock
$\lambda/20$	50.80	Fused Silica	$R_{avg} > 95\% @ 450 - 650nm$	Enhanced Aluminum (450-650nm)	12.70	#43-416-533	₹26,235 Volume Pricing	3 In Stock
$\lambda/10$	50.80	ZERODUR®	$R_{avg} > 95\% @ 450 - 650nm$	Enhanced Aluminum (450-650nm)	12.70	#32-199-533	₹22,499 Volume Pricing	1 In Stock
$\lambda/20$	50.80	ZERODUR®	$R_{avg} > 95\% @ 450 - 650nm$	Enhanced Aluminum (450-650nm)	12.70	#43-420-533	₹29,972 Volume Pricing	6 In Stock
$\lambda/10$	50.80	Fused Silica	$R_{avg} > 96\% @ 700 - 2000nm$ $R_{avg} > 96\% @ 2000 - 10,000nm$	Protected Gold (700-10000nm)	12.70	#01-914-566	₹25,223 Volume Pricing	4 In Stock
$\lambda/20$	50.80	Fused Silica	$R_{avg} > 96\% @ 700 - 2000nm$ $R_{avg} > 96\% @ 2000 - 10,000nm$	Protected Gold (700-10000nm)	12.70	#43-416-566	₹30,906 Volume Pricing	10 In Stock
$\lambda/10$	50.80	ZERODUR®	$R_{avg} > 96\% @ 700 - 2000nm$ $R_{avg} > 96\% @ 2000 - 10,000nm$	Protected Gold (700-10000nm)	12.70	#32-199-566	₹27,170 Volume Pricing	1 In Stock
$\lambda/20$	50.80	ZERODUR®	$R_{avg} > 96\% @ 700 - 2000nm$ $R_{avg} > 96\% @ 2000 - 10,000nm$	Protected Gold (700-10000nm)	12.70	#43-420-566	₹34,643 Volume Pricing	3 In Stock
$\lambda/10$	50.80	Fused Silica	$R_{avg} > 98\% @ 450 - 2000nm$ $R_{avg} > 98\% @ 2000 - 10,000nm$	Protected Silver (450-10000nm)	12.70	#01-914-577	₹24,445 Volume Pricing	Contact Us
$\lambda/20$	50.80	Fused Silica	$R_{avg} > 98\% @ 450 - 2000nm$ $R_{avg} > 98\% @ 2000 - 10,000nm$	Protected Silver (450-10000nm)	12.70	#43-416-577	₹30,128 Volume Pricing	3 In Stock

$\lambda/10$	50.80	ZERODUR®	$R_{avg} > 98\% @$ 450 - 2000nm $R_{avg} > 98\% @$ 2000 - 10,000nm	Protected Silver (450-10000nm)	12.70	#32-199-577	₹26,391 Volume Pricing	2 In Stock
$\lambda/20$	50.80	ZERODUR®	$R_{avg} > 98\% @$ 450 - 2000nm $R_{avg} > 98\% @$ 2000 - 10,000nm	Protected Silver (450-10000nm)	12.70	#43-420-577	₹33,865 Volume Pricing	9 In Stock
$\lambda/10$	76.20	Fused Silica	$R_{avg} > 85\% @$ 400 - 700nm $R_{avg} > 90\% @$ 400 - 2000nm	Protected Aluminum (400-2000nm)	19.10	#01-915-522	₹39,704 Volume Pricing	Contact Us
$\lambda/20$	76.20	Fused Silica	$R_{avg} > 85\% @$ 400 - 700nm $R_{avg} > 90\% @$ 400 - 2000nm	Protected Aluminum (400-2000nm)	19.10	#47-573-522	₹44,764 Volume Pricing	5 In Stock
$\lambda/10$	76.20	ZERODUR®	$R_{avg} > 85\% @$ 400 - 700nm $R_{avg} > 90\% @$ 400 - 2000nm	Protected Aluminum (400-2000nm)	19.10	#31-391-522	₹49,435 Volume Pricing	1 In Stock
$\lambda/20$	76.20	ZERODUR®	$R_{avg} > 85\% @$ 400 - 700nm $R_{avg} > 90\% @$ 400 - 2000nm	Protected Aluminum (400-2000nm)	19.10	#48-117-522	₹68,119 Volume Pricing	1 In Stock
$\lambda/10$	76.20	Fused Silica	$R_{avg} > 95\% @$ 450 - 650nm	Enhanced Aluminum (450-650nm)	19.10	#01-915-533	₹43,596 Volume Pricing	2 In Stock
$\lambda/20$	76.20	Fused Silica	$R_{avg} > 95\% @$ 450 - 650nm	Enhanced Aluminum (450-650nm)	19.10	#47-573-533	₹48,656 Volume Pricing	3 In Stock
$\lambda/10$	76.20	ZERODUR®	$R_{avg} > 95\% @$ 450 - 650nm	Enhanced Aluminum (450-650nm)	19.10	#31-391-533	₹53,327 Volume Pricing	1 In Stock
$\lambda/20$	76.20	ZERODUR®	$R_{avg} > 95\% @$ 450 - 650nm	Enhanced Aluminum (450-650nm)	19.10	#48-117-533	₹72,011 Volume Pricing	1 In Stock
$\lambda/10$	76.20	Fused Silica	$R_{avg} > 96\% @$ 700 - 2000nm $R_{avg} > 96\% @$ 2000 - 10,000nm	Protected Gold (700-10000nm)	19.10	#01-915-566	₹45,932 Volume Pricing	Contact Us
$\lambda/20$	76.20	Fused Silica	$R_{avg} > 96\% @$ 700 - 2000nm $R_{avg} > 96\% @$ 2000 - 10,000nm	Protected Gold (700-10000nm)	19.10	#47-573-566	₹50,992 Volume Pricing	Contact Us

$\lambda/10$	76.20	ZERODUR®	$R_{avg} > 96\% @ 700 - 2000nm$ $R_{avg} > 96\% @ 2000 - 10,000nm$	Protected Gold (700-10000nm)	19.10	#31-391-566	₹55,663 Volume Pricing	4 In Stock
$\lambda/20$	76.20	ZERODUR®	$R_{avg} > 96\% @ 700 - 2000nm$ $R_{avg} > 96\% @ 2000 - 10,000nm$	Protected Gold (700-10000nm)	19.10	#48-117-566	₹74,347 Volume Pricing	4 In Stock
$\lambda/10$	76.20	Fused Silica	$R_{avg} > 98\% @ 450 - 2000nm$ $R_{avg} > 98\% @ 2000 - 10,000nm$	Protected Silver (450-10000nm)	19.10	#01-915-577	₹45,153 Volume Pricing	8 In Stock
$\lambda/20$	76.20	Fused Silica	$R_{avg} > 98\% @ 450 - 2000nm$ $R_{avg} > 98\% @ 2000 - 10,000nm$	Protected Silver (450-10000nm)	19.10	#47-573-577	₹50,213 Volume Pricing	10 In Stock
$\lambda/10$	76.20	ZERODUR®	$R_{avg} > 98\% @ 450 - 2000nm$ $R_{avg} > 98\% @ 2000 - 10,000nm$	Protected Silver (450-10000nm)	19.10	#31-391-577	₹54,884 Volume Pricing	1 In Stock
$\lambda/20$	76.20	ZERODUR®	$R_{avg} > 98\% @ 450 - 2000nm$ $R_{avg} > 98\% @ 2000 - 10,000nm$	Protected Silver (450-10000nm)	19.10	#48-117-577	₹73,568 Volume Pricing	10 In Stock
$\lambda/10$	101.60	Fused Silica	$R_{avg} > 85\% @ 400 - 700nm$ $R_{avg} > 90\% @ 400 - 2000nm$	Protected Aluminum (400-2000nm)	19.10	#01-611-522	₹71,233 Volume Pricing	1 In Stock
$\lambda/20$	101.60	Fused Silica	$R_{avg} > 85\% @ 400 - 700nm$ $R_{avg} > 90\% @ 400 - 2000nm$	Protected Aluminum (400-2000nm)	19.10	#47-574-522	₹77,072 Volume Pricing	8 In Stock
$\lambda/10$	101.60	ZERODUR®	$R_{avg} > 85\% @ 400 - 700nm$ $R_{avg} > 90\% @ 400 - 2000nm$	Protected Aluminum (400-2000nm)	19.10	#31-392-522	₹73,179 Volume Pricing	Contact Us
$\lambda/20$	101.60	ZERODUR®	$R_{avg} > 85\% @ 400 - 700nm$ $R_{avg} > 90\% @ 400 - 2000nm$	Protected Aluminum (400-2000nm)	19.10	#48-118-522	₹81,353 Volume Pricing	5 In Stock
$\lambda/10$	101.60	Fused Silica	$R_{avg} > 95\% @ 450 - 650nm$	Enhanced Aluminum (450-650nm)	19.10	#01-611-533	₹75,125 Volume Pricing	5 In Stock
$\lambda/20$	101.60	Fused Silica	$R_{avg} > 95\% @ 450 - 650nm$	Enhanced Aluminum (450-650nm)	19.10	#47-574-533	₹80,964 Volume Pricing	2 In Stock

$\lambda/10$	101.60	ZERODUR®	$R_{avg} > 95\% @ 450 - 650nm$	Enhanced Aluminum (450-650nm)	19.10	#31-392-533	₹77,072 Volume Pricing	1 In Stock
$\lambda/20$	101.60	ZERODUR®	$R_{avg} > 95\% @ 450 - 650nm$	Enhanced Aluminum (450-650nm)	19.10	#48-118-533	₹85,246 Volume Pricing	1 In Stock
$\lambda/10$	101.60	Fused Silica	$R_{avg} > 96\% @ 700 - 2000nm$ $R_{avg} > 96\% @ 2000 - 10,000nm$	Protected Gold (700-10000nm)	19.10	#01-611-566	₹78,239 Volume Pricing	5 In Stock
$\lambda/20$	101.60	Fused Silica	$R_{avg} > 96\% @ 700 - 2000nm$ $R_{avg} > 96\% @ 2000 - 10,000nm$	Protected Gold (700-10000nm)	19.10	#47-574-566	₹84,078 Volume Pricing	3 In Stock
$\lambda/10$	101.60	ZERODUR®	$R_{avg} > 96\% @ 700 - 2000nm$ $R_{avg} > 96\% @ 2000 - 10,000nm$	Protected Gold (700-10000nm)	19.10	#31-392-566	₹80,186 Volume Pricing	4 In Stock
$\lambda/20$	101.60	ZERODUR®	$R_{avg} > 96\% @ 700 - 2000nm$ $R_{avg} > 96\% @ 2000 - 10,000nm$	Protected Gold (700-10000nm)	19.10	#48-118-566	₹88,360 Volume Pricing	20+ In Stock
$\lambda/10$	101.60	Fused Silica	$R_{avg} > 98\% @ 450 - 2000nm$ $R_{avg} > 98\% @ 2000 - 10,000nm$	Protected Silver (450-10000nm)	19.10	#01-611-577	₹77,072 Volume Pricing	4 In Stock
$\lambda/20$	101.60	Fused Silica	$R_{avg} > 98\% @ 450 - 2000nm$ $R_{avg} > 98\% @ 2000 - 10,000nm$	Protected Silver (450-10000nm)	19.10	#47-574-577	₹82,910 Volume Pricing	4 In Stock
$\lambda/10$	101.60	ZERODUR®	$R_{avg} > 98\% @ 450 - 2000nm$ $R_{avg} > 98\% @ 2000 - 10,000nm$	Protected Silver (450-10000nm)	19.10	#31-392-577	₹79,018 Volume Pricing	2 In Stock
$\lambda/20$	101.60	ZERODUR®	$R_{avg} > 98\% @ 450 - 2000nm$ $R_{avg} > 98\% @ 2000 - 10,000nm$	Protected Silver (450-10000nm)	19.10	#48-118-577	₹87,192 Volume Pricing	Contact Us

[#71-130-522 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

$\lambda/10$	127.00	Fused Silica (Corning 7980)	$R_{avg} > 85\%$ @ 400 - 700nm $R_{avg} > 90\%$ @ 400 - 2000nm	Protected Aluminum (400-2000nm)	25.40	₹1,19,500 Volume Pricing	1 In Stock
--------------	--------	--------------------------------	---	------------------------------------	-------	---	------------

[#71-247-522 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

$\lambda/20$	355.60	ZERODUR®	$R_{avg} > 85\%$ @ 400 - 700nm $R_{avg} > 90\%$ @ 400 - 2000nm	Protected Aluminum (400-2000nm)	88.90	₹10,37,903	Contact Us
--------------	--------	----------	---	------------------------------------	-------	------------	------------

[#71-130-533 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

$\lambda/10$ 127.00 Fused Silica (Corning 7980) $R_{avg} > 95\%$ @ 450 - 650nm Enhanced Aluminum (450-650nm) 25.40

₹1,26,117
[Volume Pricing](#)

1 In Stock

[#71-130-566 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

$\lambda/10$ 127.00 Fused Silica (Corning 7980) $R_{avg} > 96\%$ @ 700 - 2000nm $R_{avg} > 96\%$ @ 2000 - 10,000nm Protected Gold (700-10000nm) 25.40

₹1,30,399
[Volume Pricing](#)

1 In Stock

[#71-130-577 New](#)



New

$\lambda/10$	127.00	Fused Silica (Corning 7980)	$R_{avg} > 98\%$ @ 450 - 2000nm $R_{avg} > 98\%$ @ 2000 - 10,000nm	Protected Silver (450- 10000nm)	25.40	Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!	₹1,28,453 Volume Pricing	1 In Stock
--------------	--------	-----------------------------------	--	--	-------	--	---	------------

[#71-131-522 New](#)



New

$\lambda/20$	127.00	Fused Silica (Corning 7980)	$R_{avg} > 85\%$ @ 400 - 700nm $R_{avg} > 90\%$ @ 400 - 2000nm	Protected Aluminum (400- 2000nm)	25.40	Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!	₹1,58,425 Volume Pricing	1 In Stock
--------------	--------	-----------------------------------	---	---	-------	--	---	------------

[#71-131-533 New](#)



New

$\lambda/20$	127.00	Fused Silica (Corning 7980)	$R_{avg} > 95\%$ @ 450 - 650nm	Enhanced Aluminum (450- 650nm)	25.40	Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!	₹1,65,042 Volume Pricing	1 In Stock
--------------	--------	-----------------------------------	-----------------------------------	---	-------	--	---	------------

[#71-247-533 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

$\lambda/20$	355.60	ZERODUR®	$R_{avg} > 95\%$ @ 450 - 650nm	Enhanced Aluminum (450-650nm)	88.90	₹10,41,570	Contact Us
--------------	--------	----------	--------------------------------	-------------------------------	-------	------------	------------

[#71-131-566 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

$\lambda/20$	127.00	Fused Silica (Corning 7980)	$R_{avg} > 96\%$ @ 700 - 2000nm $R_{avg} > 96\%$ @ 2000 - 10,000nm	Protected Gold (700-10000nm)	25.40	₹1,69,324 Volume Pricing	1 In Stock
--------------	--------	-----------------------------	---	------------------------------	-------	---	------------

[#71-247-566 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

$\lambda/20$	355.60	ZERODUR®	$R_{avg} > 96\%$ @ 700 - 2000nm $R_{avg} > 96\%$ @ 2000 - 10,000nm	Protected Gold (700-10000nm)	88.90	₹11,00,250	Contact Us
--------------	--------	----------	---	------------------------------	-------	------------	------------

[#71-131-577 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

$\lambda/20$	127.00	Fused Silica (Corning 7980)	$R_{avg} > 98\%$ @ 450 - 2000nm $R_{avg} > 98\%$ @ 2000 - 10,000nm	Protected Silver (450-10000nm)	25.40		₹1,67,378 Volume Pricing	Contact Us
--------------	--------	-----------------------------	---	--------------------------------	-------	--	---	------------

[#71-247-577 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

$\lambda/20$	355.60	ZERODUR®	$R_{avg} > 98\%$ @ 450 - 2000nm $R_{avg} > 98\%$ @ 2000 - 10,000nm	Protected Silver (450-10000nm)	88.90		₹10,78,245	Contact Us
--------------	--------	----------	---	--------------------------------	-------	--	------------	------------

$\lambda/10$	152.40	Fused Silica	$R_{avg} > 85\%$ @ 400 - 700nm $R_{avg} > 90\%$ @ 400 - 2000nm	Protected Aluminum (400-2000nm)	25.40	#01-612-522	₹1,55,311 Volume Pricing	2 In Stock
--------------	--------	------------------------------	---	---------------------------------	-------	-----------------------------	---	------------

$\lambda/20$	152.40	Fused Silica	$R_{avg} > 85\%$ @ 400 - 700nm $R_{avg} > 90\%$ @ 400 - 2000nm	Protected Aluminum (400-2000nm)	25.40	#47-575-522	₹2,19,926 Volume Pricing	4 In Stock
--------------	--------	------------------------------	---	---------------------------------	-------	-----------------------------	---	------------

$\lambda/10$	152.40	ZERODUR®	$R_{avg} > 85\%$ @ 400 - 700nm $R_{avg} > 90\%$ @ 400 - 2000nm	Protected Aluminum (400-2000nm)	25.40	#31-393-522	₹1,66,210 Volume Pricing	2 In Stock
--------------	--------	--------------------------	---	---------------------------------	-------	-----------------------------	---	------------

$\lambda/20$	152.40	ZERODUR®	$R_{avg} > 85\%$ @ 400 - 700nm $R_{avg} > 90\%$ @ 400 - 2000nm	Protected Aluminum (400-2000nm)	25.40	#48-119-522	₹2,46,785 Volume Pricing	2 In Stock
--------------	--------	--------------------------	---	---------------------------------	-------	-----------------------------	---	------------

$\lambda/10$	152.40	Fused Silica	$R_{avg} > 95\% @ 450 - 650nm$	Enhanced Aluminum (450-650nm)	25.40	#01-612-533	$\text{₹}1,59,203$ Volume Pricing	6 In Stock
$\lambda/20$	152.40	Fused Silica	$R_{avg} > 95\% @ 450 - 650nm$	Enhanced Aluminum (450-650nm)	25.40	#47-575-533	$\text{₹}2,23,819$ Volume Pricing	5 In Stock
$\lambda/10$	152.40	ZERODUR®	$R_{avg} > 95\% @ 450 - 650nm$	Enhanced Aluminum (450-650nm)	25.40	#31-393-533	$\text{₹}1,70,102$ Volume Pricing	Contact Us
$\lambda/20$	152.40	ZERODUR®	$R_{avg} > 95\% @ 450 - 650nm$	Enhanced Aluminum (450-650nm)	25.40	#48-119-533	$\text{₹}2,50,677$ Volume Pricing	1 In Stock
$\lambda/10$	152.40	Fused Silica	$R_{avg} > 96\% @ 700 - 2000nm$ $R_{avg} > 96\% @ 2000 - 10,000nm$	Protected Gold (700-10000nm)	25.40	#01-612-566	$\text{₹}1,68,935$ Volume Pricing	5 In Stock
$\lambda/20$	152.40	Fused Silica	$R_{avg} > 96\% @ 700 - 2000nm$ $R_{avg} > 96\% @ 2000 - 10,000nm$	Protected Gold (700-10000nm)	25.40	#47-575-566	$\text{₹}2,33,550$ Volume Pricing	3 In Stock
$\lambda/10$	152.40	ZERODUR®	$R_{avg} > 96\% @ 700 - 2000nm$ $R_{avg} > 96\% @ 2000 - 10,000nm$	Protected Gold (700-10000nm)	25.40	#31-393-566	$\text{₹}1,79,834$ Volume Pricing	1 In Stock
$\lambda/20$	152.40	ZERODUR®	$R_{avg} > 96\% @ 700 - 2000nm$ $R_{avg} > 96\% @ 2000 - 10,000nm$	Protected Gold (700-10000nm)	25.40	#48-119-566	$\text{₹}2,60,408$ Volume Pricing	2 In Stock
$\lambda/10$	152.40	Fused Silica	$R_{avg} > 98\% @ 450 - 2000nm$ $R_{avg} > 98\% @ 2000 - 10,000nm$	Protected Silver (450-10000nm)	25.40	#01-612-577	$\text{₹}1,66,988$ Volume Pricing	1 In Stock
$\lambda/20$	152.40	Fused Silica	$R_{avg} > 98\% @ 450 - 2000nm$ $R_{avg} > 98\% @ 2000 - 10,000nm$	Protected Silver (450-10000nm)	25.40	#47-575-577	$\text{₹}2,31,604$ Volume Pricing	Contact Us
$\lambda/10$	152.40	ZERODUR®	$R_{avg} > 98\% @ 450 - 2000nm$ $R_{avg} > 98\% @ 2000 - 10,000nm$	Protected Silver (450-10000nm)	25.40	#31-393-577	$\text{₹}1,77,887$ Volume Pricing	4 In Stock

$\lambda/20$	152.40	ZERODUR®	$R_{avg} > 98\% @ 450 - 2000nm$ $R_{avg} > 98\% @ 2000 - 10,000nm$	Protected Silver (450-10000nm)	25.40	#48-119-577	₹2,58,462 Volume Pricing	3 In Stock
$\lambda/10$	203.20	Fused Silica	$R_{avg} > 85\% @ 400 - 700nm$ $R_{avg} > 90\% @ 400 - 2000nm$	Protected Aluminum (400-2000nm)	38.10	#31-390-522	₹3,17,239 Volume Pricing	2 In Stock
$\lambda/20$	203.20	Fused Silica	$R_{avg} > 85\% @ 400 - 700nm$ $R_{avg} > 90\% @ 400 - 2000nm$	Protected Aluminum (400-2000nm)	38.10	#49-048-522	₹3,90,418 Volume Pricing	Contact Us
$\lambda/10$	203.20	ZERODUR®	$R_{avg} > 85\% @ 400 - 700nm$ $R_{avg} > 90\% @ 400 - 2000nm$	Protected Aluminum (400-2000nm)	38.10	#31-394-522	₹3,35,923 Volume Pricing	1 In Stock
$\lambda/20$	203.20	ZERODUR®	$R_{avg} > 85\% @ 400 - 700nm$ $R_{avg} > 90\% @ 400 - 2000nm$	Protected Aluminum (400-2000nm)	38.10	#49-049-522	₹4,01,706 Volume Pricing	Contact Us
$\lambda/10$	203.20	Fused Silica	$R_{avg} > 95\% @ 450 - 650nm$	Enhanced Aluminum (450-650nm)	38.10	#31-390-533	₹3,23,078 Volume Pricing	4 In Stock
$\lambda/20$	203.20	Fused Silica	$R_{avg} > 95\% @ 450 - 650nm$	Enhanced Aluminum (450-650nm)	38.10	#49-048-533	₹3,96,257 Volume Pricing	1 In Stock
$\lambda/10$	203.20	ZERODUR®	$R_{avg} > 95\% @ 450 - 650nm$	Enhanced Aluminum (450-650nm)	38.10	#31-394-533	₹3,41,762 Volume Pricing	1 In Stock
$\lambda/20$	203.20	ZERODUR®	$R_{avg} > 95\% @ 450 - 650nm$	Enhanced Aluminum (450-650nm)	38.10	#49-049-533	₹4,07,545 Volume Pricing	3 In Stock
$\lambda/10$	203.20	Fused Silica	$R_{avg} > 96\% @ 700 - 2000nm$ $R_{avg} > 96\% @ 2000 - 10,000nm$	Protected Gold (700-10000nm)	38.10	#31-390-566	₹3,32,809 Volume Pricing	1 In Stock
$\lambda/20$	203.20	Fused Silica	$R_{avg} > 96\% @ 700 - 2000nm$ $R_{avg} > 96\% @ 2000 - 10,000nm$	Protected Gold (700-10000nm)	38.10	#49-048-566	₹4,05,988 Volume Pricing	4 In Stock
$\lambda/10$	203.20	ZERODUR®	$R_{avg} > 96\% @ 700 - 2000nm$ $R_{avg} > 96\% @ 2000 - 10,000nm$	Protected Gold (700-10000nm)	38.10	#31-394-566	₹3,51,493 Volume Pricing	2 In Stock

λ/20	203.20	ZERODUR®	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	Protected Gold (700- 10000nm)	38.10	#49-049-566	₹4,17,276 Volume Pricing	5 In Stock
λ/10	203.20	Fused Silica	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	Protected Silver (450- 10000nm)	38.10	#31-390-577	₹3,30,863 Volume Pricing	2 In Stock
λ/20	203.20	Fused Silica	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	Protected Silver (450- 10000nm)	38.10	#49-048-577	₹4,04,042 Volume Pricing	Contact Us
λ/10	203.20	ZERODUR®	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	Protected Silver (450- 10000nm)	38.10	#31-394-577	₹3,49,547 Volume Pricing	1 In Stock
λ/20	203.20	ZERODUR®	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	Protected Silver (450- 10000nm)	38.10	#49-049-577	₹4,15,330 Volume Pricing	Contact Us
λ/10	254.00	Fused Silica	R _{avg} >85% @ 400 - 700nm R _{avg} >90% @ 400 - 2000nm	Protected Aluminum (400- 2000nm)	38.10	#46-715-522	₹4,82,670 Volume Pricing	1 In Stock
λ/20	254.00	Fused Silica	R _{avg} >85% @ 400 - 700nm R _{avg} >90% @ 400 - 2000nm	Protected Aluminum (400- 2000nm)	38.10	#65-879-522	₹7,10,771 Volume Pricing	Contact Us
λ/10	254.00	Fused Silica	R _{avg} >95% @ 450 - 650nm	Enhanced Aluminum (450- 650nm)	38.10	#46-715-533	₹4,90,455 Volume Pricing	4 In Stock
λ/20	254.00	Fused Silica	R _{avg} >95% @ 450 - 650nm	Enhanced Aluminum (450- 650nm)	38.10	#65-879-533	₹7,18,556 Volume Pricing	Contact Us
λ/10	254.00	Fused Silica	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	Protected Gold (700- 10000nm)	38.10	#46-715-566	₹5,00,186 Volume Pricing	1 In Stock
λ/20	254.00	Fused Silica	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	Protected Gold (700- 10000nm)	38.10	#65-879-566	₹7,28,287 Volume Pricing	2 In Stock

$\lambda/10$	254.00	Fused Silica	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	Protected Silver (450- 10000nm)	38.10	#46-715-577	₹4,98,240 Volume Pricing	3 In Stock
$\lambda/20$	254.00	Fused Silica	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	Protected Silver (450- 10000nm)	38.10	#65-879-577	₹7,26,341 Volume Pricing	4 In Stock
#71-108-522 New								
								
						New		
$\lambda/10$	254.00	ZERODUR®	R _{avg} >85% @ 400 - 700nm R _{avg} >90% @ 400 - 2000nm	Protected Aluminum (400- 2000nm)	38.10	Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!	₹4,86,563 Volume Pricing	Contact Us
#71-110-522 New								
								
						New		
$\lambda/20$	254.00	ZERODUR®	R _{avg} >85% @ 400 - 700nm R _{avg} >90% @ 400 - 2000nm	Protected Aluminum (400- 2000nm)	38.10	Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!	₹7,04,543 Volume Pricing	Contact Us

[#71-108-533 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

$\lambda/10$	254.00	ZERODUR®	$R_{avg} > 95\% @ 450 - 650nm$	Enhanced Aluminum (450-650nm)	38.10	₹4,94,348 Volume Pricing	Contact Us
--------------	--------	--------------------------	--------------------------------	-------------------------------	-------	---	------------

[#71-110-533 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

$\lambda/20$	254.00	ZERODUR®	$R_{avg} > 95\% @ 450 - 650nm$	Enhanced Aluminum (450-650nm)	38.10	₹7,12,328 Volume Pricing	Contact Us
--------------	--------	--------------------------	--------------------------------	-------------------------------	-------	---	------------

[#71-108-566 New](#)



New

$\lambda/10$	254.00	ZERODUR®	$R_{avg} > 96\%$ @ 700 - 2000nm $R_{avg} > 96\%$ @ 2000 - 10,000nm	Protected Gold (700- 10000nm)	38.10	Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!	₹5,04,079 Volume Pricing	Contact Us
--------------	--------	--------------------------	--	--	-------	--	---	------------

[#71-110-566 New](#)



New

$\lambda/20$	254.00	ZERODUR®	$R_{avg} > 96\%$ @ 700 - 2000nm $R_{avg} > 96\%$ @ 2000 - 10,000nm	Protected Gold (700- 10000nm)	38.10	Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!	₹7,22,059 Volume Pricing	Contact Us
--------------	--------	--------------------------	--	--	-------	--	---	------------

[#71-108-577 New](#)



New

$\lambda/10$	254.00	ZERODUR®	$R_{avg} > 98\% @$ 450 - 2000nm $R_{avg} > 98\% @$ 2000 - 10,000nm	Protected Silver (450-10000nm)	38.10	Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!	₹5,02,133 Volume Pricing	Contact Us
--------------	--------	--------------------------	---	-----------------------------------	-------	--	---	------------

[#71-110-577 New](#)



New

$\lambda/20$	254.00	ZERODUR®	$R_{avg} > 98\% @$ 450 - 2000nm $R_{avg} > 98\% @$ 2000 - 10,000nm	Protected Silver (450-10000nm)	38.10	Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!	₹7,20,113 Volume Pricing	Contact Us
--------------	--------	--------------------------	---	-----------------------------------	-------	--	---	------------

$\lambda/10$	304.80	Fused Silica	$R_{avg} > 85\% @$ 400 - 700nm $R_{avg} > 90\% @$ 400 - 2000nm	Protected Aluminum (400-2000nm)	38.10	#69-921-522	₹6,29,417 Volume Pricing	Contact Us
--------------	--------	------------------------------	---	------------------------------------	-------	-----------------------------	---	------------

$\lambda/20$	304.80	Fused Silica	$R_{avg} > 85\% @$ 400 - 700nm $R_{avg} > 90\% @$ 400 - 2000nm	Protected Aluminum (400-2000nm)	38.10	#65-880-522	₹9,61,837 Volume Pricing	Contact Us
--------------	--------	------------------------------	---	------------------------------------	-------	-----------------------------	---	------------

[#71-109-522 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

$\lambda/10$	304.80	ZERODUR®	$R_{avg} > 85\% @ 400 - 700nm$ $R_{avg} > 90\% @ 400 - 2000nm$	Protected Aluminum (400-2000nm)	38.10	₹6,32,531 Volume Pricing	Contact Us
--------------	--------	--------------------------	---	---------------------------------	-------	---	------------

[#71-111-522 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

$\lambda/20$	304.80	ZERODUR®	$R_{avg} > 85\% @ 400 - 700nm$ $R_{avg} > 90\% @ 400 - 2000nm$	Protected Aluminum (400-2000nm)	38.10	₹9,63,394 Volume Pricing	Contact Us
--------------	--------	--------------------------	---	---------------------------------	-------	---	------------

$\lambda/10$	304.80	Fused Silica	$R_{avg} > 95\% @ 450 - 650nm$	Enhanced Aluminum (450-650nm)	38.10	#69-921-533 ₹6,35,256 Volume Pricing	1 In Stock
--------------	--------	------------------------------	--------------------------------	-------------------------------	-------	--	------------

[#71-109-533 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

$\lambda/10$	304.80	ZERODUR®	$R_{avg} > 95\% @ 450 - 650nm$	Enhanced Aluminum (450-650nm)	38.10		₹6,38,370 Volume Pricing	Contact Us
--------------	--------	--------------------------	--------------------------------	-------------------------------	-------	--	---	------------

[#71-111-533 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

$\lambda/20$	304.80	ZERODUR®	$R_{avg} > 95\% @ 450 - 650nm$	Enhanced Aluminum (450-650nm)	38.10		₹9,69,233 Volume Pricing	Contact Us
--------------	--------	--------------------------	--------------------------------	-------------------------------	-------	--	---	------------

$\lambda/20$	304.80	Fused Silica	$R_{avg} > 95\% @ 450 - 650nm$	Enhanced Aluminum (450-650nm)	38.10	#65-880-533	₹9,67,676 Volume Pricing	Contact Us
--------------	--------	------------------------------	--------------------------------	-------------------------------	-------	-----------------------------	---	------------

$\lambda/10$	304.80	Fused Silica	$R_{avg} > 96\% @ 700 - 2000nm$ $R_{avg} > 96\% @ 2000 - 10,000nm$	Protected Gold (700-10000nm)	38.10	#69-921-566	₹6,44,987 Volume Pricing	1 In Stock
--------------	--------	------------------------------	---	------------------------------	-------	-----------------------------	---	------------

[#71-109-566 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

$\lambda/10$	304.80	ZERODUR®	$R_{avg} > 96\% @ 700 - 2000nm$ $R_{avg} > 96\% @ 2000 - 10,000nm$	Protected Gold (700-10000nm)	38.10		₹6,48,101 Volume Pricing	Contact Us
--------------	--------	--------------------------	---	------------------------------	-------	--	---	------------

[#71-111-566 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

$\lambda/20$	304.80	ZERODUR®	$R_{avg} > 96\% @ 700 - 2000nm$ $R_{avg} > 96\% @ 2000 - 10,000nm$	Protected Gold (700-10000nm)	38.10		₹9,78,964 Volume Pricing	Contact Us
--------------	--------	--------------------------	---	------------------------------	-------	--	---	------------

$\lambda/20$	304.80	Fused Silica	$R_{avg} > 96\% @ 700 - 2000nm$ $R_{avg} > 96\% @ 2000 - 10,000nm$	Protected Gold (700-10000nm)	38.10	#65-880-566	₹9,77,407 Volume Pricing	Contact Us
--------------	--------	------------------------------	---	------------------------------	-------	-----------------------------	---	------------

$\lambda/10$	304.80	Fused Silica	$R_{avg} > 98\% @ 450 - 2000nm$ $R_{avg} > 98\% @ 2000 - 10,000nm$	Protected Silver (450-10000nm)	38.10	#69-921-577	₹6,43,041 Volume Pricing	1 In Stock
--------------	--------	------------------------------	---	--------------------------------	-------	-----------------------------	---	------------

$\lambda/20$	304.80	Fused Silica	$R_{avg} > 98\% @ 450 - 2000nm$ $R_{avg} > 98\% @ 2000 - 10,000nm$	Protected Silver (450-10000nm)	38.10	#65-880-577	₹9,75,461 Volume Pricing	Contact Us
--------------	--------	------------------------------	---	--------------------------------	-------	-----------------------------	---	------------

[#71-109-577 New](#)



New

$\lambda/10$	304.80	ZERODUR®	$R_{avg} > 98\%$ @ 450 - 2000nm $R_{avg} > 98\%$ @ 2000 - 10,000nm	Protected Silver (450- 10000nm)	38.10	Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!	₹6,46,155 Volume Pricing	Contact Us
--------------	--------	--------------------------	--	--	-------	--	---	------------

[#71-111-577 New](#)



New

$\lambda/20$	304.80	ZERODUR®	$R_{avg} > 98\%$ @ 450 - 2000nm $R_{avg} > 98\%$ @ 2000 - 10,000nm	Protected Silver (450- 10000nm)	38.10	Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!	₹9,77,018 Volume Pricing	Contact Us
--------------	--------	--------------------------	--	--	-------	--	---	------------



Copyright 2023, Edmund Optics India Private Limited, #267, Greystone Building, Second Floor, 6th Cross Rd, Binnamangala, Stage 1, Indiranagar, Bengaluru, Karnataka, India 560038

Phone: 1-800-363-1992 :

www.edmundoptics.com