


[All Products](#) / [Optomechanics](#) / [Manual Translation Stages and Slides](#) / [Manual Stages and Slides](#)

Linear Motion Ball Bearing Slides

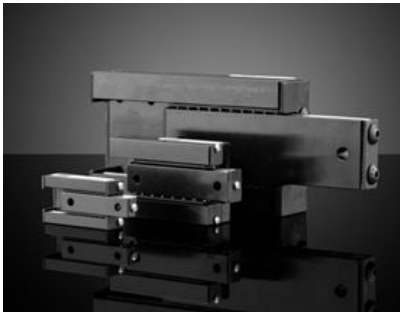

- High Straight Line Accuracy
- Low Wear, Low Friction Sliding Motion
- Preloaded to Eliminate Wobble and Unwanted Play

Common Specifications

Physical & Mechanical Properties

Type of Movement:	Linear (X)	Guide System:	Ball Bearing
Construction:	Aluminum Top and Base/440C Stainless Steel Bearings		

Hardware & Interface Connectivity

Type of Drive:	Manual
----------------	--------

Technical Information

Products

Type of Drive	Type	Stage Size (inches)	Height (inches)	Travel (inches)	Load Capacity, Normal (lbs)	Stock Number	Price	Buy
Manual	English	2.62 x 2.62	1.00	1	40.0	#37-356	₹19,878	10 to 12 days
Manual	English	1.75 x 3.00	0.75	2	40.0	#37-361	₹18,264	Contact Us
Manual	English	0.59 x 1.12	0.32	0.5	4.9	#53-849	₹14,817	10 to 12 days
#53-850 Clearance								
× Clearance Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.								
Manual	English	0.59 x 2.12	0.32	1	10.3		₹23,850	10 to 12 days
Manual	English	2.62 x 4.00	1.00	2	88	#37-363	₹20,245	Contact Us
Manual	English	2.62 x 5.00	1.00	3	100	#37-364	₹22,078	Contact Us
Manual	English	2.62 x 6.00	1.00	4	123	#37-365	₹25,306	10 to 12 days

