

[All Products](#) / [Optomechanics](#) / [Manual Translation Stages and Slides](#) / [Manual Stages and Slides](#)

Heavy Load Capacity Rotary Positioning Stages



- Normal Load Capacity of 25lb (11.3kg) for heavy duty applications
- Precision Worm Gear Drive
- Compatible with Metric and English 5" Ball Stages

Common Specifications


Physical & Mechanical Properties

Type of Movement:	Rotary	Stage Size (mm):	120.7 x 120.7
Travel (°):	360	Construction:	Aluminum Top and Base; Steel/bronze Worm Gear Drive
Gear Drive Ratio:	120:1	Increments (arcmin):	6 (Vernier)

Hardware & Interface Connectivity

Type of Drive:	Worm Gear
----------------	-----------

Technical Information

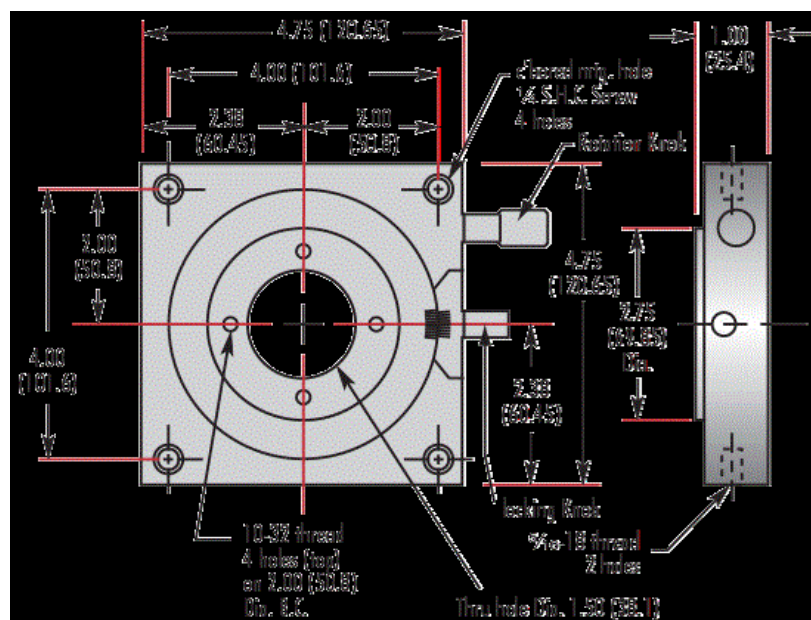

Products

Stage Size (mm)	Type	Table Diameter (inches)	Table Diameter (mm)	Center Hole	Travel (°)	Stock Number	Price	Buy
120.7 x 120.7	English	2.75 (69.8mm)	-	1.5" Dia. Thru	360	#38-195	₹83,619	10 to 12 days
#13-773 Clearance								
<div><div><div></div><div>x</div></div></div> <div>Clearance</div> <div>Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.</div>								
120.7 x 120.7	Metric	-	69.8	38.1mm Dia. Thru	360		₹63,332	Contact Us

