

[All Products](#) / [Optics](#) / [Windows and Diffusers](#) / [Optical Diffusers](#)

Ground Glass Diffusers



- Available in Sizes Ranging from 5mm Diameter to 250mm Square
- Low Scatter Loss
- Evenly Ground Surface for Even Diffusion
- [Fused Silica Substrates](#) Available

Common Specifications

General

Note:

Sandblasted on first surface

Physical & Mechanical Properties

Thickness (mm): 1.60


Optical Properties

Coating: Uncoated

Substrate: Float Glass

Wavelength Range (nm): 350 - 2000

Technical Information

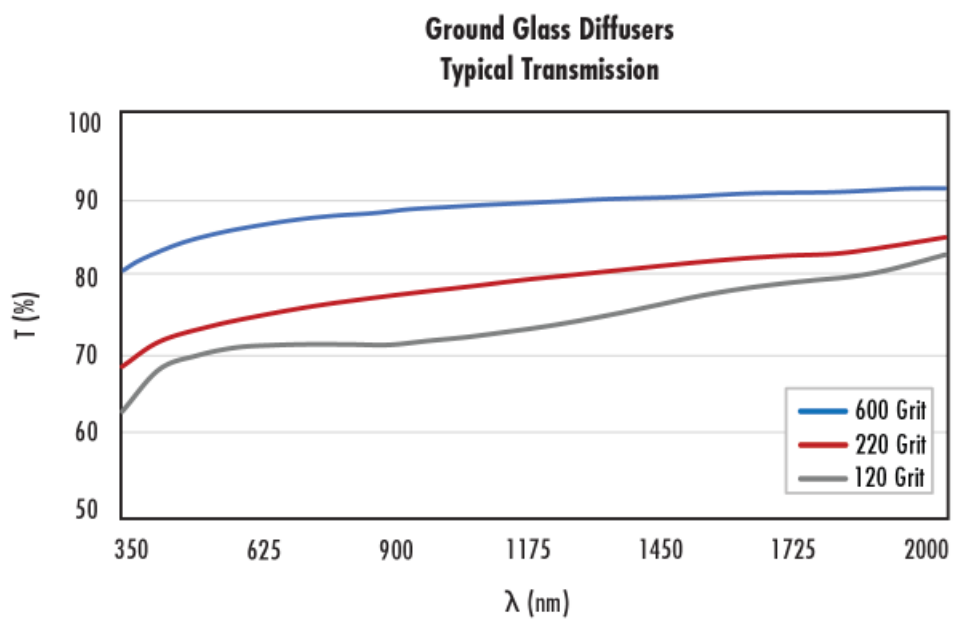

Products

Dia. (mm)	Coating	Dimensions (mm)	Grit	Thickness (mm)	Stock Number	Price	Buy
5.00	Uncoated	-	120	1.60	#83-416	₹1,357 Qty 11+ ₹1,155	10 to 12 days
6.00	Uncoated	-	120	1.60	#83-081	₹1,357 Qty 11+ ₹1,155	10 to 12 days
10.00	Uncoated	-	120	1.60	#83-082	₹1,357 Qty 11+ ₹1,155	10 to 12 days
-	Uncoated	10.00 x 10.00	120	1.60	#83-083	₹1,357 Qty 11+ ₹1,155	10 to 12 days
12.50	Uncoated	-	120	1.60	#83-418	₹899 Qty 11+ ₹825	10 to 12 days
-	Uncoated	12.50 x 12.50	120	1.60	#83-084	₹1,357 Qty 11+ ₹1,155	10 to 12 days
15.00	Uncoated	-	120	1.60	#83-379	₹1,559 Qty 11+ ₹1,375	10 to 12 days
20.00	Uncoated	-	120	1.60	#83-380	₹1,559 Qty 11+ ₹1,375	10 to 12 days
25.00	Uncoated	-	120	1.60	#83-419	₹1,009 Qty 11+ ₹899	10 to 12 days
-	Uncoated	25.00 x 25.00	120	1.60	#83-381	₹1,559 Qty 11+ ₹1,375	10 to 12 days
50.00	Uncoated	-	120	1.60	#83-420	₹1,302 Qty 11+ ₹1,174	10 to 12 days
-	Uncoated	50.00 x 50.00	120	1.60	#83-382	₹1,797 Qty 11+ ₹1,559	10 to 12 days
100.00	Uncoated	-	120	1.60	#83-383	₹4,438 Qty 11+ ₹3,998	10 to 12 days
-	Uncoated	100.00 x 100.00	120	1.60	#83-384	₹3,392 Qty 11+ ₹3,136	10 to 12 days
-	Uncoated	150.00 x 150.00	120	1.60	#83-385	₹4,878 Qty 11+ ₹4,401	10 to 12 days
-	Uncoated	200.00 x 200.00	120	1.60	#83-386	₹5,575 Qty 11+ ₹5,024	10 to 12 days

-	Uncoated	250.00 x 250.00	120	1.60	#83-387	₹7,262 Qty 11+ ₹6,748	10 to 12 days
5.00	Uncoated	-	220	1.60	#62-614	₹1,357 Qty 11+ ₹1,155	10 to 12 days
6.00	Uncoated	-	220	1.60	#45-650	₹1,357 Qty 11+ ₹1,155	10 to 12 days
10.00	Uncoated	-	220	1.60	#45-651	₹1,357 Qty 11+ ₹1,155	10 to 12 days
-	Uncoated	10.00 x 10.00	220	1.60	#62-615	₹1,357 Qty 11+ ₹1,155	10 to 12 days
12.50	Uncoated	-	220	1.60	#62-616	₹899 Qty 11+ ₹825	10 to 12 days
-	Uncoated	12.50 x 12.50	220	1.60	#62-617	₹1,357 Qty 11+ ₹1,155	10 to 12 days
15.00	Uncoated	-	220	1.60	#45-652	₹1,559 Qty 11+ ₹1,375	10 to 12 days
20.00	Uncoated	-	220	1.60	#62-618	₹1,559 Qty 11+ ₹1,375	10 to 12 days
25.00	Uncoated	-	220	1.60	#45-653	₹1,082 Qty 11+ ₹990	10 to 12 days
-	Uncoated	25.00 x 25.00	220	1.60	#45-654	₹1,559 Qty 11+ ₹1,375	10 to 12 days
50.00	Uncoated	-	220	1.60	#62-619	₹1,302 Qty 11+ ₹1,174	10 to 12 days
-	Uncoated	50.00 x 50.00	220	1.60	#45-655	₹1,797 Qty 11+ ₹1,559	10 to 12 days
100.00	Uncoated	-	220	1.60	#62-620	₹4,438 Qty 11+ ₹3,998	10 to 12 days
-	Uncoated	100.00 x 100.00	220	1.60	#45-656	₹3,392 Qty 11+ ₹3,136	10 to 12 days
-	Uncoated	150.00 x 150.00	220	1.60	#47-951	₹4,878 Qty 11+ ₹4,401	10 to 12 days
-	Uncoated	200.00 x 200.00	220	1.60	#47-952	₹5,575 Qty 11+ ₹5,024	10 to 12 days
-	Uncoated	250.00 x 250.00	220	1.60	#47-953	₹7,262 Qty 11+ ₹6,748	10 to 12 days
10.00	Uncoated	-	600	1.60	#38-782	₹1,357 Qty 11+ ₹1,155	10 to 12 days

-	Uncoated	10.00 x 10.00	600	1.60	#38-783	₹1,357 Qty 11+ ₹1,155	10 to 12 days
12.50	Uncoated	-	600	1.60	#38-784	₹899 Qty 11+ ₹825	10 to 12 days
-	Uncoated	12.50 x 12.50	600	1.60	#38-785	₹1,357 Qty 11+ ₹1,155	10 to 12 days
25.00	Uncoated	-	600	1.60	#38-786	₹1,082 Qty 11+ ₹990	10 to 12 days
-	Uncoated	25.00 x 25.00	600	1.60	#38-787	₹1,559 Qty 11+ ₹1,375	7 days
50.00	Uncoated	-	600	1.60	#38-788	₹1,302 Qty 11+ ₹1,174	10 to 12 days
-	Uncoated	50.00 x 50.00	600	1.60	#38-789	₹1,797 Qty 11+ ₹1,559	10 to 12 days
100.00	Uncoated	-	600	1.60	#38-790	₹4,438 Qty 11+ ₹3,998	10 to 12 days
-	Uncoated	100.00 x 100.00	600	1.60	#38-791	₹3,392 Qty 11+ ₹3,136	10 to 12 days



Copyright 2023, Edmund Optics India Private Limited, #267, Greystone Building, Second Floor, 6th Cross Rd, Binnamangala, Stage 1, Indiranagar, Bengaluru, Karnataka, India 560038

Phone: 1-800-363-1992 :

www.edmundoptics.com