

[All Products](#) / [Optics](#) / [Optical Filters](#) / [Bandpass Filters](#)

Traditional Coated 400 – 699nm Bandpass Interference Filters



- Available in UV, Visible, and IR Center Wavelengths
- 10 – 80nm Bandwidths Available
- Ideal for Biomedical Applications and Instrumentation Integration
- [193-399nm](#), 400-699nm, and [700-1650nm](#) CWL Options Available

Common Specifications




Physical & Mechanical Properties

Construction:	Mounted in Black Anodized Ring
---------------	--------------------------------

Optical Properties

Angle of Incidence (°):		0	
Coating:		Traditional Coated	
Surface Quality:		80-50	

Technical Information

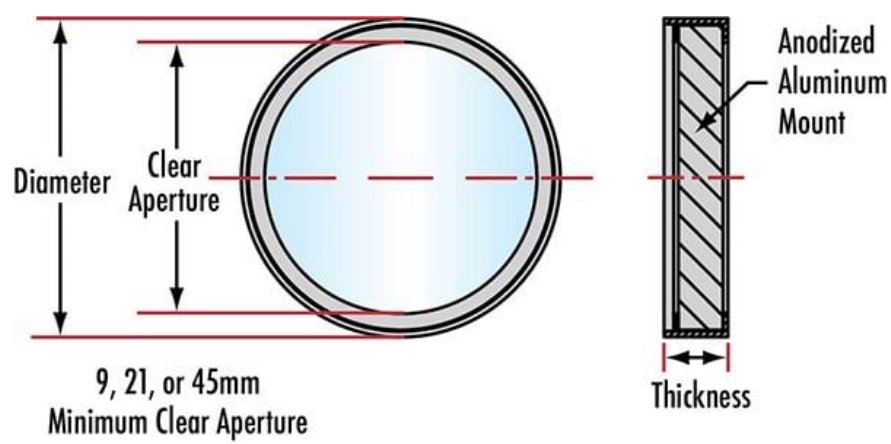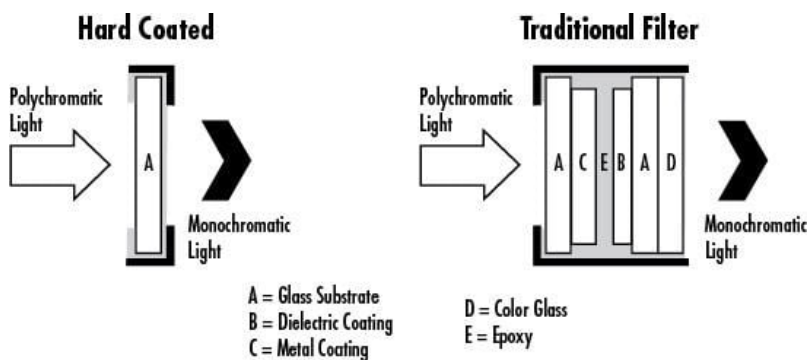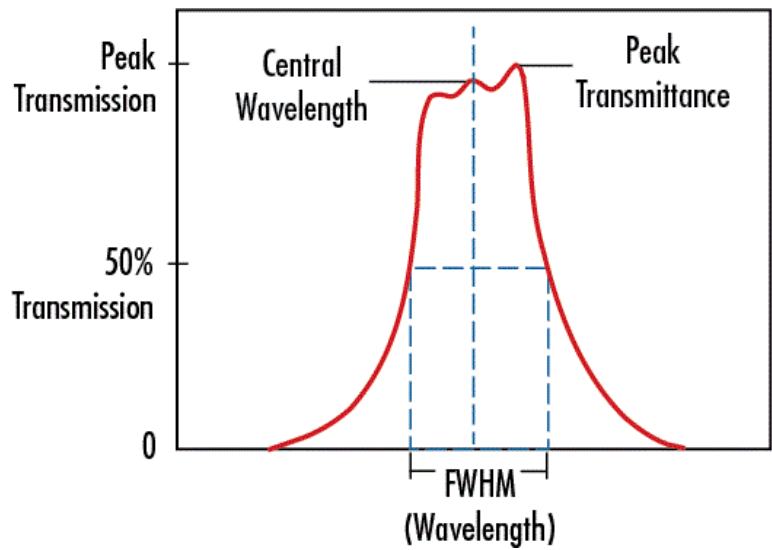

Products

Dia. (mm)	CWL (nm)	FWHM (nm)	Minimum Transmission (%)	Blocking Wavelength Range (nm)	Dimensions (mm)	Stock Number	Price	Buy
12.50	400.00	10.00	≥30	200 - 1200	-	#65-617	₹7,240 Qty 10+ ₹6,500	10 to 12 days
25.00	400.00	10.00	≥30	200 - 1200	-	#65-677	₹13,390 Qty 10+ ₹12,067	10 to 12 days
12.50	400.00	50.00	≥55	200 - 1200	-	#65-732	₹7,240 Qty 10+ ₹6,500	10 to 12 days
25.00	400.00	50.00	≥55	200 - 1200	-	#65-741	₹13,390 Qty 10+ ₹12,067	10 to 12 days
12.50	405.00	10.00	≥40	200 - 1200	-	#65-618	₹7,240 Qty 10+ ₹6,500	10 to 12 days
25.00	405.00	10.00	≥40	200 - 1200	-	#65-678	₹13,390 Qty 10+ ₹12,067	10 to 12 days
50.00	405.00	10.00	≥40	200 - 1200	-	#86-622	₹36,122 Qty 10+ ₹32,541	10 to 12 days
12.50	410.00	10.00	≥40	200 - 1200	-	#65-619	₹7,240 Qty 10+ ₹6,500	10 to 12 days
25.00	410.00	10.00	≥40	200 - 1200	-	#65-679	₹13,390 Qty 10+ ₹12,067	10 to 12 days
12.50	415.00	10.00	≥40	200 - 1200	-	#65-620	₹7,240 Qty 10+ ₹6,500	10 to 12 days
25.00	415.00	10.00	≥40	200 - 1200	-	#65-680	₹13,390 Qty 10+ ₹12,067	10 to 12 days
12.50	420.00	10.00	≥40	200 - 1200	-	#65-621	₹7,240 Qty 10+ ₹6,500	10 to 12 days
25.00	420.00	10.00	≥40	200 - 1200	-	#65-681	₹13,390 Qty 10+ ₹12,067	10 to 12 days
50.00	420.00	10.00	≥40	200 - 1200	-	#86-623	₹36,122 Qty 10+ ₹32,541	10 to 12 days
12.50	430.00	10.00	≥40	200 - 1200	-	#65-622	₹7,240 Qty 10+ ₹6,500	10 to 12 days
25.00	430.00	10.00	≥40	200 - 1200	-	#65-682	₹13,390 Qty 10+ ₹12,067	10 to 12 days
12.50	436.00	10.00	≥40	200 - 1200	-	#65-623	₹7,240 Qty 10+ ₹6,500	10 to 12 days

25.00	436.00	10.00	≥40	200 - 1200	-	#65-683	₹13,390 Qty 10+ ₹12,067	10 to 12 days
50.00	436.00	10.00	≥40	200 - 1200	-	#86-998	₹36,122 Qty 10+ ₹32,541	10 to 12 days
12.50	440.00	10.00	>45	200 - Far IR	-	#67-764	₹7,240 Qty 10+ ₹6,500	10 to 12 days
25.00	440.00	10.00	>45	200 - Far IR	-	#67-831	₹13,390 Qty 10+ ₹12,067	10 to 12 days
50.00	440.00	10.00	>45	200 - Far IR	-	#67-898	₹36,122 Qty 10+ ₹32,541	10 to 12 days
12.50	442.00	10.00	≥40	200 - 1200	-	#65-624	₹7,240 Qty 10+ ₹6,500	10 to 12 days
25.00	442.00	10.00	≥40	200 - 1200	-	#65-684	₹13,390 Qty 10+ ₹12,067	10 to 12 days
50.00	442.00	10.00	≥40	200 - 1200	-	#86-624	₹36,122 Qty 10+ ₹32,541	10 to 12 days
12.50	450.00	10.00	≥45	200 - 1200	-	#65-625	₹7,240 Qty 10+ ₹6,500	10 to 12 days
25.00	450.00	10.00	≥45	200 - 1200	-	#65-685	₹13,390 Qty 10+ ₹12,067	10 to 12 days
50.00	450.00	10.00	≥45	200 - 1200	-	#86-999	₹36,122 Qty 10+ ₹32,541	10 to 12 days
12.50	450.00	80.00	≥60	200 - 1200	-	#65-733	₹7,240 Qty 10+ ₹6,500	10 to 12 days
25.00	450.00	80.00	≥60	200 - 1200	-	#65-742	₹13,390 Qty 10+ ₹12,067	10 to 12 days
50.00	450.00	80.00	≥60	200 - 1200	-	#87-007	₹36,122 Qty 10+ ₹32,541	Contact Us
12.50	455.00	10.00	≥45	200 - 1200	-	#65-626	₹7,240 Qty 10+ ₹6,500	10 to 12 days
25.00	455.00	10.00	≥45	200 - 1200	-	#65-686	₹13,390 Qty 10+ ₹12,067	10 to 12 days
12.50	458.00	10.00	≥45	200 - 1200	-	#65-627	₹7,240 Qty 10+ ₹6,500	10 to 12 days
25.00	458.00	10.00	≥45	200 - 1200	-	#65-687	₹13,390 Qty 10+ ₹12,067	10 to 12 days
12.50	460.00	10.00	>50	200 - Far IR	-	#67-765	₹7,240 Qty 10+ ₹6,500	10 to 12 days
25.00	460.00	10.00	>50	200 - Far IR	-	#67-832	₹13,390 Qty 10+ ₹12,067	10 to 12 days
50.00	460.00	10.00	>50	200 - Far IR	-	#67-899	₹36,122 Qty 10+ ₹32,541	10 to 12 days

12.50	467.00	10.00	≥45	200 - 1200	-	#65-628	₹7,240 Qty 10+ ₹6,500	10 to 12 days
25.00	467.00	10.00	≥45	200 - 1200	-	#65-688	₹13,390 Qty 10+ ₹12,067	10 to 12 days
12.50	470.00	10.00	≥45	200 - 1200	-	#65-629	₹7,240 Qty 10+ ₹6,500	10 to 12 days
25.00	470.00	10.00	≥45	200 - 1200	-	#65-689	₹13,390 Qty 10+ ₹12,067	10 to 12 days
50.00	470.00	10.00	≥45	200 - 1200	-	#86-625	₹36,122 Qty 10+ ₹32,541	10 to 12 days
12.50	480.00	10.00	≥45	200 - 1200	-	#65-630	₹7,240 Qty 10+ ₹6,500	10 to 12 days
25.00	480.00	10.00	≥45	200 - 1200	-	#65-690	₹13,390 Qty 10+ ₹12,067	10 to 12 days
50.00	480.00	10.00	≥45	200 - 1200	-	#87-000	₹36,122 Qty 10+ ₹32,541	10 to 12 days
12.50	486.00	10.00	≥45	200 - 1200	-	#65-631	₹7,240 Qty 10+ ₹6,500	10 to 12 days
25.00	486.00	10.00	≥45	200 - 1200	-	#65-691	₹13,390 Qty 10+ ₹12,067	10 to 12 days
12.50	488.00	10.00	≥45	200 - 1200	-	#65-632	₹7,240 Qty 10+ ₹6,500	10 to 12 days
25.00	488.00	10.00	≥45	200 - 1200	-	#65-692	₹13,390 Qty 10+ ₹12,067	10 to 12 days
50.00	488.00	10.00	≥45	200 - 1200	-	#86-626	₹36,122 Qty 10+ ₹32,541	10 to 12 days
12.50	492.00	10.00	≥45	200 - 1200	-	#65-633	₹7,240 Qty 10+ ₹6,500	10 to 12 days
25.00	492.00	10.00	≥45	200 - 1200	-	#65-693	₹13,390 Qty 10+ ₹12,067	10 to 12 days
12.50	500.00	10.00	≥45	200 - 1200	-	#65-634	₹7,240 Qty 10+ ₹6,500	10 to 12 days
25.00	500.00	10.00	≥45	200 - 1200	-	#65-694	₹13,390 Qty 10+ ₹12,067	10 to 12 days
12.50	500.00	80.00	≥60	200 - 1200	-	#65-734	₹7,240 Qty 10+ ₹6,500	10 to 12 days
25.00	500.00	80.00	≥60	200 - 1200	-	#65-743	₹13,390 Qty 10+ ₹12,067	10 to 12 days
50.00	500.00	80.00	≥60	200 - 1200	-	#87-008	₹36,122 Qty 10+ ₹32,541	10 to 12 days

12.50	505.00	10.00	≥45	200 - 1200	-	#65-635	₹7,240 Qty 10+ ₹6,500	10 to 12 days
25.00	505.00	10.00	≥45	200 - 1200	-	#65-695	₹13,390 Qty 10+ ₹12,067	10 to 12 days
12.50	508.00	10.00	≥45	200 - 1200	-	#65-636	₹7,240 Qty 10+ ₹6,500	10 to 12 days
25.00	508.00	10.00	≥45	200 - 1200	-	#65-696	₹13,390 Qty 10+ ₹12,067	10 to 12 days
12.50	510.00	10.00	≥45	200 - 1200	-	#65-637	₹7,240 Qty 10+ ₹6,500	10 to 12 days
25.00	510.00	10.00	≥45	200 - 1200	-	#65-697	₹13,390 Qty 10+ ₹12,067	10 to 12 days
50.00	510.00	10.00	≥45	200 - 1200	-	#87-001	₹36,122 Qty 10+ ₹32,541	10 to 12 days
12.50	515.00	10.00	≥45	200 - 1200	-	#65-638	₹7,240 Qty 10+ ₹6,500	10 to 12 days
25.00	515.00	10.00	≥45	200 - 1200	-	#65-698	₹13,390 Qty 10+ ₹12,067	10 to 12 days
12.50	520.00	10.00	≥45	200 - 1200	-	#65-639	₹7,240 Qty 10+ ₹6,500	10 to 12 days
25.00	520.00	10.00	≥45	200 - 1200	-	#65-699	₹13,390 Qty 10+ ₹12,067	10 to 12 days
50.00	520.00	10.00	≥45	200 - 1200	-	#86-627	₹36,122 Qty 10+ ₹32,541	10 to 12 days
12.50	532.00	10.00	≥45	200 - 1200	-	#65-640	₹7,240 Qty 10+ ₹6,500	10 to 12 days
25.00	532.00	10.00	≥45	200 - 1200	-	#65-700	₹13,390 Qty 10+ ₹12,067	10 to 12 days
50.00	532.00	10.00	≥45	200 - 1200	-	#86-628	₹36,122 Qty 10+ ₹32,541	10 to 12 days
12.50	535.00	10.00	≥45	200 - 1200	-	#65-641	₹7,240 Qty 10+ ₹6,500	10 to 12 days
25.00	535.00	10.00	≥45	200 - 1200	-	#65-701	₹13,390 Qty 10+ ₹12,067	10 to 12 days
12.50	540.00	10.00	≥45	200 - 1200	-	#65-642	₹7,240 Qty 10+ ₹6,500	10 to 12 days
25.00	540.00	10.00	≥45	200 - 1200	-	#65-702	₹13,390 Qty 10+ ₹12,067	10 to 12 days
50.00	540.00	10.00	≥45	200 - 1200	-	#87-002	₹36,122 Qty 10+ ₹32,541	10 to 12 days

12.50	546.00	10.00	≥45	200 - 1200	-	#65-643	₹7,240 Qty 10+ ₹6,500	10 to 12 days
25.00	546.00	10.00	≥45	200 - 1200	-	#65-703	₹13,390 Qty 10+ ₹12,067	10 to 12 days
50.00	546.00	10.00	≥45	200 - 1200	-	#86-629	₹36,122 Qty 10+ ₹32,541	10 to 12 days
12.50	550.00	10.00	≥45	200 - 1200	-	#65-644	₹7,240 Qty 10+ ₹6,500	10 to 12 days
25.00	550.00	10.00	≥45	200 - 1200	-	#65-704	₹13,390 Qty 10+ ₹12,067	10 to 12 days
50.00	550.00	10.00	≥45	200 - 1200	-	#86-630	₹36,122 Qty 10+ ₹32,541	10 to 12 days
12.50	550.00	80.00	≥60	200 - 1200	-	#65-735	₹7,240 Qty 10+ ₹6,500	10 to 12 days
25.00	550.00	80.00	≥60	200 - 1200	-	#65-744	₹13,390 Qty 10+ ₹12,067	10 to 12 days
50.00	550.00	80.00	≥60	200 - 1200	-	#87-009	₹36,122 Qty 10+ ₹32,541	10 to 12 days
12.50	560.00	10.00	>55	200 - Far IR	-	#67-766	₹7,240 Qty 10+ ₹6,500	10 to 12 days
25.00	560.00	10.00	>55	200 - Far IR	-	#67-833	₹13,390 Qty 10+ ₹12,067	10 to 12 days
50.00	560.00	10.00	>55	200 - Far IR	-	#67-900	₹36,122 Qty 10+ ₹32,541	Contact Us
12.50	568.00	10.00	≥45	200 - 1200	-	#65-645	₹7,240 Qty 10+ ₹6,500	10 to 12 days
25.00	568.00	10.00	≥45	200 - 1200	-	#65-705	₹13,390 Qty 10+ ₹12,067	10 to 12 days
12.50	570.00	10.00	>55	200 - Far IR	-	#67-767	₹7,240 Qty 10+ ₹6,500	10 to 12 days
25.00	570.00	10.00	>55	200 - Far IR	-	#67-834	₹13,390 Qty 10+ ₹12,067	10 to 12 days
50.00	570.00	10.00	>55	200 - Far IR	-	#67-901	₹36,122 Qty 10+ ₹32,541	10 to 12 days
12.50	577.00	10.00	>55	200 - Far IR	-	#67-768	₹7,240 Qty 10+ ₹6,500	10 to 12 days
25.00	577.00	10.00	>55	200 - Far IR	-	#67-835	₹13,390 Qty 10+ ₹12,067	10 to 12 days
50.00	577.00	10.00	>55	200 - Far IR	-	#67-902	₹36,122 Qty 10+ ₹32,541	10 to 12 days

12.50	580.00	10.00	≥45	200 - 1200	-	#65-646	₹7,240 Qty 10+ ₹6,500	10 to 12 days
25.00	580.00	10.00	≥45	200 - 1200	-	#65-706	₹13,390 Qty 10+ ₹12,067	10 to 12 days
50.00	580.00	10.00	≥45	200 - 1200	-	#87-003	₹36,122 Qty 10+ ₹32,541	10 to 12 days
12.50	589.00	10.00	≥45	200 - 1200	-	#65-647	₹7,240 Qty 10+ ₹6,500	10 to 12 days
25.00	589.00	10.00	≥45	200 - 1200	-	#65-707	₹13,390 Qty 10+ ₹12,067	10 to 12 days
50.00	589.00	10.00	≥45	200 - 1200	-	#86-631	₹36,122 Qty 10+ ₹32,541	10 to 12 days
12.50	600.00	10.00	≥45	200 - 1200	-	#65-648	₹7,240 Qty 10+ ₹6,500	10 to 12 days
25.00	600.00	10.00	≥45	200 - 1200	-	#65-708	₹13,390 Qty 10+ ₹12,067	10 to 12 days
50.00	600.00	10.00	≥45	200 - 1200	-	#87-004	₹36,122 Qty 10+ ₹32,541	10 to 12 days
12.50	600.00	80.00	≥60	200 - 1200	-	#65-736	₹7,240 Qty 10+ ₹6,500	10 to 12 days
25.00	600.00	80.00	≥60	200 - 1200	-	#65-745	₹13,390 Qty 10+ ₹12,067	10 to 12 days
50.00	600.00	80.00	≥60	200 - 1200	-	#87-010	₹36,122 Qty 10+ ₹32,541	10 to 12 days
12.50	610.00	10.00	≥45	200 - 1200	-	#65-649	₹7,240 Qty 10+ ₹6,500	10 to 12 days
25.00	610.00	10.00	≥45	200 - 1200	-	#65-709	₹13,390 Qty 10+ ₹12,067	10 to 12 days
12.50	620.00	10.00	≥45	200 - 1200	-	#65-650	₹7,240 Qty 10+ ₹6,500	Contact Us
25.00	620.00	10.00	≥45	200 - 1200	-	#65-710	₹13,390 Qty 10+ ₹12,067	10 to 12 days
12.50	632.00	10.00	≥45	200 - 1200	-	#65-651	₹7,240 Qty 10+ ₹6,500	10 to 12 days
25.00	632.00	10.00	≥45	200 - 1200	-	#65-711	₹13,390 Qty 10+ ₹12,067	10 to 12 days
50.00	632.00	10.00	≥45	200 - 1200	-	#86-632	₹36,122 Qty 10+ ₹32,541	Contact Us
12.50	636.00	10.00	≥45	200 - 1200	-	#65-652	₹7,240 Qty 10+ ₹6,500	10 to 12 days

25.00	636.00	10.00	≥45	200 - 1200	-	#65-712	₹13,390 Qty 10+ ₹12,067	10 to 12 days
50.00	636.00	10.00	≥45	200 - 1200	-	#86-633	₹36,122 Qty 10+ ₹32,541	10 to 12 days
12.50	640.00	10.00	≥45	200 - 1200	-	#65-653	₹7,240 Qty 10+ ₹6,500	10 to 12 days
25.00	640.00	10.00	≥45	200 - 1200	-	#65-713	₹13,390 Qty 10+ ₹12,067	10 to 12 days
12.50	647.00	10.00	≥45	200 - 1200	-	#65-654	₹7,240 Qty 10+ ₹6,500	10 to 12 days
25.00	647.00	10.00	≥45	200 - 1200	-	#65-714	₹13,390 Qty 10+ ₹12,067	10 to 12 days
12.50	650.00	10.00	≥50	200 - 1200	-	#65-655	₹7,240 Qty 10+ ₹6,500	10 to 12 days
25.00	650.00	10.00	≥50	200 - 1200	-	#65-715	₹13,390 Qty 10+ ₹12,067	10 to 12 days
50.00	650.00	10.00	≥50	200 - 1200	-	#86-634	₹36,122 Qty 10+ ₹32,541	10 to 12 days
12.50	650.00	80.00	≥60	200 - 1200	-	#65-737	₹7,240 Qty 10+ ₹6,500	10 to 12 days
25.00	650.00	80.00	≥60	200 - 1200	-	#65-746	₹13,390 Qty 10+ ₹12,067	10 to 12 days
50.00	650.00	80.00	≥60	200 - 1200	-	#87-011	₹36,122 Qty 10+ ₹32,541	10 to 12 days
12.50	656.00	10.00	≥50	200 - 1200	-	#65-656	₹7,240 Qty 10+ ₹6,500	10 to 12 days
25.00	656.00	10.00	≥50	200 - 1200	-	#65-716	₹13,390 Qty 10+ ₹12,067	10 to 12 days
50.00	656.00	10.00	≥50	200 - 1200	-	#86-635	₹36,122 Qty 10+ ₹32,541	10 to 12 days
12.50	660.00	10.00	>55	200 - Far IR	-	#67-769	₹7,240 Qty 10+ ₹6,500	10 to 12 days
25.00	660.00	10.00	>55	200 - Far IR	-	#67-836	₹13,390 Qty 10+ ₹12,067	10 to 12 days
50.00	660.00	10.00	>55	200 - Far IR	-	#67-903	₹36,122 Qty 10+ ₹32,541	10 to 12 days
12.50	671.00	10.00	≥50	200 - 1200	-	#65-657	₹7,240 Qty 10+ ₹6,500	10 to 12 days
25.00	671.00	10.00	≥50	200 - 1200	-	#65-717	₹13,390 Qty 10+ ₹12,067	10 to 12 days
50.00	671.00	10.00	≥50	200 - 1200	-	#86-636	₹36,122 Qty 10+ ₹32,541	10 to 12 days

12.50	676.00	10.00	≥50	200 - 1200	-	#65-658	₹7,240 Qty 10+ ₹6,500	10 to 12 days
25.00	676.00	10.00	≥50	200 - 1200	-	#65-718	₹13,390 Qty 10+ ₹12,067	10 to 12 days
12.50	680.00	10.00	>55	200 - Far IR	-	#67-770	₹7,240 Qty 10+ ₹6,500	10 to 12 days
25.00	680.00	10.00	>55	200 - Far IR	-	#67-837	₹13,390 Qty 10+ ₹12,067	10 to 12 days
50.00	680.00	10.00	>55	200 - Far IR	-	#67-904	₹36,122 Qty 10+ ₹32,541	10 to 12 days
12.50	690.00	10.00	≥50	200 - 1200	-	#65-659	₹7,240 Qty 10+ ₹6,500	10 to 12 days
25.00	690.00	10.00	≥50	200 - 1200	-	#65-719	₹13,390 Qty 10+ ₹12,067	10 to 12 days
12.50	694.00	10.00	≥50	200 - 1200	-	#65-660	₹7,240 Qty 10+ ₹6,500	10 to 12 days
25.00	694.00	10.00	≥50	200 - 1200	-	#65-720	₹13,390 Qty 10+ ₹12,067	10 to 12 days
50.00	694.00	10.00	≥50	200 - 1200	-	#87-005	₹36,122 Qty 10+ ₹32,541	10 to 12 days



Copyright 2023, Edmund Optics India Private Limited, #267, Greystone Building, Second Floor, 6th Cross Rd, Binnamangala, Stage 1, Indiranagar, Bengaluru, Karnataka, India 560038
Phone: 1-800-363-1992 :
www.edmundoptics.com