


[All Products](#) / [Optics](#) / [Optical Lenses](#) / [Double-Convex \(DCX\) Lenses](#)

TECHSPEC® UV Fused Silica Double-Convex (DCX) Lenses

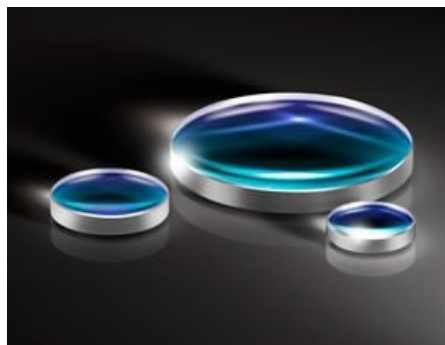

- Ideal for Imaging Applications
- Minimize Aberrations Including Spherical and Coma
- Precision Fused Silica Substrate

Common Specifications

Physical & Mechanical Properties

Bevel:


Protective bevel as needed

Optical Properties


Substrate:
[Fused Silica](#) (Corning 7980)

Surface Quality:	40-20	Power (P-V) @ 632.8nm:	1.5λ
Irregularity (P-V) @ 632.8nm:	λ/4	Focal Length Specification Wavelength (nm):	587.6
Focal Length Tolerance (%):	±1		


Technical Information

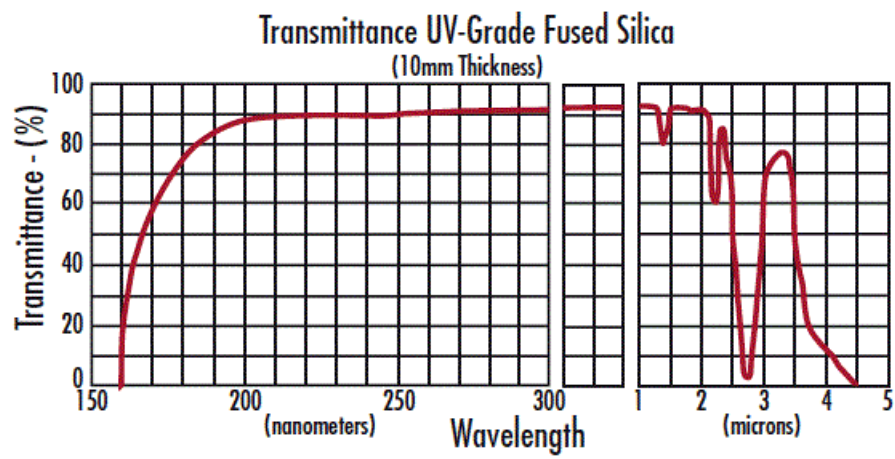


UV FS Transmission Curve

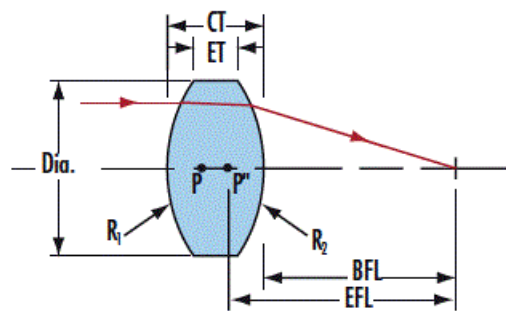

Standard Visible Anti-Reflection Coatings

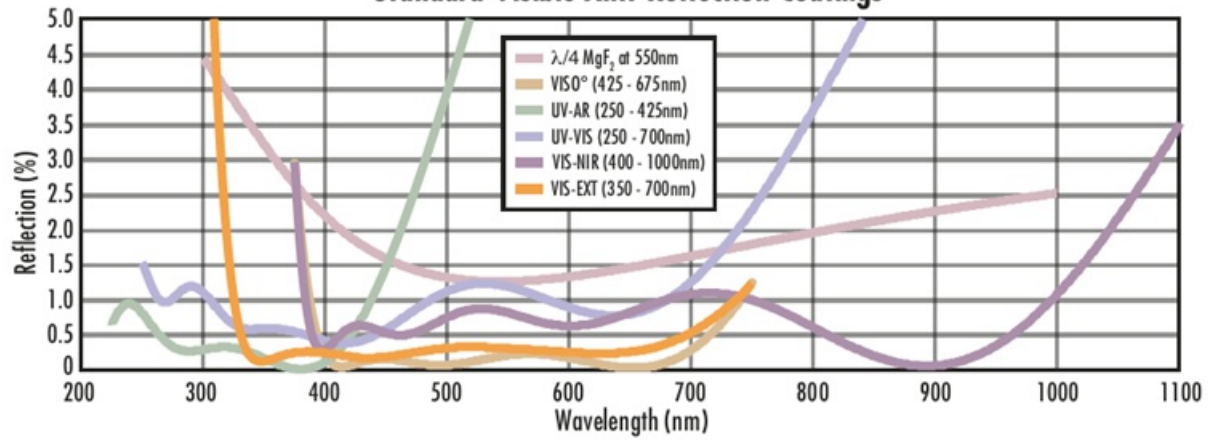

Standard Near Infrared Anti-Reflection Coatings

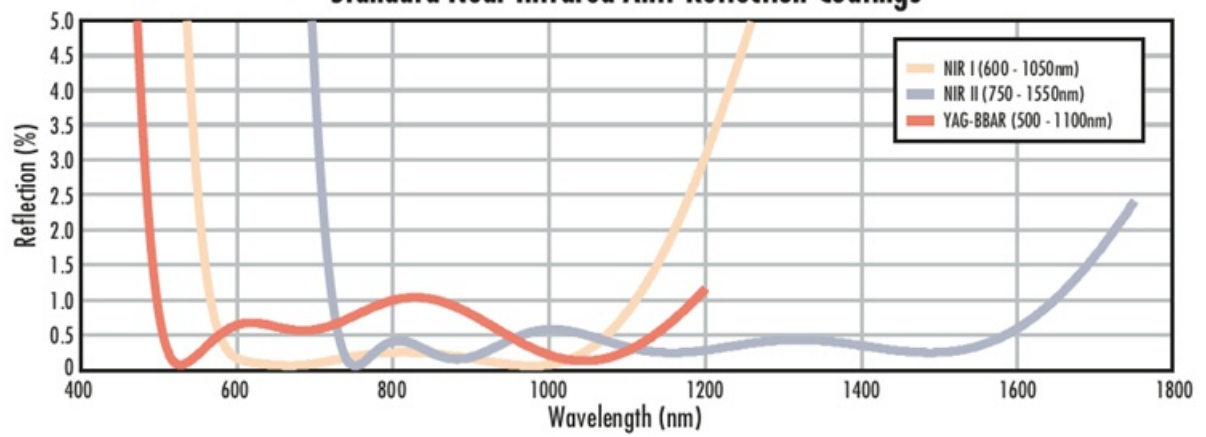

Products

Dia. (mm)	BFL (mm)	EFL (mm)	Coating	Substrate	Stock Number	Price	Buy
6.00	4.38	6.00	Uncoated	Fused Silica	#49-238	₹9,108 Qty 6+ ₹7,318	10 to 12 days
6.00	4.38	6.00	UV-AR (250-425nm)	Fused Silica	#49-246	₹10,743 Qty 6+ ₹8,564	10 to 12 days
6.00	4.38	6.00	UV-VIS (250-700nm)	Fused Silica	#49-254	₹10,743 Qty 6+ ₹8,564	10 to 12 days
6.00	4.38	6.00	VIS-EXT (350-700nm)	Fused Silica	#22-196	₹10,743 Qty 6+ ₹8,564	10 to 12 days
6.00	4.38	6.00	VIS 0° (425-675nm)	Fused Silica	#49-262	₹10,588 Qty 6+ ₹8,486	Contact Us
6.00	4.38	6.00	VIS-NIR (400-1000nm)	Fused Silica	#63-817	₹10,743 Qty 6+ ₹8,564	10 to 12 days
6.00	4.38	6.00	NIR I (600-1050nm)	Fused Silica	#22-156	₹10,588 Qty 6+ ₹8,486	10 to 12 days
6.00	4.38	6.00	NIR II (750-1550nm)	Fused Silica	#22-176	₹10,588 Qty 6+ ₹8,486	10 to 12 days
6.00	8.02	9.00	Uncoated	Fused Silica	#49-239	₹9,108 Qty 6+ ₹7,318	10 to 12 days
6.00	8.02	9.00	UV-AR (250-425nm)	Fused Silica	#49-247	₹10,743 Qty 6+ ₹8,564	10 to 12 days
6.00	8.02	9.00	UV-VIS (250-700nm)	Fused Silica	#49-255	₹10,743 Qty 6+ ₹8,564	10 to 12 days
6.00	8.02	9.00	VIS 0° (425-675nm)	Fused Silica	#49-263	₹10,588 Qty 6+ ₹8,486	10 to 12 days
6.00	8.02	9.00	VIS-NIR (400-1000nm)	Fused Silica	#63-818	₹10,743 Qty 6+ ₹8,564	10 to 12 days
6.00	11.23	12.00	Uncoated	Fused Silica	#49-240	₹9,108 Qty 6+ ₹7,318	10 to 12 days

6.00	11.23	12.00	UV-AR (250-425nm)	Fused Silica	#49-248	₹10,743 Qty 6+ ₹8,564	Contact Us
6.00	11.23	12.00	UV-VIS (250-700nm)	Fused Silica	#49-256	₹10,743 Qty 6+ ₹8,564	10 to 12 days
6.00	11.23	12.00	VIS-EXT (350-700nm)	Fused Silica	#22-195	₹10,743 Qty 6+ ₹8,564	10 to 12 days
6.00	11.23	12.00	VIS 0° (425-675nm)	Fused Silica	#49-264	₹10,588 Qty 6+ ₹8,486	10 to 12 days
6.00	11.23	12.00	VIS-NIR (400-1000nm)	Fused Silica	#63-819	₹10,743 Qty 6+ ₹8,564	10 to 12 days
6.00	11.23	12.00	NIR I (600-1050nm)	Fused Silica	#22-155	₹10,588 Qty 6+ ₹8,486	10 to 12 days
6.00	11.23	12.00	NIR II (750-1550nm)	Fused Silica	#22-175	₹10,588 Qty 6+ ₹8,486	10 to 12 days
6.00	17.30	18.00	Uncoated	Fused Silica	#49-983	₹8,719 Qty 6+ ₹7,007	10 to 12 days
6.00	17.30	18.00	UV-AR (250-425nm)	Fused Silica	#49-987	₹10,354 Qty 6+ ₹8,252	10 to 12 days
6.00	17.30	18.00	UV-VIS (250-700nm)	Fused Silica	#49-991	₹10,354 Qty 6+ ₹8,252	10 to 12 days
6.00	17.30	18.00	VIS 0° (425-675nm)	Fused Silica	#49-995	₹10,198 Qty 6+ ₹8,174	10 to 12 days
6.00	17.30	18.00	VIS-NIR (400-1000nm)	Fused Silica	#63-820	₹10,354 Qty 6+ ₹8,252	10 to 12 days
6.00	23.31	24.00	Uncoated	Fused Silica	#49-984	₹8,719 Qty 6+ ₹7,007	10 to 12 days
6.00	23.31	24.00	UV-AR (250-425nm)	Fused Silica	#49-988	₹10,354 Qty 6+ ₹8,252	10 to 12 days
6.00	23.31	24.00	UV-VIS (250-700nm)	Fused Silica	#49-992	₹10,354 Qty 6+ ₹8,252	Contact Us
6.00	23.31	24.00	VIS 0° (425-675nm)	Fused Silica	#49-996	₹10,198 Qty 6+ ₹8,174	10 to 12 days

6.00	23.31	24.00	VIS-NIR (400-1000nm)	Fused Silica	#63-821	₹10,354 Qty 6+ ₹8,252	10 to 12 days
9.00	7.12	9.00	Uncoated	Fused Silica	#49-241	₹9,342 Qty 6+ ₹7,474	10 to 12 days
9.00	7.12	9.00	UV-AR (250-425nm)	Fused Silica	#49-249	₹10,977 Qty 6+ ₹8,797	10 to 12 days
9.00	7.12	9.00	UV-VIS (250-700nm)	Fused Silica	#49-257	₹10,977 Qty 6+ ₹8,797	10 to 12 days
9.00	7.12	9.00	VIS-EXT (350-700nm)	Fused Silica	#22-200	₹10,977 Qty 6+ ₹8,797	10 to 12 days
9.00	7.12	9.00	VIS 0° (425-675nm)	Fused Silica	#49-265	₹10,821 Qty 6+ ₹8,641	10 to 12 days
9.00	7.12	9.00	VIS-NIR (400-1000nm)	Fused Silica	#63-822	₹10,977 Qty 6+ ₹8,797	10 to 12 days
9.00	7.12	9.00	NIR I (600-1050nm)	Fused Silica	#22-160	₹10,821 Qty 6+ ₹8,641	10 to 12 days
9.00	7.12	9.00	NIR II (750-1550nm)	Fused Silica	#22-180	₹10,821 Qty 6+ ₹8,641	10 to 12 days
9.00	12.32	13.50	Uncoated	Fused Silica	#49-242	₹9,342 Qty 6+ ₹7,474	10 to 12 days
9.00	12.32	13.50	UV-AR (250-425nm)	Fused Silica	#49-250	₹10,977 Qty 6+ ₹8,797	10 to 12 days
9.00	12.32	13.50	UV-VIS (250-700nm)	Fused Silica	#49-258	₹10,977 Qty 6+ ₹8,797	10 to 12 days
9.00	12.32	13.50	VIS-EXT (350-700nm)	Fused Silica	#22-197	₹10,977 Qty 6+ ₹8,797	Contact Us
9.00	12.32	13.50	VIS 0° (425-675nm)	Fused Silica	#49-266	₹10,821 Qty 6+ ₹8,641	10 to 12 days
9.00	12.32	13.50	VIS-NIR (400-1000nm)	Fused Silica	#63-823	₹10,977 Qty 6+ ₹8,797	10 to 12 days
9.00	12.32	13.50	NIR I (600-1050nm)	Fused Silica	#22-157	₹10,821 Qty 6+ ₹8,641	10 to 12 days

9.00	12.32	13.50	NIR II (750-1550nm)	Fused Silica	#22-177	₹10,821 Qty 6+ ₹8,641	10 to 12 days
9.00	17.09	18.00	Uncoated	Fused Silica	#49-243	₹9,342 Qty 6+ ₹7,474	10 to 12 days
9.00	17.09	18.00	UV-AR (250-425nm)	Fused Silica	#49-251	₹10,977 Qty 6+ ₹8,797	10 to 12 days
9.00	17.09	18.00	UV-VIS (250-700nm)	Fused Silica	#49-259	₹10,977 Qty 6+ ₹8,797	Contact Us
9.00	17.09	18.00	VIS-EXT (350-700nm)	Fused Silica	#22-198	₹10,977 Qty 6+ ₹8,797	10 to 12 days
9.00	17.09	18.00	VIS 0° (425-675nm)	Fused Silica	#49-267	₹10,821 Qty 6+ ₹8,641	Contact Us
9.00	17.09	18.00	VIS-NIR (400-1000nm)	Fused Silica	#63-824	₹10,977 Qty 6+ ₹8,797	Contact Us
9.00	17.09	18.00	NIR I (600-1050nm)	Fused Silica	#22-158	₹10,821 Qty 6+ ₹8,641	10 to 12 days
9.00	17.09	18.00	NIR II (750-1550nm)	Fused Silica	#22-178	₹10,821 Qty 6+ ₹8,641	10 to 12 days
9.00	26.13	27.00	Uncoated	Fused Silica	#49-985	₹8,953 Qty 6+ ₹7,162	10 to 12 days
9.00	26.13	27.00	UV-AR (250-425nm)	Fused Silica	#49-989	₹10,588 Qty 6+ ₹8,486	10 to 12 days
9.00	26.13	27.00	UV-VIS (250-700nm)	Fused Silica	#49-993	₹10,588 Qty 6+ ₹8,486	10 to 12 days
9.00	26.13	27.00	VIS-EXT (350-700nm)	Fused Silica	#22-199	₹10,588 Qty 6+ ₹8,486	10 to 12 days
9.00	26.13	27.00	VIS 0° (425-675nm)	Fused Silica	#49-997	₹10,354 Qty 6+ ₹8,252	10 to 12 days
9.00	26.13	27.00	VIS-NIR (400-1000nm)	Fused Silica	#63-825	₹10,588 Qty 6+ ₹8,486	10 to 12 days
9.00	26.13	27.00	NIR I (600-1050nm)	Fused Silica	#22-159	₹10,354 Qty 6+ ₹8,252	10 to 12 days

9.00	26.13	27.00	NIR II (750-1550nm)	Fused Silica	#22-179	₹10,354 Qty 6+ ₹8,252	10 to 12 days
9.00	35.31	36.00	Uncoated	Fused Silica	#49-986	₹8,953 Qty 6+ ₹7,162	10 to 12 days
9.00	35.31	36.00	UV-AR (250-425nm)	Fused Silica	#49-990	₹10,588 Qty 6+ ₹8,486	10 to 12 days
9.00	35.31	36.00	UV-VIS (250-700nm)	Fused Silica	#49-994	₹10,588 Qty 6+ ₹8,486	10 to 12 days
9.00	35.31	36.00	VIS 0° (425-675nm)	Fused Silica	#49-998	₹10,354 Qty 6+ ₹8,252	10 to 12 days
9.00	35.31	36.00	VIS-NIR (400-1000nm)	Fused Silica	#63-826	₹10,588 Qty 6+ ₹8,486	10 to 12 days
12.00	9.25	12.00	Uncoated	Fused Silica	#48-034	₹9,342 Qty 6+ ₹7,474	10 to 12 days
12.00	9.25	12.00	UV-AR (250-425nm)	Fused Silica	#48-040	₹11,210 Qty 6+ ₹8,953	10 to 12 days
12.00	9.25	12.00	UV-VIS (250-700nm)	Fused Silica	#48-834	₹11,210 Qty 6+ ₹8,953	10 to 12 days
12.00	9.25	12.00	VIS-EXT (350-700nm)	Fused Silica	#22-203	₹11,210 Qty 6+ ₹8,953	10 to 12 days
12.00	9.25	12.00	VIS 0° (425-675nm)	Fused Silica	#48-974	₹10,977 Qty 6+ ₹8,797	10 to 12 days
12.00	9.25	12.00	VIS-NIR (400-1000nm)	Fused Silica	#63-827	₹11,210 Qty 6+ ₹8,953	10 to 12 days
12.00	9.25	12.00	NIR I (600-1050nm)	Fused Silica	#22-163	₹10,977 Qty 6+ ₹8,797	10 to 12 days
12.00	9.25	12.00	NIR II (750-1550nm)	Fused Silica	#22-183	₹10,977 Qty 6+ ₹8,797	10 to 12 days
12.00	13.37	15.00	Uncoated	Fused Silica	#49-244	₹9,342 Qty 6+ ₹7,474	10 to 12 days
12.00	13.37	15.00	UV-AR (250-425nm)	Fused Silica	#49-252	₹11,210 Qty 6+ ₹8,953	10 to 12 days

12.00	13.37	15.00	UV-VIS (250-700nm)	Fused Silica	#49-260	₹11,210 Qty 6+ ₹8,953	10 to 12 days
12.00	13.37	15.00	VIS-EXT (350-700nm)	Fused Silica	#22-204	₹11,210 Qty 6+ ₹8,953	10 to 12 days
12.00	13.37	15.00	VIS 0° (425-675nm)	Fused Silica	#49-268	₹10,977 Qty 6+ ₹8,797	10 to 12 days
12.00	13.37	15.00	VIS-NIR (400-1000nm)	Fused Silica	#63-828	₹11,210 Qty 6+ ₹8,953	10 to 12 days
12.00	13.37	15.00	NIR I (600-1050nm)	Fused Silica	#22-164	₹10,977 Qty 6+ ₹8,797	10 to 12 days
12.00	13.37	15.00	NIR II (750-1550nm)	Fused Silica	#22-184	₹10,977 Qty 6+ ₹8,797	10 to 12 days
12.00	18.44	20.00	Uncoated	Fused Silica	#48-035	₹9,342 Qty 6+ ₹7,474	10 to 12 days
12.00	18.44	20.00	UV-AR (250-425nm)	Fused Silica	#48-041	₹11,210 Qty 6+ ₹8,953	Contact Us
12.00	18.44	20.00	UV-VIS (250-700nm)	Fused Silica	#48-835	₹11,210 Qty 6+ ₹8,953	10 to 12 days
12.00	18.44	20.00	VIS-EXT (350-700nm)	Fused Silica	#22-205	₹11,210 Qty 6+ ₹8,953	10 to 12 days
12.00	18.44	20.00	VIS 0° (425-675nm)	Fused Silica	#48-975	₹10,977 Qty 6+ ₹8,797	10 to 12 days
12.00	18.44	20.00	VIS-NIR (400-1000nm)	Fused Silica	#63-829	₹11,210 Qty 6+ ₹8,953	10 to 12 days
12.00	18.44	20.00	NIR I (600-1050nm)	Fused Silica	#22-165	₹10,977 Qty 6+ ₹8,797	10 to 12 days
12.00	18.44	20.00	NIR II (750-1550nm)	Fused Silica	#22-185	₹10,977 Qty 6+ ₹8,797	10 to 12 days
12.00	22.92	24.00	Uncoated	Fused Silica	#49-245	₹9,342 Qty 6+ ₹7,474	10 to 12 days
12.00	22.92	24.00	UV-AR (250-425nm)	Fused Silica	#49-253	₹11,210 Qty 6+ ₹8,953	Contact Us

12.00	22.92	24.00	UV-VIS (250-700nm)	Fused Silica	#49-261	₹11,210 Qty 6+ ₹8,953	10 to 12 days
12.00	22.92	24.00	VIS-EXT (350-700nm)	Fused Silica	#22-206	₹11,210 Qty 6+ ₹8,953	10 to 12 days
12.00	22.92	24.00	VIS 0° (425-675nm)	Fused Silica	#49-269	₹10,977 Qty 6+ ₹8,797	10 to 12 days
12.00	22.92	24.00	VIS-NIR (400-1000nm)	Fused Silica	#63-830	₹11,210 Qty 6+ ₹8,953	10 to 12 days
12.00	22.92	24.00	NIR I (600-1050nm)	Fused Silica	#22-166	₹10,977 Qty 6+ ₹8,797	10 to 12 days
12.00	22.92	24.00	NIR II (750-1550nm)	Fused Silica	#22-186	₹10,977 Qty 6+ ₹8,797	10 to 12 days
12.00	28.77	30.00	Uncoated	Fused Silica	#48-036	₹8,875 Qty 6+ ₹7,084	10 to 12 days
12.00	28.77	30.00	UV-AR (250-425nm)	Fused Silica	#48-042	₹10,743 Qty 6+ ₹8,564	10 to 12 days
12.00	28.77	30.00	UV-VIS (250-700nm)	Fused Silica	#48-836	₹10,743 Qty 6+ ₹8,564	10 to 12 days
12.00	28.77	30.00	VIS-EXT (350-700nm)	Fused Silica	#22-201	₹10,743 Qty 6+ ₹8,564	10 to 12 days
12.00	28.77	30.00	VIS 0° (425-675nm)	Fused Silica	#48-976	₹10,510 Qty 6+ ₹8,408	10 to 12 days
12.00	28.77	30.00	VIS-NIR (400-1000nm)	Fused Silica	#63-831	₹10,743 Qty 6+ ₹8,564	10 to 12 days
12.00	28.77	30.00	NIR I (600-1050nm)	Fused Silica	#22-161	₹10,510 Qty 6+ ₹8,408	10 to 12 days
12.00	28.77	30.00	NIR II (750-1550nm)	Fused Silica	#22-181	₹10,510 Qty 6+ ₹8,408	10 to 12 days
12.00	33.85	35.00	Uncoated	Fused Silica	#48-037	₹8,875 Qty 6+ ₹7,084	10 to 12 days
12.00	33.85	35.00	UV-AR (250-425nm)	Fused Silica	#48-043	₹10,743 Qty 6+ ₹8,564	10 to 12 days

12.00	33.85	35.00	UV-VIS (250-700nm)	Fused Silica	#48-837	₹10,743 Qty 6+ ₹8,564	Contact Us
12.00	33.85	35.00	VIS-EXT (350-700nm)	Fused Silica	#22-202	₹10,743 Qty 6+ ₹8,564	10 to 12 days
12.00	33.85	35.00	VIS 0° (425-675nm)	Fused Silica	#48-977	₹10,510 Qty 6+ ₹8,408	10 to 12 days
12.00	33.85	35.00	VIS-NIR (400-1000nm)	Fused Silica	#63-832	₹10,743 Qty 6+ ₹8,564	10 to 12 days
12.00	33.85	35.00	NIR I (600-1050nm)	Fused Silica	#22-162	₹10,510 Qty 6+ ₹8,408	10 to 12 days
12.00	33.85	35.00	NIR II (750-1550nm)	Fused Silica	#22-182	₹10,510 Qty 6+ ₹8,408	10 to 12 days
12.00	43.96	45.00	Uncoated	Fused Silica	#48-038	₹8,875 Qty 6+ ₹7,084	10 to 12 days
12.00	43.96	45.00	UV-AR (250-425nm)	Fused Silica	#48-044	₹10,743 Qty 6+ ₹8,564	10 to 12 days
12.00	43.96	45.00	UV-VIS (250-700nm)	Fused Silica	#48-838	₹10,743 Qty 6+ ₹8,564	Contact Us
12.00	43.96	45.00	VIS 0° (425-675nm)	Fused Silica	#48-978	₹10,510 Qty 6+ ₹8,408	10 to 12 days
12.00	43.96	45.00	VIS-NIR (400-1000nm)	Fused Silica	#63-833	₹10,743 Qty 6+ ₹8,564	10 to 12 days
12.00	74.11	75.00	Uncoated	Fused Silica	#48-039	₹8,875 Qty 6+ ₹7,084	10 to 12 days
12.00	74.11	75.00	UV-VIS (250-700nm)	Fused Silica	#48-839	₹10,743 Qty 6+ ₹8,564	10 to 12 days
12.00	74.11	75.00	UV-AR (250-425nm)	Fused Silica	#48-045	₹10,743 Qty 6+ ₹8,564	10 to 12 days
12.00	74.11	75.00	VIS-EXT (350-700nm)	Fused Silica	#22-207	₹10,743 Qty 6+ ₹8,564	10 to 12 days
12.00	74.11	75.00	VIS 0° (425-675nm)	Fused Silica	#48-979	₹10,510 Qty 6+ ₹8,408	10 to 12 days

12.00	74.11	75.00	VIS-NIR (400-1000nm)	Fused Silica	#63-834	₹10,743 Qty 6+ ₹8,564	10 to 12 days
12.00	74.11	75.00	NIR I (600-1050nm)	Fused Silica	#22-167	₹10,510 Qty 6+ ₹8,408	10 to 12 days
12.00	74.11	75.00	NIR II (750-1550nm)	Fused Silica	#22-187	₹10,510 Qty 6+ ₹8,408	10 to 12 days
18.00	17.18	20.00	Uncoated	Fused Silica	#08-083	₹9,965 Qty 6+ ₹7,941	10 to 12 days
18.00	17.18	20.00	UV-AR (250-425nm)	Fused Silica	#46-290	₹11,755 Qty 6+ ₹9,420	10 to 12 days
18.00	17.18	20.00	UV-VIS (250-700nm)	Fused Silica	#48-840	₹11,755 Qty 6+ ₹9,420	10 to 12 days
18.00	17.18	20.00	VIS-EXT (350-700nm)	Fused Silica	#22-208	₹11,755 Qty 6+ ₹9,420	10 to 12 days
18.00	17.18	20.00	VIS 0° (425-675nm)	Fused Silica	#48-980	₹11,600 Qty 6+ ₹9,264	10 to 12 days
18.00	17.18	20.00	VIS-NIR (400-1000nm)	Fused Silica	#63-835	₹11,755 Qty 6+ ₹9,420	10 to 12 days
18.00	17.18	20.00	NIR I (600-1050nm)	Fused Silica	#22-168	₹11,600 Qty 6+ ₹9,264	10 to 12 days
18.00	17.18	20.00	NIR II (750-1550nm)	Fused Silica	#22-188	₹11,600 Qty 6+ ₹9,264	10 to 12 days
18.00	38.50	40.00	Uncoated	Fused Silica	#08-084	₹9,965 Qty 6+ ₹7,941	10 to 12 days
18.00	38.50	40.00	UV-AR (250-425nm)	Fused Silica	#46-291	₹11,755 Qty 6+ ₹9,420	10 to 12 days
18.00	38.50	40.00	UV-VIS (250-700nm)	Fused Silica	#48-841	₹11,755 Qty 6+ ₹9,420	Contact Us
18.00	38.50	40.00	VIS-EXT (350-700nm)	Fused Silica	#22-209	₹11,755 Qty 6+ ₹9,420	10 to 12 days
18.00	38.50	40.00	VIS 0° (425-675nm)	Fused Silica	#48-981	₹11,600 Qty 6+ ₹9,264	10 to 12 days

18.00	38.50	40.00	VIS-NIR (400-1000nm)	Fused Silica	#63-836	₹11,755 Qty 6+ ₹9,420	10 to 12 days
18.00	38.50	40.00	NIR I (600-1050nm)	Fused Silica	#22-169	₹11,600 Qty 6+ ₹9,264	10 to 12 days
18.00	38.50	40.00	NIR II (750-1550nm)	Fused Silica	#22-189	₹11,600 Qty 6+ ₹9,264	10 to 12 days
25.00	20.93	25.00	Uncoated	Fused Silica	#48-293	₹10,510 Qty 6+ ₹8,408	7 days
25.00	20.93	25.00	UV-AR (250-425nm)	Fused Silica	#48-304	₹12,300 Qty 6+ ₹9,809	Contact Us
25.00	20.93	25.00	UV-VIS (250-700nm)	Fused Silica	#48-842	₹12,300 Qty 6+ ₹9,809	10 to 12 days
25.00	20.93	25.00	VIS-EXT (350-700nm)	Fused Silica	#22-212	₹12,300 Qty 6+ ₹9,809	10 to 12 days
25.00	20.93	25.00	VIS 0° (425-675nm)	Fused Silica	#48-982	₹12,145 Qty 6+ ₹9,731	10 to 12 days
25.00	20.93	25.00	VIS-NIR (400-1000nm)	Fused Silica	#63-837	₹12,300 Qty 6+ ₹9,809	10 to 12 days
25.00	20.93	25.00	NIR I (600-1050nm)	Fused Silica	#22-172	₹12,145 Qty 6+ ₹9,731	10 to 12 days
25.00	20.93	25.00	NIR II (750-1550nm)	Fused Silica	#22-192	₹12,145 Qty 6+ ₹9,731	10 to 12 days
25.00	48.02	50.00	Uncoated	Fused Silica	#48-294	₹10,510 Qty 6+ ₹8,408	10 to 12 days
25.00	48.02	50.00	UV-AR (250-425nm)	Fused Silica	#48-305	₹12,300 Qty 6+ ₹9,809	10 to 12 days
25.00	48.02	50.00	UV-VIS (250-700nm)	Fused Silica	#48-843	₹12,300 Qty 6+ ₹9,809	10 to 12 days
25.00	48.02	50.00	VIS-EXT (350-700nm)	Fused Silica	#22-213	₹12,300 Qty 6+ ₹9,809	10 to 12 days
25.00	48.02	50.00	VIS 0° (425-675nm)	Fused Silica	#48-983	₹12,145 Qty 6+ ₹9,731	10 to 12 days

25.00	48.02	50.00	VIS-NIR (400-1000nm)	Fused Silica	#63-838	₹12,300 Qty 6+ ₹9,809	10 to 12 days
25.00	48.02	50.00	NIR I (600-1050nm)	Fused Silica	#22-173	₹12,145 Qty 6+ ₹9,731	10 to 12 days
25.00	48.02	50.00	NIR II (750-1550nm)	Fused Silica	#22-193	₹12,145 Qty 6+ ₹9,731	10 to 12 days
25.00	58.08	60.00	Uncoated	Fused Silica	#48-295	₹10,121 Qty 6+ ₹8,096	10 to 12 days
25.00	58.08	60.00	UV-AR (250-425nm)	Fused Silica	#48-306	₹11,911 Qty 6+ ₹9,498	10 to 12 days
25.00	58.08	60.00	UV-VIS (250-700nm)	Fused Silica	#48-844	₹11,911 Qty 6+ ₹9,498	10 to 12 days
25.00	58.08	60.00	VIS-EXT (350-700nm)	Fused Silica	#22-214	₹11,911 Qty 6+ ₹9,498	10 to 12 days
25.00	58.08	60.00	VIS 0° (425-675nm)	Fused Silica	#48-984	₹11,755 Qty 6+ ₹9,420	10 to 12 days
25.00	58.08	60.00	VIS-NIR (400-1000nm)	Fused Silica	#63-839	₹11,911 Qty 6+ ₹9,498	10 to 12 days
25.00	58.08	60.00	NIR I (600-1050nm)	Fused Silica	#22-174	₹11,755 Qty 6+ ₹9,420	10 to 12 days
25.00	58.08	60.00	NIR II (750-1550nm)	Fused Silica	#22-194	₹11,755 Qty 6+ ₹9,420	Contact Us
25.00	73.91	75.60	Uncoated	Fused Silica	#48-296	₹10,121 Qty 6+ ₹8,096	10 to 12 days
25.00	73.91	75.60	UV-AR (250-425nm)	Fused Silica	#48-307	₹11,911 Qty 6+ ₹9,498	10 to 12 days
25.00	73.91	75.60	UV-VIS (250-700nm)	Fused Silica	#48-845	₹11,911 Qty 6+ ₹9,498	10 to 12 days
25.00	73.91	75.60	VIS-EXT (350-700nm)	Fused Silica	#22-210	₹11,911 Qty 6+ ₹9,498	10 to 12 days
25.00	73.91	75.60	VIS 0° (425-675nm)	Fused Silica	#48-985	₹11,755 Qty 6+ ₹9,420	10 to 12 days

25.00	73.91	75.60	VIS-NIR (400-1000nm)	Fused Silica	#63-840	₹11,911 Qty 6+ ₹9,498	10 to 12 days
25.00	73.91	75.60	NIR I (600-1050nm)	Fused Silica	#22-170	₹11,755 Qty 6+ ₹9,420	10 to 12 days
25.00	73.91	75.60	NIR II (750-1550nm)	Fused Silica	#22-190	₹11,755 Qty 6+ ₹9,420	10 to 12 days
25.00	98.70	100.00	Uncoated	Fused Silica	#48-297	₹10,121 Qty 6+ ₹8,096	10 to 12 days
25.00	98.70	100.00	UV-AR (250-425nm)	Fused Silica	#48-308	₹11,911 Qty 6+ ₹9,498	10 to 12 days
25.00	98.70	100.00	UV-VIS (250-700nm)	Fused Silica	#48-846	₹11,911 Qty 6+ ₹9,498	10 to 12 days
25.00	98.70	100.00	VIS-EXT (350-700nm)	Fused Silica	#22-211	₹11,911 Qty 6+ ₹9,498	10 to 12 days
25.00	98.70	100.00	VIS 0° (425-675nm)	Fused Silica	#48-986	₹11,755 Qty 6+ ₹9,420	10 to 12 days
25.00	98.70	100.00	VIS-NIR (400-1000nm)	Fused Silica	#63-841	₹11,911 Qty 6+ ₹9,498	10 to 12 days
25.00	98.70	100.00	NIR I (600-1050nm)	Fused Silica	#22-171	₹11,755 Qty 6+ ₹9,420	10 to 12 days
25.00	98.70	100.00	NIR II (750-1550nm)	Fused Silica	#22-191	₹11,755 Qty 6+ ₹9,420	10 to 12 days
25.00	123.82	125.00	Uncoated	Fused Silica	#48-298	₹9,653 Qty 6+ ₹7,707	10 to 12 days
25.00	123.82	125.00	UV-AR (250-425nm)	Fused Silica	#48-309	₹11,522 Qty 6+ ₹9,186	10 to 12 days
25.00	123.82	125.00	UV-VIS (250-700nm)	Fused Silica	#48-847	₹11,522 Qty 6+ ₹9,186	10 to 12 days
25.00	123.82	125.00	VIS 0° (425-675nm)	Fused Silica	#48-987	₹11,288 Qty 6+ ₹9,031	10 to 12 days
25.00	123.82	125.00	VIS-NIR (400-1000nm)	Fused Silica	#63-842	₹11,522 Qty 6+ ₹9,186	10 to 12 days

25.00	148.37	150.00	Uncoated	Fused Silica	#48-299	₹9,653 Qty 6+ ₹7,707	10 to 12 days
25.00	148.37	150.00	UV-AR (250-425nm)	Fused Silica	#48-310	₹11,522 Qty 6+ ₹9,186	10 to 12 days
25.00	148.37	150.00	UV-VIS (250-700nm)	Fused Silica	#48-848	₹11,522 Qty 6+ ₹9,186	10 to 12 days
25.00	148.37	150.00	VIS 0° (425-675nm)	Fused Silica	#48-988	₹11,288 Qty 6+ ₹9,031	10 to 12 days
25.00	148.37	150.00	VIS-NIR (400-1000nm)	Fused Silica	#63-843	₹11,522 Qty 6+ ₹9,186	10 to 12 days
25.00	198.84	200.00	Uncoated	Fused Silica	#48-300	₹9,653 Qty 6+ ₹7,707	10 to 12 days
25.00	198.84	200.00	UV-AR (250-425nm)	Fused Silica	#48-311	₹11,522 Qty 6+ ₹9,186	10 to 12 days
25.00	198.84	200.00	UV-VIS (250-700nm)	Fused Silica	#48-849	₹11,522 Qty 6+ ₹9,186	10 to 12 days
25.00	198.84	200.00	VIS 0° (425-675nm)	Fused Silica	#48-989	₹11,288 Qty 6+ ₹9,031	10 to 12 days
25.00	198.84	200.00	VIS-NIR (400-1000nm)	Fused Silica	#63-844	₹11,522 Qty 6+ ₹9,186	10 to 12 days
25.00	248.90	250.00	Uncoated	Fused Silica	#48-301	₹9,653 Qty 6+ ₹7,707	10 to 12 days
25.00	248.90	250.00	UV-AR (250-425nm)	Fused Silica	#48-312	₹11,522 Qty 6+ ₹9,186	10 to 12 days
25.00	248.90	250.00	UV-VIS (250-700nm)	Fused Silica	#48-850	₹11,522 Qty 6+ ₹9,186	Contact Us
25.00	248.90	250.00	VIS 0° (425-675nm)	Fused Silica	#48-990	₹11,288 Qty 6+ ₹9,031	10 to 12 days
25.00	248.90	250.00	VIS-NIR (400-1000nm)	Fused Silica	#63-845	₹11,522 Qty 6+ ₹9,186	10 to 12 days
25.00	298.94	300.00	Uncoated	Fused Silica	#48-302	₹9,653 Qty 6+ ₹7,707	10 to 12 days

25.00	298.94	300.00	UV-AR (250-425nm)	Fused Silica	#48-313	₹11,522 Qty 6+ ₹9,186	10 to 12 days
25.00	298.94	300.00	UV-VIS (250-700nm)	Fused Silica	#48-851	₹11,522 Qty 6+ ₹9,186	10 to 12 days
25.00	298.94	300.00	VIS 0° (425-675nm)	Fused Silica	#48-991	₹11,288 Qty 6+ ₹9,031	10 to 12 days
25.00	298.94	300.00	VIS-NIR (400-1000nm)	Fused Silica	#63-846	₹11,522 Qty 6+ ₹9,186	10 to 12 days
25.00	498.85	500.00	Uncoated	Fused Silica	#48-303	₹9,653 Qty 6+ ₹7,707	10 to 12 days
25.00	498.85	500.00	UV-AR (250-425nm)	Fused Silica	#48-314	₹11,522 Qty 6+ ₹9,186	Contact Us
25.00	498.85	500.00	UV-VIS (250-700nm)	Fused Silica	#48-852	₹11,522 Qty 6+ ₹9,186	10 to 12 days
25.00	498.85	500.00	VIS 0° (425-675nm)	Fused Silica	#48-992	₹11,288 Qty 6+ ₹9,031	10 to 12 days
25.00	498.85	500.00	VIS-NIR (400-1000nm)	Fused Silica	#63-847	₹11,522 Qty 6+ ₹9,186	10 to 12 days
30.00	25.12	30.00	Uncoated	Fused Silica	#22-413	₹12,067 Qty 6+ ₹9,653	10 to 12 days
30.00	25.12	30.00	UV-AR (250-425nm)	Fused Silica	#26-600	₹14,402 Qty 6+ ₹11,522	10 to 12 days
30.00	25.12	30.00	UV-VIS (250-700nm)	Fused Silica	#26-606	₹14,013 Qty 6+ ₹11,210	10 to 12 days
30.00	25.12	30.00	VIS 0° (425-675nm)	Fused Silica	#26-612	₹14,402 Qty 6+ ₹11,522	10 to 12 days
30.00	25.12	30.00	VIS-NIR (400-1000nm)	Fused Silica	#26-618	₹14,402 Qty 6+ ₹11,522	10 to 12 days
40.00	33.49	40.00	Uncoated	Fused Silica	#22-420	₹13,468 Qty 6+ ₹10,743	10 to 12 days

40.00	33.49	40.00	UV-AR (250-425nm)	Fused Silica	#26-601	₹16,037 Qty 6+ ₹12,845	10 to 12 days
40.00	33.49	40.00	UV-VIS (250-700nm)	Fused Silica	#26-607	₹15,648 Qty 6+ ₹12,534	10 to 12 days
40.00	33.49	40.00	VIS 0° (425-675nm)	Fused Silica	#26-613	₹16,037 Qty 6+ ₹12,845	10 to 12 days
40.00	33.49	40.00	VIS-NIR (400-1000nm)	Fused Silica	#26-619	₹16,037 Qty 6+ ₹12,845	10 to 12 days
50.00	41.87	50.00	Uncoated	Fused Silica	#22-426	₹22,654 Qty 6+ ₹18,139	10 to 12 days
50.00	41.87	50.00	UV-AR (250-425nm)	Fused Silica	#26-602	₹24,990 Qty 6+ ₹20,007	Contact Us
50.00	41.87	50.00	UV-VIS (250-700nm)	Fused Silica	#26-608	₹24,601 Qty 6+ ₹19,696	10 to 12 days
50.00	41.87	50.00	VIS 0° (425-675nm)	Fused Silica	#26-614	₹24,990 Qty 6+ ₹20,007	10 to 12 days
50.00	41.87	50.00	VIS-NIR (400-1000nm)	Fused Silica	#26-620	₹24,990 Qty 6+ ₹20,007	10 to 12 days
50.00	97.13	100.00	Uncoated	Fused Silica	#22-427	₹22,654 Qty 6+ ₹18,139	10 to 12 days
50.00	97.13	100.00	UV-AR (250-425nm)	Fused Silica	#26-603	₹24,990 Qty 6+ ₹20,007	10 to 12 days
50.00	97.13	100.00	UV-VIS (250-700nm)	Fused Silica	#26-609	₹24,601 Qty 6+ ₹19,696	10 to 12 days
50.00	97.13	100.00	VIS 0° (425-675nm)	Fused Silica	#26-615	₹24,990 Qty 6+ ₹20,007	10 to 12 days
50.00	97.13	100.00	VIS-NIR (400-1000nm)	Fused Silica	#26-621	₹24,990 Qty 6+ ₹20,007	Contact Us
50.00	148.00	150.00	Uncoated	Fused Silica	#22-428	₹22,654 Qty 6+ ₹18,139	10 to 12 days

50.00	148.00	150.00	UV-AR (250-425nm)	Fused Silica	#26-604	₹24,990 Qty 6+ ₹20,007	10 to 12 days
50.00	148.00	150.00	UV-VIS (250-700nm)	Fused Silica	#26-610	₹24,601 Qty 6+ ₹19,696	10 to 12 days
50.00	148.00	150.00	VIS 0° (425-675nm)	Fused Silica	#26-616	₹24,990 Qty 6+ ₹20,007	10 to 12 days
50.00	148.00	150.00	VIS-NIR (400-1000nm)	Fused Silica	#26-622	₹24,990 Qty 6+ ₹20,007	10 to 12 days
50.00	198.39	200.00	Uncoated	Fused Silica	#22-429	₹22,654 Qty 6+ ₹18,139	10 to 12 days
50.00	198.39	200.00	UV-AR (250-425nm)	Fused Silica	#26-605	₹24,990 Qty 6+ ₹20,007	10 to 12 days
50.00	198.39	200.00	UV-VIS (250-700nm)	Fused Silica	#26-611	₹24,601 Qty 6+ ₹19,696	10 to 12 days
50.00	198.39	200.00	VIS 0° (425-675nm)	Fused Silica	#26-617	₹24,990 Qty 6+ ₹20,007	10 to 12 days
50.00	198.39	200.00	VIS-NIR (400-1000nm)	Fused Silica	#26-623	₹24,990 Qty 6+ ₹20,007	10 to 12 days



Copyright 2023, Edmund Optics India Private Limited, #267, Greystone Building, Second Floor, 6th Cross Rd, Binnamangala, Stage 1, Indiranagar, Bengaluru, Karnataka, India 560038

Phone: 1-800-363-1992 :

www.edmundoptics.com