


[All Products](#) / [Optics](#) / [Optical Lenses](#) / [Fresnel Lenses](#)

Lenticular Arrays


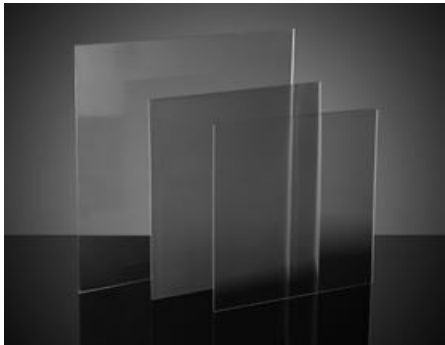


- Arrays of Conventional Cylinder Lenses
- Used as High-Efficiency Diffusers
- Cylindrical Axis of Lenslet is Aligned Along the First Dimension

Common Specifications

Physical & Mechanical Properties			
Dimensional Tolerance (inches):		±0.05	Thickness Tolerance (%):
			±40
Optical Properties			
Substrate:		Acrylic	Coating:
			Uncoated
Wavelength Range (nm):		400 - 1100	Index of Refraction (n _d):
			1.49
Environmental & Durability Factors			
Operating Temperature (°C):		80 (Maximum)	

Technical Information

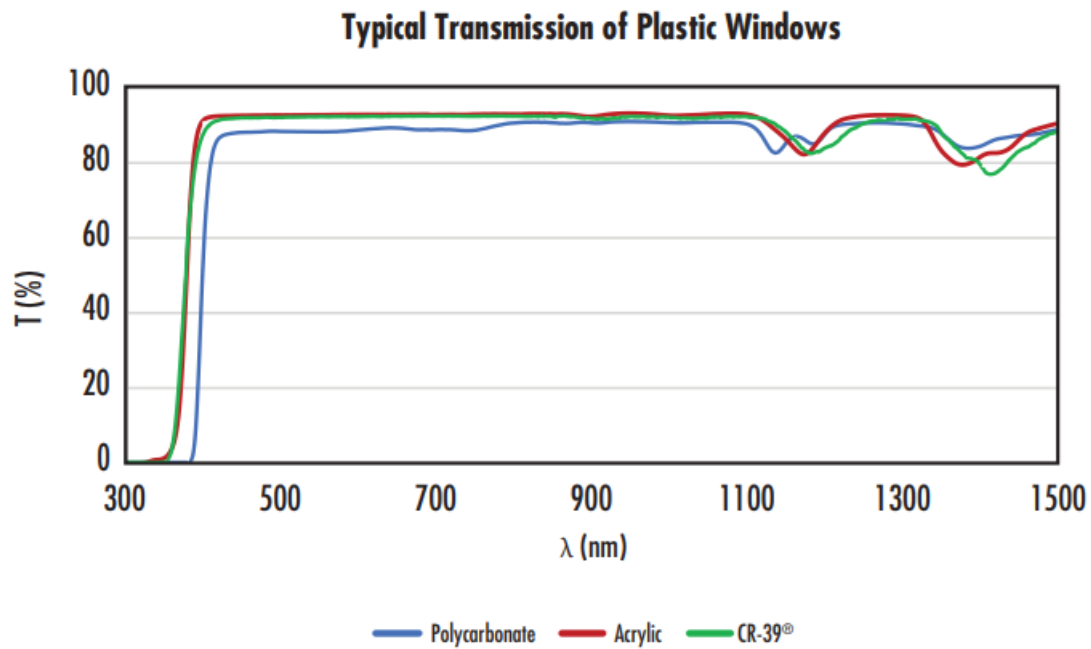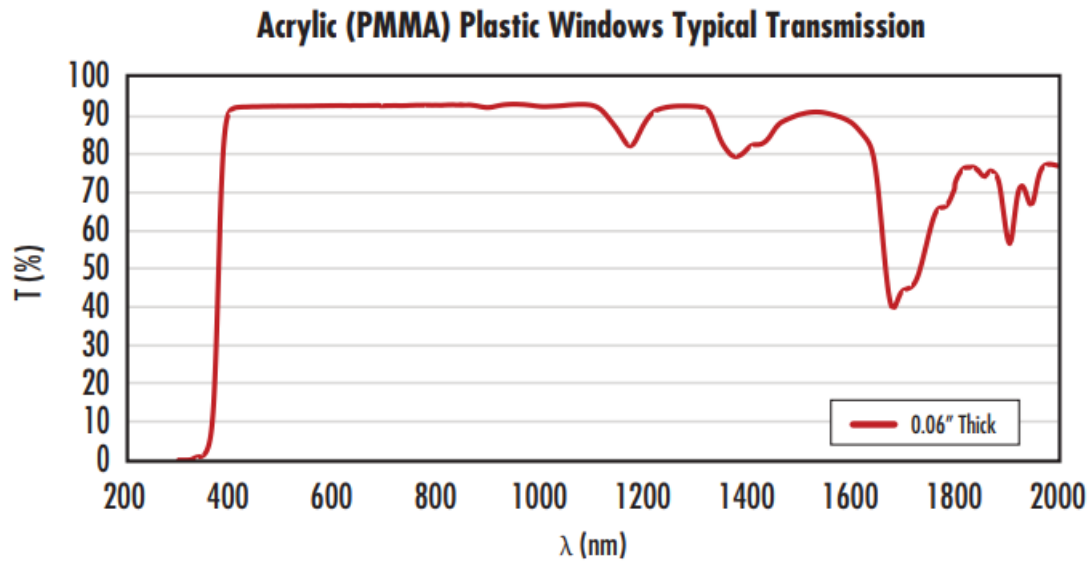

Products

Dimensions (inches)	EFL (inches)	Stock Number	Price	Buy
11 x 11	0.085	#43-028	₹10,276 Qty 11+ ₹9,264	10 to 12 days
12 x 12	0.01	#43-029	₹10,276 Qty 11+ ₹9,264	10 to 12 days
15 x 15	0.09	#43-027	₹21,097 Qty 11+ ₹18,995	10 to 12 days
9.75 x 13	0.41	#43-026	₹10,276 Qty 11+ ₹9,264	10 to 12 days



Copyright 2023, Edmund Optics India Private Limited, #267, Greystone Building, Second Floor, 6th Cross Rd, Binnamangala, Stage 1, Indiranagar, Bengaluru, Karnataka, India 560038

Phone: 1-800-363-1992 :

www.edmundoptics.com