

[All Products](#) / [Optics](#) / [Beamsplitters](#) / [Cube Beamsplitters](#)

TECHSPEC® C-Mounted Cube Beamsplitters



- Simplifies Mounting and Alignment
- Standard Female C-Mount Threaded Holes
- Additional C-Mounted [Beamsplitters](#), [Filters](#), and [Mirrors](#) Available

Common Specifications

Physical & Mechanical Properties

Construction:	Cube	Dimensions (mm):	38.0 x 38.0 x 50.0
Extension Length (mm):	38.0	Housing:	Black Anodized Aluminum


Optical Properties

Reflection/Transmission Ratio (R/T):	50/50	Reflection/Transmission Tolerance (%):	±5
Substrate:	N-BK7	Power (fringes) @ 632.8nm:	1.25
Irregularity (fringes) @ 632.8nm:	0.25		

Threading & Mounting

Mount:	C-Mount Enclosure
Thread Type:	C-Mount (1" x 32 TPI)

Technical Information

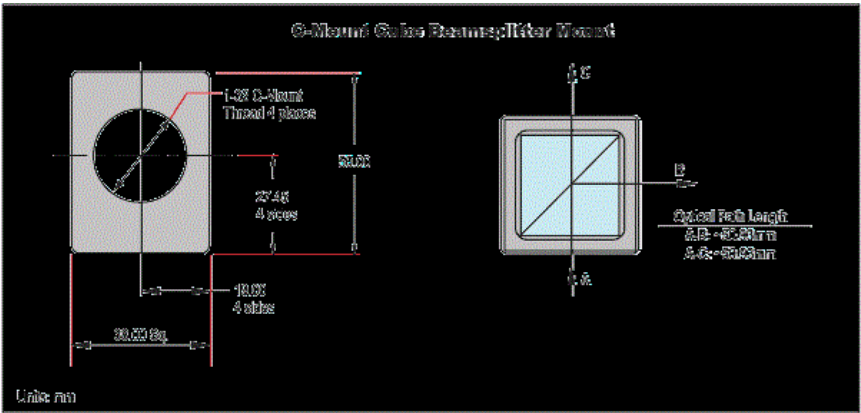

Products

Dimensions (mm)	Wavelength Range (nm)	Reflection/Transmission Ratio (R/T)	Type of Optics	Stock Number	Price	Buy
38.0 x 38.0 x 50.0	400 - 700	50/50	Standard Cube Beamsplitter	#54-823	₹30,060 Qty 5+ ₹24,300	Contact Us
38.0 x 38.0 x 50.0	430 - 670	50/50	Non-Polarizing Cube Beamsplitter, VIS Coating	#49-682	₹37,440 Qty 5+ ₹30,330	10 to 12 days
38.0 x 38.0 x 50.0	720 - 1080	50/50	Non-Polarizing Cube Beamsplitter, NIR Coating	#49-683	₹39,150 Qty 5+ ₹31,680	10 to 12 days



Copyright 2023, Edmund Optics India Private Limited, #267, Greystone Building, Second Floor, 6th Cross Rd, Binnamangala, Stage 1, Indiranagar, Bengaluru, Karnataka, India 560038
Phone: 1-800-363-1992 : www.edmundoptics.com