

[All Products](#) / [Optomechanics](#) / [Manual Translation Stages and Slides](#) / [Manual Stages and Slides](#)

Miniature Screw Drive Stages



- 8-32 or M4 Mounting Options Available
- Up to 19mm of Linear Travel
- Three-Start Screw Drive and Precision Lapped Surfaces for Smooth, Accurate Movement

Common Specifications


Physical & Mechanical Properties

Type of Movement:	Linear (X)	Guide System:	Dovetail
Stage Size (mm):	12 x 35	Travel (mm):	19
Height (mm):	25	Load Capacity (kg):	3 (Horizontal)
Straight Line Accuracy (µm):	100	Travel Per Knob Rotation (mm):	3
Table Size (mm):	12 x 30		

Hardware & Interface Connectivity

Type of Drive:	Three Start Screw Drive
-----------------------	-------------------------

Technical Information

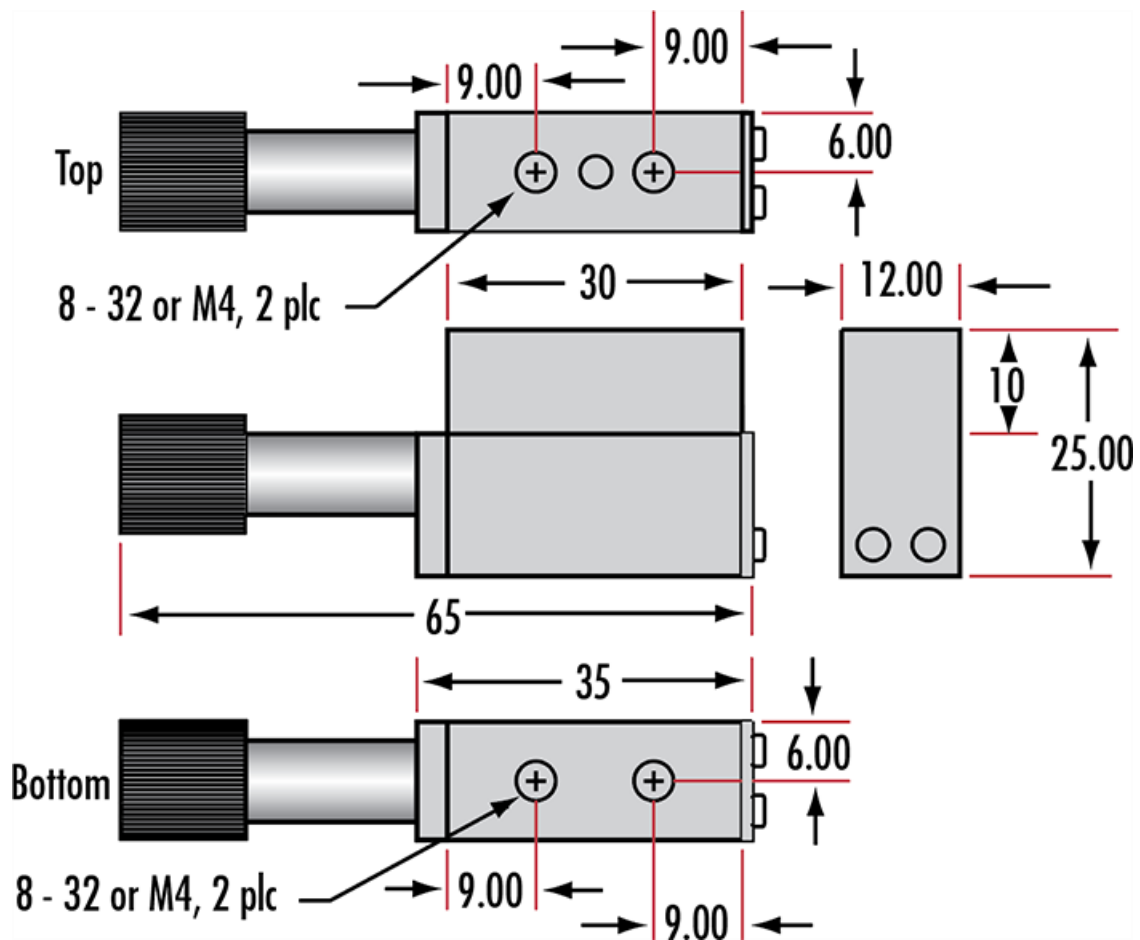

Products

Type	Type of Drive	Travel (mm)	Stock Number	Price	Buy
English	Three Start Screw Drive	19	#53-383	₹12,176 Qty 10+ ₹10,753	10 to 12 days
Metric	Three Start Screw Drive	19	#12-651	₹12,176 Qty 10+ ₹10,753	10 to 12 days



Copyright 2023, Edmund Optics India Private Limited, #267, Greystone Building, Second Floor, 6th Cross Rd, Binnamangala, Stage 1, Indiranagar, Bengaluru, Karnataka, India 560038

Phone: 1-800-363-1992 :

www.edmundoptics.com