

[All Products](#) / [Imaging Lenses](#) / [Variable Magnification Lenses](#)

Infiniprobe™ UV Microscopes

See More by [Infinity Photo-Optical Company](#)



- Available in Standard and Right Angle Versions
- Magnification Range from 0X to 8.0X
- Max. 2/3" Sensor Format
- Direct Video C-Mount Coupling
- No Adapters Required

Common Specifications

Sensor

Maximum Sensor Format:


2/3"

Threading & Mounting


Mount:

C-Mount


Infiniprobe™ UV Video Microscopes Right Angle Configuration

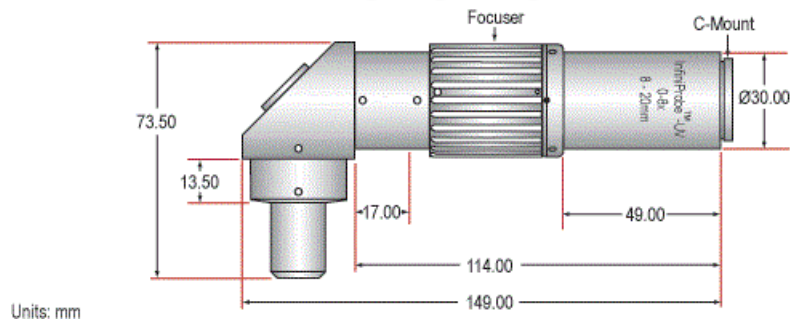

Infiniprobe™ UV Video Microscopes Standard Configuration

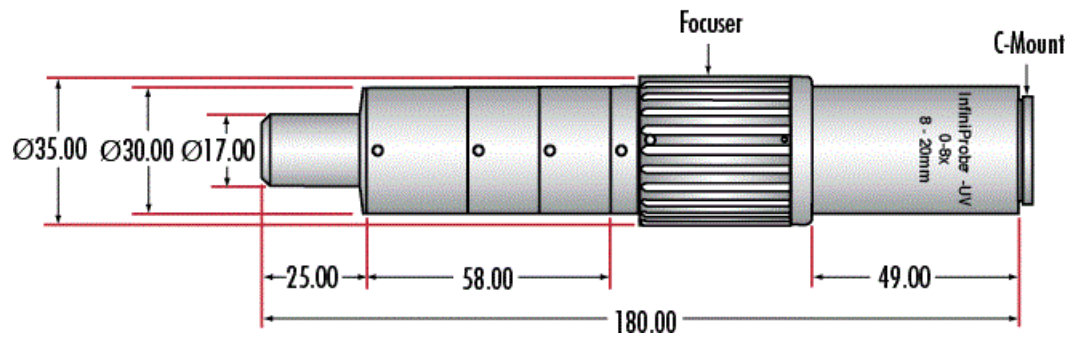

Standard S-32 Configuration

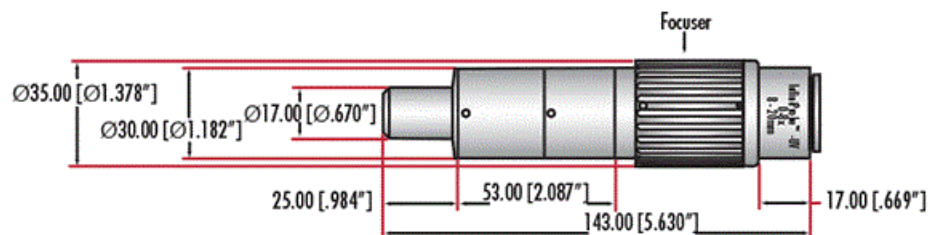

Products

Title	Stock Number	Price	Buy
Infiniprobe S-80 UV Video Microscope	#58-946	₹3,77,550	Contact Us
Infiniprobe N-80 UV Right Angle Video Microscope	#59-121	₹4,13,550	Contact Us
Infiniprobe S-32 UV Video Microscope	#62-853	₹3,10,500	Contact Us
Infiniprobe N-32 UV Right Angle Video Microscope	#62-854	₹3,44,250	Contact Us



Copyright 2023, Edmund Optics India Private Limited, #267, Greystone Building, Second Floor, 6th Cross Rd, Binnamangala, Stage 1, Indiranagar, Bengaluru, Karnataka, India 560038

Phone: 1-800-363-1992 :

www.edmundoptics.com