

[All Products](#) / [Optics](#) / [Optical Lenses](#) / [Plano-Convex \(PCX\) Lenses](#) / [Standard Plano-Convex \(PCX\) Lenses](#)

TECHSPEC® NIR I Coated Plano-Convex (PCX) Lenses



- AR Coated to Provide <0.5% Reflectance per Surface for 600 - 1050nm
- Designed for 0° Angle of Incidence
- Various PCX Coating Options: [Uncoated](#), [MgF₂](#), [VIS 0°](#), [VIS-NIR](#), [NIR II](#), [VIS-EXT](#), and [YAG-BBAR](#)

Common Specifications

Physical & Mechanical Properties

Bevel: Protective as needed


Optical Properties

Coating: NIR I (600-1050nm)

Focal Length Tolerance (%): ±1

Wavelength Range (nm): 600 - 1050

Technical Information

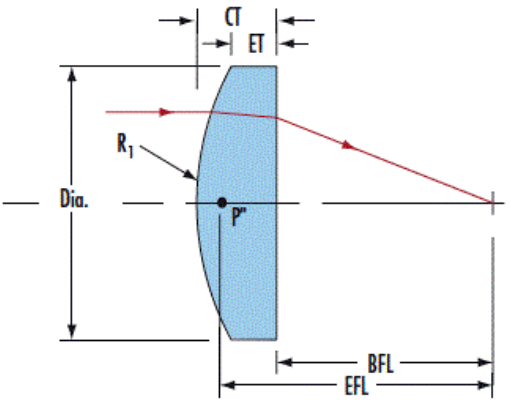

Products

Dia. (mm)	EFL (mm)	BFL (mm)	Coating	Substrate	Stock Number	Price	Buy
1.00	0.60	0.17	NIR I (600-1050nm)	N-LASF9	#45-951	₹6,228 Volume Pricing	Contact Us
1.00	1.00	0.57	NIR I (600-1050nm)	N-LASF9	#45-952	₹6,228 Volume Pricing	5 In Stock
1.00	1.50	1.07	NIR I (600-1050nm)	N-LASF9	#65-305	₹6,228 Volume Pricing	Contact Us
1.00	2.00	1.57	NIR I (600-1050nm)	N-LASF9	#65-306	₹6,228 Volume Pricing	6 In Stock
1.50	1.00	0.57	NIR I (600-1050nm)	N-LASF9	#45-953	₹6,228 Volume Pricing	8 In Stock
1.50	1.50	1.07	NIR I (600-1050nm)	N-LASF9	#45-954	₹6,228 Volume Pricing	20+ In Stock
1.50	2.00	1.57	NIR I (600-1050nm)	N-LASF9	#65-307	₹6,228 Volume Pricing	5 In Stock
2.00	1.50	1.07	NIR I (600-1050nm)	N-LASF9	#45-955	₹6,150 Volume Pricing	10 In Stock
2.00	2.00	1.57	NIR I (600-1050nm)	N-LASF9	#45-956	₹6,150 Volume Pricing	8 In Stock
2.00	3.00	2.57	NIR I (600-1050nm)	N-LASF9	#65-308	₹6,150 Volume Pricing	20+ In Stock
2.00	4.00	3.57	NIR I (600-1050nm)	N-LASF9	#65-309	₹6,150 Volume Pricing	7 In Stock
2.00	4.00	3.46	NIR I (600-1050nm)	Fused Silica (Corning 7980)	#72-255	₹8,096 Volume Pricing	5 In Stock

2.00	6.00	5.45	NIR I (600-1050nm)	Fused Silica (Corning 7980)	#72-263	₹7,668 Volume Pricing	3 In Stock
2.50	2.00	1.57	NIR I (600-1050nm)	N-LASF9	#45-957	₹6,150 Volume Pricing	20+ In Stock
2.50	2.50	2.07	NIR I (600-1050nm)	N-LASF9	#45-958	₹6,150 Volume Pricing	9 In Stock
2.50	3.00	2.57	NIR I (600-1050nm)	N-LASF9	#45-959	₹6,150 Volume Pricing	9 In Stock
2.50	4.00	3.57	NIR I (600-1050nm)	N-LASF9	#48-646	₹6,150 Volume Pricing	2 In Stock
2.50	5.00	4.57	NIR I (600-1050nm)	N-LASF9	#48-647	₹6,150 Volume Pricing	20+ In Stock
3.00	3.00	1.88	NIR I (600-1050nm)	N-SF11	#45-960	₹5,177 Volume Pricing	10 In Stock
3.00	4.50	3.50	NIR I (600-1050nm)	N-LASF44	#45-961	₹5,177 Volume Pricing	14 In Stock
3.00	6.00	4.81	NIR I (600-1050nm)	N-BK7	#45-962	₹4,788 Volume Pricing	20+ In Stock
3.00	6.00	5.01	NIR I (600-1050nm)	Fused Silica (Corning 7980)	#72-271	₹8,096 Volume Pricing	5 In Stock
3.00	7.50	6.51	NIR I (600-1050nm)	N-BK7	#48-648	₹4,788 Volume Pricing	20+ In Stock
3.00	9.00	8.01	NIR I (600-1050nm)	N-BK7	#45-963	₹4,788 Volume Pricing	14 In Stock
3.00	9.00	8.11	NIR I (600-1050nm)	Fused Silica (Corning 7980)	#72-280	₹7,668 Volume Pricing	1 In Stock
3.00	12.00	11.29	NIR I (600-1050nm)	N-BK7	#45-964	₹4,788 Volume Pricing	4 In Stock

3.00	15.00	14.22	NIR I (600-1050nm)	N-BK7	#45-965	₹4,788 Volume Pricing	20+ In Stock
4.00	4.00	3.06	NIR I (600-1050nm)	N-LASF44	#48-702	₹4,982 Volume Pricing	20+ In Stock
4.00	6.00	4.51	NIR I (600-1050nm)	N-BK7	#48-703	₹4,982 Volume Pricing	14 In Stock
4.00	8.00	7.17	NIR I (600-1050nm)	N-BAF10	#48-704	₹4,671 Volume Pricing	10 In Stock
4.00	8.00	6.91	NIR I (600-1050nm)	Fused Silica (Corning 7980)	#72-288	₹9,653 Volume Pricing	5 In Stock
4.00	10.00	8.92	NIR I (600-1050nm)	N-BK7	#48-705	₹4,671 Volume Pricing	20+ In Stock
4.00	12.00	11.00	NIR I (600-1050nm)	N-BK7	#48-706	₹4,671 Volume Pricing	3 In Stock
4.00	12.00	11.04	NIR I (600-1050nm)	Fused Silica (Corning 7980)	#72-296	₹9,264 Volume Pricing	5 In Stock
4.50	4.50	3.05	NIR I (600-1050nm)	N-LASF44	#48-707	₹4,982 Volume Pricing	20+ In Stock
4.50	9.00	7.41	NIR I (600-1050nm)	N-BK7	#48-708	₹4,671 Volume Pricing	8 In Stock
5.00	5.00	3.96	NIR I (600-1050nm)	N-LASF44	#48-709	₹3,756 Volume Pricing	20+ In Stock
5.00	7.50	6.43	NIR I (600-1050nm)	N-SF11	#48-710	₹3,717 Volume Pricing	Contact Us
5.00	10.00	8.91	NIR I (600-1050nm)	N-BK7	#48-711	₹3,717 Volume Pricing	20+ In Stock
5.00	12.00	10.83	NIR I (600-1050nm)	N-BK7	#48-712	₹3,717 Volume Pricing	20+ In Stock

5.00	15.00	13.94	NIR I (600-1050nm)	N-BK7	#48-713	₹3,717 Volume Pricing	Contact Us
5.00	20.00	19.02	NIR I (600-1050nm)	N-BK7	#49-903	₹3,717 Volume Pricing	20+ In Stock
5.00	25.00	23.95	NIR I (600-1050nm)	N-BK7	#87-919	₹3,717 Volume Pricing	20+ In Stock
5.00	30.00	28.95	NIR I (600-1050nm)	N-BK7	#87-920	₹3,717 Volume Pricing	5 In Stock
6.00	6.00	4.60	NIR I (600-1050nm)	N-SF11	#48-714	₹3,114 Volume Pricing	7 In Stock
6.00	7.50	6.10	NIR I (600-1050nm)	N-SF11	#49-904	₹3,075 Volume Pricing	Contact Us
6.00	9.00	7.95	NIR I (600-1050nm)	N-SF5	#48-715	₹3,075 Volume Pricing	Contact Us
6.00	10.00	8.82	NIR I (600-1050nm)	N-BK7	#38-328	₹3,075 Volume Pricing	Contact Us
6.00	12.00	10.94	NIR I (600-1050nm)	N-BK7	#48-716	₹2,997 Volume Pricing	20+ In Stock
6.00	15.00	13.68	NIR I (600-1050nm)	N-BK7	#48-717	₹2,997 Volume Pricing	20+ In Stock
6.00	18.00	17.07	NIR I (600-1050nm)	N-BK7	#48-718	₹2,997 Volume Pricing	20+ In Stock
6.00	20.00	19.04	NIR I (600-1050nm)	N-BK7	#38-329	₹2,997 Volume Pricing	13 In Stock
6.00	21.00	20.06	NIR I (600-1050nm)	N-BK7	#48-719	₹2,997 Volume Pricing	20+ In Stock
6.00	24.00	23.01	NIR I (600-1050nm)	N-BK7	#48-720	₹2,997 Volume Pricing	3 In Stock

6.00	25.00	24.04	NIR I (600-1050nm)	N-BK7	#38-330	₹2,997 Volume Pricing	Contact Us
6.00	30.00	29.14	NIR I (600-1050nm)	N-BK7	#48-721	₹2,997 Volume Pricing	20+ In Stock
6.00	36.00	34.95	NIR I (600-1050nm)	N-BK7	#48-722	₹2,997 Volume Pricing	1 In Stock
6.00	48.00	46.95	NIR I (600-1050nm)	N-BK7	#48-723	₹2,997 Volume Pricing	20+ In Stock
6.00	60.00	58.95	NIR I (600-1050nm)	N-BK7	#67-170	₹2,997 Volume Pricing	5 In Stock
6.00	72.00	70.97	NIR I (600-1050nm)	N-BK7	#48-724	₹2,997 Volume Pricing	4 In Stock
7.00	7.00	5.50	NIR I (600-1050nm)	N-SF11	#71-295	₹3,114 Volume Pricing	Contact Us
7.00	10.00	8.10	NIR I (600-1050nm)	N-BK7	#71-302	₹3,075 Volume Pricing	4 In Stock
7.00	12.00	10.30	NIR I (600-1050nm)	N-BK7	#71-309	₹3,075 Volume Pricing	5 In Stock
8.00	8.00	6.40	NIR I (600-1050nm)	N-SF11	#71-316	₹3,114 Volume Pricing	20+ In Stock
8.00	10.00	7.60	NIR I (600-1050nm)	N-BK7	#71-323	₹3,075 Volume Pricing	Contact Us
8.00	12.00	10.00	NIR I (600-1050nm)	N-BK7	#71-330	₹3,075 Volume Pricing	1 In Stock
9.00	9.00	7.32	NIR I (600-1050nm)	N-SF11	#48-725	₹3,153 Volume Pricing	Contact Us
9.00	10.00	8.49	NIR I (600-1050nm)	N-SF11	#38-332	₹3,153 Volume Pricing	4 In Stock

9.00	12.00	10.60	NIR I (600-1050nm)	N-SF11	#49-905	₹3,153 Volume Pricing	20+ In Stock
9.00	13.50	11.94	NIR I (600-1050nm)	N-SF5	#48-726	₹3,153 Volume Pricing	20+ In Stock
9.00	15.00	13.02	NIR I (600-1050nm)	N-BK7	#49-906	₹3,153 Volume Pricing	10 In Stock
9.00	18.00	16.41	NIR I (600-1050nm)	N-BK7	#48-727	₹3,075 Volume Pricing	20+ In Stock
9.00	20.00	18.55	NIR I (600-1050nm)	N-BK7	#38-333	₹3,075 Volume Pricing	3 In Stock
9.00	22.00	20.73	NIR I (600-1050nm)	N-BK7	#48-728	₹3,075 Volume Pricing	3 In Stock
9.00	25.00	23.68	NIR I (600-1050nm)	N-BK7	#38-334	₹3,075 Volume Pricing	20+ In Stock
9.00	27.00	25.34	NIR I (600-1050nm)	N-BK7	#48-729	₹3,075 Volume Pricing	Contact Us
9.00	36.00	34.48	NIR I (600-1050nm)	N-BK7	#48-730	₹3,075 Volume Pricing	12 In Stock
9.00	45.00	43.98	NIR I (600-1050nm)	N-BK7	#48-731	₹3,075 Volume Pricing	10 In Stock
9.00	54.00	52.69	NIR I (600-1050nm)	N-BK7	#67-171	₹3,075 Volume Pricing	Contact Us
9.00	72.00	70.68	NIR I (600-1050nm)	N-BK7	#67-172	₹3,075 Volume Pricing	Contact Us
9.00	90.00	88.68	NIR I (600-1050nm)	N-BK7	#67-173	₹3,075 Volume Pricing	20+ In Stock
10.00	10.00	8.18	NIR I (600-1050nm)	N-SF11	#63-508	₹3,153 Volume Pricing	Contact Us

10.00	12.50	10.99	NIR I (600-1050nm)	N-SF11	#38-335	₹3,153 Volume Pricing	5 In Stock
10.00	15.00	13.32	NIR I (600-1050nm)	N-SF11	#63-509	₹3,153 Volume Pricing	12 In Stock
10.00	17.50	15.66	NIR I (600-1050nm)	N-BK7	#38-336	₹3,075 Volume Pricing	1 In Stock
10.00	20.00	18.03	NIR I (600-1050nm)	N-BK7	#63-510	₹3,075 Volume Pricing	17 In Stock
10.00	25.00	23.02	NIR I (600-1050nm)	N-BK7	#63-511	₹3,075 Volume Pricing	20+ In Stock
10.00	30.00	28.01	NIR I (600-1050nm)	N-BK7	#63-512	₹3,075 Volume Pricing	14 In Stock
10.00	40.00	38.02	NIR I (600-1050nm)	N-BK7	#63-513	₹3,075 Volume Pricing	5 In Stock
10.00	50.00	48.02	NIR I (600-1050nm)	N-BK7	#63-514	₹3,075 Volume Pricing	Contact Us
10.00	75.00	73.02	NIR I (600-1050nm)	N-BK7	#63-515	₹3,075 Volume Pricing	1 In Stock
10.00	100.00	98.02	NIR I (600-1050nm)	N-BK7	#63-516	₹3,075 Volume Pricing	1 In Stock
12.00	12.00	9.76	NIR I (600-1050nm)	N-SF11	#48-732	₹3,425 Volume Pricing	Contact Us
12.00	15.00	12.03	NIR I (600-1050nm)	N-BK7	#48-733	₹3,425 Volume Pricing	20+ In Stock
12.00	18.00	16.22	NIR I (600-1050nm)	N-SF5	#48-734	₹3,425 Volume Pricing	20+ In Stock
12.00	20.00	17.69	NIR I (600-1050nm)	N-BK7	#49-907	₹3,425 Volume Pricing	10 In Stock

12.00	24.00	22.15	NIR I (600-1050nm)	N-BK7	#48-735	₹3,348 Volume Pricing	20+ In Stock
12.00	25.00	23.22	NIR I (600-1050nm)	N-BK7	#38-338	₹3,348 Volume Pricing	7 In Stock
12.00	30.00	28.02	NIR I (600-1050nm)	N-BK7	#48-736	₹3,348 Volume Pricing	Contact Us
12.00	36.00	34.02	NIR I (600-1050nm)	N-BK7	#33-356	₹3,348 Volume Pricing	16 In Stock
12.00	42.00	40.22	NIR I (600-1050nm)	N-BK7	#48-738	₹3,348 Volume Pricing	4 In Stock
12.00	48.00	46.36	NIR I (600-1050nm)	N-BK7	#48-739	₹3,348 Volume Pricing	20+ In Stock
12.00	50.00	48.75	NIR I (600-1050nm)	N-BK7	#38-345	₹3,348 Volume Pricing	6 In Stock
12.00	54.00	52.02	NIR I (600-1050nm)	N-BK7	#48-740	₹3,348 Volume Pricing	20+ In Stock
12.00	60.00	58.37	NIR I (600-1050nm)	N-BK7	#48-741	₹3,348 Volume Pricing	20+ In Stock
12.00	72.00	70.42	NIR I (600-1050nm)	N-BK7	#48-742	₹3,348 Volume Pricing	6 In Stock
12.00	84.00	82.39	NIR I (600-1050nm)	N-BK7	#48-743	₹3,348 Volume Pricing	20+ In Stock
12.00	100.00	98.35	NIR I (600-1050nm)	N-BK7	#48-744	₹3,348 Volume Pricing	10 In Stock
12.50	12.50	10.40	NIR I (600-1050nm)	N-SF11	#38-348	₹3,348 Volume Pricing	10 In Stock
12.50	15.00	13.26	NIR I (600-1050nm)	N-SF11	#38-350	₹3,348 Volume Pricing	14 In Stock

12.50	17.50	15.00	NIR I (600-1050nm)	N-BK7	#38-353	₹3,348 Volume Pricing	Contact Us
12.50	20.00	17.69	NIR I (600-1050nm)	N-BK7	#38-354	₹3,348 Volume Pricing	12 In Stock
12.50	25.00	22.96	NIR I (600-1050nm)	N-BK7	#38-357	₹3,270 Volume Pricing	6 In Stock
12.50	30.00	28.22	NIR I (600-1050nm)	N-BK7	#38-358	₹3,270 Volume Pricing	1 In Stock
12.50	35.00	33.42	NIR I (600-1050nm)	N-BK7	#38-359	₹3,270 Volume Pricing	5 In Stock
12.50	40.00	38.55	NIR I (600-1050nm)	N-BK7	#38-361	₹3,270 Volume Pricing	1 In Stock
12.50	45.00	43.68	NIR I (600-1050nm)	N-BK7	#38-362	₹3,270 Volume Pricing	20+ In Stock
12.50	50.00	48.68	NIR I (600-1050nm)	N-BK7	#38-363	₹3,270 Volume Pricing	Contact Us
12.50	75.00	73.88	NIR I (600-1050nm)	N-BK7	#38-364	₹3,270 Volume Pricing	8 In Stock
12.50	100.00	98.95	NIR I (600-1050nm)	N-BK7	#38-365	₹3,270 Volume Pricing	2 In Stock
12.70	12.70	10.46	NIR I (600-1050nm)	N-SF11	#62-576	₹3,348 Volume Pricing	14 In Stock
12.70	15.00	11.53	NIR I (600-1050nm)	N-BK7	#62-577	₹3,348 Volume Pricing	12 In Stock
12.70	19.10	16.46	NIR I (600-1050nm)	N-BK7	#62-578	₹3,348 Volume Pricing	20+ In Stock
12.70	20.00	17.49	NIR I (600-1050nm)	N-BK7	#38-366	₹3,348 Volume Pricing	1 In Stock

12.70	25.40	23.43	NIR I (600-1050nm)	N-BK7	#62-579	₹3,270 Volume Pricing	10 In Stock
12.70	30.00	28.22	NIR I (600-1050nm)	N-BK7	#38-367	₹3,270 Volume Pricing	5 In Stock
12.70	31.80	29.81	NIR I (600-1050nm)	N-BK7	#62-580	₹3,270 Volume Pricing	11 In Stock
12.70	38.10	36.12	NIR I (600-1050nm)	N-BK7	#62-581	₹3,270 Volume Pricing	20+ In Stock
12.70	40.00	38.48	NIR I (600-1050nm)	N-BK7	#38-368	₹3,270 Volume Pricing	13 In Stock
12.70	44.50	42.69	NIR I (600-1050nm)	N-BK7	#62-582	₹3,270 Volume Pricing	5 In Stock
12.70	50.80	49.15	NIR I (600-1050nm)	N-BK7	#62-583	₹3,270 Volume Pricing	20+ In Stock
12.70	100.00	98.88	NIR I (600-1050nm)	N-BK7	#38-369	₹3,270 Volume Pricing	8 In Stock
15.00	15.00	11.71	NIR I (600-1050nm)	N-SF5	#48-745	₹3,425 Volume Pricing	20+ In Stock
15.00	18.00	15.61	NIR I (600-1050nm)	N-SF5	#49-908	₹3,425 Volume Pricing	16 In Stock
15.00	20.00	17.74	NIR I (600-1050nm)	N-SF5	#63-517	₹3,425 Volume Pricing	17 In Stock
15.00	22.50	20.50	NIR I (600-1050nm)	N-SF5	#48-746	₹3,425 Volume Pricing	20+ In Stock
15.00	25.00	22.50	NIR I (600-1050nm)	N-BK7	#38-370	₹3,348 Volume Pricing	17 In Stock
15.00	30.00	27.90	NIR I (600-1050nm)	N-BK7	#48-747	₹3,348 Volume Pricing	20+ In Stock

15.00	40.00	38.02	NIR I (600-1050nm)	N-BK7	#48-748	₹3,348 Volume Pricing	17 In Stock
15.00	45.00	43.35	NIR I (600-1050nm)	N-BK7	#49-909	₹3,348 Volume Pricing	11 In Stock
15.00	50.00	48.35	NIR I (600-1050nm)	N-BK7	#38-371	₹3,348 Volume Pricing	3 In Stock
15.00	60.00	58.65	NIR I (600-1050nm)	N-BK7	#48-749	₹3,348 Volume Pricing	20+ In Stock
15.00	75.00	73.79	NIR I (600-1050nm)	N-BK7	#48-750	₹3,348 Volume Pricing	20+ In Stock
15.00	100.00	98.02	NIR I (600-1050nm)	N-BK7	#48-751	₹3,348 Volume Pricing	9 In Stock
15.00	200.00	197.89	NIR I (600-1050nm)	N-BK7	#14-377	₹3,348 Volume Pricing	Contact Us
15.00	250.00	248.02	NIR I (600-1050nm)	N-BK7	#14-385	₹3,348 Volume Pricing	1 In Stock
18.00	18.00	15.20	NIR I (600-1050nm)	N-SF11	#48-752	₹3,464 Volume Pricing	20+ In Stock
18.00	20.00	17.59	NIR I (600-1050nm)	N-SF11	#38-372	₹3,425 Volume Pricing	2 In Stock
18.00	22.50	20.26	NIR I (600-1050nm)	N-SF11	#49-910	₹3,425 Volume Pricing	15 In Stock
18.00	25.00	21.51	NIR I (600-1050nm)	N-BK7	#38-373	₹3,425 Volume Pricing	3 In Stock
18.00	27.00	24.73	NIR I (600-1050nm)	N-SF5	#48-753	₹3,425 Volume Pricing	20+ In Stock
18.00	30.00	27.10	NIR I (600-1050nm)	N-BK7	#38-374	₹3,309 Volume Pricing	20+ In Stock

18.00	36.00	33.65	NIR I (600-1050nm)	N-BK7	#48-754	₹3,309 Volume Pricing	20+ In Stock
18.00	50.00	48.09	NIR I (600-1050nm)	N-BK7	#38-375	₹3,309 Volume Pricing	4 In Stock
18.00	54.00	52.02	NIR I (600-1050nm)	N-BK7	#48-755	₹3,309 Volume Pricing	20+ In Stock
18.00	72.00	70.05	NIR I (600-1050nm)	N-BK7	#48-756	₹3,309 Volume Pricing	Contact Us
20.00	20.00	17.42	NIR I (600-1050nm)	N-SF11	#48-757	₹3,503 Volume Pricing	4 In Stock
20.00	25.00	22.76	NIR I (600-1050nm)	N-SF11	#49-911	₹3,464 Volume Pricing	Contact Us
20.00	30.00	27.30	NIR I (600-1050nm)	N-BAF10	#48-758	₹3,464 Volume Pricing	20+ In Stock
20.00	35.00	32.04	NIR I (600-1050nm)	N-BK7	#49-912	₹3,464 Volume Pricing	11 In Stock
20.00	40.00	36.77	NIR I (600-1050nm)	N-BK7	#48-759	₹3,348 Volume Pricing	1 In Stock
20.00	50.00	47.87	NIR I (600-1050nm)	N-BK7	#48-760	₹3,348 Volume Pricing	20+ In Stock
20.00	60.00	57.03	NIR I (600-1050nm)	N-BK7	#48-761	₹3,348 Volume Pricing	Contact Us
20.00	70.00	68.03	NIR I (600-1050nm)	N-BK7	#48-762	₹3,348 Volume Pricing	7 In Stock
20.00	80.00	78.45	NIR I (600-1050nm)	N-BK7	#48-763	₹3,348 Volume Pricing	17 In Stock
20.00	100.00	97.13	NIR I (600-1050nm)	N-BK7	#48-764	₹3,348 Volume Pricing	20+ In Stock

20.00	150.00	148.02	NIR I (600-1050nm)	N-BK7	#48-765	₹3,348 Volume Pricing	Contact Us
25.00	25.00	20.22	NIR I (600-1050nm)	N-SF5	#48-766	₹3,503 Volume Pricing	20+ In Stock
25.00	30.00	24.69	NIR I (600-1050nm)	N-BK7	#48-767	₹3,503 Volume Pricing	Contact Us
25.00	35.00	30.42	NIR I (600-1050nm)	N-BK7	#48-768	₹3,503 Volume Pricing	7 In Stock
25.00	40.00	36.31	NIR I (600-1050nm)	N-BK7	#48-769	₹3,503 Volume Pricing	20+ In Stock
25.00	50.00	46.75	NIR I (600-1050nm)	N-BK7	#48-770	₹3,348 Volume Pricing	20+ In Stock
25.00	60.00	56.90	NIR I (600-1050nm)	N-BK7	#48-771	₹3,348 Volume Pricing	4 In Stock
25.00	75.00	72.00	NIR I (600-1050nm)	N-BK7	#48-772	₹3,348 Volume Pricing	20+ In Stock
25.00	85.00	82.17	NIR I (600-1050nm)	N-BK7	#48-773	₹3,348 Volume Pricing	14 In Stock
25.00	100.00	97.17	NIR I (600-1050nm)	N-BK7	#48-774	₹3,348 Volume Pricing	15 In Stock
25.00	125.00	122.70	NIR I (600-1050nm)	N-BK7	#48-775	₹3,348 Volume Pricing	4 In Stock
25.00	150.00	147.81	NIR I (600-1050nm)	N-BK7	#48-776	₹3,348 Volume Pricing	11 In Stock
25.00	175.00	172.85	NIR I (600-1050nm)	N-BK7	#48-777	₹3,348 Volume Pricing	9 In Stock
25.00	200.00	197.89	NIR I (600-1050nm)	N-BK7	#33-362	₹3,348 Volume Pricing	6 In Stock

25.00	250.00	248.02	NIR I (600-1050nm)	N-BK7	#67-174	₹3,348 Volume Pricing	20+ In Stock
25.00	300.00	298.02	NIR I (600-1050nm)	N-BK7	#67-175	₹3,348 Volume Pricing	20+ In Stock
25.00	400.00	397.89	NIR I (600-1050nm)	N-BK7	#33-368	₹3,348 Volume Pricing	4 In Stock
25.00	500.00	497.89	NIR I (600-1050nm)	N-BK7	#48-780	₹3,348 Volume Pricing	20+ In Stock
25.00	750.00	747.89	NIR I (600-1050nm)	N-BK7	#48-781	₹3,348 Volume Pricing	1 In Stock
25.40	25.40	21.48	NIR I (600-1050nm)	N-SF11	#62-584	₹3,503 Volume Pricing	13 In Stock
25.40	35.00	30.46	NIR I (600-1050nm)	N-BK7	#38-376	₹3,503 Volume Pricing	4 In Stock
25.40	38.10	33.48	NIR I (600-1050nm)	N-BK7	#62-585	₹3,503 Volume Pricing	6 In Stock
25.40	40.00	36.11	NIR I (600-1050nm)	N-BK7	#38-377	₹3,503 Volume Pricing	1 In Stock
25.40	50.80	47.50	NIR I (600-1050nm)	N-BK7	#62-586	₹3,348 Volume Pricing	7 In Stock
25.40	63.50	60.37	NIR I (600-1050nm)	N-BK7	#62-587	₹3,348 Volume Pricing	Contact Us
25.40	75.00	72.69	NIR I (600-1050nm)	N-BK7	#38-378	₹3,348 Volume Pricing	4 In Stock
25.40	76.20	73.56	NIR I (600-1050nm)	N-BK7	#62-588	₹3,348 Volume Pricing	8 In Stock
25.40	88.90	86.26	NIR I (600-1050nm)	N-BK7	#62-589	₹3,348 Volume Pricing	20+ In Stock

25.40	100.00	98.02	NIR I (600-1050nm)	N-BK7	#38-379	₹3,348 Volume Pricing	8 In Stock
25.40	101.60	98.97	NIR I (600-1050nm)	N-BK7	#62-590	₹3,348 Volume Pricing	1 In Stock
25.40	125.00	123.02	NIR I (600-1050nm)	N-BK7	#38-380	₹3,348 Volume Pricing	5 In Stock
25.40	150.00	148.02	NIR I (600-1050nm)	N-BK7	#38-381	₹3,348 Volume Pricing	2 In Stock
30.00	30.00	26.13	NIR I (600-1050nm)	N-SF11	#48-782	₹4,321 Volume Pricing	5 In Stock
30.00	40.00	37.20	NIR I (600-1050nm)	N-SF11	#67-176	₹4,165 Volume Pricing	15 In Stock
30.00	50.00	46.17	NIR I (600-1050nm)	N-SF5	#48-783	₹4,165 Volume Pricing	20+ In Stock
30.00	60.00	56.03	NIR I (600-1050nm)	N-BK7	#48-784	₹4,048 Volume Pricing	8 In Stock
30.00	75.00	70.95	NIR I (600-1050nm)	N-BK7	#48-785	₹4,048 Volume Pricing	5 In Stock
30.00	100.00	96.01	NIR I (600-1050nm)	N-BK7	#48-786	₹4,048 Volume Pricing	5 In Stock
30.00	120.00	116.04	NIR I (600-1050nm)	N-BK7	#48-787	₹4,048 Volume Pricing	2 In Stock
35.00	35.00	30.52	NIR I (600-1050nm)	N-SF11	#38-382	₹4,437 Volume Pricing	5 In Stock
35.00	50.00	44.40	NIR I (600-1050nm)	N-BK7	#38-383	₹4,321 Volume Pricing	Contact Us
35.00	70.00	66.04	NIR I (600-1050nm)	N-BK7	#38-384	₹4,321 Volume Pricing	4 In Stock

35.00	100.00	97.03	NIR I (600-1050nm)	N-BK7	#38-385	₹4,321 Volume Pricing	7 In Stock
40.00	40.00	35.13	NIR I (600-1050nm)	N-SF11	#48-788	₹4,827 Volume Pricing	20+ In Stock
40.00	60.00	53.90	NIR I (600-1050nm)	N-BK7	#48-789	₹4,827 Volume Pricing	3 In Stock
40.00	80.00	74.73	NIR I (600-1050nm)	N-BK7	#33-386	₹4,749 Volume Pricing	Contact Us
40.00	100.00	95.39	NIR I (600-1050nm)	N-BK7	#33-374	₹4,749 Volume Pricing	16 In Stock
40.00	200.00	196.7	NIR I (600-1050nm)	N-BK7	#33-380	₹4,749 Volume Pricing	13 In Stock
40.00	300.00	296.70	NIR I (600-1050nm)	N-BK7	#48-793	₹4,749 Volume Pricing	Contact Us
40.00	400.00	396.70	NIR I (600-1050nm)	N-BK7	#48-794	₹4,749 Volume Pricing	10 In Stock
50.00	50.00	43.28	NIR I (600-1050nm)	N-SF11	#48-795	₹5,216 Volume Pricing	20+ In Stock
50.00	75.00	67.75	NIR I (600-1050nm)	N-BK7	#48-796	₹5,060 Volume Pricing	4 In Stock
50.00	100.00	93.41	NIR I (600-1050nm)	N-BK7	#48-797	₹4,866 Volume Pricing	20+ In Stock
50.00	125.00	118.39	NIR I (600-1050nm)	N-BK7	#48-798	₹4,866 Volume Pricing	Contact Us
50.00	150.00	144.07	NIR I (600-1050nm)	N-BK7	#48-799	₹4,866 Volume Pricing	4 In Stock
50.00	175.00	169.05	NIR I (600-1050nm)	N-BK7	#48-800	₹4,866 Volume Pricing	Contact Us

50.00	200.00	196.66	NIR I (600-1050nm)	N-BK7	#48-801	₹4,866 Volume Pricing	5 In Stock
50.00	250.00	246.74	NIR I (600-1050nm)	N-BK7	#48-802	₹4,866 Volume Pricing	4 In Stock
50.00	500.00	496.70	NIR I (600-1050nm)	N-BK7	#48-803	₹4,866 Volume Pricing	6 In Stock
50.80	50.81	44.08	NIR I (600-1050nm)	N-SF11	#71-337	₹5,216 Volume Pricing	5 In Stock
50.80	76.20	68.95	NIR I (600-1050nm)	N-BK7	#71-344	₹5,060 Volume Pricing	6 In Stock
75.00	75.00	53.49	NIR I (600-1050nm)	N-BK7	#86-916	₹10,121 Volume Pricing	Contact Us
#71-852 New							
 New Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!							
75.00	100.00	87.57	NIR I (600-1050nm)	N-BK7		₹9,965 Volume Pricing	3 In Stock
75.00	100.00	85.61	NIR I (600-1050nm)	Fused Silica (Corning 7980)	#72-304	₹50,992 Volume Pricing	2 In Stock
75.00	125.00	115.99	NIR I (600-1050nm)	N-BK7	#71-853	₹9,965 Volume Pricing	3 In Stock

75.00	125.00	112.66	NIR I (600-1050nm)	Fused Silica (Corning 7980)	#72-312	₹49,435 Volume Pricing	2 In Stock
75.00	150.00	142.45	NIR I (600-1050nm)	N-BK7	#86-917	₹9,965 Volume Pricing	Contact Us
75.00	150.00	136.31	NIR I (600-1050nm)	Fused Silica (Corning 7980)	#72-320	₹47,878 Volume Pricing	1 In Stock
#71-854 New							
 New Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!							
75.00	175.00	168.68	NIR I (600-1050nm)	N-BK7		₹9,965 Volume Pricing	1 In Stock
75.00	200.00	194.24	NIR I (600-1050nm)	N-BK7	#86-918	₹9,965 Volume Pricing	5 In Stock
75.00	200.00	187.18	NIR I (600-1050nm)	Fused Silica (Corning 7980)	#72-328	₹46,321 Volume Pricing	2 In Stock
75.00	250.00	244.73	NIR I (600-1050nm)	N-BK7	#86-919	₹9,965 Volume Pricing	1 In Stock

[#71-855 New](#)



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

75.00 300.00 294.4
NIR I
(600-
1050nm)

[N-BK7](#)

₹9,965
[Volume Pricing](#)

5 In Stock

[#71-856 New](#)



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

75.00 400.00 394.4
NIR I
(600-
1050nm)

[N-BK7](#)

₹9,965
[Volume Pricing](#)

4 In Stock

75.00 500.00 494.73
NIR I
(600-
1050nm)

[N-BK7](#)

[#86-920](#)

₹9,965
[Volume Pricing](#)

5 In Stock

[#71-857 New](#)



Copyright 2023, Edmund Optics India Private Limited, #267, Greystone Building, Second Floor, 6th Cross Rd, Binnamangala, Stage 1, Indiranagar, Bengaluru, Karnataka, India 560038
Phone: 1-800-363-1992 : 1050nm)
[www.edmundoptics.com](#)

NIR1
(600-
NIR1

New
Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

₹9,965

[Volume Pricing](#)

10 In Stock