

[All Products](#) / [Optics](#) / [Optical Lenses](#) / [Plano-Convex \(PCX\) Lenses](#) / [Standard Plano-Convex \(PCX\) Lenses](#)

TECHSPEC® MgF₂ Coated Plano-Convex (PCX) Lenses



- AR Coated to Provide <1.75% Reflectance per Surface for 400 - 700nm
- Designed for 0° Angle of Incidence
- Various PCX Coating Options: [Uncoated](#), [VIS 0°](#), [VIS-NIR](#), [NIR I](#), [NIR II](#), [VIS-EXT](#), and [YAG-BBAR](#)
- Also Available [Pre-Mounted in Engraved C-Mount Housings](#)

Common Specifications

Physical & Mechanical Properties

Bevel:



Protective bevel as needed

Optical Properties

Wavelength Range (nm):

400 - 700

Technical Information

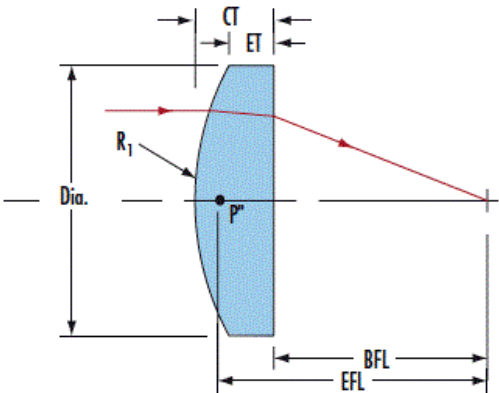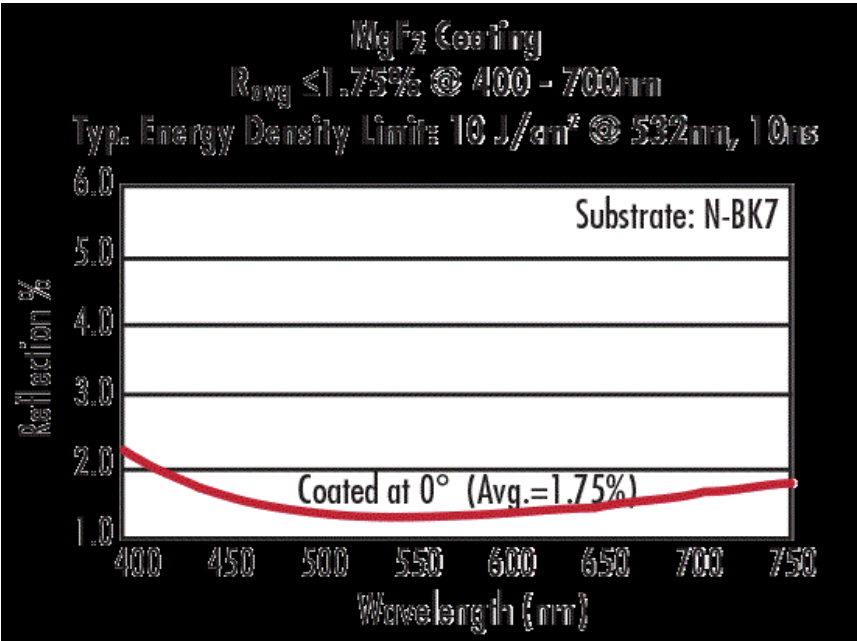

Products

Dia. (mm)	EFL (mm)	BFL (mm)	Coating	Substrate	Stock Number	Price	Buy
1.00	0.60	0.17	MgF ₂ (400-700nm)	N-LASF9	#65-257	₹5,644 Qty 10+ ₹5,099	10 to 12 days
1.00	1.00	0.57	MgF ₂ (400-700nm)	N-LASF9	#65-258	₹5,644 Qty 10+ ₹5,099	10 to 12 days
1.00	1.50	1.07	MgF ₂ (400-700nm)	N-LASF9	#65-259	₹5,644 Qty 10+ ₹5,099	Contact Us
1.00	2.00	1.57	MgF ₂ (400-700nm)	N-LASF9	#65-260	₹5,644 Qty 10+ ₹5,099	10 to 12 days
1.50	1.00	0.57	MgF ₂ (400-700nm)	N-LASF9	#65-261	₹5,644 Qty 10+ ₹5,099	10 to 12 days
1.50	1.50	1.07	MgF ₂ (400-700nm)	N-LASF9	#65-262	₹5,644 Qty 10+ ₹5,099	10 to 12 days
1.50	2.00	1.57	MgF ₂ (400-700nm)	N-LASF9	#65-263	₹5,644 Qty 10+ ₹5,099	10 to 12 days
2.00	1.50	1.07	MgF ₂ (400-700nm)	N-LASF9	#65-264	₹5,566 Qty 10+ ₹4,982	10 to 12 days
2.00	2.00	1.57	MgF ₂ (400-700nm)	N-LASF9	#65-265	₹5,566 Qty 10+ ₹4,982	10 to 12 days
2.00	3.00	2.57	MgF ₂ (400-700nm)	N-LASF9	#65-266	₹5,566 Qty 10+ ₹4,982	10 to 12 days
2.00	4.00	3.57	MgF ₂ (400-700nm)	N-LASF9	#65-267	₹5,566 Qty 10+ ₹4,982	10 to 12 days
2.50	2.00	1.57	MgF ₂ (400-700nm)	N-LASF9	#65-268	₹5,566 Qty 10+ ₹4,982	10 to 12 days

2.50	2.50	2.05	MgF ₂ (400-700nm)	N-LASF9	#65-269	₹5,566 Qty 10+ ₹4,982	Contact Us
2.50	3.00	2.57	MgF ₂ (400-700nm)	N-LASF9	#65-270	₹5,566 Qty 10+ ₹4,982	10 to 12 days
2.50	4.00	3.57	MgF ₂ (400-700nm)	N-LASF9	#65-271	₹5,566 Qty 10+ ₹4,982	10 to 12 days
2.50	5.00	4.57	MgF ₂ (400-700nm)	N-LASF9	#65-272	₹5,566 Qty 10+ ₹4,982	10 to 12 days
3.00	3.00	1.88	MgF ₂ (400-700nm)	N-SF11	#45-118	₹4,593 Qty 10+ ₹4,126	10 to 12 days
3.00	4.50	3.50	MgF ₂ (400-700nm)	N-LASF44	#45-142	₹4,593 Qty 10+ ₹4,126	10 to 12 days
3.00	6.00	4.81	MgF ₂ (400-700nm)	N-BK7	#32-953	₹4,204 Qty 10+ ₹3,776	10 to 12 days
3.00	7.50	6.51	MgF ₂ (400-700nm)	N-BK7	#48-910	₹4,204 Qty 10+ ₹3,776	10 to 12 days
3.00	9.00	8.01	MgF ₂ (400-700nm)	N-BK7	#32-955	₹4,204 Qty 10+ ₹3,776	10 to 12 days
3.00	12.00	11.29	MgF ₂ (400-700nm)	N-BK7	#45-273	₹4,204 Qty 10+ ₹3,776	10 to 12 days
3.00	15.00	14.17	MgF ₂ (400-700nm)	N-BK7	#45-426	₹4,204 Qty 10+ ₹3,776	10 to 12 days
4.00	4.00	3.06	MgF ₂ (400-700nm)	N-LASF44	#45-224	₹4,204 Qty 10+ ₹3,776	10 to 12 days
4.00	6.00	4.51	MgF ₂ (400-700nm)	N-BK7	#45-428	₹4,204 Qty 10+ ₹3,776	10 to 12 days
4.00	8.00	7.17	MgF ₂ (400-700nm)	N-BAF10	#45-226	₹3,873 Qty 10+ ₹3,484	10 to 12 days

4.00	10.00	8.92	MgF ₂ (400-700nm)	N-BK7	#45-430	₹3,873 Qty 10+ ₹3,484	Contact Us
4.00	12.00	11.00	MgF ₂ (400-700nm)	N-BK7	#45-432	₹3,873 Qty 10+ ₹3,484	10 to 12 days
4.50	4.50	3.05	MgF ₂ (400-700nm)	N-LASF44	#45-144	₹4,204 Qty 10+ ₹3,776	10 to 12 days
4.50	9.00	7.41	MgF ₂ (400-700nm)	N-BK7	#45-148	₹3,873 Qty 10+ ₹3,484	10 to 12 days
5.00	5.00	3.96	MgF ₂ (400-700nm)	N-LASF44	#45-228	₹3,367 Qty 10+ ₹3,017	10 to 12 days
5.00	7.50	6.43	MgF ₂ (400-700nm)	N-SF11	#48-655	₹3,328 Qty 10+ ₹2,997	10 to 12 days
5.00	10.00	8.91	MgF ₂ (400-700nm)	N-BK7	#45-230	₹3,328 Qty 10+ ₹2,997	10 to 12 days
5.00	12.00	10.83	MgF ₂ (400-700nm)	N-BK7	#45-434	₹3,328 Qty 10+ ₹2,997	10 to 12 days
5.00	15.00	13.94	MgF ₂ (400-700nm)	N-BK7	#45-355	₹3,328 Qty 10+ ₹2,997	10 to 12 days
5.00	20.00	19.02	MgF ₂ (400-700nm)	N-BK7	#49-883	₹3,328 Qty 10+ ₹2,997	10 to 12 days
5.00	25.00	23.95	MgF ₂ (400-700nm)	N-BK7	#87-913	₹3,328 Qty 10+ ₹2,997	10 to 12 days
5.00	30.00	28.95	MgF ₂ (400-700nm)	N-BK7	#87-914	₹3,328 Qty 10+ ₹2,997	10 to 12 days
6.00	6.00	4.60	MgF ₂ (400-700nm)	N-SF11	#45-078	₹2,725 Qty 10+ ₹2,452	10 to 12 days
6.00	7.50	6.10	MgF ₂ (400-700nm)	N-SF11	#49-884	₹2,686 Qty 10+ ₹2,413	10 to 12 days

6.00	9.00	7.95	MgF ₂ (400-700nm)	N-SF5	#32-470	₹2,686 Qty 10+ ₹2,413	10 to 12 days
6.00	10.00	8.82	MgF ₂ (400-700nm)	N-BK7	#38-215	₹2,686 Qty 10+ ₹2,413	10 to 12 days
6.00	12.00	10.94	MgF ₂ (400-700nm)	N-BK7	#32-472	₹2,608 Qty 10+ ₹2,336	10 to 12 days
6.00	15.00	13.68	MgF ₂ (400-700nm)	N-BK7	#45-080	₹2,608 Qty 10+ ₹2,336	10 to 12 days
6.00	18.00	17.07	MgF ₂ (400-700nm)	N-BK7	#32-474	₹2,608 Qty 10+ ₹2,336	10 to 12 days
6.00	20.00	19.04	MgF ₂ (400-700nm)	N-BK7	#38-216	₹2,608 Qty 10+ ₹2,336	10 to 12 days
6.00	21.00	20.06	MgF ₂ (400-700nm)	N-BK7	#45-232	₹2,608 Qty 10+ ₹2,336	10 to 12 days
6.00	24.00	23.01	MgF ₂ (400-700nm)	N-BK7	#32-957	₹2,608 Qty 10+ ₹2,336	10 to 12 days
6.00	25.00	24.04	MgF ₂ (400-700nm)	N-BK7	#38-217	₹2,608 Qty 10+ ₹2,336	10 to 12 days
6.00	30.00	29.14	MgF ₂ (400-700nm)	N-BK7	#45-120	₹2,608 Qty 10+ ₹2,336	10 to 12 days
6.00	36.00	34.95	MgF ₂ (400-700nm)	N-BK7	#32-849	₹2,608 Qty 10+ ₹2,336	10 to 12 days
6.00	48.00	46.95	MgF ₂ (400-700nm)	N-BK7	#45-234	₹2,608 Qty 10+ ₹2,336	10 to 12 days
6.00	60.00	58.95	MgF ₂ (400-700nm)	N-BK7	#67-154	₹2,608 Qty 10+ ₹2,336	10 to 12 days
6.00	72.00	70.97	MgF ₂ (400-700nm)	N-BK7	#32-851	₹2,608 Qty 10+ ₹2,336	10 to 12 days

[#71-293 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

7.00

7.00

5.50

MgF2
(400-700nm)

[N-SF11](#)

₹2,725
Qty 11+ ₹2,452

10 to 12 days

[#71-300 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

7.00

10.00

8.10

MgF2
(400-700nm)

[N-BK7](#)

₹2,686
Qty 11+ ₹2,413

10 to 12 days

#71-307 New



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

7.00 12.00 10.30

MgF2
(400-700nm)

[N-BK7](#)

₹2,686
Qty 11+ ₹2,413

10 to 12 days

#71-314 New



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

8.00 8.00 6.40

MgF2
(400-700nm)

[N-SF11](#)

₹2,725
Qty 11+ ₹2,452

10 to 12 days

[#71-321 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

8.00	10.00	7.60	MgF ₂ (400-700nm)	N-BK7		₹2,686 Qty 11+ ₹2,413	10 to 12 days
------	-------	------	---------------------------------	-----------------------	--	--------------------------	---------------

[#71-328 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

8.00	12.00	10.00	MgF ₂ (400-700nm)	N-BK7		₹2,686 Qty 11+ ₹2,413	10 to 12 days
------	-------	-------	---------------------------------	-----------------------	--	--------------------------	---------------

9.00	9.00	7.32	MgF ₂ (400-700nm)	N-SF11	#45-082	₹2,764 Qty 10+ ₹2,472	10 to 12 days
------	------	------	---------------------------------	------------------------	-------------------------	--------------------------	---------------

9.00	10.00	8.49	MgF ₂ (400-700nm)	N-SF11	#38-218	₹2,764 Qty 10+ ₹2,472	10 to 12 days
------	-------	------	---------------------------------	------------------------	-------------------------	--------------------------	---------------

9.00	12.00	10.60	MgF ₂ (400-700nm)	N-SF11	#49-885	₹2,764 Qty 10+ ₹2,472	10 to 12 days
------	-------	-------	---------------------------------	------------------------	-------------------------	--------------------------	---------------

9.00	13.50	11.94	MgF ₂ (400-700nm)	N-SF5	#32-010	₹2,764 Qty 10+ ₹2,472	10 to 12 days
9.00	15.00	13.02	MgF ₂ (400-700nm)	N-BK7	#49-886	₹2,764 Qty 10+ ₹2,472	10 to 12 days
9.00	18.00	16.41	MgF ₂ (400-700nm)	N-BK7	#31-854	₹2,686 Qty 10+ ₹2,413	10 to 12 days
9.00	20.00	18.55	MgF ₂ (400-700nm)	N-BK7	#38-219	₹2,686 Qty 10+ ₹2,413	10 to 12 days
9.00	22.00	20.73	MgF ₂ (400-700nm)	N-BK7	#45-236	₹2,686 Qty 10+ ₹2,413	10 to 12 days
9.00	25.00	23.68	MgF ₂ (400-700nm)	N-BK7	#38-220	₹2,686 Qty 10+ ₹2,413	10 to 12 days
9.00	27.00	25.35	MgF ₂ (400-700nm)	N-BK7	#32-959	₹2,686 Qty 10+ ₹2,413	10 to 12 days
9.00	36.00	34.48	MgF ₂ (400-700nm)	N-BK7	#45-122	₹2,686 Qty 10+ ₹2,413	10 to 12 days
9.00	45.00	43.98	MgF ₂ (400-700nm)	N-BK7	#45-357	₹2,686 Qty 10+ ₹2,413	10 to 12 days
9.00	54.00	52.69	MgF ₂ (400-700nm)	N-BK7	#67-155	₹2,686 Qty 10+ ₹2,413	10 to 12 days
9.00	72.00	70.68	MgF ₂ (400-700nm)	N-BK7	#67-156	₹2,686 Qty 10+ ₹2,413	10 to 12 days
9.00	90.00	88.68	MgF ₂ (400-700nm)	N-BK7	#67-157	₹2,686 Qty 10+ ₹2,413	10 to 12 days
10.00	10.00	8.18	MgF ₂ (400-700nm)	N-SF11	#63-484	₹2,764 Qty 10+ ₹2,472	10 to 12 days
10.00	12.50	10.99	MgF ₂ (400-700nm)	N-SF11	#38-223	₹2,764 Qty 10+ ₹2,472	10 to 12 days

10.00	15.00	13.32	MgF ₂ (400-700nm)	N-SF11	#63-485	₹2,764 Qty 10+ ₹2,472	10 to 12 days
10.00	17.50	15.66	MgF ₂ (400-700nm)	N-BK7	#38-224	₹2,686 Qty 10+ ₹2,413	10 to 12 days
10.00	20.00	18.03	MgF ₂ (400-700nm)	N-BK7	#63-486	₹2,686 Qty 10+ ₹2,413	10 to 12 days
10.00	25.00	23.02	MgF ₂ (400-700nm)	N-BK7	#63-487	₹2,686 Qty 10+ ₹2,413	10 to 12 days
10.00	30.00	28.01	MgF ₂ (400-700nm)	N-BK7	#63-488	₹2,686 Qty 10+ ₹2,413	10 to 12 days
10.00	40.00	38.02	MgF ₂ (400-700nm)	N-BK7	#63-489	₹2,686 Qty 10+ ₹2,413	10 to 12 days
10.00	50.00	48.02	MgF ₂ (400-700nm)	N-BK7	#63-490	₹2,686 Qty 10+ ₹2,413	10 to 12 days
10.00	75.00	73.02	MgF ₂ (400-700nm)	N-BK7	#63-491	₹2,686 Qty 10+ ₹2,413	10 to 12 days
10.00	100.00	98.02	MgF ₂ (400-700nm)	N-BK7	#63-492	₹2,686 Qty 10+ ₹2,413	10 to 12 days
12.00	12.00	9.76	MgF ₂ (400-700nm)	N-SF11	#45-084	₹2,919 Qty 10+ ₹2,627	7 days
12.00	15.00	12.03	MgF ₂ (400-700nm)	N-BK7	#45-303	₹2,919 Qty 10+ ₹2,627	10 to 12 days
12.00	18.00	16.22	MgF ₂ (400-700nm)	N-SF5	#32-007	₹2,919 Qty 10+ ₹2,627	10 to 12 days
12.00	20.00	17.69	MgF ₂ (400-700nm)	N-BK7	#49-887	₹2,919 Qty 10+ ₹2,627	10 to 12 days
12.00	24.00	22.15	MgF ₂ (400-700nm)	N-BK7	#31-855	₹2,842 Qty 10+ ₹2,550	Contact Us

12.00	25.00	23.22	MgF ₂ (400-700nm)	N-BK7	#38-226	₹2,842 Qty 10+ ₹2,550	10 to 12 days
12.00	30.00	28.02	MgF ₂ (400-700nm)	N-BK7	#45-086	₹2,842 Qty 10+ ₹2,550	10 to 12 days
12.00	36.00	34.02	MgF ₂ (400-700nm)	N-BK7	#33-353	₹2,842 Qty 10+ ₹2,550	10 to 12 days
12.00	42.00	40.22	MgF ₂ (400-700nm)	N-BK7	#45-124	₹2,842 Qty 10+ ₹2,550	10 to 12 days
12.00	48.00	46.36	MgF ₂ (400-700nm)	N-BK7	#32-853	₹2,842 Qty 10+ ₹2,550	10 to 12 days
12.00	50.00	48.75	MgF ₂ (400-700nm)	N-BK7	#38-230	₹2,842 Qty 10+ ₹2,550	10 to 12 days
12.00	54.00	52.02	MgF ₂ (400-700nm)	N-BK7	#45-305	₹2,842 Qty 10+ ₹2,550	10 to 12 days
12.00	60.00	58.37	MgF ₂ (400-700nm)	N-BK7	#32-855	₹2,842 Qty 10+ ₹2,550	10 to 12 days
12.00	72.00	70.42	MgF ₂ (400-700nm)	N-BK7	#45-126	₹2,842 Qty 10+ ₹2,550	10 to 12 days
12.00	84.00	82.39	MgF ₂ (400-700nm)	N-BK7	#32-857	₹2,842 Qty 10+ ₹2,550	10 to 12 days
12.00	100.00	98.35	MgF ₂ (400-700nm)	N-BK7	#45-275	₹2,842 Qty 10+ ₹2,550	Contact Us
12.50	12.50	10.40	MgF ₂ (400-700nm)	N-SF11	#38-231	₹2,842 Qty 10+ ₹2,550	10 to 12 days
12.50	15.00	13.26	MgF ₂ (400-700nm)	N-SF11	#38-232	₹2,842 Qty 10+ ₹2,550	10 to 12 days
12.50	17.50	15.00	MgF ₂ (400-700nm)	N-BK7	#38-233	₹2,842 Qty 10+ ₹2,550	10 to 12 days

12.50	20.00	17.69	MgF ₂ (400-700nm)	N-BK7	#38-234	₹2,842 Qty 10+ ₹2,550	Contact Us
12.50	25.00	22.96	MgF ₂ (400-700nm)	N-BK7	#38-235	₹2,764 Qty 10+ ₹2,472	10 to 12 days
12.50	30.00	28.22	MgF ₂ (400-700nm)	N-BK7	#38-237	₹2,764 Qty 10+ ₹2,472	10 to 12 days
12.50	35.00	33.42	MgF ₂ (400-700nm)	N-BK7	#38-238	₹2,764 Qty 10+ ₹2,472	Contact Us
12.50	40.00	38.55	MgF ₂ (400-700nm)	N-BK7	#38-239	₹2,764 Qty 10+ ₹2,472	10 to 12 days
12.50	45.00	43.68	MgF ₂ (400-700nm)	N-BK7	#38-240	₹2,764 Qty 10+ ₹2,472	10 to 12 days
12.50	50.00	48.68	MgF ₂ (400-700nm)	N-BK7	#38-241	₹2,764 Qty 10+ ₹2,472	10 to 12 days
12.50	75.00	73.88	MgF ₂ (400-700nm)	N-BK7	#38-242	₹2,764 Qty 10+ ₹2,472	Contact Us
12.50	100.00	98.95	MgF ₂ (400-700nm)	N-BK7	#38-243	₹2,764 Qty 10+ ₹2,472	10 to 12 days
12.70	12.70	10.46	MgF ₂ (400-700nm)	N-SF11	#49-854	₹2,842 Qty 10+ ₹2,550	10 to 12 days
12.70	15.00	11.53	MgF ₂ (400-700nm)	N-BK7	#49-855	₹2,842 Qty 10+ ₹2,550	10 to 12 days
12.70	19.10	16.46	MgF ₂ (400-700nm)	N-BK7	#49-856	₹2,842 Qty 10+ ₹2,550	10 to 12 days
12.70	20.00	17.49	MgF ₂ (400-700nm)	N-BK7	#38-244	₹2,842 Qty 10+ ₹2,550	10 to 12 days
12.70	25.40	23.43	MgF ₂ (400-700nm)	N-BK7	#49-857	₹2,764 Qty 10+ ₹2,472	10 to 12 days

12.70	30.00	28.22	MgF ₂ (400-700nm)	N-BK7	#38-245	₹2,764 Qty 10+ ₹2,472	10 to 12 days
12.70	31.80	29.81	MgF ₂ (400-700nm)	N-BK7	#49-858	₹2,764 Qty 10+ ₹2,472	10 to 12 days
12.70	38.10	36.12	MgF ₂ (400-700nm)	N-BK7	#49-859	₹2,764 Qty 10+ ₹2,472	10 to 12 days
12.70	40.00	38.48	MgF ₂ (400-700nm)	N-BK7	#38-246	₹2,764 Qty 10+ ₹2,472	10 to 12 days
12.70	44.50	42.69	MgF ₂ (400-700nm)	N-BK7	#49-860	₹2,764 Qty 10+ ₹2,472	10 to 12 days
12.70	50.80	49.15	MgF ₂ (400-700nm)	N-BK7	#49-861	₹2,764 Qty 10+ ₹2,472	10 to 12 days
12.70	100.00	98.88	MgF ₂ (400-700nm)	N-BK7	#38-247	₹2,764 Qty 10+ ₹2,472	10 to 12 days
15.00	15.00	11.71	MgF ₂ (400-700nm)	N-SF5	#45-094	₹2,919 Qty 10+ ₹2,627	10 to 12 days
15.00	18.00	15.61	MgF ₂ (400-700nm)	N-SF5	#49-888	₹2,919 Qty 10+ ₹2,627	10 to 12 days
15.00	20.00	17.74	MgF ₂ (400-700nm)	N-SF5	#63-493	₹2,919 Qty 10+ ₹2,627	10 to 12 days
15.00	22.50	20.50	MgF ₂ (400-700nm)	N-SF5	#32-005	₹2,919 Qty 10+ ₹2,627	10 to 12 days
15.00	25.00	22.50	MgF ₂ (400-700nm)	N-BK7	#38-248	₹2,842 Qty 10+ ₹2,550	10 to 12 days
15.00	30.00	27.90	MgF ₂ (400-700nm)	N-BK7	#31-856	₹2,842 Qty 10+ ₹2,550	10 to 12 days
15.00	40.00	38.02	MgF ₂ (400-700nm)	N-BK7	#45-096	₹2,842 Qty 10+ ₹2,550	10 to 12 days

15.00	45.00	43.35	MgF ₂ (400-700nm)	N-BK7	#49-889	₹2,842 Qty 10+ ₹2,550	10 to 12 days
15.00	50.00	48.35	MgF ₂ (400-700nm)	N-BK7	#38-249	₹2,842 Qty 10+ ₹2,550	10 to 12 days
15.00	60.00	58.65	MgF ₂ (400-700nm)	N-BK7	#45-436	₹2,842 Qty 10+ ₹2,550	10 to 12 days
15.00	75.00	73.79	MgF ₂ (400-700nm)	N-BK7	#45-359	₹2,842 Qty 10+ ₹2,550	10 to 12 days
15.00	100.00	98.02	MgF ₂ (400-700nm)	N-BK7	#45-260	₹2,842 Qty 10+ ₹2,550	10 to 12 days
15.00	200.00	197.89	MgF ₂ (400-700nm)	N-BK7	#14-375	₹2,842 Qty 10+ ₹2,550	Contact Us
15.00	250.00	248.02	MgF ₂ (400-700nm)	N-BK7	#14-383	₹2,842 Qty 10+ ₹2,550	10 to 12 days

[#45-438 Clearance](#)



Clearance

Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.

18.00	18.00	11.20	MgF ₂ (400-700nm)	N-BK7		₹2,003	10 to 12 days
18.00	18.00	15.20	MgF ₂ (400-700nm)	N-SF11	#48-424	₹2,958 Qty 10+ ₹2,647	10 to 12 days

18.00	20.00	17.59	MgF ₂ (400-700nm)	N-SF11	#38-250	₹2,919 Qty 10+ ₹2,627	Contact Us
18.00	22.50	20.26	MgF ₂ (400-700nm)	N-SF11	#49-890	₹2,919 Qty 10+ ₹2,627	10 to 12 days
18.00	25.00	21.51	MgF ₂ (400-700nm)	N-BK7	#38-251	₹2,919 Qty 10+ ₹2,627	10 to 12 days
18.00	27.00	24.73	MgF ₂ (400-700nm)	N-SF5	#32-002	₹2,919 Qty 10+ ₹2,627	10 to 12 days
18.00	30.00	27.10	MgF ₂ (400-700nm)	N-BK7	#38-252	₹2,803 Qty 10+ ₹2,511	10 to 12 days
18.00	36.00	33.65	MgF ₂ (400-700nm)	N-BK7	#31-857	₹2,803 Qty 10+ ₹2,511	10 to 12 days
18.00	50.00	48.09	MgF ₂ (400-700nm)	N-BK7	#38-253	₹2,803 Qty 10+ ₹2,511	10 to 12 days
18.00	54.00	52.02	MgF ₂ (400-700nm)	N-BK7	#45-307	₹2,803 Qty 10+ ₹2,511	10 to 12 days
18.00	72.00	70.05	MgF ₂ (400-700nm)	N-BK7	#32-860	₹2,803 Qty 10+ ₹2,511	Contact Us
20.00	20.00	17.42	MgF ₂ (400-700nm)	N-SF11	#45-238	₹2,997 Qty 10+ ₹2,686	10 to 12 days
20.00	25.00	22.76	MgF ₂ (400-700nm)	N-SF11	#49-891	₹2,958 Qty 10+ ₹2,647	10 to 12 days
20.00	30.00	27.30	MgF ₂ (400-700nm)	N-BAF10	#45-240	₹2,958 Qty 10+ ₹2,647	10 to 12 days
20.00	35.00	32.04	MgF ₂ (400-700nm)	N-BK7	#49-892	₹2,958 Qty 10+ ₹2,647	10 to 12 days
20.00	40.00	36.77	MgF ₂ (400-700nm)	N-BK7	#32-961	₹2,842 Qty 10+ ₹2,550	10 to 12 days

20.00	50.00	47.87	MgF ₂ (400-700nm)	N-BK7	#45-361	₹2,842 Qty 10+ ₹2,550	10 to 12 days
20.00	60.00	57.03	MgF ₂ (400-700nm)	N-BK7	#32-963	₹2,842 Qty 10+ ₹2,550	10 to 12 days
20.00	70.00	68.03	MgF ₂ (400-700nm)	N-BK7	#32-937	₹2,842 Qty 10+ ₹2,550	10 to 12 days
20.00	80.00	78.45	MgF ₂ (400-700nm)	N-BK7	#45-440	₹2,842 Qty 10+ ₹2,550	10 to 12 days
20.00	100.00	97.13	MgF ₂ (400-700nm)	N-BK7	#32-476	₹2,842 Qty 10+ ₹2,550	10 to 12 days
20.00	150.00	148.02	MgF ₂ (400-700nm)	N-BK7	#45-277	₹2,842 Qty 10+ ₹2,550	10 to 12 days
25.00	25.00	20.22	MgF ₂ (400-700nm)	N-SF5	#45-098	₹2,997 Qty 10+ ₹2,686	10 to 12 days
25.00	30.00	24.69	MgF ₂ (400-700nm)	N-BK7	#45-363	₹2,997 Qty 10+ ₹2,686	10 to 12 days
25.00	35.00	30.42	MgF ₂ (400-700nm)	N-BK7	#45-146	₹2,997 Qty 10+ ₹2,686	10 to 12 days
25.00	40.00	36.31	MgF ₂ (400-700nm)	N-BK7	#45-279	₹2,997 Qty 10+ ₹2,686	10 to 12 days
25.00	50.00	46.75	MgF ₂ (400-700nm)	N-BK7	#32-478	₹2,842 Qty 10+ ₹2,550	10 to 12 days
25.00	60.00	56.90	MgF ₂ (400-700nm)	N-BK7	#45-128	₹2,842 Qty 10+ ₹2,550	10 to 12 days
25.00	75.00	72.00	MgF ₂ (400-700nm)	N-BK7	#32-480	₹2,842 Qty 10+ ₹2,550	10 to 12 days
25.00	85.00	82.17	MgF ₂ (400-700nm)	N-BK7	#45-365	₹2,842 Qty 10+ ₹2,550	10 to 12 days

25.00	100.00	97.17	MgF ₂ (400-700nm)	N-BK7	#32-482	₹2,842 Qty 10+ ₹2,550	7 days
25.00	125.00	122.70	MgF ₂ (400-700nm)	N-BK7	#32-862	₹2,842 Qty 10+ ₹2,550	10 to 12 days
25.00	150.00	147.81	MgF ₂ (400-700nm)	N-BK7	#32-864	₹2,842 Qty 10+ ₹2,550	10 to 12 days
25.00	175.00	172.85	MgF ₂ (400-700nm)	N-BK7	#32-866	₹2,842 Qty 10+ ₹2,550	10 to 12 days
25.00	200.00	197.89	MgF ₂ (400-700nm)	N-BK7	#33-359	₹2,842 Qty 10+ ₹2,550	10 to 12 days
25.00	250.00	248.02	MgF ₂ (400-700nm)	N-BK7	#67-158	₹2,842 Qty 10+ ₹2,550	10 to 12 days
25.00	300.00	298.02	MgF ₂ (400-700nm)	N-BK7	#67-159	₹2,842 Qty 10+ ₹2,550	10 to 12 days
25.00	400.00	397.89	MgF ₂ (400-700nm)	N-BK7	#33-365	₹2,842 Qty 10+ ₹2,550	10 to 12 days
25.00	500.00	497.89	MgF ₂ (400-700nm)	N-BK7	#45-281	₹2,842 Qty 10+ ₹2,550	10 to 12 days
25.00	750.00	747.89	MgF ₂ (400-700nm)	N-BK7	#45-283	₹2,842 Qty 10+ ₹2,550	10 to 12 days
25.40	25.40	21.48	MgF ₂ (400-700nm)	N-SF11	#49-862	₹2,997 Qty 10+ ₹2,686	10 to 12 days
25.40	35.00	30.46	MgF ₂ (400-700nm)	N-BK7	#38-254	₹2,997 Qty 10+ ₹2,686	10 to 12 days
25.40	38.10	33.48	MgF ₂ (400-700nm)	N-BK7	#49-863	₹2,997 Qty 10+ ₹2,686	10 to 12 days
25.40	40.00	36.11	MgF ₂ (400-700nm)	N-BK7	#38-255	₹2,997 Qty 10+ ₹2,686	10 to 12 days

25.40	50.80	47.50	MgF ₂ (400-700nm)	N-BK7	#49-864	₹2,842 Qty 10+ ₹2,550	Contact Us
25.40	63.50	60.37	MgF ₂ (400-700nm)	N-BK7	#49-865	₹2,842 Qty 10+ ₹2,550	10 to 12 days
25.40	75.00	72.69	MgF ₂ (400-700nm)	N-BK7	#38-262	₹2,842 Qty 10+ ₹2,550	10 to 12 days
25.40	76.20	73.56	MgF ₂ (400-700nm)	N-BK7	#49-866	₹2,842 Qty 10+ ₹2,550	10 to 12 days
25.40	88.90	86.26	MgF ₂ (400-700nm)	N-BK7	#49-867	₹2,842 Qty 10+ ₹2,550	10 to 12 days
25.40	100.00	98.02	MgF ₂ (400-700nm)	N-BK7	#38-264	₹2,842 Qty 10+ ₹2,550	10 to 12 days
25.40	101.60	98.97	MgF ₂ (400-700nm)	N-BK7	#49-868	₹2,842 Qty 10+ ₹2,550	Contact Us
25.40	125.00	123.02	MgF ₂ (400-700nm)	N-BK7	#38-265	₹2,842 Qty 10+ ₹2,550	10 to 12 days
25.40	150.00	148.02	MgF ₂ (400-700nm)	N-BK7	#38-266	₹2,842 Qty 10+ ₹2,550	10 to 12 days
30.00	30.00	26.13	MgF ₂ (400-700nm)	N-SF11	#48-656	₹3,912 Qty 10+ ₹3,523	10 to 12 days
30.00	40.00	37.20	MgF ₂ (400-700nm)	N-SF11	#67-160	₹3,795 Qty 10+ ₹3,406	10 to 12 days
30.00	50.00	46.17	MgF ₂ (400-700nm)	N-SF5	#32-484	₹3,795 Qty 10+ ₹3,406	10 to 12 days
30.00	60.00	56.03	MgF ₂ (400-700nm)	N-BK7	#45-242	₹3,678 Qty 10+ ₹3,309	10 to 12 days
30.00	75.00	70.95	MgF ₂ (400-700nm)	N-BK7	#32-486	₹3,678 Qty 10+ ₹3,309	10 to 12 days

30.00	100.00	96.01	MgF ₂ (400-700nm)	N-BK7	#32-488	₹3,678 Qty 10+ ₹3,309	10 to 12 days
30.00	120.00	116.04	MgF ₂ (400-700nm)	N-BK7	#45-244	₹3,678 Qty 10+ ₹3,309	10 to 12 days
35.00	35.00	30.52	MgF ₂ (400-700nm)	N-SF11	#38-267	₹4,048 Qty 10+ ₹3,639	10 to 12 days
35.00	50.00	44.40	MgF ₂ (400-700nm)	N-BK7	#38-268	₹3,912 Qty 10+ ₹3,523	10 to 12 days
35.00	70.00	66.04	MgF ₂ (400-700nm)	N-BK7	#38-269	₹3,912 Qty 10+ ₹3,523	10 to 12 days
35.00	100.00	97.03	MgF ₂ (400-700nm)	N-BK7	#38-270	₹3,912 Qty 10+ ₹3,523	10 to 12 days
40.00	40.00	35.13	MgF ₂ (400-700nm)	N-SF11	#48-657	₹4,243 Qty 10+ ₹3,815	10 to 12 days
40.00	60.00	53.90	MgF ₂ (400-700nm)	N-BK7	#45-150	₹4,243 Qty 10+ ₹3,815	10 to 12 days
40.00	80.00	74.73	MgF ₂ (400-700nm)	N-BK7	#33-383	₹4,165 Qty 10+ ₹3,737	10 to 12 days
40.00	100.00	95.39	MgF ₂ (400-700nm)	N-BK7	#33-371	₹4,165 Qty 10+ ₹3,737	10 to 12 days
40.00	200.00	196.7	MgF ₂ (400-700nm)	N-BK7	#33-377	₹4,165 Qty 10+ ₹3,737	10 to 12 days
40.00	300.00	296.70	MgF ₂ (400-700nm)	N-BK7	#45-285	₹4,165 Qty 10+ ₹3,737	10 to 12 days
40.00	400.00	396.70	MgF ₂ (400-700nm)	N-BK7	#45-287	₹4,165 Qty 10+ ₹3,737	10 to 12 days
50.00	50.00	43.28	MgF ₂ (400-700nm)	N-SF11	#32-971	₹4,632 Qty 10+ ₹4,165	10 to 12 days

50.00	75.00	67.75	MgF ₂ (400-700nm)	N-BK7	#45-246	₹4,476 Qty 10+ ₹4,048	10 to 12 days
50.00	100.00	93.41	MgF ₂ (400-700nm)	N-BK7	#32-973	₹4,282 Qty 10+ ₹3,854	Contact Us
50.00	125.00	118.39	MgF ₂ (400-700nm)	N-BK7	#45-248	₹4,282 Qty 10+ ₹3,854	10 to 12 days
50.00	150.00	144.07	MgF ₂ (400-700nm)	N-BK7	#32-975	₹4,282 Qty 10+ ₹3,854	10 to 12 days
50.00	175.00	169.05	MgF ₂ (400-700nm)	N-BK7	#45-250	₹4,282 Qty 10+ ₹3,854	10 to 12 days
50.00	200.00	196.66	MgF ₂ (400-700nm)	N-BK7	#45-152	₹4,282 Qty 10+ ₹3,854	10 to 12 days
50.00	250.00	246.74	MgF ₂ (400-700nm)	N-BK7	#45-154	₹4,282 Qty 10+ ₹3,854	Contact Us
50.00	500.00	496.70	MgF ₂ (400-700nm)	N-BK7	#45-289	₹4,282 Qty 10+ ₹3,854	10 to 12 days

[#71-335 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

50.80	50.81	44.08	MgF ₂ (400-700nm)	N-SF11		₹4,632 Qty 11+ ₹4,165	10 to 12 days
-------	-------	-------	---------------------------------	------------------------	--	--------------------------	---------------

#71-342 New



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

50.80	76.20	68.95	MgF2 (400-700nm)	N-BK7		₹4,476 Qty 11+ ₹4,048	10 to 12 days
-------	-------	-------	---------------------	-----------------------	--	--------------------------	---------------

75.00	75.00	53.49	MgF ₂ (400-700nm)	N-BK7	#45-368	₹7,746 Qty 10+ ₹6,968	10 to 12 days
-------	-------	-------	---------------------------------	-----------------------	-------------------------	--------------------------	---------------

#71-840 New



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

75.00	100.00	87.57	MgF2 (400-700nm)	N-BK7		₹7,590 Qty 10+ ₹6,851	10 to 12 days
-------	--------	-------	---------------------	-----------------------	--	--------------------------	---------------

[#71-841 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

75.00	125.00	115.99	MgF ₂ (400-700nm)	N-BK7		₹7,590 Qty 10+ ₹6,851	10 to 12 days
-------	--------	--------	---------------------------------	-----------------------	--	--------------------------	---------------

75.00	150.00	142.45	MgF ₂ (400-700nm)	N-BK7	#45-370	₹7,590 Qty 10+ ₹6,851	10 to 12 days
-------	--------	--------	---------------------------------	-----------------------	-------------------------	--------------------------	---------------

[#71-842 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

75.00	175.00	168.68	MgF ₂ (400-700nm)	N-BK7		₹7,590 Qty 10+ ₹6,851	10 to 12 days
-------	--------	--------	---------------------------------	-----------------------	--	--------------------------	---------------

75.00	200.00	194.24	MgF ₂ (400-700nm)	N-BK7	#45-372	₹7,590 Qty 10+ ₹6,851	10 to 12 days
-------	--------	--------	---------------------------------	-----------------------	-------------------------	--------------------------	---------------

75.00	250.00	244.73	MgF2 (400-700nm)	N-BK7	#63-495	₹7,590 Qty 10+ ₹6,851	10 to 12 days
#71-843 New							
×							
New							
Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!							
75.00	300.00	294.4	MgF2 (400-700nm)	N-BK7		₹7,590 Qty 10+ ₹6,851	10 to 12 days
#71-844 New							
×							
New							
Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!							
75.00	400.00	394.4	MgF2 (400-700nm)	N-BK7		₹7,590 Qty 10+ ₹6,851	10 to 12 days
75.00	500.00	494.73	MgF2 (400-700nm)	N-BK7	#63-496	₹7,590 Qty 10+ ₹6,851	10 to 12 days

[#71-845 New](#)



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the first
to buy
before
anyone
else!

75.00	750.00	745.35	MgF ₂ (400- 700nm)	N-BK7		₹7,590 Qty 10+ ₹6,851	10 to 12 days
-------	--------	--------	-------------------------------------	-----------------------	--	--------------------------	---------------

100.00	200.00	190.77	MgF ₂ (400- 700nm)	N-BK7	#17-900	₹24,134 Qty 6+ ₹21,720	Contact Us
--------	--------	--------	-------------------------------------	-----------------------	-------------------------	---------------------------	------------

150.00	300.00	285.50	MgF ₂ (400- 700nm)	N-BK7	#17-916	₹44,375 Qty 6+ ₹40,093	10 to 12 days
--------	--------	--------	-------------------------------------	-----------------------	-------------------------	---------------------------	---------------

200.00	400.00	381.54	MgF ₂ (400- 700nm)	N-BK7	#17-932	₹83,300 Qty 6+ ₹75,125	10 to 12 days
--------	--------	--------	-------------------------------------	-----------------------	-------------------------	---------------------------	---------------



Copyright 2023, Edmund Optics India Private Limited, #267, Greystone Building, Second Floor, 6th Cross Rd, Binnamangala, Stage 1, Indiranagar, Bengaluru, Karnataka, India 560038

Phone: 1-800-363-1992 :

www.edmundoptics.com