

[All Products](#) / [Optics](#) / [Optical Filters](#) / [Neutral Density \(ND\) Filters](#)

Non-Reflective Neutral Density (ND) Filters



- Prevent Unwanted Reflection Towards the Light Source
- Spectrally Flat
- VIS and NIR Ranges Available

Common Specifications


Physical & Mechanical Properties

Thickness (mm):	1.50 ±0.1	Parallelism (arcmin):	<5
Clear Aperture (%):	90.00		

Optical Properties

Substrate:	B270		
Coating:	Non-Reflective ND	Surface Quality:	60-40
Surface Accuracy:	2λ		

Technical Information

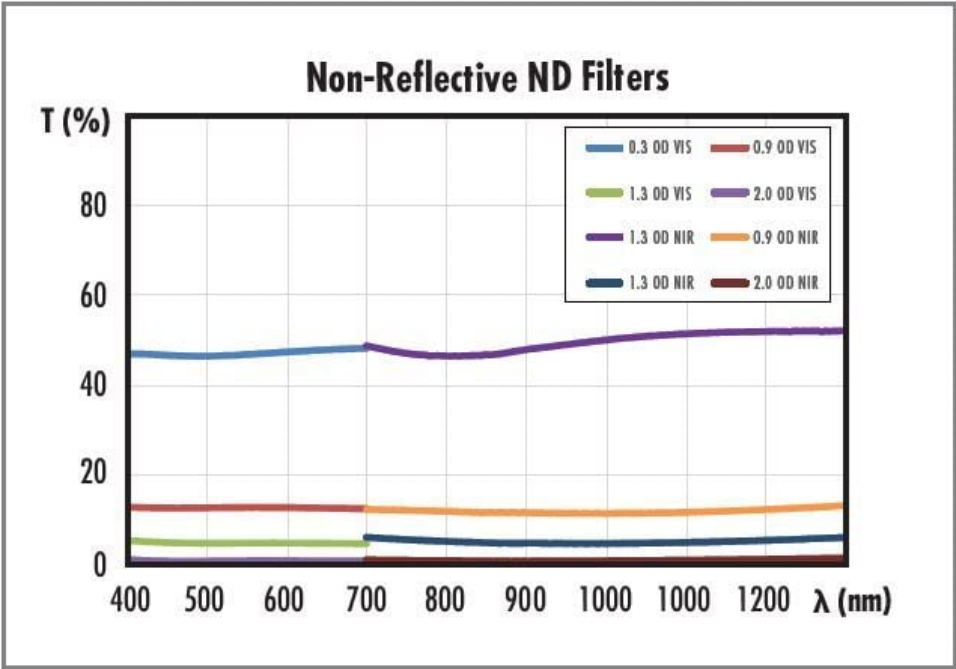

Products

Dia. (mm)	Optical Density OD (Average)	Thickness (mm)	Transmission (%)	Wavelength Range (nm)	Stock Number	Price	Buy
12.50	0.3	1.50	50.00	700 - 1200	#63-396	₹8,953 Qty 11+ ₹8,096	10 to 12 days
25.00	0.3	1.50	50.00	700 - 1200	#63-406	₹11,522 Qty 11+ ₹10,354	10 to 12 days
12.50	0.3	1.50	50.00	400 - 700	#63-376	₹8,953 Qty 11+ ₹8,096	Contact Us
25.00	0.3	1.50	50.00	400 - 700	#63-386	₹11,522 Qty 11+ ₹10,354	10 to 12 days
12.50	0.5	1.50	32.00	700 - 1200	#63-397	₹8,953 Qty 11+ ₹8,096	10 to 12 days
25.00	0.5	1.50	32.00	700 - 1200	#63-407	₹11,522 Qty 11+ ₹10,354	10 to 12 days
12.50	0.5	1.50	32.00	400 - 700	#63-377	₹8,953 Qty 11+ ₹8,096	10 to 12 days
25.00	0.5	1.50	32.00	400 - 700	#63-387	₹11,522 Qty 11+ ₹10,354	10 to 12 days
12.50	0.6	1.50	25.00	700 - 1200	#63-398	₹8,953 Qty 11+ ₹8,096	10 to 12 days
25.00	0.6	1.50	25.00	700 - 1200	#63-408	₹11,522 Qty 11+ ₹10,354	10 to 12 days
12.50	0.6	1.50	25.00	400 - 700	#63-378	₹8,953 Qty 11+ ₹8,096	10 to 12 days
25.00	0.6	1.50	25.00	400 - 700	#63-388	₹11,522 Qty 11+ ₹10,354	10 to 12 days
12.50	0.9	1.50	12.50	700 - 1200	#63-399	₹8,953 Qty 11+ ₹8,096	10 to 12 days
25.00	0.9	1.50	12.50	700 - 1200	#63-409	₹11,522 Qty 11+ ₹10,354	10 to 12 days
12.50	0.9	1.50	12.50	400 - 700	#63-379	₹8,953 Qty 11+ ₹8,096	10 to 12 days
25.00	0.9	1.50	12.50	400 - 700	#63-389	₹11,522 Qty 11+ ₹10,354	10 to 12 days
12.50	1.0	1.50	10.00	700 - 1200	#63-400	₹8,953 Qty 11+ ₹8,096	10 to 12 days

25.00	1.0	1.50	10.00	700 - 1200	#63-410	₹11,522 Qty 11+ ₹10,354	10 to 12 days
12.50	1.0	1.50	10.00	400 - 700	#63-380	₹8,953 Qty 11+ ₹8,096	10 to 12 days
25.00	1.0	1.50	10.00	400 - 700	#63-390	₹11,522 Qty 11+ ₹10,354	Contact Us
12.50	1.3	1.50	5.00	700 - 1200	#63-401	₹8,953 Qty 11+ ₹8,096	10 to 12 days
25.00	1.3	1.50	5.00	700 - 1200	#63-411	₹11,522 Qty 11+ ₹10,354	10 to 12 days
12.50	1.3	1.50	5.00	400 - 700	#63-381	₹8,953 Qty 11+ ₹8,096	10 to 12 days
25.00	1.3	1.50	5.00	400 - 700	#63-391	₹11,522 Qty 11+ ₹10,354	10 to 12 days
12.50	1.5	1.50	3.20	700 - 1200	#63-402	₹8,953 Qty 11+ ₹8,096	10 to 12 days
25.00	1.5	1.50	3.20	700 - 1200	#63-412	₹11,522 Qty 11+ ₹10,354	10 to 12 days
12.50	1.5	1.50	3.20	400 - 700	#63-382	₹8,953 Qty 11+ ₹8,096	10 to 12 days
25.00	1.5	1.50	3.20	400 - 700	#63-392	₹11,522 Qty 11+ ₹10,354	10 to 12 days
12.50	2.0	1.50	1.00	700 - 1200	#63-403	₹8,953 Qty 11+ ₹8,096	Contact Us
25.00	2.0	1.50	1.00	700 - 1200	#63-413	₹11,522 Qty 11+ ₹10,354	10 to 12 days
12.50	2.0	1.50	1.00	400 - 700	#63-383	₹8,953 Qty 11+ ₹8,096	10 to 12 days
25.00	2.0	1.50	1.00	400 - 700	#63-393	₹11,522 Qty 11+ ₹10,354	7 days
12.50	2.5	1.50	0.30	700 - 1200	#63-404	₹8,953 Qty 11+ ₹8,096	10 to 12 days
25.00	2.5	1.50	0.30	700 - 1200	#63-414	₹11,522 Qty 11+ ₹10,354	10 to 12 days
12.50	2.5	1.50	0.30	400 - 700	#63-384	₹8,953 Qty 11+ ₹8,096	10 to 12 days
25.00	2.5	1.50	0.30	400 - 700	#63-394	₹11,522 Qty 11+ ₹10,354	10 to 12 days
12.50	3.0	1.50	0.10	700 - 1200	#63-405	₹8,953 Qty 11+ ₹8,096	10 to 12 days

25.00	3.0	1.50	0.10	700 - 1200	#63-415	₹11,522 Qty 11+ ₹10,354	10 to 12 days
12.50	3.0	1.50	0.10	400 - 700	#63-385	₹8,953 Qty 11+ ₹8,096	10 to 12 days
25.00	3.0	1.50	0.10	400 - 700	#63-395	₹11,522 Qty 11+ ₹10,354	7 days



Copyright 2023, Edmund Optics India Private Limited, #267, Greystone Building, Second Floor, 6th Cross Rd, Binnamangala, Stage 1, Indiranagar, Bengaluru, Karnataka, India 560038
Phone: 1-800-363-1992 :
www.edmundoptics.com