

[All Products](#) / [Optics](#) / [Optical Mirrors](#) / [Focusing \(Concave\) Mirrors](#)

Precision Ellipsoidal Reflectors



- Precision Polished Substrate
- Protected Aluminum and Cold Mirror Coating Options
- Ideal for Solar and Condensing Applications
- [Precision Parabolic Reflectors](#) Also Available


Common Specifications

Optical Properties

Substrate: [BOROFLOAT®](#)

Coating Type: Metal

Technical Information

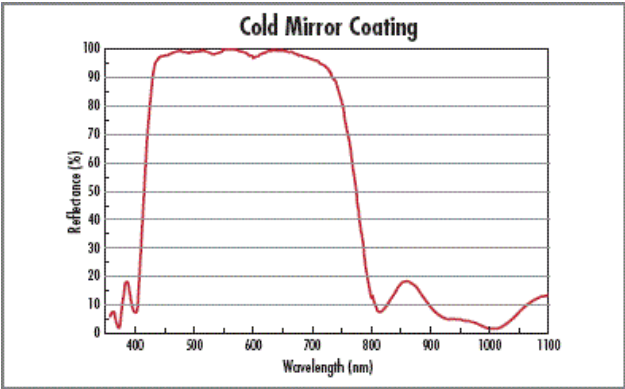

Products

Coating	Center Hole Diameter (mm)	Outer Diameter (mm)	Distance to Focal Point f_1 (mm)	Distance to Focal Point f_2 (mm)	Stock Number	Price	Buy
Protected Aluminum (400-700nm)	18.0	64.00	11	78	#90-968	₹19,073 Qty 11+ ₹16,893	10 to 12 days
Protected Aluminum (400-700nm)	20.0	86.00	14	134	#68-797	₹28,415 Qty 11+ ₹24,912	10 to 12 days
Protected Aluminum (400-700nm)	27.0	105.00	22	145	#90-969	₹29,661 Qty 11+ ₹26,080	10 to 12 days
Protected Aluminum (400-700nm)	27.0	113.00	17	272	#68-798	₹31,763 Qty 11+ ₹27,715	Contact Us
Protected Aluminum (400-700nm)	31.0	128.00	17.8	294	#90-970	₹37,991 Qty 11+ ₹33,320	10 to 12 days
Protected Aluminum (400-700nm)	40.0	150.00	22.5	360	#90-971	₹54,495 Qty 11+ ₹48,267	10 to 12 days
Protected Aluminum (400-700nm)	60.0	220.00	40	440	#68-799	₹68,119 Qty 11+ ₹59,945	Contact Us
Protected Aluminum (400-700nm)	80.0	300.00	45	790	#90-972	₹1,00,427 Qty 11+ ₹88,749	10 to 12 days
Cold Mirror, 0°	18.0	64.00	11	78	#90-973	₹22,109 Qty 11+ ₹19,307	Contact Us
Cold Mirror, 0°	20.0	88.00	14	134	#68-800	₹37,602 Qty 11+ ₹32,931	10 to 12 days

Cold Mirror, 0°	27.0	105.00	22	145	#90-974	₹39,314 Qty 11+ ₹34,643	10 to 12 days
Cold Mirror, 0°	27.0	113.00	17	272	#68-801	₹42,039 Qty 11+ ₹37,368	Contact Us
Cold Mirror, 0°	60.0	220.00	40	440	#68-803	₹1,00,427 Qty 11+ ₹88,749	10 to 12 days



Copyright 2023, Edmund Optics India Private Limited, #267, Greystone Building, Second Floor, 6th Cross Rd, Binnamangala, Stage 1, Indiranagar, Bengaluru, Karnataka, India 560038

Phone: 1-800-363-1992 :

www.edmundoptics.com