


[All Products](#) / [Optics](#) / [Polarization Optics](#) / [Linear Polarizers](#) / [Crystalline Polarizers](#)

Rochon Polarizers

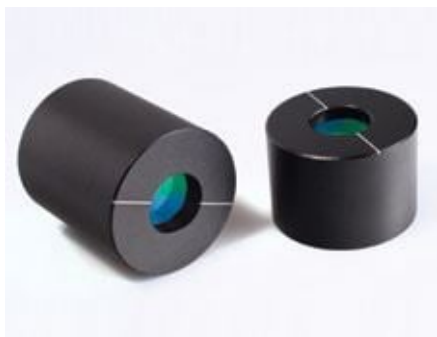

- Multiple Polarization Materials Available
- Ordinary Rays Pass Through Undeviated
- Extraordinary Rays Deviate
- [Wollaston Polarizers](#) Also Available

Common Specifications


Physical & Mechanical Properties

Clear Aperture CA (mm):	10.0	Diameter (mm):	25.40
Dimensional Tolerance (mm):	+0.0/-0.2	Construction:	Crystalline Rochon Polarizer
Length Tolerance (mm):	±0.1	Housing:	Black Anodized Aluminum

Optical Properties

Surface Quality:	20-10	Transmitted Wavefront, P-V:	$\lambda/4$ @ 632.8nm
Beam Deviation (arcmin):	<3	Damage Threshold, By Design:	10 J/cm ² @ 1064nm, 20ns

Technical Information

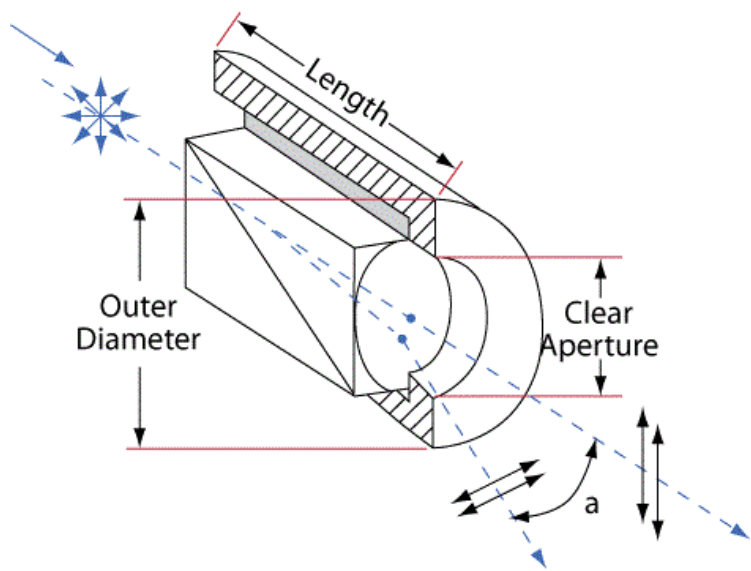

Products

Wavelength Range (nm)	Extinction Ratio	Substrate	CA (mm)	Length (mm)	Stock Number	Price	Buy
200 - 2300	20,000:1	Crystal Quartz	10.0	28.00	#68-824	₹61,891	10 to 12 days
130 - 7000	10,000:1	MgF ₂	10.0	28.00	#68-825	₹75,904	10 to 12 days
200 - 3500	200,000:1	α-BBO	10.0	18.00	#68-827	₹90,773	10 to 12 days



Copyright 2023, Edmund Optics India Private Limited, #267, Greystone Building, Second Floor, 6th Cross Rd, Binnamangala, Stage 1, Indiranagar, Bengaluru, Karnataka, India 560038
Phone: 1-800-363-1992 :
www.edmundoptics.com