


[All Products](#) / [Optics](#) / [Optical Filters](#) / [Shortpass Filters](#)

TECHSPEC® Dichroic Shortpass Filters

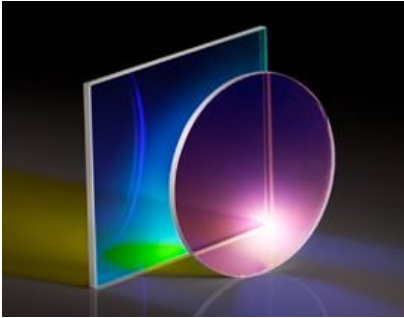

- Sharp Cut-Off Wavelength
- Broad Transmission and Reflection Ranges
- Available in a Range of Common Sizes

Common Specifications

Physical & Mechanical Properties

Thickness (mm):	1.05 ±0.1	Dimensional Tolerance (mm):	+0.0/-0.2
Physical Durability:	Adhesion per MIL-PRF-13830B, Section C.4.5.12 Moderate abrasion per MIL-PRF-13830B, Section C.4.5.11 Cleaning per MIL-C-48497A Section 4.5.4.2		


Optical Properties

Angle of Incidence (°):	45		
Substrate:	Fused Silica (Corning 7980)	Coating:	Hard Coated
P-Polarization Transmission (%):	>80	Reflection (%):	>97 Average Polarization
S-Polarization Transmission (%):	>80	Surface Quality:	60-40
Transmission (%):	>85 Average Polarization	Transmitted Wavefront, RMS:	λ/4
Cut-Off Tolerance (%):	±2	S-Polarization Reflection (%):	>95
P-Polarization Reflection (%):	>95	Coating Specification:	Surface 1: Hard Dielectric Sputtered Surface 2: AR Coated

Environmental & Durability Factors

Environmental Durability:	Humidity per MIL-STD-810H, Section 507.6 Temperature per MIL-STD-810H, Section 501.7 and 502.7
---------------------------	---

Technical Information

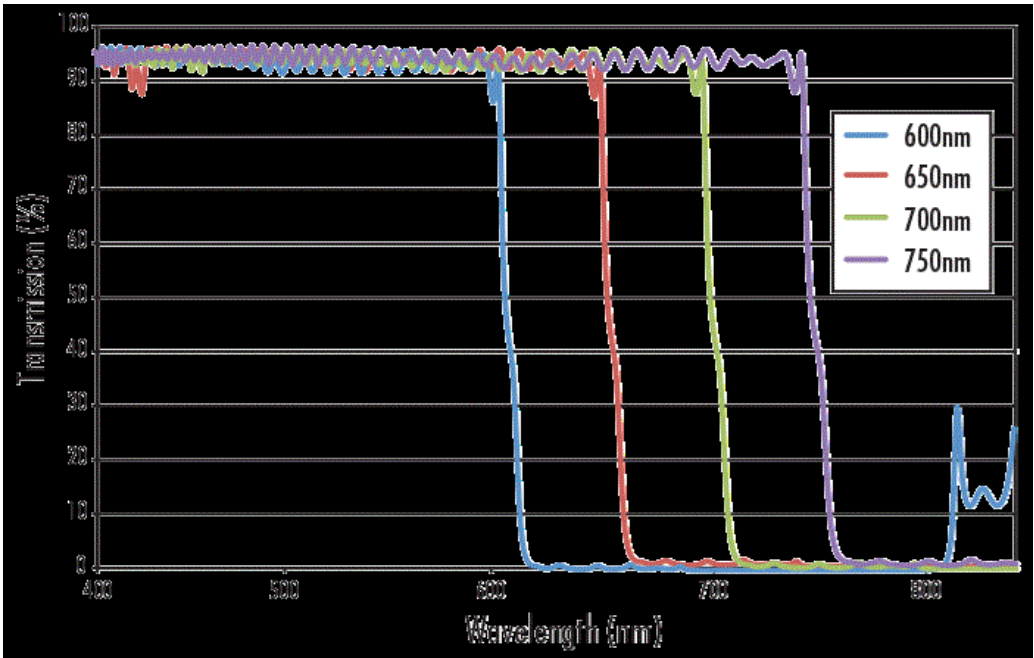

Products

Dimensions (mm)	Dia. (mm)	Cut-Off Wavelength (nm)	Transmission Wavelength (nm)	Wavelength Range (nm)	Stock Number	Price	Buy
-	12.50	400.00	325 - 385	325 - 485	#69-176	₹10,121 Qty 6+ ₹7,785	10 to 12 days
-	12.50	450.00	325 - 430	325 - 545	#69-177	₹10,121 Qty 6+ ₹7,785	10 to 12 days
-	12.50	500.00	325 - 480	325 - 610	#69-178	₹10,121 Qty 6+ ₹7,785	Contact Us
-	12.50	550.00	400 - 530	400 - 725	#69-179	₹10,121 Qty 6+ ₹7,785	10 to 12 days
-	12.50	600.00	400 - 580	400 - 795	#69-180	₹10,121 Qty 6+ ₹7,785	10 to 12 days
-	12.50	650.00	400 - 630	400 - 850	#69-181	₹10,121 Qty 6+ ₹7,785	10 to 12 days
-	12.50	700.00	400 - 680	400 - 900	#69-182	₹10,121 Qty 6+ ₹7,785	10 to 12 days
-	12.50	750.00	400 - 725	400 - 990	#69-183	₹10,276 Qty 6+ ₹8,019	10 to 12 days
-	12.50	800.00	400 - 775	400 - 1050	#69-184	₹10,276 Qty 6+ ₹8,019	10 to 12 days
-	12.50	850.00	400 - 820	400 - 1110	#69-185	₹10,276 Qty 6+ ₹8,019	10 to 12 days
-	12.50	900.00	465 - 865	465 - 1170	#69-186	₹10,276 Qty 6+ ₹8,019	10 to 12 days
12.5 x 17.6	-	400.00	325 - 385	325 - 485	#69-188	₹10,121 Qty 6+ ₹7,785	10 to 12 days
12.5 x 17.6	-	450.00	325 - 430	325 - 545	#69-189	₹10,121 Qty 6+ ₹7,785	10 to 12 days
12.5 x 17.6	-	500.00	325 - 480	325 - 610	#69-190	₹10,121 Qty 6+ ₹7,785	10 to 12 days
12.5 x 17.6	-	550.00	400 - 530	400 - 725	#69-191	₹10,121 Qty 6+ ₹7,785	10 to 12 days
12.5 x 17.6	-	600.00	400 - 580	400 - 795	#69-192	₹10,121 Qty 6+ ₹7,785	10 to 12 days
12.5 x 17.6	-	650.00	400 - 630	400 - 850	#69-193	₹10,121 Qty 6+ ₹7,785	10 to 12 days

12.5 x 17.6	-	700.00	400 - 680	400 - 900	#69-194	₹10,121 Qty 6+ ₹7,785	10 to 12 days
12.5 x 17.6	-	750.00	400 - 725	400 - 990	#69-195	₹10,276 Qty 6+ ₹8,019	10 to 12 days
12.5 x 17.6	-	800.00	400 - 775	400 - 1050	#69-196	₹10,276 Qty 6+ ₹8,019	10 to 12 days
12.5 x 17.6	-	850.00	400 - 820	400 - 1110	#69-197	₹10,276 Qty 6+ ₹8,019	10 to 12 days
12.5 x 17.6	-	900.00	465 - 865	465 - 1170	#69-198	₹10,276 Qty 6+ ₹8,019	10 to 12 days
-	25.00	400.00	325 - 385	325 - 485	#69-200	₹13,546 Qty 6+ ₹10,588	10 to 12 days
-	25.00	450.00	325 - 430	325 - 545	#69-201	₹13,546 Qty 6+ ₹10,588	10 to 12 days
-	25.00	500.00	325 - 480	325 - 610	#69-202	₹13,546 Qty 6+ ₹10,588	10 to 12 days
-	25.00	550.00	400 - 530	400 - 725	#69-203	₹13,546 Qty 6+ ₹10,588	10 to 12 days
-	25.00	600.00	400 - 580	400 - 795	#69-204	₹13,546 Qty 6+ ₹10,588	10 to 12 days
-	25.00	650.00	400 - 630	400 - 850	#69-205	₹13,546 Qty 6+ ₹10,588	10 to 12 days
-	25.00	700.00	400 - 680	400 - 900	#69-206	₹13,546 Qty 6+ ₹10,588	10 to 12 days
-	25.00	750.00	400 - 725	400 - 990	#69-207	₹14,013 Qty 6+ ₹10,899	10 to 12 days
-	25.00	800.00	400 - 775	400 - 1050	#69-208	₹14,013 Qty 6+ ₹10,899	10 to 12 days
-	25.00	850.00	400 - 820	400 - 1110	#69-209	₹14,013 Qty 6+ ₹10,899	10 to 12 days
-	25.00	900.00	465 - 865	465 - 1170	#69-210	₹14,013 Qty 6+ ₹10,899	10 to 12 days
25.2 x 35.6	-	400.00	325 - 385	325 - 485	#69-212	₹13,546 Qty 6+ ₹10,588	10 to 12 days
25.2 x 35.6	-	450.00	325 - 430	325 - 545	#69-213	₹13,546 Qty 6+ ₹10,588	10 to 12 days
25.2 x 35.6	-	500.00	325 - 480	325 - 610	#69-214	₹13,546 Qty 6+ ₹10,588	10 to 12 days
25.2 x 35.6	-	550.00	400 - 530	400 - 725	#69-215	₹13,546 Qty 6+ ₹10,588	10 to 12 days

25.2 x 35.6	-	600.00	400 - 580	400 - 795	#69-216	₹13,546 Qty 6+ ₹10,588	10 to 12 days
25.2 x 35.6	-	650.00	400 - 630	400 - 850	#69-217	₹13,546 Qty 6+ ₹10,588	10 to 12 days
25.2 x 35.6	-	700.00	400 - 680	400 - 900	#69-218	₹13,546 Qty 6+ ₹10,588	10 to 12 days
25.2 x 35.6	-	750.00	400 - 725	400 - 990	#69-219	₹14,013 Qty 6+ ₹10,899	Contact Us
25.2 x 35.6	-	800.00	400 - 775	400 - 1050	#69-220	₹14,013 Qty 6+ ₹10,899	10 to 12 days
25.2 x 35.6	-	850.00	400 - 820	400 - 1110	#69-221	₹14,013 Qty 6+ ₹10,899	10 to 12 days
25.2 x 35.6	-	900.00	465 - 865	465 - 1170	#69-222	₹14,013 Qty 6+ ₹10,899	10 to 12 days
-	12.50	950.00	495 - 912	495 - 1235	#86-676	₹10,276 Qty 6+ ₹8,019	Contact Us
-	12.50	1,000.00	520 - 960	520 - 1300	#86-677	₹10,588 Qty 6+ ₹8,174	10 to 12 days
-	12.50	1,050.00	546 - 1008	546 - 1365	#86-678	₹10,588 Qty 6+ ₹8,174	Contact Us
-	12.50	1,100.00	572 - 1056	572 - 1430	#86-679	₹10,588 Qty 6+ ₹8,174	10 to 12 days
-	12.50	1,200.00	624 - 1152	624 - 1560	#86-681	₹10,588 Qty 6+ ₹8,174	10 to 12 days
12.5 x 17.6	-	950.00	495 - 912	495 - 1235	#86-682	₹10,276 Qty 6+ ₹8,019	10 to 12 days
12.5 x 17.6	-	1,000.00	520 - 960	520 - 1300	#86-683	₹10,588 Qty 6+ ₹8,174	10 to 12 days
12.5 x 17.6	-	1,050.00	546 - 1008	546 - 1365	#86-684	₹10,588 Qty 6+ ₹8,174	10 to 12 days
12.5 x 17.6	-	1,100.00	572 - 1056	572 - 1430	#86-685	₹10,588 Qty 6+ ₹8,174	10 to 12 days
12.5 x 17.6	-	1,150.00	598 - 1104	598 - 1495	#86-686	₹10,588 Qty 6+ ₹8,174	10 to 12 days
12.5 x 17.6	-	1,200.00	624 - 1152	624 - 1560	#86-687	₹10,588 Qty 6+ ₹8,174	10 to 12 days
-	25.00	950.00	495 - 912	495 - 1325	#86-688	₹14,013 Qty 6+ ₹10,899	Contact Us
-	25.00	1,000.00	520 - 960	520 - 1300	#86-689	₹14,402 Qty 6+ ₹11,210	10 to 12 days

-	25.00	1,050.00	546 - 1008	546 - 1365	#86-690	₹14,402 Qty 6+ ₹11,210	10 to 12 days
-	25.00	1,100.00	572 - 1056	572 - 1430	#86-691	₹14,402 Qty 6+ ₹11,210	10 to 12 days
-	25.00	1,150.00	598 - 1104	598 - 1495	#86-692	₹14,402 Qty 6+ ₹11,210	10 to 12 days
-	25.00	1,200.00	624 - 1152	624 - 1560	#86-693	₹14,402 Qty 6+ ₹11,210	10 to 12 days
25.2 x 35.6	-	950.00	495 - 912	495 - 1235	#86-694	₹14,013 Qty 6+ ₹10,899	10 to 12 days
25.2 x 35.6	-	1,000.00	520 - 960	520 - 1300	#86-695	₹14,402 Qty 6+ ₹11,210	10 to 12 days
25.2 x 35.6	-	1,050.00	546 - 1008	546 - 1365	#86-696	₹14,402 Qty 6+ ₹11,210	10 to 12 days
25.2 x 35.6	-	1,100.00	572 - 1056	572 - 1430	#86-697	₹14,402 Qty 6+ ₹11,210	10 to 12 days
25.2 x 35.6	-	1,150.00	598 - 1104	598 - 1495	#86-698	₹14,402 Qty 6+ ₹11,210	10 to 12 days
25.2 x 35.6	-	1,200.00	624 - 1152	624 - 1560	#86-699	₹14,402 Qty 6+ ₹11,210	10 to 12 days



Edmund
optics | worldwide

Copyright 2023, Edmund Optics India Private Limited, #267, Greystone Building, Second Floor, 6th Cross Rd, Binnamangala, Stage 1, Indiranagar, Bengaluru, Karnataka, India 560038
Phone: 1-800-363-1992 :
www.edmundoptics.com