

[All Products](#) / [Laser Optics](#) / [Laser Lenses](#) / [Plano-Convex \(PCX\) Laser Lenses](#)

**TECHSPEC®**

## 1550nm Laser Line Coated Plano-Convex (PCX) Lenses



- <0.25% Reflection at Design Wavelength
- Coatings Available for Diode, HeNe, and Nd:YAG Laser Sources
- BBAR Coating Options Also Available: [uncoated](#), [MgF<sub>2</sub>](#), [VIS 0°](#), [VIS-NIR](#), [NIR I](#), [NIR II](#)
- [405nm](#), [532nm](#), [633nm](#), [785nm](#), [980nm](#), [1064nm](#), and 1550nm V-Coated Options Offered

### Common Specifications

#### Physical & Mechanical Properties


Bevel: Protective as needed

#### Optical Properties

Coating: Laser V-Coat (1550nm)

|                               |       |                              |                                    |
|-------------------------------|-------|------------------------------|------------------------------------|
| Surface Quality:              | 40-20 | Power (P-V) @ 632.8nm:       | 1.5λ                               |
| Irregularity (P-V) @ 632.8nm: | λ/4   | Focal Length Tolerance (%):  | ±1                                 |
| Design Wavelength DWL (nm):   | 1550  | Damage Threshold, By Design: | 5 J/cm <sup>2</sup> @ 1550nm, 10ns |

Technical Information

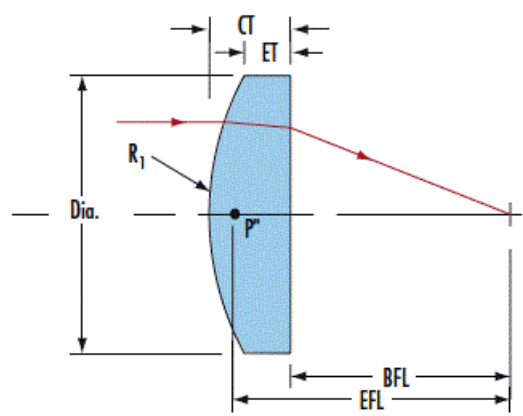

## Products

| Dia.<br>(mm) | EFL<br>(mm) | BFL<br>(mm) | Coating                      | Substrate              | Stock<br>Number         | Price                    | Buy           |
|--------------|-------------|-------------|------------------------------|------------------------|-------------------------|--------------------------|---------------|
| 5.00         | 7.50        | 6.43        | Laser V-<br>Coat<br>(1550nm) | <a href="#">N-SF11</a> | <a href="#">#89-048</a> | ₹4,243<br>Qty 10+ ₹3,834 | 10 to 12 days |
| 5.00         | 10.00       | 8.92        | Laser V-<br>Coat<br>(1550nm) | <a href="#">N-BK7</a>  | <a href="#">#89-049</a> | ₹4,243<br>Qty 10+ ₹3,834 | 10 to 12 days |
| 5.00         | 12.00       | 10.83       | Laser V-<br>Coat<br>(1550nm) | <a href="#">N-BK7</a>  | <a href="#">#89-050</a> | ₹4,243<br>Qty 10+ ₹3,834 | 10 to 12 days |
| 5.00         | 15.00       | 13.94       | Laser V-<br>Coat<br>(1550nm) | <a href="#">N-BK7</a>  | <a href="#">#89-051</a> | ₹4,243<br>Qty 10+ ₹3,834 | 10 to 12 days |
| 5.00         | 20.00       | 19.02       | Laser V-<br>Coat<br>(1550nm) | <a href="#">N-BK7</a>  | <a href="#">#89-052</a> | ₹4,243<br>Qty 10+ ₹3,834 | 10 to 12 days |
| 5.00         | 25.00       | 23.95       | Laser V-<br>Coat<br>(1550nm) | <a href="#">N-BK7</a>  | <a href="#">#89-053</a> | ₹4,243<br>Qty 10+ ₹3,834 | 10 to 12 days |
| 5.00         | 30.00       | 28.95       | Laser V-<br>Coat<br>(1550nm) | <a href="#">N-BK7</a>  | <a href="#">#89-054</a> | ₹4,243<br>Qty 10+ ₹3,834 | 10 to 12 days |
| 6.00         | 6.00        | 4.6         | Laser V-<br>Coat<br>(1550nm) | <a href="#">N-SF11</a> | <a href="#">#84-205</a> | ₹3,659<br>Qty 10+ ₹3,309 | 10 to 12 days |
| 6.00         | 7.50        | 6.1         | Laser V-<br>Coat<br>(1550nm) | <a href="#">N-SF11</a> | <a href="#">#84-206</a> | ₹3,620<br>Qty 10+ ₹3,270 | Contact Us    |
| 6.00         | 9.00        | 7.95        | Laser V-<br>Coat<br>(1550nm) | <a href="#">N-SF5</a>  | <a href="#">#84-207</a> | ₹3,620<br>Qty 10+ ₹3,270 | 10 to 12 days |
| 6.00         | 12.00       | 10.94       | Laser V-<br>Coat<br>(1550nm) | <a href="#">N-BK7</a>  | <a href="#">#84-208</a> | ₹3,503<br>Qty 10+ ₹3,153 | Contact Us    |
| 6.00         | 15.00       | 13.68       | Laser V-<br>Coat<br>(1550nm) | <a href="#">N-BK7</a>  | <a href="#">#84-209</a> | ₹3,503<br>Qty 10+ ₹3,153 | 10 to 12 days |

|      |       |       |                          |                        |                         |                          |               |
|------|-------|-------|--------------------------|------------------------|-------------------------|--------------------------|---------------|
| 6.00 | 18.00 | 17.07 | Laser V-Coat<br>(1550nm) | <a href="#">N-BK7</a>  | <a href="#">#84-210</a> | ₹3,542<br>Qty 10+ ₹3,192 | 10 to 12 days |
| 6.00 | 21.00 | 20.06 | Laser V-Coat<br>(1550nm) | <a href="#">N-BK7</a>  | <a href="#">#84-211</a> | ₹3,542<br>Qty 10+ ₹3,192 | 10 to 12 days |
| 6.00 | 24.00 | 23.01 | Laser V-Coat<br>(1550nm) | <a href="#">N-BK7</a>  | <a href="#">#84-212</a> | ₹3,542<br>Qty 10+ ₹3,192 | 10 to 12 days |
| 6.00 | 30.00 | 29.14 | Laser V-Coat<br>(1550nm) | <a href="#">N-BK7</a>  | <a href="#">#84-213</a> | ₹3,503<br>Qty 10+ ₹3,153 | Contact Us    |
| 6.00 | 36.00 | 34.95 | Laser V-Coat<br>(1550nm) | <a href="#">N-BK7</a>  | <a href="#">#84-214</a> | ₹3,542<br>Qty 10+ ₹3,192 | 10 to 12 days |
| 6.00 | 48.00 | 46.95 | Laser V-Coat<br>(1550nm) | <a href="#">N-BK7</a>  | <a href="#">#84-215</a> | ₹3,542<br>Qty 10+ ₹3,192 | 10 to 12 days |
| 6.00 | 60.00 | 58.95 | Laser V-Coat<br>(1550nm) | <a href="#">N-BK7</a>  | <a href="#">#84-216</a> | ₹3,542<br>Qty 10+ ₹3,192 | 10 to 12 days |
| 6.00 | 72.00 | 70.97 | Laser V-Coat<br>(1550nm) | <a href="#">N-BK7</a>  | <a href="#">#84-217</a> | ₹3,542<br>Qty 10+ ₹3,192 | 10 to 12 days |
| 9.00 | 9.00  | 7.32  | Laser V-Coat<br>(1550nm) | <a href="#">N-SF11</a> | <a href="#">#84-218</a> | ₹3,698<br>Qty 10+ ₹3,328 | 10 to 12 days |
| 9.00 | 12.00 | 10.6  | Laser V-Coat<br>(1550nm) | <a href="#">N-SF11</a> | <a href="#">#84-219</a> | ₹3,698<br>Qty 10+ ₹3,328 | 10 to 12 days |
| 9.00 | 13.50 | 11.94 | Laser V-Coat<br>(1550nm) | <a href="#">N-SF5</a>  | <a href="#">#84-220</a> | ₹3,698<br>Qty 10+ ₹3,328 | 10 to 12 days |
| 9.00 | 15.00 | 13.02 | Laser V-Coat<br>(1550nm) | <a href="#">N-BK7</a>  | <a href="#">#84-221</a> | ₹3,698<br>Qty 10+ ₹3,328 | 10 to 12 days |
| 9.00 | 18.00 | 16.41 | Laser V-Coat<br>(1550nm) | <a href="#">N-BK7</a>  | <a href="#">#84-222</a> | ₹3,620<br>Qty 10+ ₹3,270 | 10 to 12 days |
| 9.00 | 22.00 | 20.73 | Laser V-Coat<br>(1550nm) | <a href="#">N-BK7</a>  | <a href="#">#84-223</a> | ₹3,620<br>Qty 10+ ₹3,270 | 10 to 12 days |

|       |       |       |                          |                        |                         |                          |               |
|-------|-------|-------|--------------------------|------------------------|-------------------------|--------------------------|---------------|
| 9.00  | 27.00 | 25.34 | Laser V-Coat<br>(1550nm) | <a href="#">N-BK7</a>  | <a href="#">#84-224</a> | ₹3,620<br>Qty 10+ ₹3,270 | 10 to 12 days |
| 9.00  | 36.00 | 34.48 | Laser V-Coat<br>(1550nm) | <a href="#">N-BK7</a>  | <a href="#">#84-225</a> | ₹3,620<br>Qty 10+ ₹3,270 | 10 to 12 days |
| 9.00  | 45.00 | 43.98 | Laser V-Coat<br>(1550nm) | <a href="#">N-BK7</a>  | <a href="#">#84-226</a> | ₹3,620<br>Qty 10+ ₹3,270 | 10 to 12 days |
| 9.00  | 54.00 | 52.69 | Laser V-Coat<br>(1550nm) | <a href="#">N-BK7</a>  | <a href="#">#84-227</a> | ₹3,620<br>Qty 10+ ₹3,270 | 10 to 12 days |
| 9.00  | 72.00 | 70.68 | Laser V-Coat<br>(1550nm) | <a href="#">N-BK7</a>  | <a href="#">#84-228</a> | ₹3,620<br>Qty 10+ ₹3,270 | 10 to 12 days |
| 9.00  | 90.00 | 88.68 | Laser V-Coat<br>(1550nm) | <a href="#">N-BK7</a>  | <a href="#">#84-229</a> | ₹3,620<br>Qty 10+ ₹3,270 | Contact Us    |
| 10.00 | 10.00 | 8.18  | Laser V-Coat<br>(1550nm) | <a href="#">N-SF11</a> | <a href="#">#84-230</a> | ₹3,698<br>Qty 10+ ₹3,328 | 10 to 12 days |
| 10.00 | 15.00 | 13.32 | Laser V-Coat<br>(1550nm) | <a href="#">N-SF11</a> | <a href="#">#84-231</a> | ₹3,698<br>Qty 10+ ₹3,328 | Contact Us    |
| 10.00 | 20.00 | 18.03 | Laser V-Coat<br>(1550nm) | <a href="#">N-BK7</a>  | <a href="#">#84-232</a> | ₹3,620<br>Qty 10+ ₹3,270 | 10 to 12 days |
| 10.00 | 25.00 | 23.02 | Laser V-Coat<br>(1550nm) | <a href="#">N-BK7</a>  | <a href="#">#84-233</a> | ₹3,620<br>Qty 10+ ₹3,270 | 10 to 12 days |
| 10.00 | 30.00 | 28.01 | Laser V-Coat<br>(1550nm) | <a href="#">N-BK7</a>  | <a href="#">#84-234</a> | ₹3,620<br>Qty 10+ ₹3,270 | 10 to 12 days |
| 10.00 | 40.00 | 38.02 | Laser V-Coat<br>(1550nm) | <a href="#">N-BK7</a>  | <a href="#">#84-235</a> | ₹3,620<br>Qty 10+ ₹3,270 | 10 to 12 days |
| 10.00 | 50.00 | 48.02 | Laser V-Coat<br>(1550nm) | <a href="#">N-BK7</a>  | <a href="#">#84-236</a> | ₹3,620<br>Qty 10+ ₹3,270 | 10 to 12 days |
| 10.00 | 75.00 | 73.02 | Laser V-Coat<br>(1550nm) | <a href="#">N-BK7</a>  | <a href="#">#84-237</a> | ₹3,620<br>Qty 10+ ₹3,270 | Contact Us    |

|       |        |       |                          |                        |                         |                          |               |
|-------|--------|-------|--------------------------|------------------------|-------------------------|--------------------------|---------------|
| 10.00 | 100.00 | 98.02 | Laser V-Coat<br>(1550nm) | <a href="#">N-BK7</a>  | <a href="#">#84-238</a> | ₹3,620<br>Qty 10+ ₹3,270 | 10 to 12 days |
| 12.00 | 12.00  | 9.76  | Laser V-Coat<br>(1550nm) | <a href="#">N-SF11</a> | <a href="#">#84-239</a> | ₹3,854<br>Qty 10+ ₹3,484 | 10 to 12 days |
| 12.00 | 15.00  | 12.03 | Laser V-Coat<br>(1550nm) | <a href="#">N-BK7</a>  | <a href="#">#84-240</a> | ₹3,854<br>Qty 10+ ₹3,484 | 10 to 12 days |
| 12.00 | 18.00  | 16.22 | Laser V-Coat<br>(1550nm) | <a href="#">N-SF5</a>  | <a href="#">#84-241</a> | ₹3,854<br>Qty 10+ ₹3,484 | 10 to 12 days |
| 12.00 | 20.00  | 17.69 | Laser V-Coat<br>(1550nm) | <a href="#">N-BK7</a>  | <a href="#">#84-242</a> | ₹3,854<br>Qty 10+ ₹3,484 | 10 to 12 days |
| 12.00 | 24.00  | 22.15 | Laser V-Coat<br>(1550nm) | <a href="#">N-BK7</a>  | <a href="#">#84-243</a> | ₹3,776<br>Qty 10+ ₹3,406 | 10 to 12 days |
| 12.00 | 30.00  | 28.02 | Laser V-Coat<br>(1550nm) | <a href="#">N-BK7</a>  | <a href="#">#84-244</a> | ₹3,776<br>Qty 10+ ₹3,406 | 10 to 12 days |
| 12.00 | 42.00  | 40.22 | Laser V-Coat<br>(1550nm) | <a href="#">N-BK7</a>  | <a href="#">#84-245</a> | ₹3,776<br>Qty 10+ ₹3,406 | 10 to 12 days |
| 12.00 | 48.00  | 46.36 | Laser V-Coat<br>(1550nm) | <a href="#">N-BK7</a>  | <a href="#">#84-246</a> | ₹3,776<br>Qty 10+ ₹3,406 | 10 to 12 days |
| 12.00 | 54.00  | 52.02 | Laser V-Coat<br>(1550nm) | <a href="#">N-BK7</a>  | <a href="#">#84-247</a> | ₹3,776<br>Qty 10+ ₹3,406 | 10 to 12 days |
| 12.00 | 60.00  | 58.37 | Laser V-Coat<br>(1550nm) | <a href="#">N-BK7</a>  | <a href="#">#84-248</a> | ₹3,776<br>Qty 10+ ₹3,406 | 10 to 12 days |
| 12.00 | 72.00  | 70.42 | Laser V-Coat<br>(1550nm) | <a href="#">N-BK7</a>  | <a href="#">#84-249</a> | ₹3,776<br>Qty 10+ ₹3,406 | 10 to 12 days |
| 12.00 | 84.00  | 82.39 | Laser V-Coat<br>(1550nm) | <a href="#">N-BK7</a>  | <a href="#">#84-250</a> | ₹3,776<br>Qty 10+ ₹3,406 | 10 to 12 days |
| 12.00 | 100.00 | 98.35 | Laser V-Coat<br>(1550nm) | <a href="#">N-BK7</a>  | <a href="#">#84-251</a> | ₹3,776<br>Qty 10+ ₹3,406 | 10 to 12 days |

|       |        |        |                          |                        |                         |                          |               |
|-------|--------|--------|--------------------------|------------------------|-------------------------|--------------------------|---------------|
| 15.00 | 15.00  | 11.71  | Laser V-Coat<br>(1550nm) | <a href="#">N-SF5</a>  | <a href="#">#87-625</a> | ₹3,970<br>Qty 10+ ₹3,581 | 10 to 12 days |
| 15.00 | 18.00  | 15.61  | Laser V-Coat<br>(1550nm) | <a href="#">N-SF5</a>  | <a href="#">#87-626</a> | ₹3,970<br>Qty 10+ ₹3,581 | 10 to 12 days |
| 15.00 | 20.00  | 17.74  | Laser V-Coat<br>(1550nm) | <a href="#">N-SF5</a>  | <a href="#">#87-627</a> | ₹3,970<br>Qty 10+ ₹3,581 | 10 to 12 days |
| 15.00 | 22.50  | 20.50  | Laser V-Coat<br>(1550nm) | <a href="#">N-SF5</a>  | <a href="#">#87-628</a> | ₹3,970<br>Qty 10+ ₹3,581 | 10 to 12 days |
| 20.00 | 20.00  | 17.42  | Laser V-Coat<br>(1550nm) | <a href="#">N-SF11</a> | <a href="#">#89-055</a> | ₹4,360<br>Qty 10+ ₹3,931 | 10 to 12 days |
| 20.00 | 25.00  | 22.76  | Laser V-Coat<br>(1550nm) | <a href="#">N-SF11</a> | <a href="#">#89-056</a> | ₹4,321<br>Qty 10+ ₹3,893 | 10 to 12 days |
| 20.00 | 35.00  | 32.04  | Laser V-Coat<br>(1550nm) | <a href="#">N-BK7</a>  | <a href="#">#89-057</a> | ₹4,321<br>Qty 10+ ₹3,893 | 10 to 12 days |
| 20.00 | 40.00  | 36.77  | Laser V-Coat<br>(1550nm) | <a href="#">N-BK7</a>  | <a href="#">#89-058</a> | ₹4,204<br>Qty 10+ ₹3,795 | 10 to 12 days |
| 20.00 | 50.00  | 47.87  | Laser V-Coat<br>(1550nm) | <a href="#">N-BK7</a>  | <a href="#">#89-059</a> | ₹4,204<br>Qty 10+ ₹3,795 | 10 to 12 days |
| 20.00 | 60.00  | 57.03  | Laser V-Coat<br>(1550nm) | <a href="#">N-BK7</a>  | <a href="#">#89-060</a> | ₹4,204<br>Qty 10+ ₹3,795 | 10 to 12 days |
| 20.00 | 70.00  | 68.03  | Laser V-Coat<br>(1550nm) | <a href="#">N-BK7</a>  | <a href="#">#89-061</a> | ₹4,204<br>Qty 10+ ₹3,795 | 10 to 12 days |
| 20.00 | 80.00  | 78.45  | Laser V-Coat<br>(1550nm) | <a href="#">N-BK7</a>  | <a href="#">#89-062</a> | ₹4,204<br>Qty 10+ ₹3,795 | 10 to 12 days |
| 20.00 | 100.00 | 97.13  | Laser V-Coat<br>(1550nm) | <a href="#">N-BK7</a>  | <a href="#">#89-063</a> | ₹4,204<br>Qty 10+ ₹3,795 | 10 to 12 days |
| 20.00 | 150.00 | 148.02 | Laser V-Coat<br>(1550nm) | <a href="#">N-BK7</a>  | <a href="#">#89-064</a> | ₹4,204<br>Qty 10+ ₹3,795 | 10 to 12 days |

|       |        |        |                          |                       |                         |                          |               |
|-------|--------|--------|--------------------------|-----------------------|-------------------------|--------------------------|---------------|
| 25.00 | 25.00  | 20.22  | Laser V-Coat<br>(1550nm) | <a href="#">N-SF5</a> | <a href="#">#84-252</a> | ₹4,360<br>Qty 10+ ₹3,931 | 10 to 12 days |
| 25.00 | 30.00  | 24.68  | Laser V-Coat<br>(1550nm) | <a href="#">N-BK7</a> | <a href="#">#84-253</a> | ₹4,360<br>Qty 10+ ₹3,931 | 10 to 12 days |
| 25.00 | 35.00  | 30.42  | Laser V-Coat<br>(1550nm) | <a href="#">N-BK7</a> | <a href="#">#84-254</a> | ₹4,360<br>Qty 10+ ₹3,931 | 10 to 12 days |
| 25.00 | 40.00  | 36.3   | Laser V-Coat<br>(1550nm) | <a href="#">N-BK7</a> | <a href="#">#84-255</a> | ₹4,360<br>Qty 10+ ₹3,931 | 10 to 12 days |
| 25.00 | 50.00  | 46.77  | Laser V-Coat<br>(1550nm) | <a href="#">N-BK7</a> | <a href="#">#84-256</a> | ₹4,204<br>Qty 10+ ₹3,795 | 10 to 12 days |
| 25.00 | 60.00  | 56.91  | Laser V-Coat<br>(1550nm) | <a href="#">N-BK7</a> | <a href="#">#84-257</a> | ₹4,204<br>Qty 10+ ₹3,795 | 10 to 12 days |
| 25.00 | 75.00  | 72.03  | Laser V-Coat<br>(1550nm) | <a href="#">N-BK7</a> | <a href="#">#84-258</a> | ₹4,204<br>Qty 10+ ₹3,795 | 10 to 12 days |
| 25.00 | 85.00  | 82.17  | Laser V-Coat<br>(1550nm) | <a href="#">N-BK7</a> | <a href="#">#84-259</a> | ₹4,204<br>Qty 10+ ₹3,795 | 10 to 12 days |
| 25.00 | 100.00 | 97.17  | Laser V-Coat<br>(1550nm) | <a href="#">N-BK7</a> | <a href="#">#84-260</a> | ₹4,204<br>Qty 10+ ₹3,795 | 10 to 12 days |
| 25.00 | 125.00 | 122.73 | Laser V-Coat<br>(1550nm) | <a href="#">N-BK7</a> | <a href="#">#84-261</a> | ₹4,204<br>Qty 10+ ₹3,795 | 10 to 12 days |
| 25.00 | 150.00 | 147.75 | Laser V-Coat<br>(1550nm) | <a href="#">N-BK7</a> | <a href="#">#84-262</a> | ₹4,204<br>Qty 10+ ₹3,795 | 10 to 12 days |
| 25.00 | 175.00 | 172.75 | Laser V-Coat<br>(1550nm) | <a href="#">N-BK7</a> | <a href="#">#84-263</a> | ₹4,204<br>Qty 10+ ₹3,795 | 10 to 12 days |
| 25.00 | 250.00 | 248.02 | Laser V-Coat<br>(1550nm) | <a href="#">N-BK7</a> | <a href="#">#84-264</a> | ₹4,204<br>Qty 10+ ₹3,795 | Contact Us    |
| 25.00 | 300.00 | 298.02 | Laser V-Coat<br>(1550nm) | <a href="#">N-BK7</a> | <a href="#">#84-265</a> | ₹4,204<br>Qty 10+ ₹3,795 | 10 to 12 days |

|       |        |        |                          |                        |                         |                          |               |
|-------|--------|--------|--------------------------|------------------------|-------------------------|--------------------------|---------------|
| 25.00 | 500.00 | 497.89 | Laser V-Coat<br>(1550nm) | <a href="#">N-BK7</a>  | <a href="#">#84-266</a> | ₹4,204<br>Qty 10+ ₹3,795 | 10 to 12 days |
| 25.00 | 750.00 | 747.89 | Laser V-Coat<br>(1550nm) | <a href="#">N-BK7</a>  | <a href="#">#84-267</a> | ₹4,204<br>Qty 10+ ₹3,795 | 10 to 12 days |
| 30.00 | 30.00  | 26.13  | Laser V-Coat<br>(1550nm) | <a href="#">N-SF11</a> | <a href="#">#26-169</a> | ₹4,943<br>Qty 10+ ₹4,437 | 10 to 12 days |
| 30.00 | 40.00  | 37.20  | Laser V-Coat<br>(1550nm) | <a href="#">N-SF11</a> | <a href="#">#26-170</a> | ₹4,827<br>Qty 10+ ₹4,360 | 10 to 12 days |
| 30.00 | 50.00  | 46.17  | Laser V-Coat<br>(1550nm) | <a href="#">N-SF5</a>  | <a href="#">#26-171</a> | ₹4,827<br>Qty 10+ ₹4,360 | 10 to 12 days |
| 30.00 | 100.00 | 96.01  | Laser V-Coat<br>(1550nm) | <a href="#">N-BK7</a>  | <a href="#">#26-172</a> | ₹4,710<br>Qty 10+ ₹4,243 | 10 to 12 days |
| 30.00 | 120.00 | 116.04 | Laser V-Coat<br>(1550nm) | <a href="#">N-BK7</a>  | <a href="#">#26-173</a> | ₹4,710<br>Qty 10+ ₹4,243 | 10 to 12 days |
| 40.00 | 40.00  | 35.13  | Laser V-Coat<br>(1550nm) | <a href="#">N-SF11</a> | <a href="#">#26-174</a> | ₹5,333<br>Qty 10+ ₹4,788 | 10 to 12 days |
| 40.00 | 60.00  | 53.90  | Laser V-Coat<br>(1550nm) | <a href="#">N-BK7</a>  | <a href="#">#26-175</a> | ₹5,333<br>Qty 10+ ₹4,788 | 10 to 12 days |
| 40.00 | 300.00 | 296.70 | Laser V-Coat<br>(1550nm) | <a href="#">N-BK7</a>  | <a href="#">#26-176</a> | ₹5,255<br>Qty 10+ ₹4,710 | 10 to 12 days |
| 40.00 | 400.00 | 396.70 | Laser V-Coat<br>(1550nm) | <a href="#">N-BK7</a>  | <a href="#">#26-177</a> | ₹5,255<br>Qty 10+ ₹4,710 | 10 to 12 days |
| 50.00 | 50.00  | 43.28  | Laser V-Coat<br>(1550nm) | <a href="#">N-SF11</a> | <a href="#">#84-268</a> | ₹5,722<br>Qty 10+ ₹5,138 | 10 to 12 days |
| 50.00 | 75.00  | 67.7   | Laser V-Coat<br>(1550nm) | <a href="#">N-BK7</a>  | <a href="#">#84-269</a> | ₹5,566<br>Qty 10+ ₹5,021 | Contact Us    |
| 50.00 | 100.00 | 93.41  | Laser V-Coat<br>(1550nm) | <a href="#">N-BK7</a>  | <a href="#">#84-270</a> | ₹5,372<br>Qty 10+ ₹4,827 | Contact Us    |

|       |        |        |                          |                       |                         |                          |               |
|-------|--------|--------|--------------------------|-----------------------|-------------------------|--------------------------|---------------|
| 50.00 | 125.00 | 118.39 | Laser V-Coat<br>(1550nm) | <a href="#">N-BK7</a> | <a href="#">#84-271</a> | ₹5,372<br>Qty 10+ ₹4,827 | 10 to 12 days |
| 50.00 | 150.00 | 144.07 | Laser V-Coat<br>(1550nm) | <a href="#">N-BK7</a> | <a href="#">#84-272</a> | ₹5,372<br>Qty 10+ ₹4,827 | 10 to 12 days |
| 50.00 | 175.00 | 169.05 | Laser V-Coat<br>(1550nm) | <a href="#">N-BK7</a> | <a href="#">#84-273</a> | ₹5,372<br>Qty 10+ ₹4,827 | 10 to 12 days |
| 50.00 | 200.00 | 196.66 | Laser V-Coat<br>(1550nm) | <a href="#">N-BK7</a> | <a href="#">#84-274</a> | ₹5,372<br>Qty 10+ ₹4,827 | 10 to 12 days |
| 50.00 | 250.00 | 246.74 | Laser V-Coat<br>(1550nm) | <a href="#">N-BK7</a> | <a href="#">#84-275</a> | ₹5,372<br>Qty 10+ ₹4,827 | 10 to 12 days |
| 50.00 | 500.00 | 496.7  | Laser V-Coat<br>(1550nm) | <a href="#">N-BK7</a> | <a href="#">#84-276</a> | ₹5,372<br>Qty 10+ ₹4,827 | 10 to 12 days |



Copyright 2023, Edmund Optics India Private Limited, #267, Greystone Building, Second Floor, 6th Cross Rd, Binnamangala, Stage 1, Indiranagar, Bengaluru, Karnataka, India 560038  
Phone: 1-800-363-1992 :  
[www.edmundoptics.com](http://www.edmundoptics.com)