

[All Products](#) / [Cameras](#) / [USB Cameras](#)

FLIR Flea®3 USB 3.0 Cameras See More by [Teledyne FLIR](#)



- Compact 29 x 29 x 30mm Design
- Captures Images at up to 150fps
- Image Capture Software and 1/4-20 Tripod Adapter are Included
- [GigE Models](#) Also Available



Common Specifications

General

Manufacturer:	FLIR	Camera Series:	Flea®3
----------------------	------	-----------------------	--------

Physical & Mechanical Properties

Dimensions (mm):	29 x 29 x 30 (excludes connectors and lens mount)	Weight (g):	41
-------------------------	---	--------------------	----

Housing:	Full
-----------------	------

Sensor

Image Buffer:	32MB
----------------------	------

Sensor Format:	1/1.8"	Resolution (Megapixels):	1.30
-----------------------	--------	---------------------------------	------

Frame Rate (fps):	60.00	Pixels (H x V):	1,280 x 1,024
--------------------------	-------	------------------------	---------------

Pixel Size, H x V (µm):	5.3 x 5.3	Sensing Area, H x V (mm):	6.78 x 5.43
--------------------------------	-----------	----------------------------------	-------------

Imaging Sensor:	e2v EV76C560	Type of Sensor:	Progressive Scan CMOS
------------------------	--------------	------------------------	-----------------------

Shutter Type:	Global	Pixel Depth:	10 bit
----------------------	--------	---------------------	--------

Exposure Time:	16µs - 1s	Machine Vision Standard:	USB3 Vision v1.0
-----------------------	-----------	---------------------------------	------------------

Electrical

Power Consumption (W):	<3
------------------------	----

Hardware & Interface Connectivity

Interface:	USB 3.0		
Connector:	USB 3.0, Micro-B with Screw Locks	Power Supply:	Power over USB or via GPIO with #86-784
GPIOs:	1 opto-isolated input, 2 opto-isolated outputs, 2 non-isolated bi-directional ports	Synchronization:	Hardware Trigger (GPIO) or Software Trigger
Interface Port Orientation:	Back Panel	GPIO Connector Type:	8-pin Hirose (HR25)
Transfer Speed (Gbit/s):	5.00		




Threading & Mounting


Mount:	C-Mount
Mounting Threads:	1/4-20 with Tripod Mount Adapter #88-210

Environmental & Durability Factors

Operating Temperature (°C):	0 to +45
Storage Temperature (°C):	-30 to +60

Technical Information

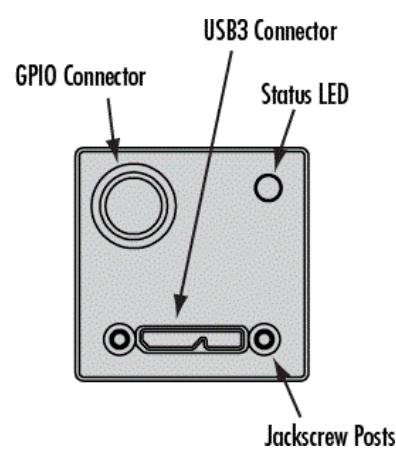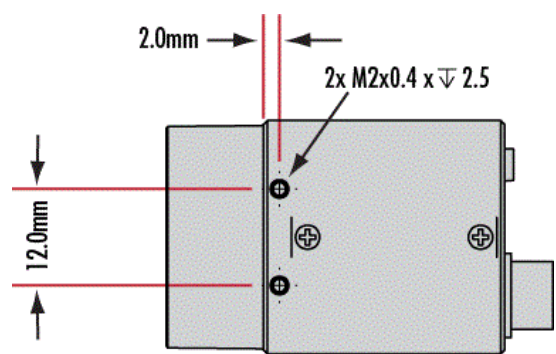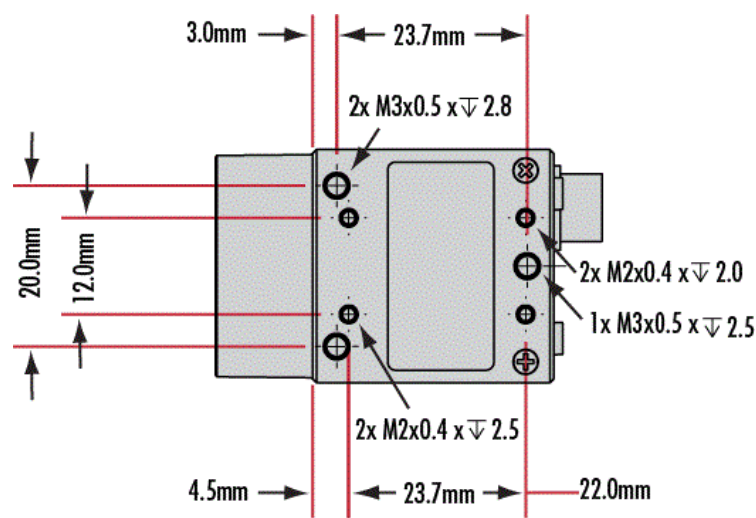

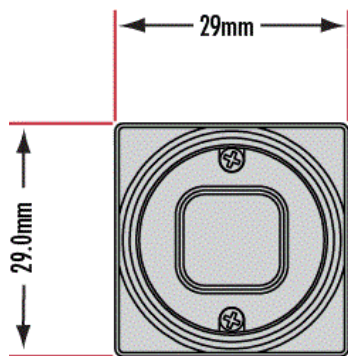

Products

Type	Model Number	Sensor Format	Resolution (Megapixels)	Connector	Mount	Stock Number	Price	Buy
Monochrome Camera	FL3-U3-13E4M-C	1/1.8"	1.30	USB 3.0, Micro-B with Screw Locks	C-Mount	#87-431	₹81,000	1 In Stock
Color Camera	FL3-U3-13E4C-C	1/1.8"	1.30	USB 3.0, Micro-B with Screw Locks	C-Mount	#87-432	₹81,000	4 In Stock



Copyright 2023, Edmund Optics India Private Limited, #267, Greystone Building, Second Floor, 6th Cross Rd, Binnamangala, Stage 1, Indiranagar, Bengaluru, Karnataka, India 560038
Phone: 1-800-363-1992 : www.edmundoptics.com