

[All Products](#) / [Optics](#) / [Optical Lenses](#) / [Specialty Lenses](#)

Focusable Collimators



- Can Be Coupled to Standard 0.22 NA Fiber Optic Cables
- Options Available for UV-VIS or VIS-NIR
- Multiple Focal Length or Aperture Options

Common Specifications


Environmental & Durability Factors

Operating Temperature (°C):

-40 to 100


Technical Information

Fiber with 4mm Aperture Fiber Optic Collimator

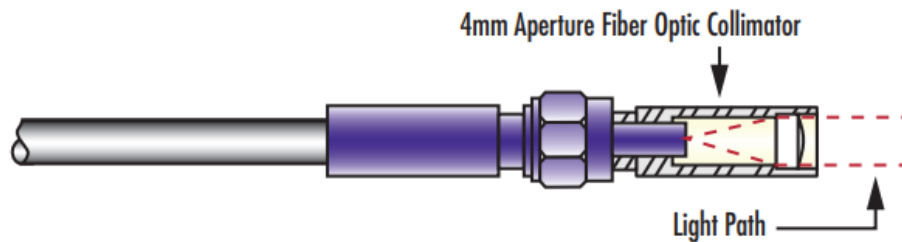


The 4mm Aperture Fiber Optic Collimator threads directly onto FC or SMA fiber.

Fiber with 10mm Aperture Fiber Optic Collimator

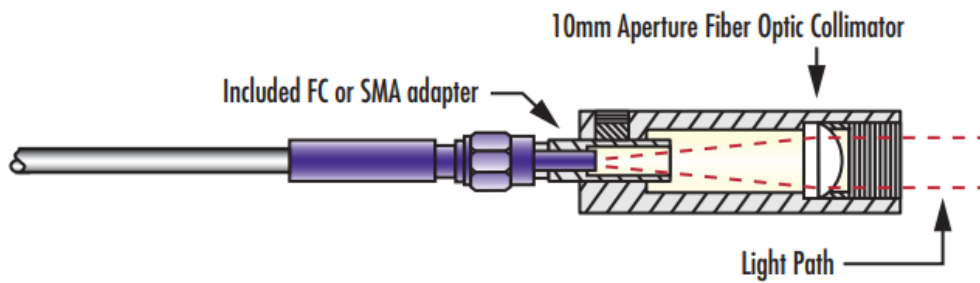

Each 10mm Aperture Fiber Optic Collimator includes an FC or SMA adapter that is inserted into the collimator and locked by a set screw.

Fiber with 10mm Aperture Fiber Optic Collimator and Refocusing Assembly

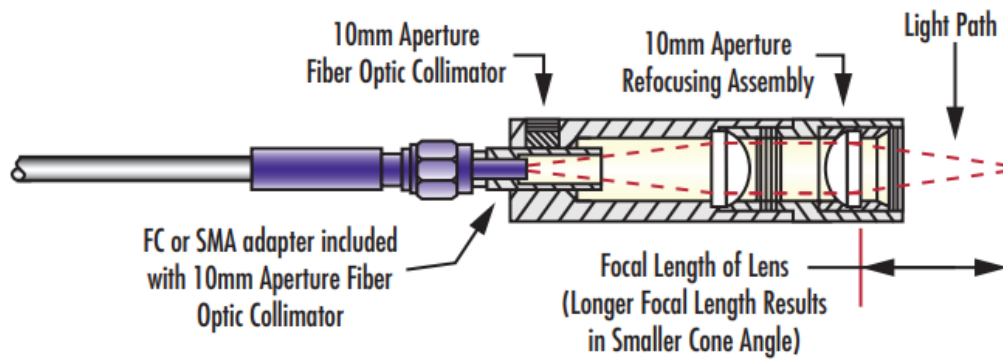

A 10mm Aperture Refocusing Assembly can then be directly threaded onto the 10mm Aperture Fiber Optic Collimator.

Products

Aperture Size	Connector	FL (mm)	Type	Wavelength Range (nm)	Stock Number	Price	Buy
4.0	FC	10.00	Fiber Collimator	190 - 1250	#88-189	₹20,610 Qty 11+ ₹18,180	10 to 12 days
4.0	SMA	10.00	Fiber Collimator	190 - 1250	#88-173	₹20,610 Qty 11+ ₹18,180	10 to 12 days
4.0	FC	10.00	Fiber Collimator	350 - 2200	#88-188	₹16,830 Qty 11+ ₹14,940	Contact Us
4.0	SMA	10.00	Fiber Collimator	350 - 2200	#88-172	₹15,930 Qty 11+ ₹14,040	10 to 12 days
10.0	FC	18.00	Fiber Collimator	190 - 1250	#88-191	₹34,650 Qty 11+ ₹30,600	10 to 12 days
10.0	SMA	18.00	Fiber Collimator	190 - 1250	#88-181	₹34,650 Qty 11+ ₹30,600	10 to 12 days
10.0	FC	18.00	Fiber Collimator	350 - 2200	#88-190	₹20,610 Qty 11+ ₹18,180	10 to 12 days
10.0	SMA	18.00	Fiber Collimator	350 - 2200	#88-180	₹20,610 Qty 11+ ₹18,180	10 to 12 days
22.2	FC	38.00	Fiber Collimator	190 - 1250	#17-569	₹47,700 Qty 11+ ₹42,300	10 to 12 days
22.2	SMA	38.00	Fiber Collimator	190 - 1250	#17-567	₹47,700 Qty 11+ ₹42,300	10 to 12 days
10.0	-	18.00	Refocusing Assembly	190 - 1250	#88-185	₹28,980 Qty 11+ ₹25,560	10 to 12 days
10.0	-	18.00	Refocusing Assembly	350 - 2200	#88-182	₹15,930 Qty 11+ ₹14,040	10 to 12 days
10.0	-	25.00	Refocusing Assembly	190 - 1250	#88-186	₹28,980 Qty 11+ ₹25,560	10 to 12 days
10.0	-	25.00	Refocusing Assembly	350 - 2200	#88-183	₹15,930 Qty 11+ ₹14,040	10 to 12 days
22.2	-	38.00	Refocusing Assembly	190 - 1250	#17-573	₹57,600 Qty 11+ ₹50,850	10 to 12 days
10.0	-	38.00	Refocusing Assembly	190 - 1250	#88-187	₹28,980 Qty 11+ ₹25,560	10 to 12 days
10.0	-	38.00	Refocusing Assembly	350 - 2200	#88-184	₹15,930 Qty 11+ ₹14,040	10 to 12 days

22.2	-	51.00	Refocusing Assembly	190 - 1250	#17-574	₹57,600 Qty 11+ ₹50,850	10 to 12 days
22.2	-	76.00	Refocusing Assembly	190 - 1250	#17-575	₹57,600 Qty 11+ ₹50,850	10 to 12 days



Copyright 2023, Edmund Optics India Private Limited, #267, Greystone Building, Second Floor, 6th Cross Rd, Binnamangala, Stage 1, Indiranagar, Bengaluru, Karnataka, India 560038

Phone: 1-800-363-1992 :

www.edmundoptics.com