


[All Products](#) / [Optics](#) / [Optical Lenses](#) / [Plano-Convex \(PCX\) Lenses](#) / [Standard Plano-Convex \(PCX\) Lenses](#)

TECHSPEC® YAG-BBAR Coated Plano-Convex (PCX) Lenses

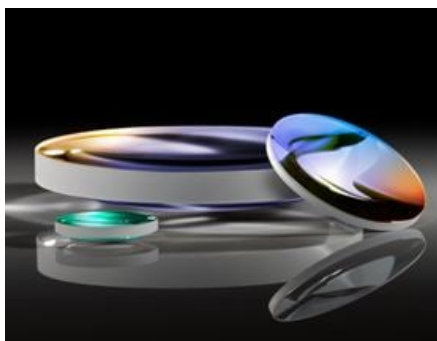

- Optimized for $R < 0.25\%$ @ Both 532nm and 1064nm
- AR Coated to Provide $< 1.0\%$ Reflectance per Surface for 500 - 1100nm
- Designed for 0° Angle of Incidence
- Various PCX Coating Options: [Uncoated](#), [MgF₂](#), [VIS 0°](#), [VIS-NIR](#), [NIR I](#), [NIR II](#), and [VIS-EXT](#)

Common Specifications

Physical & Mechanical Properties


Bevel:	Protective as needed
--------	----------------------

Optical Properties

Coating:	YAG-BBAR (500-1100nm)
----------	-----------------------

Focal Length Tolerance (%):	± 1
-----------------------------	---------

Technical Information

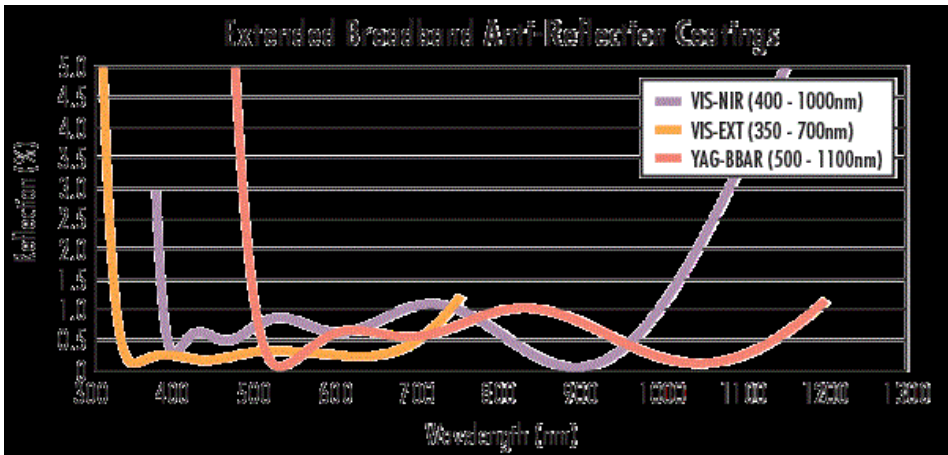

Products

Dia. (mm)	EFL (mm)	BFL (mm)	Coating	Substrate	Stock Number	Price	Buy
1.00	0.60	0.17	YAG-BBAR (500-1100nm)	N-LASF9	#35-710	₹6,345 Qty 10+ ₹5,683	Contact Us
1.00	1.00	0.57	YAG-BBAR (500-1100nm)	N-LASF9	#35-711	₹6,345 Qty 10+ ₹5,683	Contact Us
1.00	1.50	1.07	YAG-BBAR (500-1100nm)	N-LASF9	#35-712	₹6,345 Qty 10+ ₹5,683	10 to 12 days
1.00	2.00	1.57	YAG-BBAR (500-1100nm)	N-LASF9	#35-713	₹6,345 Qty 10+ ₹5,683	10 to 12 days
1.50	1.00	0.57	YAG-BBAR (500-1100nm)	N-LASF9	#35-714	₹6,345 Qty 10+ ₹5,683	10 to 12 days
1.50	1.50	1.07	YAG-BBAR (500-1100nm)	N-LASF9	#35-715	₹6,345 Qty 10+ ₹5,683	10 to 12 days
1.50	2.00	1.57	YAG-BBAR (500-1100nm)	N-LASF9	#35-716	₹6,345 Qty 10+ ₹5,683	10 to 12 days
2.00	1.50	1.07	YAG-BBAR (500-1100nm)	N-LASF9	#35-717	₹6,267 Qty 10+ ₹5,644	10 to 12 days
2.00	2.00	1.57	YAG-BBAR (500-1100nm)	N-LASF9	#35-718	₹6,267 Qty 10+ ₹5,644	10 to 12 days
2.00	3.00	2.57	YAG-BBAR (500-1100nm)	N-LASF9	#35-719	₹6,267 Qty 10+ ₹5,644	10 to 12 days

2.00	4.00	3.57	YAG-BBAR (500-1100nm)	N-LASF9	#35-720	₹6,267 Qty 10+ ₹5,644	10 to 12 days
#72-259 New							
×							
New							
Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!							
2.00	4.00	3.46	YAG-BBAR (500-1100nm)	Fused Silica (Corning 7980)		₹8,486 Qty 6+ ₹6,773	10 to 12 days
#72-267 New							
×							
New							
Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!							
2.00	6.00	5.45	YAG-BBAR (500-1100nm)	Fused Silica (Corning 7980)		₹8,096 Qty 6+ ₹6,462	10 to 12 days
2.50	2.00	1.57	YAG-BBAR (500-1100nm)	N-LASF9	#35-721	₹6,267 Qty 10+ ₹5,644	10 to 12 days

2.50	2.50	2.07	YAG-BBAR (500-1100nm)	N-LASF9	#35-722	₹6,267 Qty 10+ ₹5,644	10 to 12 days
2.50	3.00	2.57	YAG-BBAR (500-1100nm)	N-LASF9	#35-723	₹6,267 Qty 10+ ₹5,644	10 to 12 days
2.50	4.00	3.57	YAG-BBAR (500-1100nm)	N-LASF9	#35-724	₹6,267 Qty 10+ ₹5,644	Contact Us
2.50	5.00	4.57	YAG-BBAR (500-1100nm)	N-LASF9	#35-725	₹6,267 Qty 10+ ₹5,644	10 to 12 days
3.00	3.00	1.88	YAG-BBAR (500-1100nm)	N-SF11	#88-774	₹5,372 Qty 10+ ₹4,827	10 to 12 days
3.00	4.50	3.5	YAG-BBAR (500-1100nm)	N-LASF44	#88-775	₹5,372 Qty 10+ ₹4,827	10 to 12 days
3.00	6.00	4.81	YAG-BBAR (500-1100nm)	N-BK7	#88-776	₹4,982 Qty 10+ ₹4,476	10 to 12 days

[#72-276 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

3.00	6.00	5.01	YAG-BBAR (500-1100nm)	Fused Silica (Corning 7980)		₹8,486 Qty 6+ ₹6,773	10 to 12 days
------	------	------	--------------------------	--------------------------------	--	-------------------------	---------------

3.00	7.50	6.51	YAG-BBAR (500-1100nm)	N-BK7	#88-777	₹4,982 Qty 10+ ₹4,476	10 to 12 days
3.00	9.00	8.01	YAG-BBAR (500-1100nm)	N-BK7	#88-778	₹4,982 Qty 10+ ₹4,476	10 to 12 days
#72-284 New							
× New Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!							
3.00	9.00	8.11	YAG-BBAR (500-1100nm)	Fused Silica (Corning 7980)		₹8,096 Qty 6+ ₹6,462	10 to 12 days
3.00	12.00	11.29	YAG-BBAR (500-1100nm)	N-BK7	#88-779	₹4,982 Qty 10+ ₹4,476	10 to 12 days
3.00	15.00	14.22	YAG-BBAR (500-1100nm)	N-BK7	#88-780	₹4,982 Qty 10+ ₹4,476	10 to 12 days
4.00	4.00	3.06	YAG-BBAR (500-1100nm)	N-LASF44	#88-781	₹5,372 Qty 10+ ₹4,827	10 to 12 days
4.00	6.00	4.51	YAG-BBAR (500-1100nm)	N-BK7	#88-782	₹5,372 Qty 10+ ₹4,827	10 to 12 days

[#72-292 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

4.00	8.00	6.91	YAG-BBAR (500-1100nm)	Fused Silica (Corning 7980)		₹10,043 Qty 6+ ₹8,096	10 to 12 days
------	------	------	-----------------------	-----------------------------	--	--------------------------	---------------

4.00	10.00	8.92	YAG-BBAR (500-1100nm)	N-BK7	#88-784	₹5,060 Qty 10+ ₹4,554	10 to 12 days
------	-------	------	-----------------------	-----------------------	-------------------------	--------------------------	---------------

4.00	12.00	11.00	YAG-BBAR (500-1100nm)	N-BK7	#88-785	₹5,060 Qty 10+ ₹4,554	10 to 12 days
------	-------	-------	-----------------------	-----------------------	-------------------------	--------------------------	---------------

[#72-300 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

4.00	12.00	11.04	YAG-BBAR (500-1100nm)	Fused Silica (Corning 7980)		₹9,653 Qty 6+ ₹7,785	10 to 12 days
------	-------	-------	-----------------------	-----------------------------	--	-------------------------	---------------

4.50	4.50	3.05	YAG-BBAR (500-1100nm)	N-LASF44	#88-786	₹5,372 Qty 10+ ₹4,827	10 to 12 days
4.50	9.00	7.41	YAG-BBAR (500-1100nm)	N-BK7	#88-787	₹5,060 Qty 10+ ₹4,554	10 to 12 days
5.00	5.00	3.96	YAG-BBAR (500-1100nm)	N-LASF44	#88-788	₹3,951 Qty 10+ ₹3,542	10 to 12 days
5.00	7.50	6.43	YAG-BBAR (500-1100nm)	N-SF11	#88-789	₹3,912 Qty 10+ ₹3,523	10 to 12 days
5.00	10.00	8.91	YAG-BBAR (500-1100nm)	N-BK7	#88-790	₹3,912 Qty 10+ ₹3,523	10 to 12 days
5.00	12.00	10.83	YAG-BBAR (500-1100nm)	N-BK7	#88-791	₹3,912 Qty 10+ ₹3,523	10 to 12 days
5.00	15.00	13.94	YAG-BBAR (500-1100nm)	N-BK7	#88-792	₹3,912 Qty 10+ ₹3,523	10 to 12 days
5.00	20.00	19.02	YAG-BBAR (500-1100nm)	N-BK7	#88-793	₹3,912 Qty 10+ ₹3,523	10 to 12 days
5.00	25.00	23.95	YAG-BBAR (500-1100nm)	N-BK7	#88-794	₹3,912 Qty 10+ ₹3,523	10 to 12 days
5.00	30.00	28.95	YAG-BBAR (500-1100nm)	N-BK7	#88-795	₹3,912 Qty 10+ ₹3,523	10 to 12 days
6.00	6.00	4.60	YAG-BBAR (500-1100nm)	N-SF11	#88-796	₹3,309 Qty 10+ ₹2,978	10 to 12 days

6.00	7.50	6.10	YAG-BBAR (500-1100nm)	N-SF11	#88-797	₹3,270 Qty 10+ ₹2,939	10 to 12 days
6.00	9.00	7.95	YAG-BBAR (500-1100nm)	N-SF5	#88-798	₹3,270 Qty 10+ ₹2,939	10 to 12 days
6.00	10.00	8.82	YAG-BBAR (500-1100nm)	N-BK7	#38-568	₹3,270 Qty 10+ ₹2,939	10 to 12 days
6.00	12.00	10.94	YAG-BBAR (500-1100nm)	N-BK7	#88-799	₹3,192 Qty 10+ ₹2,861	10 to 12 days
6.00	15.00	13.68	YAG-BBAR (500-1100nm)	N-BK7	#88-800	₹3,192 Qty 10+ ₹2,861	10 to 12 days
6.00	18.00	17.07	YAG-BBAR (500-1100nm)	N-BK7	#88-801	₹3,192 Qty 10+ ₹2,861	10 to 12 days
6.00	20.00	19.04	YAG-BBAR (500-1100nm)	N-BK7	#38-569	₹3,192 Qty 10+ ₹2,861	10 to 12 days
6.00	21.00	20.06	YAG-BBAR (500-1100nm)	N-BK7	#88-802	₹3,192 Qty 10+ ₹2,861	10 to 12 days
6.00	24.00	23.01	YAG-BBAR (500-1100nm)	N-BK7	#88-803	₹3,192 Qty 10+ ₹2,861	Contact Us
6.00	25.00	24.04	YAG-BBAR (500-1100nm)	N-BK7	#38-570	₹3,192 Qty 10+ ₹2,861	10 to 12 days
6.00	30.00	29.14	YAG-BBAR (500-1100nm)	N-BK7	#88-804	₹3,192 Qty 10+ ₹2,861	10 to 12 days

6.00	36.00	34.95	YAG-BBAR (500-1100nm)	N-BK7	#88-805	₹3,192 Qty 10+ ₹2,861	10 to 12 days
6.00	48.00	46.95	YAG-BBAR (500-1100nm)	N-BK7	#88-806	₹3,192 Qty 10+ ₹2,861	10 to 12 days
6.00	60.00	58.95	YAG-BBAR (500-1100nm)	N-BK7	#88-807	₹3,192 Qty 10+ ₹2,861	10 to 12 days
6.00	72.00	70.97	YAG-BBAR (500-1100nm)	N-BK7	#88-808	₹3,192 Qty 10+ ₹2,861	10 to 12 days
#71-299 New							
7.00	7.00	5.50	YAG-BBAR (500-1100nm)	N-LASF9	 New Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!	₹3,270 Qty 11+ ₹2,939	10 to 12 days
7.00	10.00	8.10	YAG-BBAR (500-1100nm)	N-LASF9	#71-306	₹3,231 Qty 11+ ₹2,900	10 to 12 days
7.00	12.00	10.30	YAG-BBAR (500-1100nm)	N-LASF9	#71-313	₹3,231 Qty 11+ ₹2,900	10 to 12 days

[#71-320 New](#)



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

8.00	8.00	6.40	YAG-BBAR (500-1100nm)	N-LASF9		₹3,270 Qty 11+ ₹2,939	10 to 12 days
------	------	------	--------------------------	-------------------------	--	--------------------------	---------------

8.00	10.00	7.60	YAG-BBAR (500-1100nm)	N-LASF9	#71-327	₹3,231 Qty 11+ ₹2,900	10 to 12 days
------	-------	------	--------------------------	-------------------------	-------------------------	--------------------------	---------------

8.00	12.00	10.00	YAG-BBAR (500-1100nm)	N-LASF9	#71-334	₹3,231 Qty 11+ ₹2,900	10 to 12 days
------	-------	-------	--------------------------	-------------------------	-------------------------	--------------------------	---------------

9.00	9.00	7.32	YAG-BBAR (500-1100nm)	N-SF11	#88-809	₹3,348 Qty 10+ ₹2,997	10 to 12 days
------	------	------	--------------------------	------------------------	-------------------------	--------------------------	---------------

9.00	10.00	8.49	YAG-BBAR (500-1100nm)	N-SF11	#38-571	₹3,348 Qty 10+ ₹2,997	10 to 12 days
------	-------	------	--------------------------	------------------------	-------------------------	--------------------------	---------------

9.00	12.00	10.60	YAG-BBAR (500-1100nm)	N-SF11	#88-810	₹3,348 Qty 10+ ₹2,997	10 to 12 days
------	-------	-------	--------------------------	------------------------	-------------------------	--------------------------	---------------

9.00	13.50	11.94	YAG-BBAR (500-1100nm)	N-SF5	#88-811	₹3,348 Qty 10+ ₹2,997	10 to 12 days
------	-------	-------	--------------------------	-----------------------	-------------------------	--------------------------	---------------

9.00	15.00	13.02	YAG-BBAR (500-1100nm)	N-BK7	#88-812	₹3,348 Qty 10+ ₹2,997	10 to 12 days
------	-------	-------	--------------------------	-----------------------	-------------------------	--------------------------	---------------

9.00	18.00	16.41	YAG-BBAR (500-1100nm)	N-BK7	#88-813	₹3,270 Qty 10+ ₹2,939	10 to 12 days
9.00	20.00	18.55	YAG-BBAR (500-1100nm)	N-BK7	#38-572	₹3,270 Qty 10+ ₹2,939	10 to 12 days
9.00	22.00	20.73	YAG-BBAR (500-1100nm)	N-BK7	#88-814	₹3,270 Qty 10+ ₹2,939	10 to 12 days
9.00	25.00	23.68	YAG-BBAR (500-1100nm)	N-BK7	#38-573	₹3,270 Qty 10+ ₹2,939	10 to 12 days
9.00	27.00	25.34	YAG-BBAR (500-1100nm)	N-BK7	#88-815	₹3,270 Qty 10+ ₹2,939	10 to 12 days
9.00	36.00	34.48	YAG-BBAR (500-1100nm)	N-BK7	#88-816	₹3,270 Qty 10+ ₹2,939	Contact Us
9.00	45.00	43.98	YAG-BBAR (500-1100nm)	N-BK7	#88-817	₹3,270 Qty 10+ ₹2,939	10 to 12 days
9.00	54.00	52.69	YAG-BBAR (500-1100nm)	N-BK7	#88-818	₹3,270 Qty 10+ ₹2,939	10 to 12 days
9.00	72.00	70.68	YAG-BBAR (500-1100nm)	N-BK7	#88-819	₹3,270 Qty 10+ ₹2,939	10 to 12 days
9.00	90.00	88.68	YAG-BBAR (500-1100nm)	N-BK7	#88-820	₹3,270 Qty 10+ ₹2,939	10 to 12 days
10.00	10.00	8.18	YAG-BBAR (500-1100nm)	N-SF11	#88-821	₹3,348 Qty 10+ ₹2,997	10 to 12 days

10.00	12.50	10.99	YAG-BBAR (500-1100nm)	N-SF11	#38-574	₹3,348 Qty 10+ ₹2,997	10 to 12 days
10.00	15.00	13.32	YAG-BBAR (500-1100nm)	N-SF11	#88-822	₹3,348 Qty 10+ ₹2,997	10 to 12 days
10.00	17.50	15.66	YAG-BBAR (500-1100nm)	N-BK7	#38-575	₹3,270 Qty 10+ ₹2,939	10 to 12 days
10.00	20.00	18.03	YAG-BBAR (500-1100nm)	N-BK7	#88-823	₹3,270 Qty 10+ ₹2,939	Contact Us
10.00	25.00	23.02	YAG-BBAR (500-1100nm)	N-BK7	#88-824	₹3,270 Qty 10+ ₹2,939	10 to 12 days
10.00	30.00	28.01	YAG-BBAR (500-1100nm)	N-BK7	#88-825	₹3,270 Qty 10+ ₹2,939	10 to 12 days
10.00	40.00	38.02	YAG-BBAR (500-1100nm)	N-BK7	#88-826	₹3,270 Qty 10+ ₹2,939	10 to 12 days
10.00	50.00	48.02	YAG-BBAR (500-1100nm)	N-BK7	#88-827	₹3,270 Qty 10+ ₹2,939	10 to 12 days
10.00	75.00	73.02	YAG-BBAR (500-1100nm)	N-BK7	#88-828	₹3,270 Qty 10+ ₹2,939	10 to 12 days
10.00	100.00	98.02	YAG-BBAR (500-1100nm)	N-BK7	#88-829	₹3,270 Qty 10+ ₹2,939	10 to 12 days
12.00	12.00	9.76	YAG-BBAR (500-1100nm)	N-SF11	#88-830	₹3,620 Qty 10+ ₹3,250	10 to 12 days

12.00	15.00	12.03	YAG-BBAR (500-1100nm)	N-BK7	#88-831	₹3,620 Qty 10+ ₹3,250	10 to 12 days
12.00	18.00	16.22	YAG-BBAR (500-1100nm)	N-SF5	#88-832	₹3,620 Qty 10+ ₹3,250	Contact Us
12.00	20.00	17.69	YAG-BBAR (500-1100nm)	N-BK7	#88-833	₹3,620 Qty 10+ ₹3,250	10 to 12 days
12.00	24.00	22.15	YAG-BBAR (500-1100nm)	N-BK7	#88-834	₹3,542 Qty 10+ ₹3,172	10 to 12 days
12.00	25.00	23.22	YAG-BBAR (500-1100nm)	N-BK7	#38-576	₹3,542 Qty 10+ ₹3,172	Contact Us
12.00	30.00	28.02	YAG-BBAR (500-1100nm)	N-BK7	#88-835	₹3,542 Qty 10+ ₹3,172	10 to 12 days
12.00	36.00	34.02	YAG-BBAR (500-1100nm)	N-BK7	#34-183	₹3,542 Qty 10+ ₹3,172	Contact Us
12.00	42.00	40.22	YAG-BBAR (500-1100nm)	N-BK7	#88-837	₹3,542 Qty 10+ ₹3,172	Contact Us
12.00	48.00	46.36	YAG-BBAR (500-1100nm)	N-BK7	#88-838	₹3,542 Qty 10+ ₹3,172	10 to 12 days
12.00	50.00	48.75	YAG-BBAR (500-1100nm)	N-BK7	#38-577	₹3,542 Qty 10+ ₹3,172	10 to 12 days
12.00	54.00	52.02	YAG-BBAR (500-1100nm)	N-BK7	#88-839	₹3,542 Qty 10+ ₹3,172	10 to 12 days

12.00	60.00	58.37	YAG-BBAR (500-1100nm)	N-BK7	#88-840	₹3,542 Qty 10+ ₹3,172	Contact Us
12.00	72.00	70.42	YAG-BBAR (500-1100nm)	N-BK7	#88-841	₹3,542 Qty 10+ ₹3,172	10 to 12 days
12.00	84.00	82.39	YAG-BBAR (500-1100nm)	N-BK7	#88-842	₹3,542 Qty 10+ ₹3,172	10 to 12 days
12.00	100.00	98.35	YAG-BBAR (500-1100nm)	N-BK7	#88-843	₹3,542 Qty 10+ ₹3,172	7 days
12.50	12.50	10.40	YAG-BBAR (500-1100nm)	N-SF11	#38-578	₹3,542 Qty 10+ ₹3,172	10 to 12 days
12.50	15.00	13.26	YAG-BBAR (500-1100nm)	N-SF11	#38-579	₹3,542 Qty 10+ ₹3,172	10 to 12 days
12.50	17.50	15.00	YAG-BBAR (500-1100nm)	N-BK7	#38-580	₹3,542 Qty 10+ ₹3,172	10 to 12 days
12.50	20.00	17.69	YAG-BBAR (500-1100nm)	N-BK7	#38-581	₹3,542 Qty 10+ ₹3,172	10 to 12 days
12.50	25.00	22.96	YAG-BBAR (500-1100nm)	N-BK7	#38-584	₹3,464 Qty 10+ ₹3,114	10 to 12 days
12.50	30.00	28.22	YAG-BBAR (500-1100nm)	N-BK7	#38-585	₹3,464 Qty 10+ ₹3,114	10 to 12 days
12.50	35.00	33.42	YAG-BBAR (500-1100nm)	N-BK7	#38-586	₹3,464 Qty 10+ ₹3,114	10 to 12 days

12.50	40.00	38.55	YAG-BBAR (500-1100nm)	N-BK7	#38-587	₹3,464 Qty 10+ ₹3,114	10 to 12 days
12.50	45.00	43.68	YAG-BBAR (500-1100nm)	N-BK7	#38-588	₹3,464 Qty 10+ ₹3,114	10 to 12 days
12.50	50.00	48.68	YAG-BBAR (500-1100nm)	N-BK7	#38-589	₹3,464 Qty 10+ ₹3,114	10 to 12 days
12.50	75.00	73.88	YAG-BBAR (500-1100nm)	N-BK7	#38-591	₹3,464 Qty 10+ ₹3,114	10 to 12 days
12.50	100.00	98.95	YAG-BBAR (500-1100nm)	N-BK7	#38-593	₹3,464 Qty 10+ ₹3,114	10 to 12 days
12.70	12.70	10.46	YAG-BBAR (500-1100nm)	N-SF11	#88-844	₹3,542 Qty 10+ ₹3,172	10 to 12 days
12.70	15.00	11.53	YAG-BBAR (500-1100nm)	N-BK7	#88-845	₹3,542 Qty 10+ ₹3,172	10 to 12 days
12.70	19.10	16.46	YAG-BBAR (500-1100nm)	N-BK7	#88-846	₹3,542 Qty 10+ ₹3,172	10 to 12 days
12.70	20.00	17.49	YAG-BBAR (500-1100nm)	N-BK7	#38-594	₹3,542 Qty 10+ ₹3,172	10 to 12 days
12.70	25.40	23.43	YAG-BBAR (500-1100nm)	N-BK7	#88-847	₹3,464 Qty 10+ ₹3,114	10 to 12 days
12.70	30.00	28.22	YAG-BBAR (500-1100nm)	N-BK7	#38-595	₹3,464 Qty 10+ ₹3,114	10 to 12 days

12.70	31.80	29.81	YAG-BBAR (500-1100nm)	N-BK7	#88-848	₹3,464 Qty 10+ ₹3,114	10 to 12 days
12.70	38.10	36.12	YAG-BBAR (500-1100nm)	N-BK7	#88-849	₹3,464 Qty 10+ ₹3,114	Contact Us
12.70	40.00	38.48	YAG-BBAR (500-1100nm)	N-BK7	#38-596	₹3,464 Qty 10+ ₹3,114	10 to 12 days
12.70	44.50	42.69	YAG-BBAR (500-1100nm)	N-BK7	#88-850	₹3,464 Qty 10+ ₹3,114	10 to 12 days
12.70	50.80	49.15	YAG-BBAR (500-1100nm)	N-BK7	#88-851	₹3,464 Qty 10+ ₹3,114	10 to 12 days
12.70	100.00	98.88	YAG-BBAR (500-1100nm)	N-BK7	#38-597	₹3,464 Qty 10+ ₹3,114	10 to 12 days
15.00	15.00	11.71	YAG-BBAR (500-1100nm)	N-SF5	#88-852	₹3,620 Qty 10+ ₹3,250	10 to 12 days
15.00	18.00	15.61	YAG-BBAR (500-1100nm)	N-SF5	#88-853	₹3,620 Qty 10+ ₹3,250	10 to 12 days
15.00	20.00	17.74	YAG-BBAR (500-1100nm)	N-SF5	#88-854	₹3,620 Qty 10+ ₹3,250	10 to 12 days
15.00	22.50	20.50	YAG-BBAR (500-1100nm)	N-SF5	#88-855	₹3,620 Qty 10+ ₹3,250	10 to 12 days
15.00	25.00	22.50	YAG-BBAR (500-1100nm)	N-BK7	#38-598	₹3,542 Qty 10+ ₹3,172	10 to 12 days

15.00	30.00	27.90	YAG-BBAR (500-1100nm)	N-BK7	#88-856	₹3,542 Qty 10+ ₹3,172	10 to 12 days
15.00	40.00	38.02	YAG-BBAR (500-1100nm)	N-BK7	#88-857	₹3,542 Qty 10+ ₹3,172	10 to 12 days
15.00	45.00	43.35	YAG-BBAR (500-1100nm)	N-BK7	#88-858	₹3,542 Qty 10+ ₹3,172	10 to 12 days
15.00	50.00	48.35	YAG-BBAR (500-1100nm)	N-BK7	#38-599	₹3,542 Qty 10+ ₹3,172	10 to 12 days
15.00	60.00	58.65	YAG-BBAR (500-1100nm)	N-BK7	#88-859	₹3,542 Qty 10+ ₹3,172	10 to 12 days
15.00	75.00	73.79	YAG-BBAR (500-1100nm)	N-BK7	#88-860	₹3,542 Qty 10+ ₹3,172	10 to 12 days
15.00	100.00	98.02	YAG-BBAR (500-1100nm)	N-BK7	#88-861	₹3,542 Qty 10+ ₹3,172	10 to 12 days
15.00	200.00	197.89	YAG-BBAR (500-1100nm)	N-BK7	#14-381	₹3,542 Qty 10+ ₹3,172	10 to 12 days
15.00	250.00	248.02	YAG-BBAR (500-1100nm)	N-BK7	#14-389	₹3,542 Qty 10+ ₹3,172	Contact Us
18.00	18.00	15.20	YAG-BBAR (500-1100nm)	N-SF11	#88-862	₹3,737 Qty 10+ ₹3,348	10 to 12 days
18.00	20.00	17.59	YAG-BBAR (500-1100nm)	N-SF11	#38-600	₹3,698 Qty 10+ ₹3,328	10 to 12 days

18.00	22.50	20.26	YAG-BBAR (500-1100nm)	N-SF11	#88-863	₹3,698 Qty 10+ ₹3,328	10 to 12 days
18.00	25.00	21.51	YAG-BBAR (500-1100nm)	N-BK7	#38-601	₹3,698 Qty 10+ ₹3,328	10 to 12 days
18.00	27.00	24.73	YAG-BBAR (500-1100nm)	N-SF5	#88-864	₹3,698 Qty 10+ ₹3,328	10 to 12 days
18.00	30.00	27.10	YAG-BBAR (500-1100nm)	N-BK7	#38-602	₹3,581 Qty 10+ ₹3,211	10 to 12 days
18.00	36.00	33.65	YAG-BBAR (500-1100nm)	N-BK7	#88-865	₹3,581 Qty 10+ ₹3,211	Contact Us
18.00	50.00	48.09	YAG-BBAR (500-1100nm)	N-BK7	#38-603	₹3,581 Qty 10+ ₹3,211	10 to 12 days
18.00	54.00	52.02	YAG-BBAR (500-1100nm)	N-BK7	#88-866	₹3,581 Qty 10+ ₹3,211	10 to 12 days
18.00	72.00	70.05	YAG-BBAR (500-1100nm)	N-BK7	#88-867	₹3,581 Qty 10+ ₹3,211	10 to 12 days
20.00	20.00	17.42	YAG-BBAR (500-1100nm)	N-SF11	#88-868	₹3,776 Qty 10+ ₹3,386	10 to 12 days
20.00	25.00	22.76	YAG-BBAR (500-1100nm)	N-SF11	#88-869	₹3,737 Qty 10+ ₹3,348	10 to 12 days
20.00	35.00	32.04	YAG-BBAR (500-1100nm)	N-BK7	#88-871	₹3,737 Qty 10+ ₹3,348	10 to 12 days

20.00	40.00	36.77	YAG-BBAR (500-1100nm)	N-BK7	#88-872	₹3,620 Qty 10+ ₹3,250	10 to 12 days
20.00	50.00	47.87	YAG-BBAR (500-1100nm)	N-BK7	#88-873	₹3,620 Qty 10+ ₹3,250	10 to 12 days
20.00	60.00	57.03	YAG-BBAR (500-1100nm)	N-BK7	#88-874	₹3,620 Qty 10+ ₹3,250	10 to 12 days
20.00	70.00	68.03	YAG-BBAR (500-1100nm)	N-BK7	#88-875	₹3,620 Qty 10+ ₹3,250	10 to 12 days
20.00	80.00	78.45	YAG-BBAR (500-1100nm)	N-BK7	#88-876	₹3,620 Qty 10+ ₹3,250	Contact Us
20.00	100.00	97.13	YAG-BBAR (500-1100nm)	N-BK7	#88-877	₹3,620 Qty 10+ ₹3,250	7 days
20.00	150.00	148.02	YAG-BBAR (500-1100nm)	N-BK7	#88-878	₹3,620 Qty 10+ ₹3,250	10 to 12 days
25.00	25.00	20.22	YAG-BBAR (500-1100nm)	N-SF5	#88-879	₹3,970 Qty 10+ ₹3,562	10 to 12 days
25.00	30.00	24.69	YAG-BBAR (500-1100nm)	N-BK7	#88-880	₹3,970 Qty 10+ ₹3,562	10 to 12 days
25.00	35.00	30.42	YAG-BBAR (500-1100nm)	N-BK7	#88-881	₹3,970 Qty 10+ ₹3,562	10 to 12 days
25.00	40.00	36.31	YAG-BBAR (500-1100nm)	N-BK7	#88-882	₹3,970 Qty 10+ ₹3,562	10 to 12 days

25.00	50.00	46.75	YAG-BBAR (500-1100nm)	N-BK7	#88-883	₹3,815 Qty 10+ ₹3,425	10 to 12 days
25.00	60.00	56.90	YAG-BBAR (500-1100nm)	N-BK7	#88-884	₹3,815 Qty 10+ ₹3,425	10 to 12 days
25.00	75.00	72.00	YAG-BBAR (500-1100nm)	N-BK7	#88-885	₹3,815 Qty 10+ ₹3,425	10 to 12 days
25.00	85.00	82.17	YAG-BBAR (500-1100nm)	N-BK7	#88-886	₹3,815 Qty 10+ ₹3,425	10 to 12 days
25.00	100.00	97.17	YAG-BBAR (500-1100nm)	N-BK7	#88-887	₹3,815 Qty 10+ ₹3,425	10 to 12 days
25.00	125.00	122.70	YAG-BBAR (500-1100nm)	N-BK7	#88-888	₹3,815 Qty 10+ ₹3,425	10 to 12 days
25.00	150.00	147.81	YAG-BBAR (500-1100nm)	N-BK7	#88-889	₹3,815 Qty 10+ ₹3,425	10 to 12 days
25.00	175.00	172.85	YAG-BBAR (500-1100nm)	N-BK7	#88-890	₹3,815 Qty 10+ ₹3,425	10 to 12 days
25.00	200.00	197.89	YAG-BBAR (500-1100nm)	N-BK7	#34-184	₹3,815 Qty 10+ ₹3,425	10 to 12 days
25.00	250.00	248.02	YAG-BBAR (500-1100nm)	N-BK7	#88-892	₹3,815 Qty 10+ ₹3,425	10 to 12 days
25.00	300.00	298.02	YAG-BBAR (500-1100nm)	N-BK7	#88-893	₹3,815 Qty 10+ ₹3,425	10 to 12 days

25.00	400.00	397.89	YAG-BBAR (500-1100nm)	N-BK7	#34-185	₹3,815 Qty 10+ ₹3,425	10 to 12 days
25.00	500.00	497.89	YAG-BBAR (500-1100nm)	N-BK7	#88-895	₹3,815 Qty 10+ ₹3,425	10 to 12 days
25.00	750.00	747.89	YAG-BBAR (500-1100nm)	N-BK7	#88-896	₹3,815 Qty 10+ ₹3,425	10 to 12 days
25.40	25.40	21.48	YAG-BBAR (500-1100nm)	N-SF11	#88-897	₹3,970 Qty 10+ ₹3,562	10 to 12 days
25.40	35.00	30.46	YAG-BBAR (500-1100nm)	N-BK7	#38-604	₹3,970 Qty 10+ ₹3,562	10 to 12 days
25.40	38.10	33.48	YAG-BBAR (500-1100nm)	N-BK7	#88-898	₹3,970 Qty 10+ ₹3,562	10 to 12 days
25.40	40.00	36.11	YAG-BBAR (500-1100nm)	N-BK7	#38-605	₹3,970 Qty 10+ ₹3,562	10 to 12 days
25.40	50.80	47.50	YAG-BBAR (500-1100nm)	N-BK7	#88-899	₹3,815 Qty 10+ ₹3,425	10 to 12 days
25.40	63.50	60.37	YAG-BBAR (500-1100nm)	N-BK7	#88-900	₹3,815 Qty 10+ ₹3,425	Contact Us
25.40	75.00	72.69	YAG-BBAR (500-1100nm)	N-BK7	#38-607	₹3,815 Qty 10+ ₹3,425	10 to 12 days
25.40	76.20	73.56	YAG-BBAR (500-1100nm)	N-BK7	#88-901	₹3,815 Qty 10+ ₹3,425	10 to 12 days

25.40	88.90	86.26	YAG-BBAR (500-1100nm)	N-BK7	#88-902	₹3,815 Qty 10+ ₹3,425	10 to 12 days
25.40	100.00	98.02	YAG-BBAR (500-1100nm)	N-BK7	#38-608	₹3,815 Qty 10+ ₹3,425	10 to 12 days
25.40	101.60	98.97	YAG-BBAR (500-1100nm)	N-BK7	#88-903	₹3,815 Qty 10+ ₹3,425	10 to 12 days
25.40	125.00	123.02	YAG-BBAR (500-1100nm)	N-BK7	#38-609	₹3,815 Qty 10+ ₹3,425	10 to 12 days
25.40	150.00	148.02	YAG-BBAR (500-1100nm)	N-BK7	#38-610	₹3,815 Qty 10+ ₹3,425	10 to 12 days
30.00	30.00	26.13	YAG-BBAR (500-1100nm)	N-SF11	#88-904	₹4,515 Qty 10+ ₹4,087	10 to 12 days
30.00	40.00	37.20	YAG-BBAR (500-1100nm)	N-SF11	#88-905	₹4,360 Qty 10+ ₹3,931	Contact Us
30.00	50.00	46.17	YAG-BBAR (500-1100nm)	N-SF5	#88-906	₹4,360 Qty 10+ ₹3,931	10 to 12 days
30.00	60.00	56.03	YAG-BBAR (500-1100nm)	N-BK7	#88-907	₹4,243 Qty 10+ ₹3,815	10 to 12 days
30.00	75.00	70.95	YAG-BBAR (500-1100nm)	N-BK7	#88-908	₹4,243 Qty 10+ ₹3,815	10 to 12 days
30.00	100.00	96.01	YAG-BBAR (500-1100nm)	N-BK7	#88-909	₹4,243 Qty 10+ ₹3,815	10 to 12 days

30.00	120.00	116.04	YAG-BBAR (500-1100nm)	N-BK7	#88-910	₹4,243 Qty 10+ ₹3,815	10 to 12 days
35.00	35.00	30.52	YAG-BBAR (500-1100nm)	N-SF11	#38-611	₹4,632 Qty 10+ ₹4,165	10 to 12 days
35.00	50.00	44.40	YAG-BBAR (500-1100nm)	N-BK7	#38-612	₹4,515 Qty 10+ ₹4,087	10 to 12 days
35.00	70.00	66.04	YAG-BBAR (500-1100nm)	N-BK7	#38-613	₹4,515 Qty 10+ ₹4,087	10 to 12 days
35.00	100.00	97.03	YAG-BBAR (500-1100nm)	N-BK7	#38-614	₹4,515 Qty 10+ ₹4,087	10 to 12 days
40.00	40.00	35.13	YAG-BBAR (500-1100nm)	N-SF11	#88-911	₹5,411 Qty 10+ ₹4,866	10 to 12 days
40.00	60.00	53.90	YAG-BBAR (500-1100nm)	N-BK7	#88-912	₹5,411 Qty 10+ ₹4,866	10 to 12 days
40.00	80.00	74.73	YAG-BBAR (500-1100nm)	N-BK7	#34-186	₹5,333 Qty 10+ ₹4,788	10 to 12 days
40.00	100.00	95.39	YAG-BBAR (500-1100nm)	N-BK7	#34-187	₹5,333 Qty 10+ ₹4,788	10 to 12 days
40.00	200.00	196.70	YAG-BBAR (500-1100nm)	N-BK7	#34-188	₹5,333 Qty 10+ ₹4,788	10 to 12 days
40.00	300.00	296.70	YAG-BBAR (500-1100nm)	N-BK7	#88-916	₹5,333 Qty 10+ ₹4,788	10 to 12 days

40.00	400.00	396.70	YAG-BBAR (500-1100nm)	N-BK7	#88-917	₹5,333 Qty 10+ ₹4,788	10 to 12 days
50.00	50.00	43.28	YAG-BBAR (500-1100nm)	N-SF11	#88-918	₹5,800 Qty 10+ ₹5,216	10 to 12 days
50.00	75.00	67.75	YAG-BBAR (500-1100nm)	N-BK7	#88-919	₹5,644 Qty 10+ ₹5,099	10 to 12 days
50.00	100.00	93.41	YAG-BBAR (500-1100nm)	N-BK7	#88-920	₹5,450 Qty 10+ ₹4,905	10 to 12 days
50.00	125.00	118.39	YAG-BBAR (500-1100nm)	N-BK7	#88-921	₹5,450 Qty 10+ ₹4,905	Contact Us
50.00	150.00	144.07	YAG-BBAR (500-1100nm)	N-BK7	#88-922	₹5,450 Qty 10+ ₹4,905	10 to 12 days
50.00	175.00	169.05	YAG-BBAR (500-1100nm)	N-BK7	#88-923	₹5,450 Qty 10+ ₹4,905	10 to 12 days
50.00	200.00	196.66	YAG-BBAR (500-1100nm)	N-BK7	#88-924	₹5,450 Qty 10+ ₹4,905	10 to 12 days
50.00	250.00	246.74	YAG-BBAR (500-1100nm)	N-BK7	#88-925	₹5,450 Qty 10+ ₹4,905	Contact Us
50.00	500.00	496.70	YAG-BBAR (500-1100nm)	N-BK7	#88-926	₹5,450 Qty 10+ ₹4,905	10 to 12 days

[#71-341 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

50.80	50.81	44.08	YAG-BBAR (500-1100nm)	N-LASF9		₹5,800 Qty 11+ ₹5,216	10 to 12 days
-------	-------	-------	-----------------------	-------------------------	--	--------------------------	---------------

50.80	76.20	68.95	YAG-BBAR (500-1100nm)	N-LASF9	#71-348	₹5,644 Qty 11+ ₹5,099	10 to 12 days
-------	-------	-------	-----------------------	-------------------------	-------------------------	--------------------------	---------------

75.00	75.00	53.49	YAG-BBAR (500-1100nm)	N-BK7	#26-114	₹11,288 Qty 10+ ₹10,121	10 to 12 days
-------	-------	-------	-----------------------	-----------------------	-------------------------	----------------------------	---------------

[#72-308 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

75.00	100.00	85.61	YAG-BBAR (500-1100nm)	Fused Silica (Corning 7980)		₹51,770 Qty 6+ ₹41,650	10 to 12 days
-------	--------	-------	-----------------------	-----------------------------	--	---------------------------	---------------

[#72-316 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

75.00	125.00	112.66	YAG-BBAR (500-1100nm)	Fused Silica (Corning 7980)		₹50,213 Qty 6+ ₹40,482	10 to 12 days
-------	--------	--------	-----------------------	-----------------------------	--	---------------------------	---------------

75.00	150.00	142.45	YAG-BBAR (500-1100nm)	N-BK7	#26-115	₹11,133 Qty 10+ ₹10,043	10 to 12 days
-------	--------	--------	-----------------------	-----------------------	-------------------------	----------------------------	---------------

[#72-324 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

75.00	150.00	136.31	YAG-BBAR (500-1100nm)	Fused Silica (Corning 7980)		₹48,656 Qty 6+ ₹39,314	10 to 12 days
-------	--------	--------	-----------------------	-----------------------------	--	---------------------------	---------------

75.00	200.00	194.24	YAG-BBAR (500-1100nm)	N-BK7	#26-116	₹11,133 Qty 10+ ₹10,043	10 to 12 days
-------	--------	--------	-----------------------	-----------------------	-------------------------	----------------------------	---------------

[#72-332 New](#)



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.

Be the
first to buy
before
anyone
else!

₹47,099
Qty 6+ ₹38,069

10 to 12 days



Copyright 2023, Edmund Optics India Private Limited, #267, Greystone Building, Second Floor, 6th Cross Rd, Binnamangala, Stage 1, Indiranagar, Bengaluru, Karnataka, India 560038
Phone: 1-800-363-1992 : www.edmundoptics.com

75.00	250.00	244.73	YAG-BBAR (500-1100nm)	N-BK7	#26-117	₹11,133 Qty 10+ ₹10,043	10 to 12 days
75.00	500.00	494.73	YAG-BBAR (500-1100nm)	N-BK7	#26-118	₹11,133 Qty 10+ ₹10,043	10 to 12 days