

[All Products](#) / [Imaging Lenses](#) / [Fixed Focal Length Lenses](#)

TECHSPEC® Cx Series Fixed Focal Length Lenses




- Up to 2/3", C-Mount Lens
- Up to 7.5 MegaPixels, 2.8µm Pixel Size Sensors
- Flexible (Cx) Version of our C Series Lenses with Interchangeable Apertures, Filters and Liquid Lens
- 12mm to 50mm Focal Length

Common Specifications

General			
Series:	Cx Series	Functionality:	Full Function
Physical & Mechanical Properties			
Iris Option:	Fixed	Maximum Rear Protrusion (mm):	0
Optical Properties			
Maximum Image Circle (mm):	11.00	Aperture (f/#):	Accessory Dependent
Coating:	425 - 675nm BBAR	Coating Specification:	425 - 675nm BBAR
Resolution (lp/mm):	180		
Sensor			
Maximum Sensor Format:		2/3"	
Pixel Size, H x V (µm):		2.74 x 2.74	
Threading & Mounting			
Filter Thread:	M25.5 x 0.50 (Male)		
Filter Thread Adapter:	#89-941 (Required)	Mount:	C-Mount
Environmental & Durability Factors			
Storage Temperature (°C):		-20 to +60	

Technical Information

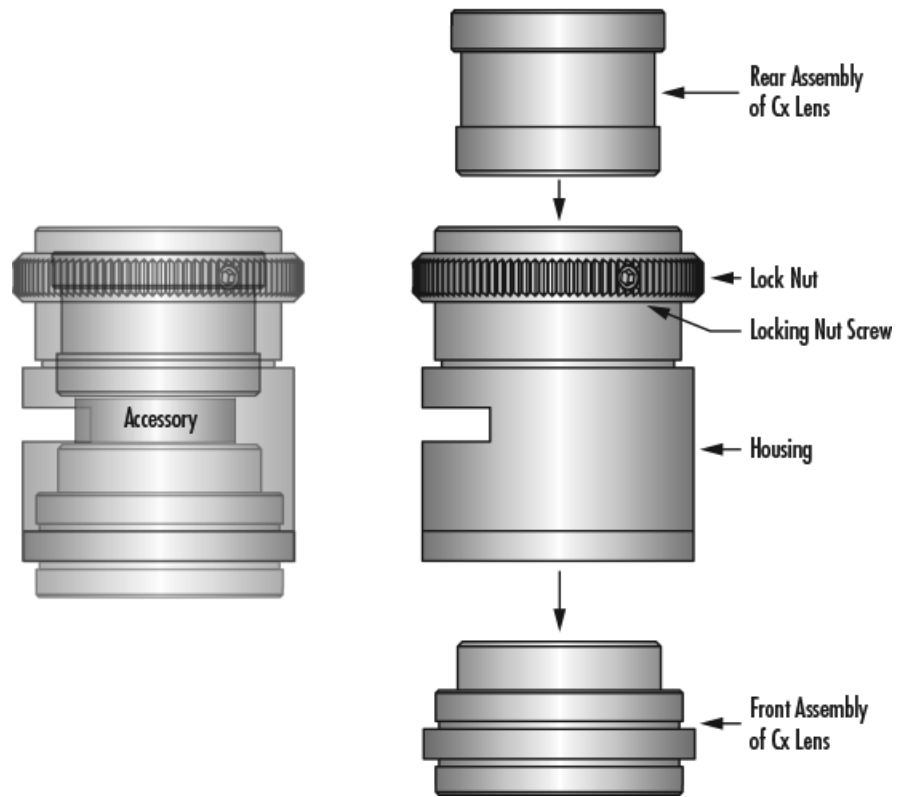

Cx Lens Assembly Diagram

Products

FL (mm)	Max. Sensor Format	Aperture (f/#)	WD (mm)	Mount	Stock Number	Price	Buy
12.00	2/3"	Accessory Dependent	100 - ∞	C- Mount	#33-562	₹15,921	10 to 12 days
16.00	2/3"	Accessory Dependent	100 - ∞	C- Mount	#33-563	₹15,921	10 to 12 days
25.00	2/3"	Accessory Dependent	150 - ∞	C- Mount	#33-564	₹15,921	10 to 12 days
35.00	2/3"	Accessory Dependent	225 - ∞	C- Mount	#33-565	₹15,921	10 to 12 days
50.00	2/3"	Accessory Dependent	300 - 1,675	C- Mount	#33-566	₹21,402	10 to 12 days



Copyright 2023, Edmund Optics India Private Limited, #267, Greystone Building, Second Floor, 6th Cross Rd, Binnamangala, Stage 1, Indiranagar, Bengaluru, Karnataka, India 560038
Phone: 1-800-363-1992 :
www.edmundoptics.com