

[All Products](#) / [Lights and Illumination](#) / [Machine Vision Lighting](#) / [Ring Lights](#)

## Effilux Adjustable LED Ring Lights



- Easy to Access Lens Array for Quick, Manual Adjustment of Illumination Emission Angles
- Included Interchangeable Windows Allows for Easy Adjustment of Light Diffusion
- Integrate Polarizer Accessory for Glare Elimination

# Common Specifications

## General

Type of Illumination:	LED Illuminator	Manufacturer:	Effilux
Geometry:	Ring Light	Illumination Mode:	Strobed or Constant

## Physical & Mechanical Properties

Inner Diameter (mm):	58.0	Dimensions (mm):	151.0 x 117.0 x 40.0
----------------------	------	------------------	----------------------

## Hardware & Interface Connectivity

Connector:	M12, 5 pins	Input Voltage (V):	24V DC
Power Supply:	Power Supply Required and Sold Separately: USA: <a href="#">#15-874</a> Europe: <a href="#">#15-875</a> Japan: <a href="#">#73-409</a> Korea: <a href="#">#73-409</a> China: <a href="#">#15-874</a>		

## Threading & Mounting


Mount:	M4 (x4) and 3.5mm Thru (x4)
--------	-----------------------------

## Environmental & Durability Factors

Operating Temperature (°C):	-10 to 50	Environmental Rating:	IP65
-----------------------------	-----------	-----------------------	------

## Technical Information

### Effilux Adjustable LED Ring Lights

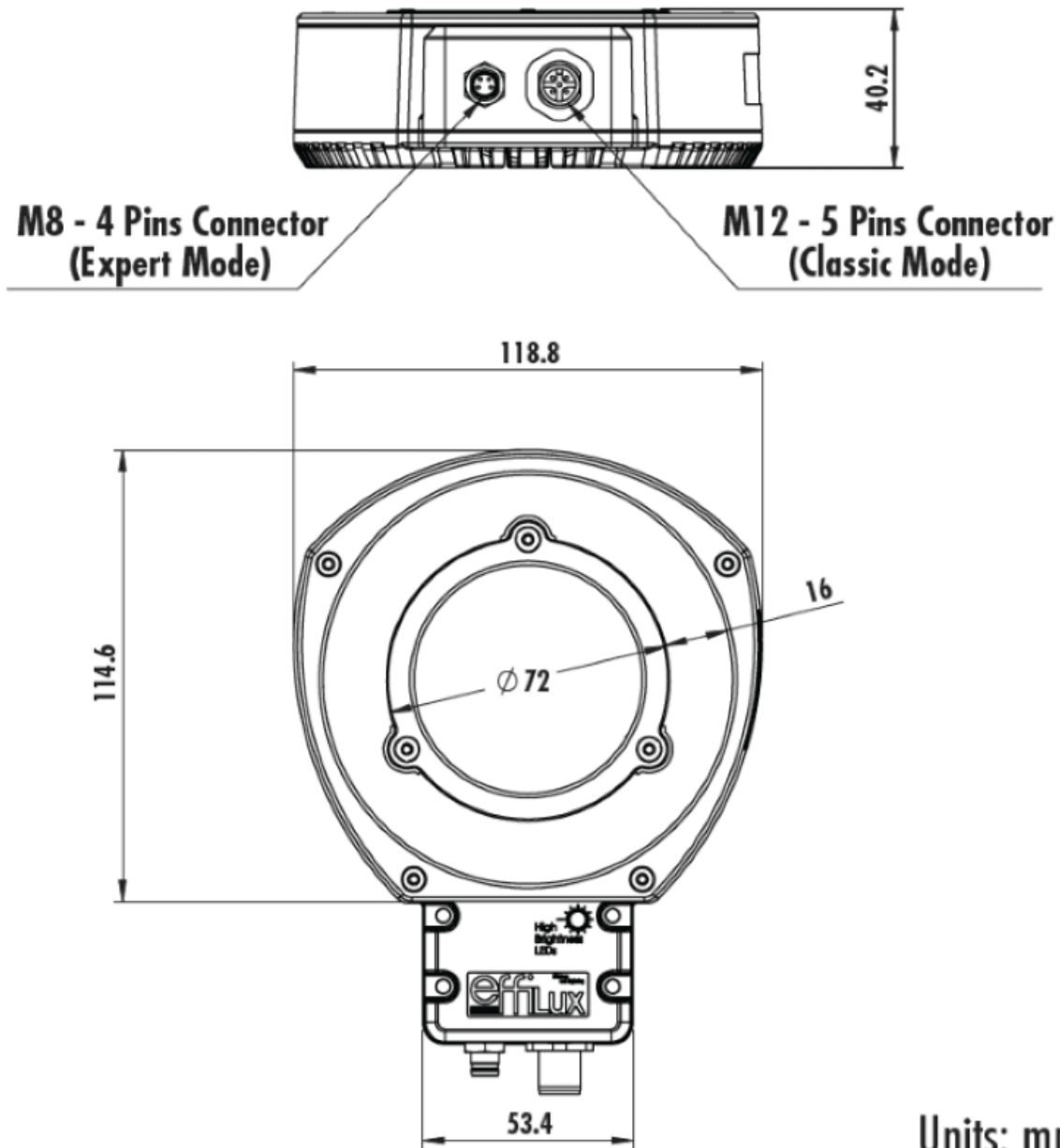

Units: mm

Products

Color	Wavelength (nm)	Illumination Mode	Inner Diameter (mm)	Stock Number	Price	Buy
White	-	Strobed or Constant	58.0	<a href="#">#34-861</a>	₹63,900	10 to 12 days
<a href="#">#75-583 New</a>						
<div><div><div>×</div></div><div>New</div><div>Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!</div></div>						
Blue	465.00	Strobed or Constant	58.0		₹67,425	10 to 12 days
<a href="#">#75-585 New</a>						
<div><div><div>×</div></div><div>New</div><div>Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!</div></div>						
Green	525.00	Strobed or Constant	58.0		₹67,425	10 to 12 days

Red	625.00	Strobed or Constant	58.0	<a href="#">#34-862</a>	₹63,900	10 to 12 days
IR	850.00	Strobed or Constant	58.0	<a href="#">#34-863</a>	₹69,750	7 days
RGB	-	Strobed or Constant	58.0	<a href="#">#34-864</a>	₹77,850	10 to 12 days

[#75-580 New](#)



New

Launched  
on our  
website  
before  
appearing  
in our  
latest print  
catalogs.  
Be the  
first to buy  
before  
anyone  
else!

White, UV, IR	-	Strobed or Constant	58.0	<a href="#">#34-865</a>	₹1,03,500	10 to 12 days
------------------	---	------------------------	------	-------------------------	-----------	---------------



Copyright 2023, Edmund Optics India Private Limited, #267, Greystone Building, Second Floor, 6th Cross Rd, Binnamangala, Stage 1, Indiranagar, Bengaluru, Karnataka, India 560038  
Phone: 1-800-363-1992 :  
[www.edmundoptics.com](http://www.edmundoptics.com)