

[All Products](#) / [Optics](#) / [Beamsplitters](#) / [Cube Beamsplitters](#)

TECHSPEC® Laser Line Non-Polarizing Cube Beamsplitters



- <3% Transmission Difference for S and P Polarization States
- AR Coated <0.25% on Entrance and Exit Faces
- Nd:YAG and HeNe Options

Common Specifications


Physical & Mechanical Properties

Bevel:	Protective as needed	Clear Aperture (%):	90
Construction:	Cube		


Optical Properties

Beam Deviation (arcmin):	±2		
Coating Specification:	<0.25% Reflection on Entrance and Exit Faces	Reflection/Transmission Tolerance (%):	±5
Substrate:	N-BK7	Surface Quality:	40-20
Transmission (%):	<45% ±5% @ DWL	 Ts-Tp :	<3% @ DWL
Power (fringes) @ 632.8nm:	1.50	Irregularity (fringes) @ 632.8nm:	0.25


Technical Information

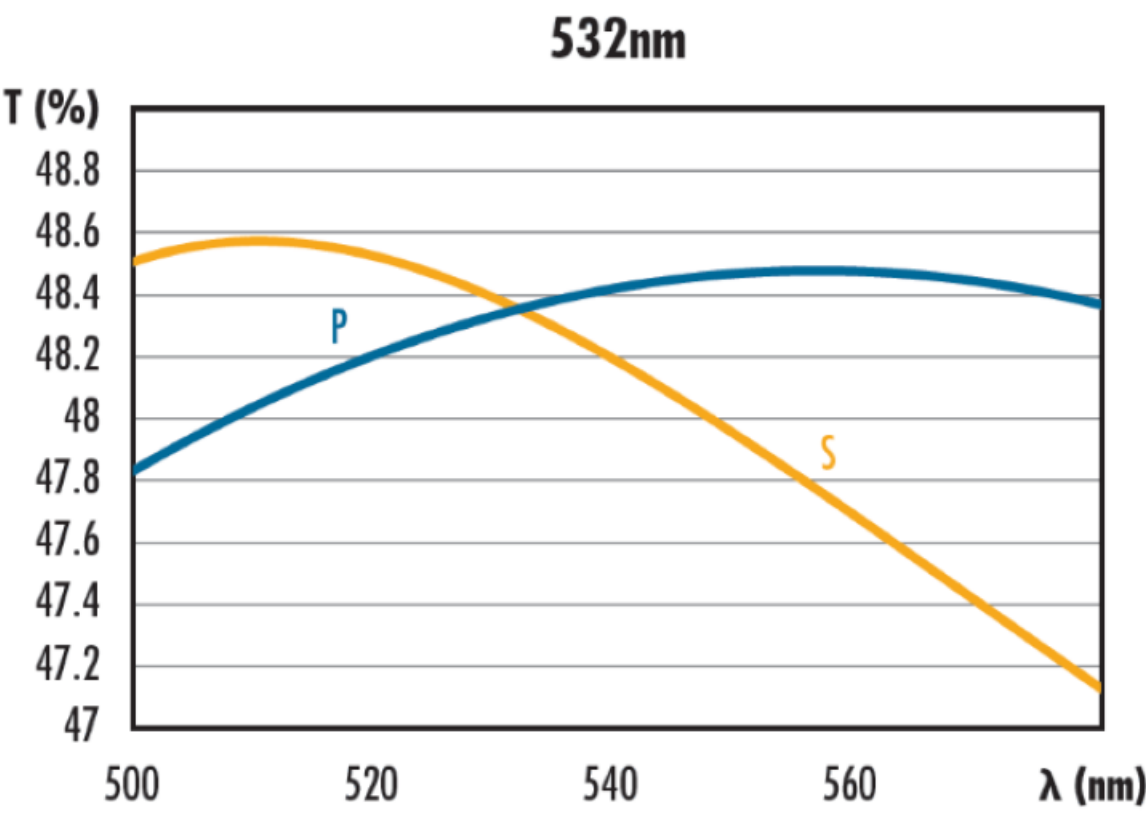

632.8nm

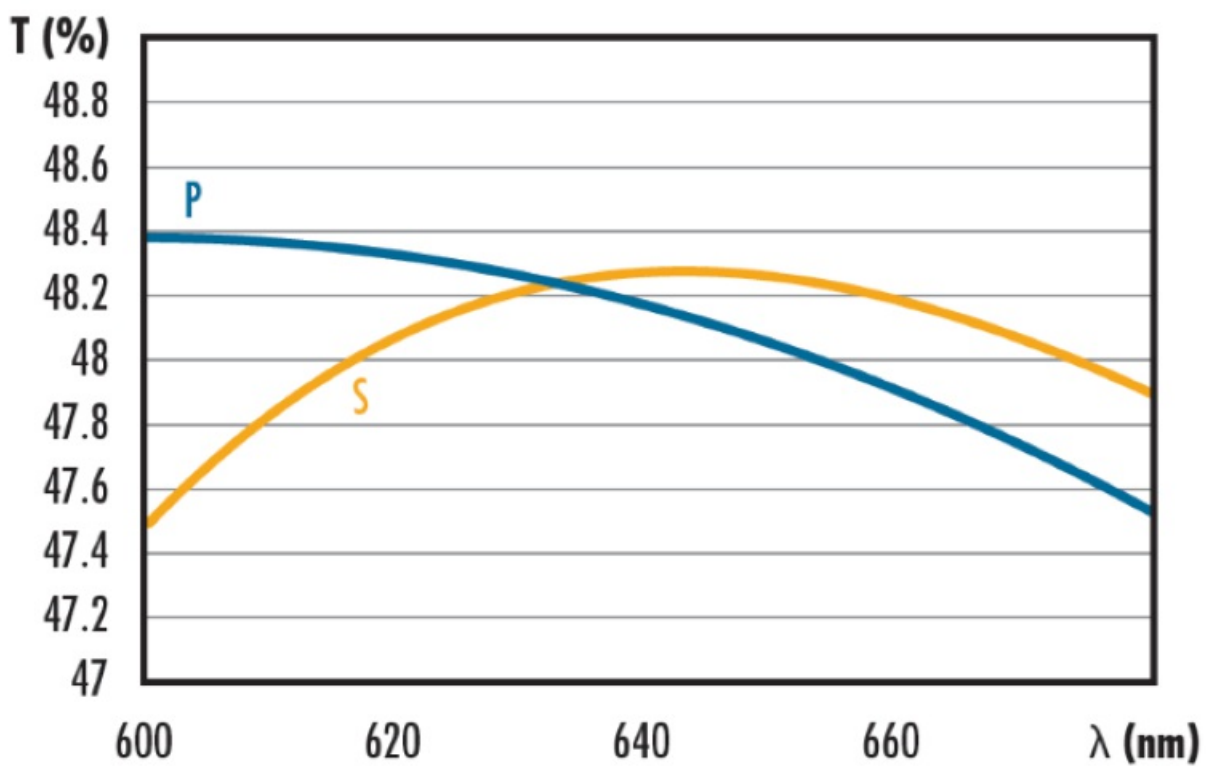

1064nm

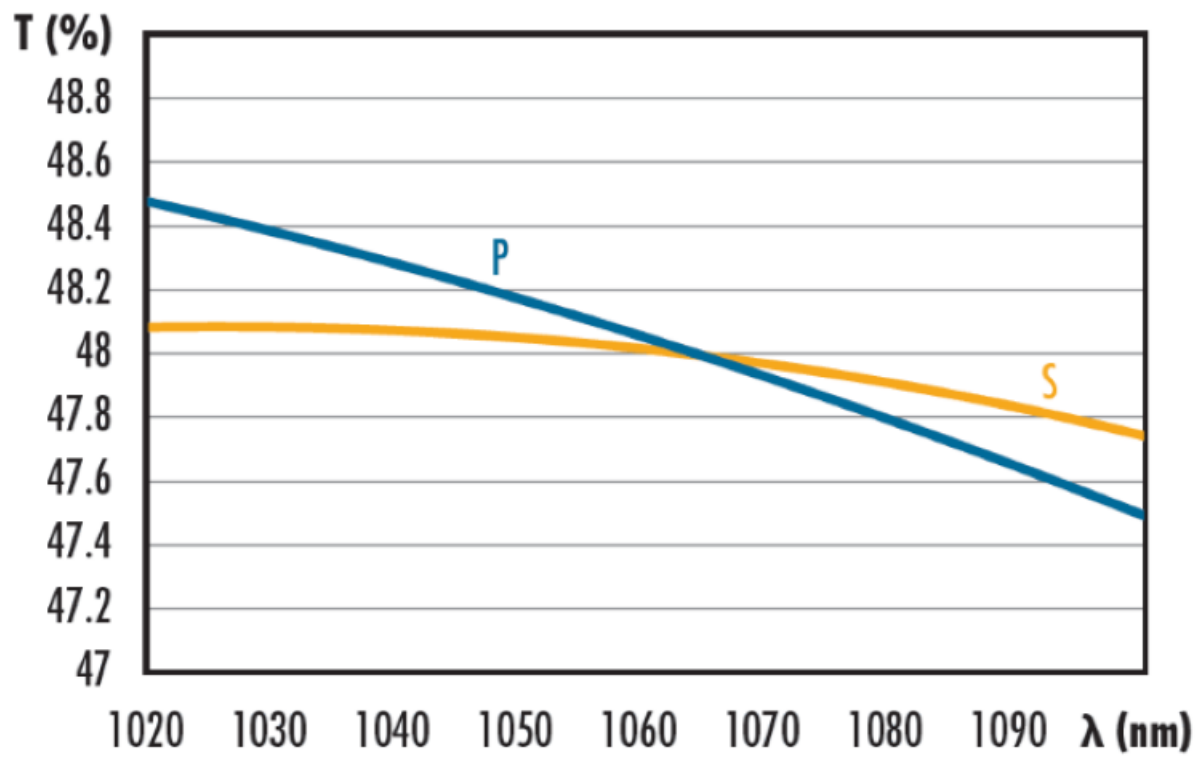

Products

Title	Stock Number	Price	Buy
5mm 532nm, Laser Line Non-Polarizing Cube Beamsplitter	#35-958	₹21,780 Qty 6+ ₹17,460	10 to 12 days
12.5mm 532nm, Laser Line Non-Polarizing Cube Beamsplitter	#35-959	₹23,670 Qty 6+ ₹18,990	10 to 12 days
25mm 532nm, Laser Line Non-Polarizing Cube Beamsplitter	#35-960	₹25,830 Qty 6+ ₹20,700	10 to 12 days
5mm 632nm, Laser Line Non-Polarizing Beamsplitter	#35-961	₹21,780 Qty 6+ ₹17,460	10 to 12 days
12.5mm 632nm, Laser Line Non-Polarizing Beamsplitter	#35-962	₹23,670 Qty 6+ ₹18,990	10 to 12 days
25mm 632nm, Laser Line Non-Polarizing Beamsplitter	#35-963	₹25,830 Qty 6+ ₹20,700	Contact Us
5mm 1064nm, Laser Line Non-Polarizing Beamsplitter	#35-964	₹21,780 Qty 6+ ₹17,460	10 to 12 days
12.5mm 1064nm, Laser Line Non-Polarizing Beamsplitter	#35-965	₹23,670 Qty 6+ ₹18,990	10 to 12 days
25mm 1064nm, Laser Line Non-Polarizing Beamsplitter	#35-966	₹25,830 Qty 6+ ₹20,700	10 to 12 days



Copyright 2023, Edmund Optics India Private Limited, #267, Greystone Building, Second Floor, 6th Cross Rd, Binnamangala, Stage 1, Indiranagar, Bengaluru, Karnataka, India 560038

Phone: 1-800-363-1992 :

www.edmundoptics.com