

[All Products](#) /
 [Laser Optics](#) /
 [Laser Windows](#) /
 [Laser Line Windows](#)

TECHSPEC® $\lambda/10$ Laser Line Coated Windows



- 10-5 Surface Quality
- Damage Thresholds at Design Wavelengths
- Diameters from 12.5 to 76.2mm Available
- [Uncoated Substrates Available](#)

Common Specifications



Physical & Mechanical Properties

Bevel:	Protective as needed	Clear Aperture (%):	90
Edges:	Fine Ground		


Optical Properties

Angle of Incidence (°):	0
Surface Quality:	10-5

Technical Information

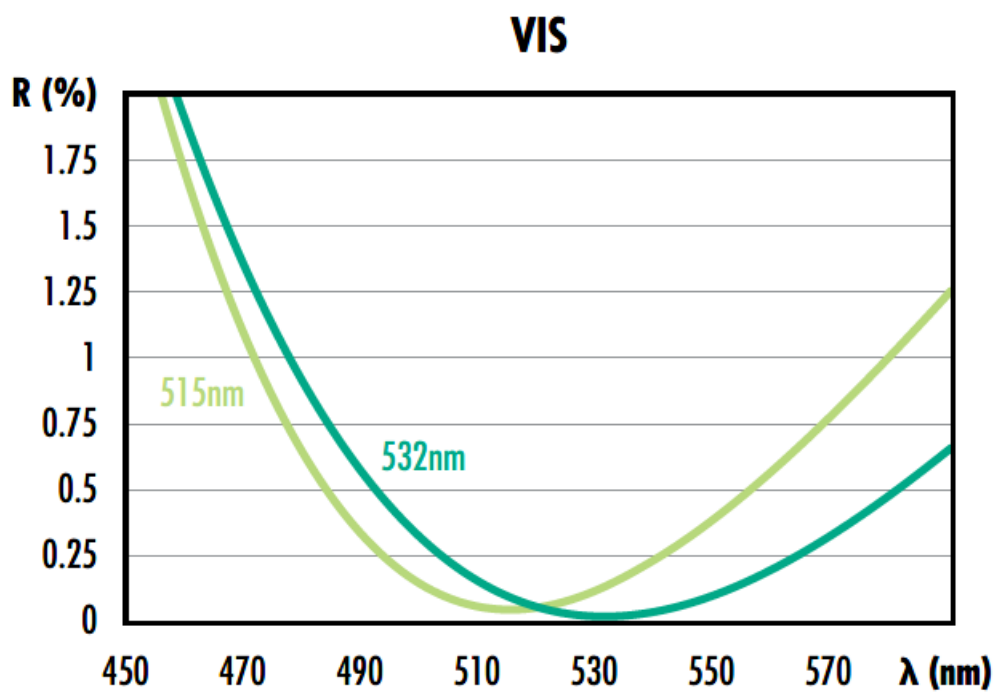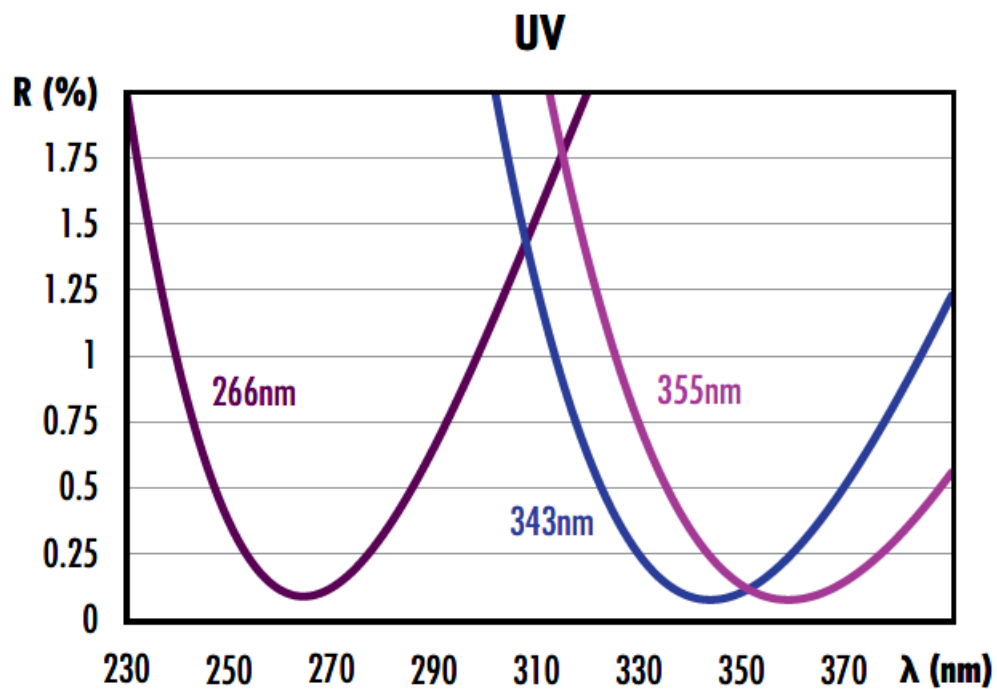

NIR

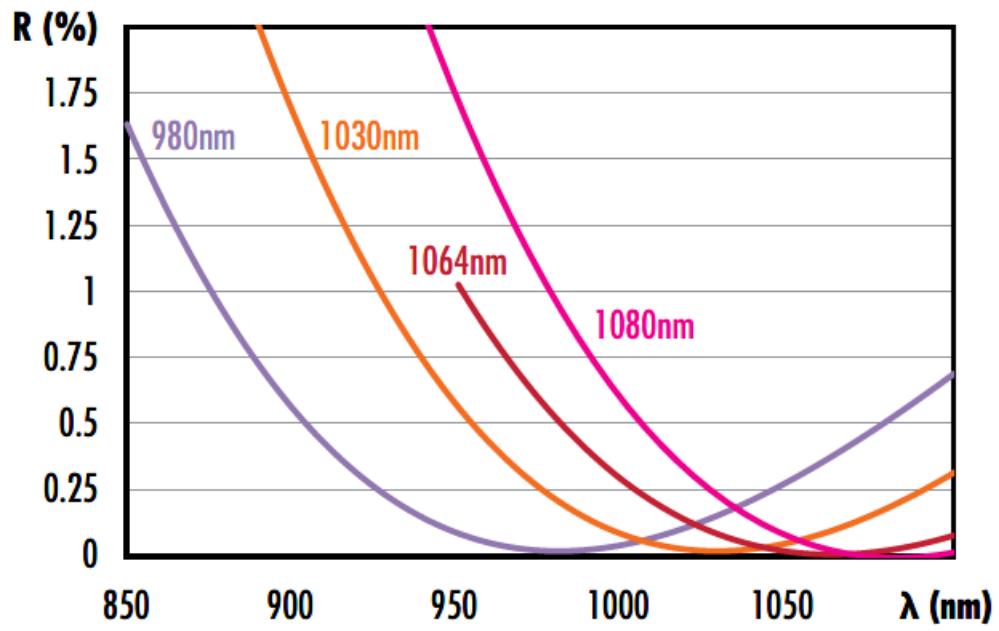

Products

Coating	Substrate	Dia. (mm)	Thickness (mm)	Stock Number	Price	Buy
Laser V-Coat (266nm)	Fused Silica	12.50	3.00	#48-204	₹9,902 Qty 6+ ₹7,922	10 to 12 days
Laser V-Coat (266nm)	Fused Silica	12.70	6.35	#38-918	₹9,902 Qty 6+ ₹7,922	10 to 12 days
Laser V-Coat (266nm)	Fused Silica	19.10	6.35	#38-921	₹10,636 Qty 6+ ₹8,509	10 to 12 days
Laser V-Coat (266nm)	Fused Silica	25.00	3.00	#48-205	₹11,589 Qty 6+ ₹9,242	10 to 12 days
Laser V-Coat (266nm)	Fused Silica	25.40	6.35	#38-923	₹11,589 Qty 6+ ₹9,242	Contact Us
Laser V-Coat (266nm)	Fused Silica	38.10	6.35	#38-925	₹16,284 Qty 6+ ₹12,983	10 to 12 days
Laser V-Coat (266nm)	Fused Silica	50.80	9.53	#38-928	₹19,805 Qty 6+ ₹15,844	10 to 12 days
Laser V-Coat (343nm)	Fused Silica	12.70	6.35	#39-668	₹9,902 Qty 6+ ₹7,922	10 to 12 days
Laser V-Coat (343nm)	Fused Silica	19.10	6.35	#39-670	₹10,636 Qty 6+ ₹8,509	10 to 12 days
Laser V-Coat (343nm)	Fused Silica	25.40	6.35	#39-671	₹11,589 Qty 6+ ₹9,242	Contact Us
Laser V-Coat (343nm)	Fused Silica	38.10	6.35	#39-673	₹16,284 Qty 6+ ₹12,983	10 to 12 days
Laser V-Coat (343nm)	Fused Silica	50.80	9.53	#39-675	₹19,805 Qty 6+ ₹15,844	10 to 12 days

Laser V-Coat (343nm)	Fused Silica	76.20	12.70	#27-040	₹58,680 Qty 6+ ₹46,944	Contact Us
Laser V-Coat (355nm)	Fused Silica	12.50	3.00	#48-206	₹9,902 Qty 6+ ₹7,922	10 to 12 days
Laser V-Coat (355nm)	Fused Silica	12.70	6.35	#38-936	₹9,902 Qty 6+ ₹7,922	10 to 12 days
Laser V-Coat (355nm)	Fused Silica	19.10	6.35	#38-938	₹10,636 Qty 6+ ₹8,509	10 to 12 days
Laser V-Coat (355nm)	Fused Silica	25.00	3.00	#48-207	₹11,589 Qty 6+ ₹9,242	10 to 12 days
Laser V-Coat (355nm)	Fused Silica	25.40	6.35	#38-942	₹11,589 Qty 6+ ₹9,242	10 to 12 days
Laser V-Coat (355nm)	Fused Silica	38.10	6.35	#38-949	₹16,284 Qty 6+ ₹12,983	10 to 12 days
Laser V-Coat (355nm)	Fused Silica	50.80	9.53	#38-951	₹19,805 Qty 6+ ₹15,844	10 to 12 days
Laser V-Coat (515nm)	Fused Silica	12.70	6.35	#39-681	₹9,902 Qty 6+ ₹7,922	10 to 12 days
Laser V-Coat (515nm)	Fused Silica	19.10	6.35	#39-683	₹10,636 Qty 6+ ₹8,509	10 to 12 days
Laser V-Coat (515nm)	Fused Silica	25.40	6.35	#39-684	₹11,589 Qty 6+ ₹9,242	10 to 12 days
Laser V-Coat (515nm)	Fused Silica	38.10	6.35	#39-688	₹16,284 Qty 6+ ₹12,983	10 to 12 days
Laser V-Coat (515nm)	Fused Silica	50.80	9.53	#39-690	₹19,805 Qty 6+ ₹15,844	10 to 12 days
Laser V-Coat (515nm)	Fused Silica	76.20	12.70	#27-041	₹58,680 Qty 6+ ₹46,944	10 to 12 days

Laser V-Coat (532nm)	Fused Silica	12.50	3.00	#48-208	₹9,902 Qty 6+ ₹7,922	10 to 12 days
Laser V-Coat (532nm)	Fused Silica	12.70	6.35	#38-966	₹9,902 Qty 6+ ₹7,922	10 to 12 days
Laser V-Coat (532nm)	Fused Silica	19.10	6.35	#38-968	₹10,636 Qty 6+ ₹8,509	10 to 12 days
Laser V-Coat (532nm)	Fused Silica	25.00	3.00	#48-209	₹11,589 Qty 6+ ₹9,242	10 to 12 days
Laser V-Coat (532nm)	Fused Silica	25.40	6.35	#38-969	₹11,589 Qty 6+ ₹9,242	10 to 12 days
Laser V-Coat (532nm)	Fused Silica	38.10	6.35	#38-973	₹16,284 Qty 6+ ₹12,983	10 to 12 days
Laser V-Coat (532nm)	Fused Silica	50.80	9.53	#38-975	₹19,805 Qty 6+ ₹15,844	10 to 12 days
Laser V-Coat (980nm)	Fused Silica	12.70	6.35	#39-702	₹9,902 Qty 6+ ₹7,922	10 to 12 days
Laser V-Coat (980nm)	Fused Silica	19.10	6.35	#39-704	₹10,636 Qty 6+ ₹8,509	10 to 12 days
Laser V-Coat (980nm)	Fused Silica	25.40	6.35	#39-705	₹11,589 Qty 6+ ₹9,242	10 to 12 days
Laser V-Coat (980nm)	Fused Silica	38.10	6.35	#39-707	₹16,284 Qty 6+ ₹12,983	10 to 12 days
Laser V-Coat (980nm)	Fused Silica	50.80	9.53	#39-710	₹19,805 Qty 6+ ₹15,844	10 to 12 days
Laser V-Coat (1030nm)	Fused Silica	12.70	6.35	#39-717	₹9,902 Qty 6+ ₹7,922	10 to 12 days
Laser V-Coat (1030nm)	Fused Silica	19.10	6.35	#39-719	₹10,636 Qty 6+ ₹8,509	10 to 12 days

Laser V-Coat (1030nm)	Fused Silica	25.40	6.35	#39-720	₹11,589 Qty 6+ ₹9,242	10 to 12 days
Laser V-Coat (1030nm)	Fused Silica	38.10	6.35	#39-722	₹16,284 Qty 6+ ₹12,983	10 to 12 days
Laser V-Coat (1030nm)	Fused Silica	50.80	9.53	#39-724	₹19,805 Qty 6+ ₹15,844	10 to 12 days
Laser V-Coat (1030nm)	Fused Silica	76.20	12.70	#27-042	₹58,680 Qty 6+ ₹46,944	10 to 12 days
Laser V-Coat (1064nm)	Fused Silica	12.50	3.00	#48-210	₹9,902 Qty 6+ ₹7,922	10 to 12 days
Laser V-Coat (1064nm)	Fused Silica	12.70	6.35	#38-982	₹9,902 Qty 6+ ₹7,922	10 to 12 days
Laser V-Coat (1064nm)	Fused Silica	19.10	6.35	#38-984	₹10,636 Qty 6+ ₹8,509	10 to 12 days
Laser V-Coat (1064nm)	Fused Silica	25.00	3.00	#48-211	₹11,589 Qty 6+ ₹9,242	10 to 12 days
Laser V-Coat (1064nm)	Fused Silica	25.40	6.35	#38-985	₹11,589 Qty 6+ ₹9,242	10 to 12 days
Laser V-Coat (1064nm)	Fused Silica	38.10	6.35	#38-988	₹16,284 Qty 6+ ₹12,983	10 to 12 days
Laser V-Coat (1064nm)	Fused Silica	50.80	9.53	#38-990	₹19,805 Qty 6+ ₹15,844	10 to 12 days
Laser V-Coat (1080nm)	Fused Silica	12.70	6.35	#11-397	₹9,902 Qty 6+ ₹7,922	10 to 12 days
Laser V-Coat (1080nm)	Fused Silica	19.10	6.35	#11-399	₹10,636 Qty 6+ ₹8,509	10 to 12 days
Laser V-Coat (1080nm)	Fused Silica	25.40	6.35	#11-400	₹11,589 Qty 6+ ₹9,242	10 to 12 days

Laser V-Coat (1080nm)	Fused Silica	38.10	6.35	#11-402	₹16,284 Qty 6+ ₹12,983	10 to 12 days
Laser V-Coat (1080nm)	Fused Silica	50.80	9.53	#11-404	₹19,805 Qty 6+ ₹15,844	10 to 12 days

[#38-933 Clearance](#)



Clearance

Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.

Laser V-Coat (355nm)	N-BK7	25.40	6.35		₹10,080	10 to 12 days
-------------------------	-----------------------	-------	------	--	---------	---------------

[#38-963 Clearance](#)



Clearance

Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.

Laser V-Coat (532nm)

[N-BK7](#)

25.40

6.35

₹9,180

10 to 12 days

[#39-699 Clearance](#)



Clearance

Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.

Laser V-Coat (980nm)

[N-BK7](#)

25.40

6.35

₹6,390

10 to 12 days

[#38-977 Clearance](#)



Clearance

Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.

Laser V-Coat
(1064nm)

[N-BK7](#)

12.70

6.35

₹9,180

10 to 12 days

[#11-453 Clearance](#)



Clearance

Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.

Laser V-Coat
(1064nm)

[N-BK7](#)

38.10

6.35

₹9,180

10 to 12 days

Laser V-Coat
(266nm)

[Fused
Silica](#)

76.20

12.70

[#20-437](#)

₹58,680
Qty 6+ ₹46,944

10 to 12 days

Laser V-Coat (355nm)	Fused Silica	76.20	12.70	#20-444	₹58,680 Qty 6+ ₹46,944	10 to 12 days
Laser V-Coat (532nm)	Fused Silica	76.20	12.70	#20-449	₹58,680 Qty 6+ ₹46,944	10 to 12 days
Laser V-Coat (1064nm)	Fused Silica	76.20	12.70	#20-450	₹58,680 Qty 6+ ₹46,944	Contact Us



Copyright 2023, Edmund Optics India Private Limited, #267, Greystone Building, Second Floor, 6th Cross Rd, Binnamangala, Stage 1, Indiranagar, Bengaluru, Karnataka, India 560038

Phone: 1-800-363-1992 :

www.edmundoptics.com