

[All Products](#) / [Optics](#) / [Optical Mirrors](#) / [Off-Axis Mirrors](#)

TECHSPEC® Aluminum Off-Axis Parabolic Mirrors




- Aluminum Coatings for UV, Visible, and NIR Applications
- Range of Surface Roughness, Including 50Å and 100Å
- 15°, 30°, 45°, 60°, or 90° Offset Angle Options
- Gold and Silver Coated Off-Axis Parabolic Mirrors Also Available

Common Specifications

Optical Properties

Focal Length Tolerance (%) : ± 1	Coating Type: Metal
Surface Quality: 80-50	Substrate: Aluminum 6061-T6

Technical Information

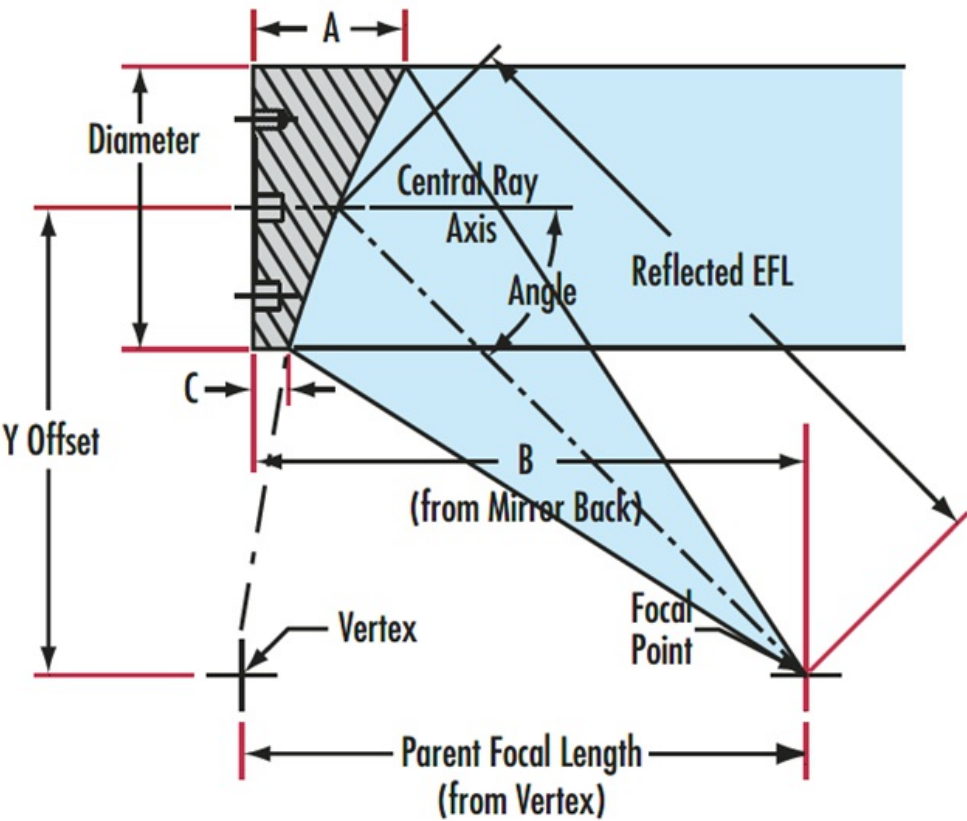

Products

Dia. (mm)	EFL (mm)	Coating	Off- Set Angle (°)	Surface Roughness (Å)	Stock Number	Price	Buy
6.35	6.35	Protected Aluminum (400-2000nm)	90	<50 RMS	#37-282	₹14,013 Qty 6+ ₹12,573	10 to 12 days
6.35	6.35	Enhanced Aluminum (250-700nm)	90	<50 RMS	#37-288	₹15,414 Qty 6+ ₹13,857	10 to 12 days
6.35	12.70	Protected Aluminum (400-2000nm)	90	<50 RMS	#37-283	₹14,013 Qty 6+ ₹12,573	Contact Us
6.35	12.70	Enhanced Aluminum (250-700nm)	90	<50 RMS	#37-289	₹15,414 Qty 6+ ₹13,857	10 to 12 days
6.35	25.40	Protected Aluminum (400-2000nm)	90	<50 RMS	#37-284	₹14,013 Qty 6+ ₹12,573	10 to 12 days
6.35	25.40	Enhanced Aluminum (250-700nm)	90	<50 RMS	#37-290	₹15,414 Qty 6+ ₹13,857	10 to 12 days
6.35	50.80	Protected Aluminum (400-2000nm)	90	<50 RMS	#37-285	₹14,013 Qty 6+ ₹12,573	Contact Us
6.35	50.80	Enhanced Aluminum (250-700nm)	90	<50 RMS	#37-291	₹15,414 Qty 6+ ₹13,857	10 to 12 days

[#37-292 Clearance](#)



Clearance

Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.

6.35	76.20	Enhanced Aluminum (250-700nm)	90	<50 RMS		₹12,510	10 to 12 days
6.35	101.60	Protected Aluminum (400-2000nm)	90	<50 RMS	#37-287	₹14,013 Qty 6+ ₹12,573	10 to 12 days
6.35	101.60	Enhanced Aluminum (250-700nm)	90	<50 RMS	#37-293	₹15,414 Qty 6+ ₹13,857	10 to 12 days
12.70	12.70	Protected Aluminum (400-2000nm)	90	<50 RMS	#37-258	₹14,947 Qty 6+ ₹13,468	Contact Us
12.70	12.70	Enhanced Aluminum (250-700nm)	90	<50 RMS	#37-264	₹16,193 Qty 6+ ₹14,558	10 to 12 days
12.70	12.70	Protected Aluminum (400-2000nm)	90	<100 RMS	#35-481	₹14,558 Qty 6+ ₹13,118	10 to 12 days
12.70	25.40	Protected Aluminum (400-2000nm)	90	<50 RMS	#37-259	₹14,947 Qty 6+ ₹13,468	10 to 12 days
12.70	25.40	Enhanced Aluminum (250-700nm)	90	<50 RMS	#37-265	₹16,193 Qty 6+ ₹14,558	10 to 12 days

12.70	25.40	Protected Aluminum (400-2000nm)	90	<100 RMS	#35-482	₹14,558 Qty 6+ ₹13,118	10 to 12 days
12.70	50.80	Protected Aluminum (400-2000nm)	90	<50 RMS	#37-260	₹14,947 Qty 6+ ₹13,468	10 to 12 days
12.70	50.80	Enhanced Aluminum (250-700nm)	90	<50 RMS	#37-266	₹16,193 Qty 6+ ₹14,558	10 to 12 days
12.70	50.80	Protected Aluminum (400-2000nm)	90	<100 RMS	#35-483	₹14,558 Qty 6+ ₹13,118	10 to 12 days
12.70	76.20	Protected Aluminum (400-2000nm)	90	<50 RMS	#37-261	₹14,947 Qty 6+ ₹13,468	10 to 12 days
12.70	76.20	Enhanced Aluminum (250-700nm)	90	<50 RMS	#37-267	₹16,193 Qty 6+ ₹14,558	10 to 12 days
12.70	101.60	Protected Aluminum (400-2000nm)	90	<50 RMS	#37-262	₹14,947 Qty 6+ ₹13,468	10 to 12 days
12.70	101.60	Enhanced Aluminum (250-700nm)	90	<50 RMS	#37-268	₹16,193 Qty 6+ ₹14,558	10 to 12 days
12.70	203.20	Protected Aluminum (400-2000nm)	90	<50 RMS	#37-263	₹14,947 Qty 6+ ₹13,468	10 to 12 days
12.70	203.20	Enhanced Aluminum (250-700nm)	90	<50 RMS	#37-269	₹16,193 Qty 6+ ₹14,558	10 to 12 days
25.40	25.40	Protected Aluminum (400-2000nm)	90	<50 RMS	#87-406	₹18,606 Qty 6+ ₹16,777	10 to 12 days
25.40	25.40	Enhanced Aluminum (250-700nm)	90	<50 RMS	#37-232	₹19,463 Qty 6+ ₹17,477	10 to 12 days

25.40	25.40	Protected Aluminum (400-2000nm)	90	<100 RMS	#35-500	₹14,947 Qty 6+ ₹13,468	10 to 12 days
25.40	27.22	Protected Aluminum (400-2000nm)	30	<100 RMS	#35-514	₹24,678 Qty 6+ ₹22,226	10 to 12 days
25.40	33.85	Protected Aluminum (400-2000nm)	60	<100 RMS	#35-496	₹17,828 Qty 6+ ₹16,037	10 to 12 days
25.40	50.80	Protected Aluminum (400-2000nm)	90	<50 RMS	#87-407	₹18,606 Qty 6+ ₹16,777	10 to 12 days
25.40	50.80	Enhanced Aluminum (250-700nm)	90	<50 RMS	#37-233	₹19,463 Qty 6+ ₹17,477	Contact Us
25.40	50.80	Protected Aluminum (400-2000nm)	90	<100 RMS	#35-502	₹14,947 Qty 6+ ₹13,468	Contact Us
25.40	50.80	Protected Aluminum (400-2000nm)	60	<100 RMS	#35-498	₹14,947 Qty 6+ ₹13,468	10 to 12 days
25.40	54.45	Protected Aluminum (400-2000nm)	30	<100 RMS	#35-490	₹19,463 Qty 6+ ₹17,477	10 to 12 days
25.40	76.20	Protected Aluminum (400-2000nm)	90	<50 RMS	#37-226	₹18,606 Qty 6+ ₹16,777	10 to 12 days
25.40	76.20	Enhanced Aluminum (250-700nm)	90	<50 RMS	#37-234	₹19,463 Qty 6+ ₹17,477	Contact Us
25.40	76.20	Protected Aluminum (400-2000nm)	90	<100 RMS	#35-517	₹14,947 Qty 6+ ₹13,468	10 to 12 days
25.40	101.60	Protected Aluminum (400-2000nm)	90	<50 RMS	#87-408	₹18,606 Qty 6+ ₹16,777	10 to 12 days

25.40	101.60	Enhanced Aluminum (250-700nm)	90	<50 RMS	#37-235	₹19,463 Qty 6+ ₹17,477	10 to 12 days
25.40	101.60	Protected Aluminum (400-2000nm)	90	<100 RMS	#35-504	₹14,947 Qty 6+ ₹13,468	10 to 12 days
#37-227 Clearance							
× Clearance Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.							
25.40	127.00	Protected Aluminum (400-2000nm)	90	<50 RMS		₹18,092	10 to 12 days
25.40	127.00	Protected Aluminum (400-2000nm)	90	<100 RMS	#35-563	₹24,678 Qty 6+ ₹22,226	10 to 12 days
25.40	152.40	Protected Aluminum (400-2000nm)	90	<100 RMS	#35-518	₹14,947 Qty 6+ ₹13,468	10 to 12 days

[#37-229 Clearance](#)



Clearance

Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.

25.40	177.80	Protected Aluminum (400-2000nm)	90	<50 RMS		₹26,280	10 to 12 days
-------	--------	---------------------------------	----	---------	--	---------	---------------

25.40	177.80	Protected Aluminum (400-2000nm)	90	<100 RMS	#34-520	₹32,775 Qty 6+ ₹29,505	10 to 12 days
-------	--------	---------------------------------	----	----------	-------------------------	---------------------------	---------------

25.40	203.20	Protected Aluminum (400-2000nm)	90	<50 RMS	#37-230	₹18,606 Qty 6+ ₹16,777	10 to 12 days
-------	--------	---------------------------------	----	---------	-------------------------	---------------------------	---------------

25.40	203.20	Enhanced Aluminum (250-700nm)	90	<50 RMS	#37-239	₹19,463 Qty 6+ ₹17,477	10 to 12 days
-------	--------	-------------------------------	----	---------	-------------------------	---------------------------	---------------

25.40	203.20	Protected Aluminum (400-2000nm)	90	<100 RMS	#35-590	₹14,947 Qty 6+ ₹13,468	10 to 12 days
-------	--------	---------------------------------	----	----------	-------------------------	---------------------------	---------------

25.40	272.24	Protected Aluminum (400-2000nm)	30	<100 RMS	#35-606	₹45,932 Qty 6+ ₹41,183	10 to 12 days
-------	--------	---------------------------------	----	----------	-------------------------	---------------------------	---------------

25.40	387.60	Protected Aluminum (400-2000nm)	15	<100 RMS	#35-538	₹19,852 Qty 6+ ₹17,867	10 to 12 days
-------	--------	---------------------------------	----	----------	-------------------------	---------------------------	---------------

25.40	646.00	Protected Aluminum (400-2000nm)	15	<100 RMS	#35-540	₹19,852 Qty 6+ ₹17,867	10 to 12 days
-------	--------	---------------------------------	----	----------	-------------------------	---------------------------	---------------

50.80	50.80	Enhanced Aluminum (250-700nm)	90	<50 RMS	#37-306	₹36,434 Qty 6+ ₹32,775	10 to 12 days
50.80	50.80	Protected Aluminum (400-2000nm)	90	<50 RMS	#87-409	₹34,020 Qty 6+ ₹30,595	10 to 12 days
50.80	50.80	Protected Aluminum (400-2000nm)	90	<100 RMS	#35-506	₹32,775 Qty 6+ ₹29,505	10 to 12 days
50.80	54.45	Protected Aluminum (400-2000nm)	30	<100 RMS	#35-492	₹35,188 Qty 6+ ₹31,685	10 to 12 days
50.80	59.51	Protected Aluminum (400-2000nm)	45	<100 RMS	#35-550	₹34,410 Qty 6+ ₹30,984	10 to 12 days
50.80	76.20	Protected Aluminum (400-2000nm)	90	<50 RMS	#37-984	₹34,020 Qty 6+ ₹30,595	10 to 12 days
50.80	76.20	Enhanced Aluminum (250-700nm)	90	<50 RMS	#37-993	₹36,434 Qty 6+ ₹32,775	10 to 12 days
50.80	76.20	Protected Aluminum (400-2000nm)	90	<100 RMS	#35-508	₹32,775 Qty 6+ ₹29,505	Contact Us
50.80	81.79	Protected Aluminum (400-2000nm)	30	<100 RMS	#35-607	₹35,188 Qty 6+ ₹31,685	10 to 12 days
50.80	89.28	Protected Aluminum (400-2000nm)	45	<100 RMS	#35-552	₹34,410 Qty 6+ ₹30,984	10 to 12 days
50.80	101.60	Protected Aluminum (400-2000nm)	90	<50 RMS	#87-410	₹34,020 Qty 6+ ₹30,595	10 to 12 days
50.80	101.60	Enhanced Aluminum (250-700nm)	90	<50 RMS	#37-307	₹36,434 Qty 6+ ₹32,775	10 to 12 days

50.80	101.60	Protected Aluminum (400-2000nm)	60	<100 RMS	#35-516	₹36,823 Qty 6+ ₹33,164	10 to 12 days
50.80	101.60	Protected Aluminum (400-2000nm)	90	<100 RMS	#35-510	₹32,775 Qty 6+ ₹29,505	10 to 12 days
50.80	108.89	Protected Aluminum (400-2000nm)	30	<100 RMS	#35-494	₹35,188 Qty 6+ ₹31,685	10 to 12 days
50.80	136.12	Protected Aluminum (400-2000nm)	30	<100 RMS	#35-609	₹38,847 Qty 6+ ₹34,994	10 to 12 days
50.80	152.40	Protected Aluminum (400-2000nm)	90	<100 RMS	#35-512	₹32,775 Qty 6+ ₹29,505	7 days
50.80	177.80	Protected Aluminum (400-2000nm)	90	<100 RMS	#35-519	₹32,775 Qty 6+ ₹29,505	10 to 12 days
50.80	190.50	Protected Aluminum (400-2000nm)	90	<100 RMS	#35-520	₹32,775 Qty 6+ ₹29,505	10 to 12 days
50.80	190.60	Protected Aluminum (400-2000nm)	90	<50 RMS	#37-988	₹34,020 Qty 6+ ₹30,595	Contact Us
50.80	190.60	Enhanced Aluminum (250-700nm)	90	<50 RMS	#37-996	₹36,434 Qty 6+ ₹32,775	10 to 12 days
50.80	272.24	Protected Aluminum (400-2000nm)	30	<100 RMS	#35-610	₹35,188 Qty 6+ ₹31,685	10 to 12 days
50.80	310.08	Protected Aluminum (400-2000nm)	15	<100 RMS	#35-542	₹27,948 Qty 6+ ₹25,146	10 to 12 days
50.80	387.60	Protected Aluminum (400-2000nm)	15	<100 RMS	#35-594	₹27,948 Qty 6+ ₹25,146	10 to 12 days

50.80	516.81	Protected Aluminum (400-2000nm)	15	<100 RMS	#35-544	₹27,948 Qty 6+ ₹25,146	10 to 12 days
76.20	50.80	Protected Aluminum (400-2000nm)	90	<100 RMS	#35-521	₹70,454 Qty 6+ ₹63,409	10 to 12 days
76.20	76.20	Protected Aluminum (400-2000nm)	90	<100 RMS	#35-522	₹57,220 Qty 6+ ₹51,381	10 to 12 days
76.20	89.28	Protected Aluminum (400-2000nm)	45	<100 RMS	#35-586	₹66,173 Qty 6+ ₹59,400	10 to 12 days
76.20	101.60	Protected Aluminum (400-2000nm)	90	<100 RMS	#35-565	₹57,220 Qty 6+ ₹51,381	10 to 12 days
76.20	127.00	Protected Aluminum (400-2000nm)	90	<100 RMS	#35-523	₹54,884 Qty 6+ ₹49,552	10 to 12 days
76.20	152.40	Protected Aluminum (400-2000nm)	90	<100 RMS	#35-524	₹54,884 Qty 6+ ₹49,552	10 to 12 days
76.20	177.80	Protected Aluminum (400-2000nm)	90	<100 RMS	#35-564	₹54,884 Qty 6+ ₹49,552	10 to 12 days
76.20	178.53	Protected Aluminum (400-2000nm)	45	<100 RMS	#35-588	₹57,220 Qty 6+ ₹51,381	Contact Us
76.20	272.23	Protected Aluminum (400-2000nm)	30	<100 RMS	#35-580	₹59,555 Qty 6+ ₹53,561	10 to 12 days
76.20	646.00	Protected Aluminum (400-2000nm)	15	<100 RMS	#35-597	₹59,555 Qty 6+ ₹53,561	10 to 12 days
101.60	101.60	Protected Aluminum (400-2000nm)	90	<100 RMS	#35-566	₹74,736 Qty 6+ ₹67,418	10 to 12 days

101.60	119.03	Protected Aluminum (400-2000nm)	45	<100 RMS	#35-628	₹70,454 Qty 6+ ₹63,409	10 to 12 days
101.60	152.40	Protected Aluminum (400-2000nm)	90	<100 RMS	#35-592	₹74,736 Qty 6+ ₹67,418	10 to 12 days
101.60	178.55	Protected Aluminum (400-2000nm)	45	<100 RMS	#35-629	₹70,454 Qty 6+ ₹63,409	10 to 12 days
101.60	326.69	Protected Aluminum (400-2000nm)	30	<100 RMS	#35-584	₹74,736 Qty 6+ ₹67,418	10 to 12 days
101.60	387.60	Protected Aluminum (400-2000nm)	15	<100 RMS	#35-574	₹70,454 Qty 6+ ₹63,409	10 to 12 days
101.60	516.81	Protected Aluminum (400-2000nm)	15	<100 RMS	#35-576	₹70,454 Qty 6+ ₹63,409	10 to 12 days



Copyright 2023, Edmund Optics India Private Limited, #267, Greystone Building, Second Floor, 6th Cross Rd, Binnamangala, Stage 1, Indiranagar, Bengaluru, Karnataka, India 560038

Phone: 1-800-363-1992 :

www.edmundoptics.com