


[All Products](#) / [Optics](#) / [Optical Lenses](#) / [Plano-Convex \(PCX\) Lenses](#) / [Standard Plano-Convex \(PCX\) Lenses](#)

Micro Plano-Convex (PCX) Lenses

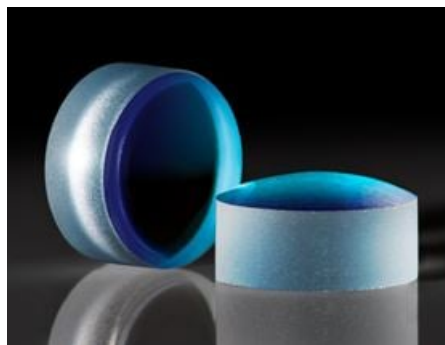

- Diameters as Small as 1mm
- Short Focal Lengths for Integration into Compact Devices
- Broadband Antireflection Coating Options Available

Common Specifications

Physical & Mechanical Properties

Bevel:

Protective as needed

Optical Properties

Focal Length Tolerance (%):

± 1

Technical Information

Products

Dia. (mm)	EFL (mm)	BFL (mm)	Coating	Substrate	Stock Number	Price	Buy
1.00	0.60	0.17	NIR I (600-1050nm)	N-LASF9	#45-951	₹6,228 Qty 10+ ₹5,605	10 to 12 days
1.00	0.60	0.17	Uncoated	N-LASF9	#45-588	₹5,177 Qty 10+ ₹4,671	10 to 12 days
1.00	1.00	0.57	NIR I (600-1050nm)	N-LASF9	#45-952	₹6,228 Qty 10+ ₹5,605	Contact Us
1.00	1.00	0.57	Uncoated	N-LASF9	#45-589	₹5,177 Qty 10+ ₹4,671	10 to 12 days
1.00	0.60	0.17	MgF ₂ (400-700nm)	N-LASF9	#65-257	₹5,644 Qty 10+ ₹5,099	10 to 12 days
1.00	0.60	0.17	NIR II (750-1550nm)	N-LASF9	#67-423	₹6,228 Qty 10+ ₹5,605	Contact Us
1.00	0.60	0.17	VIS 0° (425-675nm)	N-LASF9	#65-273	₹6,228 Qty 10+ ₹5,605	10 to 12 days
1.00	0.60	0.17	VIS-EXT (350-700nm)	N-LASF9	#35-694	₹6,345 Qty 10+ ₹5,683	10 to 12 days
1.00	0.60	0.17	VIS-NIR (400-1000nm)	N-LASF9	#65-289	₹6,345 Qty 10+ ₹5,683	10 to 12 days
1.00	0.60	0.17	YAG-BBAR (500-1100nm)	N-LASF9	#35-710	₹6,345 Qty 10+ ₹5,683	Contact Us
1.00	1.00	0.57	MgF ₂ (400-700nm)	N-LASF9	#65-258	₹5,644 Qty 10+ ₹5,099	10 to 12 days
1.00	1.00	0.57	NIR II (750-1550nm)	N-LASF9	#67-424	₹6,228 Qty 10+ ₹5,605	10 to 12 days
1.00	1.00	0.57	VIS 0° (425-675nm)	N-LASF9	#65-274	₹6,228 Qty 10+ ₹5,605	Contact Us
1.00	1.00	0.57	VIS-EXT (350-700nm)	N-LASF9	#35-695	₹6,345 Qty 10+ ₹5,683	10 to 12 days
1.00	1.00	0.57	VIS-NIR (400-1000nm)	N-LASF9	#65-290	₹6,345 Qty 10+ ₹5,683	10 to 12 days
1.00	1.00	0.57	YAG-BBAR (500-1100nm)	N-LASF9	#35-711	₹6,345 Qty 10+ ₹5,683	Contact Us

1.00	1.50	1.07	MgF ₂ (400-700nm)	N-LASF9	#65-259	₹5,644 Qty 10+ ₹5,099	Contact Us
1.00	1.50	1.07	NIR I (600-1050nm)	N-LASF9	#65-305	₹6,228 Qty 10+ ₹5,605	Contact Us
1.00	1.50	1.07	NIR II (750-1550nm)	N-LASF9	#67-425	₹6,228 Qty 10+ ₹5,605	10 to 12 days
1.00	1.50	1.07	Uncoated	N-LASF9	#65-252	₹5,177 Qty 10+ ₹4,671	10 to 12 days
1.00	1.50	1.07	VIS 0° (425-675nm)	N-LASF9	#65-275	₹6,228 Qty 10+ ₹5,605	10 to 12 days
1.00	1.50	1.07	VIS-EXT (350-700nm)	N-LASF9	#35-696	₹6,345 Qty 10+ ₹5,683	10 to 12 days
1.00	1.50	1.07	VIS-NIR (400-1000nm)	N-LASF9	#65-291	₹6,345 Qty 10+ ₹5,683	Contact Us
1.00	1.50	1.07	YAG-BBAR (500-1100nm)	N-LASF9	#35-712	₹6,345 Qty 10+ ₹5,683	10 to 12 days
1.00	2.00	1.57	MgF ₂ (400-700nm)	N-LASF9	#65-260	₹5,644 Qty 10+ ₹5,099	10 to 12 days
1.00	2.00	1.57	NIR I (600-1050nm)	N-LASF9	#65-306	₹6,228 Qty 10+ ₹5,605	10 to 12 days
1.00	2.00	1.57	NIR II (750-1550nm)	N-LASF9	#67-426	₹6,228 Qty 10+ ₹5,605	10 to 12 days
1.00	2.00	1.57	Uncoated	N-LASF9	#65-253	₹5,177 Qty 10+ ₹4,671	10 to 12 days
1.00	2.00	1.57	VIS 0° (425-675nm)	N-LASF9	#65-276	₹6,228 Qty 10+ ₹5,605	Contact Us
1.00	2.00	1.57	VIS-EXT (350-700nm)	N-LASF9	#35-697	₹6,345 Qty 10+ ₹5,683	10 to 12 days
1.00	2.00	1.57	VIS-NIR (400-1000nm)	N-LASF9	#65-292	₹6,345 Qty 10+ ₹5,683	10 to 12 days
1.00	2.00	1.57	YAG-BBAR (500-1100nm)	N-LASF9	#35-713	₹6,345 Qty 10+ ₹5,683	10 to 12 days
1.50	1.00	0.57	NIR I (600-1050nm)	N-LASF9	#45-953	₹6,228 Qty 10+ ₹5,605	10 to 12 days
1.50	1.00	0.57	Uncoated	N-LASF9	#43-394	₹5,177 Qty 10+ ₹4,671	10 to 12 days
1.50	1.00	0.57	MgF ₂ (400-700nm)	N-LASF9	#65-261	₹5,644 Qty 10+ ₹5,099	10 to 12 days

1.50	1.00	0.57	NIR II (750-1550nm)	N-LASF9	#67-427	₹6,228 Qty 10+ ₹5,605	Contact Us
1.50	1.00	0.57	VIS 0° (425-675nm)	N-LASF9	#65-277	₹6,228 Qty 10+ ₹5,605	10 to 12 days
1.50	1.00	0.57	VIS-EXT (350-700nm)	N-LASF9	#35-698	₹6,345 Qty 10+ ₹5,683	Contact Us
1.50	1.00	0.57	VIS-NIR (400-1000nm)	N-LASF9	#65-293	₹6,345 Qty 10+ ₹5,683	10 to 12 days
1.50	1.00	0.57	YAG-BBAR (500-1100nm)	N-LASF9	#35-714	₹6,345 Qty 10+ ₹5,683	10 to 12 days
1.50	1.50	1.07	MgF ₂ (400-700nm)	N-LASF9	#65-262	₹5,644 Qty 10+ ₹5,099	10 to 12 days
1.50	1.50	1.07	NIR II (750-1550nm)	N-LASF9	#67-428	₹6,228 Qty 10+ ₹5,605	10 to 12 days
1.50	1.50	1.07	NIR I (600-1050nm)	N-LASF9	#45-954	₹6,228 Qty 10+ ₹5,605	10 to 12 days
1.50	1.50	1.07	Uncoated	N-LASF9	#43-395	₹5,177 Qty 10+ ₹4,671	10 to 12 days
1.50	1.50	1.07	VIS 0° (425-675nm)	N-LASF9	#65-278	₹6,228 Qty 10+ ₹5,605	10 to 12 days
1.50	1.50	1.07	VIS-EXT (350-700nm)	N-LASF9	#35-699	₹6,345 Qty 10+ ₹5,683	Contact Us
1.50	1.50	1.07	VIS-NIR (400-1000nm)	N-LASF9	#65-294	₹6,345 Qty 10+ ₹5,683	10 to 12 days
1.50	1.50	1.07	YAG-BBAR (500-1100nm)	N-LASF9	#35-715	₹6,345 Qty 10+ ₹5,683	10 to 12 days
1.50	2.00	1.57	MgF ₂ (400-700nm)	N-LASF9	#65-263	₹5,644 Qty 10+ ₹5,099	10 to 12 days
1.50	2.00	1.57	NIR I (600-1050nm)	N-LASF9	#65-307	₹6,228 Qty 10+ ₹5,605	10 to 12 days
1.50	2.00	1.57	NIR II (750-1550nm)	N-LASF9	#67-429	₹6,228 Qty 10+ ₹5,605	10 to 12 days
1.50	2.00	1.57	Uncoated	N-LASF9	#65-254	₹5,177 Qty 10+ ₹4,671	10 to 12 days
1.50	2.00	1.57	VIS 0° (425-675nm)	N-LASF9	#65-279	₹6,228 Qty 10+ ₹5,605	10 to 12 days

1.50	2.00	1.57	VIS-EXT (350-700nm)	N-LASF9	#35-700	₹6,345 Qty 10+ ₹5,683	10 to 12 days
1.50	2.00	1.57	VIS-NIR (400- 1000nm)	N-LASF9	#65-295	₹6,345 Qty 10+ ₹5,683	10 to 12 days
1.50	2.00	1.57	YAG-BBAR (500-1100nm)	N-LASF9	#35-716	₹6,345 Qty 10+ ₹5,683	10 to 12 days
2.00	1.50	1.07	NIR I (600- 1050nm)	N-LASF9	#45-955	₹6,150 Qty 10+ ₹5,527	10 to 12 days
2.00	1.50	1.07	Uncoated	N-LASF9	#43-396	₹5,099 Qty 10+ ₹4,593	10 to 12 days
2.00	2.00	1.57	NIR I (600- 1050nm)	N-LASF9	#45-956	₹6,150 Qty 10+ ₹5,527	10 to 12 days
2.00	2.00	1.57	Uncoated	N-LASF9	#43-397	₹5,099 Qty 10+ ₹4,593	10 to 12 days
2.00	1.50	1.07	MgF ₂ (400- 700nm)	N-LASF9	#65-264	₹5,566 Qty 10+ ₹4,982	10 to 12 days
2.00	1.50	1.07	NIR II (750- 1550nm)	N-LASF9	#67-430	₹6,150 Qty 10+ ₹5,527	10 to 12 days
2.00	1.50	1.07	VIS 0° (425- 675nm)	N-LASF9	#65-280	₹6,150 Qty 10+ ₹5,527	10 to 12 days
2.00	1.50	1.07	VIS-EXT (350-700nm)	N-LASF9	#35-701	₹6,267 Qty 10+ ₹5,644	10 to 12 days
2.00	1.50	1.07	VIS-NIR (400- 1000nm)	N-LASF9	#65-296	₹6,267 Qty 10+ ₹5,644	10 to 12 days
2.00	1.50	1.07	YAG-BBAR (500-1100nm)	N-LASF9	#35-717	₹6,267 Qty 10+ ₹5,644	10 to 12 days
2.00	2.00	1.57	MgF ₂ (400- 700nm)	N-LASF9	#65-265	₹5,566 Qty 10+ ₹4,982	10 to 12 days
2.00	2.00	1.57	NIR II (750- 1550nm)	N-LASF9	#67-431	₹6,150 Qty 10+ ₹5,527	10 to 12 days
2.00	2.00	1.57	VIS 0° (425- 675nm)	N-LASF9	#65-281	₹6,150 Qty 10+ ₹5,527	Contact Us
2.00	2.00	1.57	VIS-EXT (350-700nm)	N-LASF9	#35-702	₹6,267 Qty 10+ ₹5,644	10 to 12 days
2.00	2.00	1.57	VIS-NIR (400- 1000nm)	N-LASF9	#65-297	₹6,267 Qty 10+ ₹5,644	10 to 12 days

2.00	2.00	1.57	YAG-BBAR (500-1100nm)	N-LASF9	#35-718	₹6,267 Qty 10+ ₹5,644	10 to 12 days
2.00	3.00	2.57	MgF ₂ (400- 700nm)	N-LASF9	#65-266	₹5,566 Qty 10+ ₹4,982	10 to 12 days
2.00	3.00	2.57	NIR I (600- 1050nm)	N-LASF9	#65-308	₹6,150 Qty 10+ ₹5,527	10 to 12 days
2.00	3.00	2.57	NIR II (750- 1550nm)	N-LASF9	#67-432	₹6,150 Qty 10+ ₹5,527	10 to 12 days
2.00	3.00	2.57	Uncoated	N-LASF9	#65-255	₹5,099 Qty 10+ ₹4,593	10 to 12 days
2.00	3.00	2.57	VIS 0° (425- 675nm)	N-LASF9	#65-282	₹6,150 Qty 10+ ₹5,527	10 to 12 days
2.00	3.00	2.57	VIS-EXT (350-700nm)	N-LASF9	#35-703	₹6,267 Qty 10+ ₹5,644	10 to 12 days
2.00	3.00	2.57	VIS-NIR (400- 1000nm)	N-LASF9	#65-298	₹6,267 Qty 10+ ₹5,644	10 to 12 days
2.00	3.00	2.57	YAG-BBAR (500-1100nm)	N-LASF9	#35-719	₹6,267 Qty 10+ ₹5,644	10 to 12 days
2.00	4.00	3.57	MgF ₂ (400- 700nm)	N-LASF9	#65-267	₹5,566 Qty 10+ ₹4,982	10 to 12 days
2.00	4.00	3.57	NIR I (600- 1050nm)	N-LASF9	#65-309	₹6,150 Qty 10+ ₹5,527	10 to 12 days
2.00	4.00	3.57	NIR II (750- 1550nm)	N-LASF9	#67-433	₹6,150 Qty 10+ ₹5,527	10 to 12 days
2.00	4.00	3.57	Uncoated	N-LASF9	#65-256	₹5,099 Qty 10+ ₹4,593	10 to 12 days
2.00	4.00	3.57	VIS 0° (425- 675nm)	N-LASF9	#65-283	₹6,150 Qty 10+ ₹5,527	10 to 12 days
2.00	4.00	3.57	VIS-EXT (350-700nm)	N-LASF9	#35-704	₹6,267 Qty 10+ ₹5,644	10 to 12 days
2.00	4.00	3.57	VIS-NIR (400- 1000nm)	N-LASF9	#65-299	₹6,267 Qty 10+ ₹5,644	10 to 12 days
2.00	4.00	3.57	YAG-BBAR (500-1100nm)	N-LASF9	#35-720	₹6,267 Qty 10+ ₹5,644	10 to 12 days
2.50	2.00	1.57	NIR I (600- 1050nm)	N-LASF9	#45-957	₹6,150 Qty 10+ ₹5,527	10 to 12 days
2.50	2.00	1.57	Uncoated	N-LASF9	#43-398	₹5,099 Qty 10+ ₹4,593	10 to 12 days

2.50	2.00	1.57	MgF ₂ (400-700nm)	N-LASF9	#65-268	₹5,566 Qty 10+ ₹4,982	10 to 12 days
2.50	2.00	1.57	NIR II (750-1550nm)	N-LASF9	#67-434	₹6,150 Qty 10+ ₹5,527	10 to 12 days
2.50	2.00	1.57	VIS 0° (425-675nm)	N-LASF9	#65-284	₹6,150 Qty 10+ ₹5,527	10 to 12 days
2.50	2.00	1.57	VIS-EXT (350-700nm)	N-LASF9	#35-705	₹6,267 Qty 10+ ₹5,644	10 to 12 days
2.50	2.00	1.57	VIS-NIR (400-1000nm)	N-LASF9	#65-300	₹6,267 Qty 10+ ₹5,644	10 to 12 days
2.50	2.00	1.57	YAG-BBAR (500-1100nm)	N-LASF9	#35-721	₹6,267 Qty 10+ ₹5,644	10 to 12 days
2.50	2.50	2.05	MgF ₂ (400-700nm)	N-LASF9	#65-269	₹5,566 Qty 10+ ₹4,982	Contact Us
2.50	2.50	2.07	NIR II (750-1550nm)	N-LASF9	#67-435	₹6,150 Qty 10+ ₹5,527	10 to 12 days
2.50	2.50	2.07	NIR I (600-1050nm)	N-LASF9	#45-958	₹6,150 Qty 10+ ₹5,527	10 to 12 days
2.50	2.50	2.07	Uncoated	N-LASF9	#43-399	₹5,099 Qty 10+ ₹4,593	10 to 12 days
2.50	2.50	2.05	VIS 0° (425-675nm)	N-LASF9	#65-285	₹6,150 Qty 10+ ₹5,527	Contact Us
2.50	2.50	2.07	VIS-EXT (350-700nm)	N-LASF9	#35-706	₹6,267 Qty 10+ ₹5,644	Contact Us
2.50	2.50	2.05	VIS-NIR (400-1000nm)	N-LASF9	#65-301	₹6,267 Qty 10+ ₹5,644	10 to 12 days
2.50	2.50	2.07	YAG-BBAR (500-1100nm)	N-LASF9	#35-722	₹6,267 Qty 10+ ₹5,644	10 to 12 days
2.50	3.00	2.57	Uncoated	N-LASF9	#45-590	₹5,099 Qty 10+ ₹4,593	10 to 12 days
2.50	3.00	2.57	MgF ₂ (400-700nm)	N-LASF9	#65-270	₹5,566 Qty 10+ ₹4,982	Contact Us
2.50	3.00	2.57	NIR I (600-1050nm)	N-LASF9	#45-959	₹6,150 Qty 10+ ₹5,527	10 to 12 days
2.50	3.00	2.57	NIR II (750-1550nm)	N-LASF9	#67-436	₹6,150 Qty 10+ ₹5,527	10 to 12 days
2.50	3.00	2.57	VIS 0° (425-675nm)	N-LASF9	#65-286	₹6,150 Qty 10+ ₹5,527	10 to 12 days

2.50	3.00	2.57	VIS-EXT (350-700nm)	N-LASF9	#35-707	₹6,267 Qty 10+ ₹5,644	10 to 12 days
2.50	3.00	2.57	VIS-NIR (400- 1000nm)	N-LASF9	#65-302	₹6,267 Qty 10+ ₹5,644	10 to 12 days
2.50	3.00	2.57	YAG-BBAR (500-1100nm)	N-LASF9	#35-723	₹6,267 Qty 10+ ₹5,644	10 to 12 days
2.50	4.00	3.57	MgF ₂ (400- 700nm)	N-LASF9	#65-271	₹5,566 Qty 10+ ₹4,982	Contact Us
2.50	4.00	3.57	NIR I (600- 1050nm)	N-LASF9	#48-646	₹6,150 Qty 10+ ₹5,527	10 to 12 days
2.50	4.00	3.57	NIR II (750- 1550nm)	N-LASF9	#67-437	₹6,150 Qty 10+ ₹5,527	10 to 12 days
2.50	4.00	3.57	Uncoated	N-LASF9	#48-643	₹5,099 Qty 10+ ₹4,593	Contact Us
2.50	4.00	3.57	VIS 0° (425- 675nm)	N-LASF9	#65-287	₹6,150 Qty 10+ ₹5,527	Contact Us
2.50	4.00	3.57	VIS-EXT (350-700nm)	N-LASF9	#35-708	₹6,267 Qty 10+ ₹5,644	10 to 12 days
2.50	4.00	3.57	VIS-NIR (400- 1000nm)	N-LASF9	#65-303	₹6,267 Qty 10+ ₹5,644	10 to 12 days
2.50	4.00	3.57	YAG-BBAR (500-1100nm)	N-LASF9	#35-724	₹6,267 Qty 10+ ₹5,644	Contact Us
2.50	5.00	4.57	MgF ₂ (400- 700nm)	N-LASF9	#65-272	₹5,566 Qty 10+ ₹4,982	10 to 12 days
2.50	5.00	4.57	NIR I (600- 1050nm)	N-LASF9	#48-647	₹6,150 Qty 10+ ₹5,527	10 to 12 days
2.50	5.00	4.57	NIR II (750- 1550nm)	N-LASF9	#67-438	₹6,150 Qty 10+ ₹5,527	10 to 12 days
2.50	5.00	4.57	Uncoated	N-LASF9	#48-644	₹5,099 Qty 10+ ₹4,593	10 to 12 days
2.50	5.00	4.57	VIS 0° (425- 675nm)	N-LASF9	#65-288	₹6,150 Qty 10+ ₹5,527	7 days
2.50	5.00	4.57	VIS-EXT (350-700nm)	N-LASF9	#35-709	₹6,267 Qty 10+ ₹5,644	10 to 12 days
2.50	5.00	4.57	VIS-NIR (400- 1000nm)	N-LASF9	#65-304	₹6,267 Qty 10+ ₹5,644	10 to 12 days
2.50	5.00	4.57	YAG-BBAR (500-1100nm)	N-LASF9	#35-725	₹6,267 Qty 10+ ₹5,644	10 to 12 days

3.00	3.00	1.88	VIS-EXT (350-700nm)	N-SF11	#88-615	₹5,372 Qty 10+ ₹4,827	Contact Us
3.00	3.00	1.88	YAG-BBAR (500-1100nm)	N-SF11	#88-774	₹5,372 Qty 10+ ₹4,827	10 to 12 days
3.00	12.00	11.29	MgF ₂ (400- 700nm)	N-BK7	#45-273	₹4,204 Qty 10+ ₹3,776	10 to 12 days
3.00	12.00	11.29	NIR I (600- 1050nm)	N-BK7	#45-964	₹4,788 Qty 10+ ₹4,321	10 to 12 days
3.00	12.00	11.29	Uncoated	N-BK7	#45-272	₹3,737 Qty 10+ ₹3,367	10 to 12 days
3.00	12.00	11.29	VIS 0° (425- 675nm)	N-BK7	#49-172	₹4,788 Qty 10+ ₹4,321	10 to 12 days
3.00	12.00	11.29	VIS-EXT (350-700nm)	N-BK7	#88-620	₹4,982 Qty 10+ ₹4,476	10 to 12 days
3.00	12.00	11.29	VIS-NIR (400- 1000nm)	N-BK7	#49-179	₹4,982 Qty 10+ ₹4,476	10 to 12 days
3.00	12.00	11.29	YAG-BBAR (500-1100nm)	N-BK7	#88-779	₹4,982 Qty 10+ ₹4,476	10 to 12 days
3.00	15.00	14.17	MgF ₂ (400- 700nm)	N-BK7	#45-426	₹4,204 Qty 10+ ₹3,776	10 to 12 days
3.00	15.00	14.22	NIR I (600- 1050nm)	N-BK7	#45-965	₹4,788 Qty 10+ ₹4,321	10 to 12 days
3.00	15.00	14.22	Uncoated	N-BK7	#45-425	₹3,737 Qty 10+ ₹3,367	10 to 12 days
3.00	15.00	14.17	VIS 0° (425- 675nm)	N-BK7	#49-173	₹4,788 Qty 10+ ₹4,321	10 to 12 days
3.00	15.00	14.22	VIS-EXT (350-700nm)	N-BK7	#88-621	₹4,982 Qty 10+ ₹4,476	Contact Us
3.00	15.00	14.17	VIS-NIR (400- 1000nm)	N-BK7	#49-180	₹4,982 Qty 10+ ₹4,476	10 to 12 days
3.00	15.00	14.22	YAG-BBAR (500-1100nm)	N-BK7	#88-780	₹4,982 Qty 10+ ₹4,476	10 to 12 days
3.00	3.00	1.88	MgF ₂ (400- 700nm)	N-SF11	#45-118	₹4,593 Qty 10+ ₹4,126	10 to 12 days
3.00	3.00	1.88	NIR I (600- 1050nm)	N-SF11	#45-960	₹5,177 Qty 10+ ₹4,671	10 to 12 days

3.00	3.00	1.88	Uncoated	N-SF11	#45-117	₹4,126 Qty 10+ ₹3,717	10 to 12 days
3.00	3.00	1.88	VIS 0° (425-675nm)	N-SF11	#49-167	₹5,177 Qty 10+ ₹4,671	10 to 12 days
3.00	3.00	1.88	VIS-NIR (400-1000nm)	N-SF11	#49-174	₹5,372 Qty 10+ ₹4,827	Contact Us
3.00	4.50	3.50	MgF ₂ (400-700nm)	N-LASF44	#45-142	₹4,593 Qty 10+ ₹4,126	10 to 12 days
3.00	4.50	3.50	NIR I (600-1050nm)	N-LASF44	#45-961	₹5,177 Qty 10+ ₹4,671	10 to 12 days
3.00	4.50	3.50	Uncoated	N-LASF44	#45-141	₹4,126 Qty 10+ ₹3,717	10 to 12 days
3.00	4.50	3.50	VIS 0° (425-675nm)	N-LASF44	#49-168	₹5,177 Qty 10+ ₹4,671	Contact Us
3.00	4.50	3.50	VIS-NIR (400-1000nm)	N-LASF44	#49-175	₹5,372 Qty 10+ ₹4,827	10 to 12 days
3.00	6.00	4.81	MgF ₂ (400-700nm)	N-BK7	#32-953	₹4,204 Qty 10+ ₹3,776	10 to 12 days
3.00	6.00	4.81	NIR I (600-1050nm)	N-BK7	#45-962	₹4,788 Qty 10+ ₹4,321	10 to 12 days
3.00	6.00	4.81	Uncoated	N-BK7	#32-952	₹3,737 Qty 10+ ₹3,367	10 to 12 days
3.00	6.00	4.81	VIS 0° (425-675nm)	N-BK7	#49-169	₹4,788 Qty 10+ ₹4,321	10 to 12 days
3.00	6.00	4.81	VIS-EXT (350-700nm)	N-BK7	#88-617	₹4,982 Qty 10+ ₹4,476	Contact Us
3.00	6.00	4.81	VIS-NIR (400-1000nm)	N-BK7	#49-176	₹4,982 Qty 10+ ₹4,476	10 to 12 days
3.00	6.00	4.81	YAG-BBAR (500-1100nm)	N-BK7	#88-776	₹4,982 Qty 10+ ₹4,476	10 to 12 days
3.00	7.50	6.51	Uncoated	N-BK7	#48-645	₹3,737 Qty 10+ ₹3,367	10 to 12 days
3.00	7.50	6.51	VIS 0° (425-675nm)	N-BK7	#49-170	₹4,788 Qty 10+ ₹4,321	10 to 12 days
3.00	7.50	6.51	VIS-EXT (350-700nm)	N-BK7	#88-618	₹4,982 Qty 10+ ₹4,476	Contact Us
3.00	7.50	6.51	VIS-NIR (400-1000nm)	N-BK7	#49-177	₹4,982 Qty 10+ ₹4,476	10 to 12 days

3.00	7.50	6.51	YAG-BBAR (500-1100nm)	N-BK7	#88-777	₹4,982 Qty 10+ ₹4,476	10 to 12 days
3.00	9.00	8.01	MgF ₂ (400- 700nm)	N-BK7	#32-955	₹4,204 Qty 10+ ₹3,776	10 to 12 days
3.00	9.00	8.01	NIR I (600- 1050nm)	N-BK7	#45-963	₹4,788 Qty 10+ ₹4,321	10 to 12 days
3.00	9.00	8.01	Uncoated	N-BK7	#32-954	₹3,737 Qty 10+ ₹3,367	10 to 12 days
3.00	9.00	8.01	VIS 0° (425- 675nm)	N-BK7	#49-171	₹4,788 Qty 10+ ₹4,321	10 to 12 days
3.00	9.00	8.01	VIS-EXT (350-700nm)	N-BK7	#88-619	₹4,982 Qty 10+ ₹4,476	Contact Us
3.00	9.00	8.01	VIS-NIR (400- 1000nm)	N-BK7	#49-178	₹4,982 Qty 10+ ₹4,476	10 to 12 days
3.00	9.00	8.01	YAG-BBAR (500-1100nm)	N-BK7	#88-778	₹4,982 Qty 10+ ₹4,476	10 to 12 days
3.00	12.00	11.29	NIR II (750- 1550nm)	N-BK7	#67-444	₹4,788 Qty 10+ ₹4,321	10 to 12 days
3.00	15.00	14.22	NIR II (750- 1550nm)	N-BK7	#67-445	₹4,788 Qty 10+ ₹4,321	10 to 12 days
3.00	3.00	1.88	NIR II (750- 1550nm)	N-SF11	#67-439	₹5,177 Qty 10+ ₹4,671	10 to 12 days
3.00	4.50	3.50	NIR II (750- 1550nm)	N-LASF44	#67-440	₹5,177 Qty 10+ ₹4,671	10 to 12 days
3.00	4.50	3.50	VIS-EXT (350-700nm)	N-LASF44	#88-616	₹5,372 Qty 10+ ₹4,827	10 to 12 days
3.00	4.50	3.5	YAG-BBAR (500-1100nm)	N-LASF44	#88-775	₹5,372 Qty 10+ ₹4,827	10 to 12 days
3.00	6.00	4.81	NIR II (750- 1550nm)	N-BK7	#67-441	₹4,788 Qty 10+ ₹4,321	10 to 12 days
3.00	7.50	6.51	MgF ₂ (400- 700nm)	N-BK7	#48-910	₹4,204 Qty 10+ ₹3,776	10 to 12 days
3.00	7.50	6.51	NIR I (600- 1050nm)	N-BK7	#48-648	₹4,788 Qty 10+ ₹4,321	10 to 12 days
3.00	7.50	6.51	NIR II (750- 1550nm)	N-BK7	#67-442	₹4,788 Qty 10+ ₹4,321	10 to 12 days

3.00	9.00	8.01	NIR II (750-1550nm)	N-BK7	#67-443	₹4,788 Qty 10+ ₹4,321	10 to 12 days
4.00	10.00	8.92	MgF ₂ (400-700nm)	N-BK7	#45-430	₹3,873 Qty 10+ ₹3,484	Contact Us
4.00	10.00	8.92	NIR I (600-1050nm)	N-BK7	#48-705	₹4,671 Qty 10+ ₹4,204	10 to 12 days
4.00	10.00	8.92	Uncoated	N-BK7	#45-429	₹3,406 Qty 10+ ₹3,075	10 to 12 days
4.00	10.00	8.92	VIS 0° (425-675nm)	N-BK7	#47-864	₹4,671 Qty 10+ ₹4,204	10 to 12 days
4.00	10.00	8.92	VIS-EXT (350-700nm)	N-BK7	#88-625	₹5,060 Qty 10+ ₹4,554	10 to 12 days
4.00	10.00	8.92	VIS-NIR (400-1000nm)	N-BK7	#47-853	₹5,060 Qty 10+ ₹4,554	10 to 12 days
4.00	10.00	8.92	YAG-BBAR (500-1100nm)	N-BK7	#88-784	₹5,060 Qty 10+ ₹4,554	10 to 12 days
4.00	12.00	11.00	MgF ₂ (400-700nm)	N-BK7	#45-432	₹3,873 Qty 10+ ₹3,484	10 to 12 days
4.00	12.00	11.00	NIR I (600-1050nm)	N-BK7	#48-706	₹4,671 Qty 10+ ₹4,204	10 to 12 days
4.00	12.00	11.00	Uncoated	N-BK7	#45-431	₹3,406 Qty 10+ ₹3,075	10 to 12 days
4.00	12.00	11.00	VIS 0° (425-675nm)	N-BK7	#47-865	₹4,671 Qty 10+ ₹4,204	10 to 12 days
4.00	12.00	11.00	VIS-EXT (350-700nm)	N-BK7	#88-626	₹5,060 Qty 10+ ₹4,554	10 to 12 days
4.00	12.00	11.00	VIS-NIR (400-1000nm)	N-BK7	#47-854	₹5,060 Qty 10+ ₹4,554	Contact Us
4.00	12.00	11.00	YAG-BBAR (500-1100nm)	N-BK7	#88-785	₹5,060 Qty 10+ ₹4,554	10 to 12 days
4.00	4.00	3.06	MgF ₂ (400-700nm)	N-LASF44	#45-224	₹4,204 Qty 10+ ₹3,776	10 to 12 days
4.00	4.00	3.06	NIR I (600-1050nm)	N-LASF44	#48-702	₹4,982 Qty 10+ ₹4,476	Contact Us
4.00	4.00	3.06	Uncoated	N-LASF44	#45-223	₹3,737 Qty 10+ ₹3,367	10 to 12 days

4.00	4.00	3.06	VIS 0° (425-675nm)	N-LASF44	#47-861	₹4,982 Qty 10+ ₹4,476	10 to 12 days
4.00	4.00	3.06	VIS-NIR (400-1000nm)	N-LASF44	#47-850	₹5,372 Qty 10+ ₹4,827	Contact Us
4.00	6.00	4.51	MgF ₂ (400-700nm)	N-BK7	#45-428	₹4,204 Qty 10+ ₹3,776	10 to 12 days
4.00	6.00	4.51	NIR I (600-1050nm)	N-BK7	#48-703	₹4,982 Qty 10+ ₹4,476	10 to 12 days
4.00	6.00	4.51	Uncoated	N-BK7	#45-427	₹3,737 Qty 10+ ₹3,367	10 to 12 days
4.00	6.00	4.51	VIS 0° (425-675nm)	N-BK7	#47-862	₹4,982 Qty 10+ ₹4,476	Contact Us
4.00	6.00	4.51	VIS-EXT (350-700nm)	N-BK7	#88-623	₹5,372 Qty 10+ ₹4,827	10 to 12 days
4.00	6.00	4.51	VIS-NIR (400-1000nm)	N-BK7	#47-851	₹5,372 Qty 10+ ₹4,827	Contact Us
4.00	6.00	4.51	YAG-BBAR (500-1100nm)	N-BK7	#88-782	₹5,372 Qty 10+ ₹4,827	10 to 12 days
4.00	8.00	7.17	MgF ₂ (400-700nm)	N-BAF10	#45-226	₹3,873 Qty 10+ ₹3,484	10 to 12 days
4.00	8.00	7.17	NIR I (600-1050nm)	N-BAF10	#48-704	₹4,671 Qty 10+ ₹4,204	10 to 12 days
4.00	8.00	7.17	Uncoated	N-BAF10	#45-225	₹3,406 Qty 10+ ₹3,075	10 to 12 days
4.00	8.00	7.17	VIS 0° (425-675nm)	N-BAF10	#47-863	₹4,671 Qty 10+ ₹4,204	10 to 12 days
4.00	8.00	7.17	VIS-NIR (400-1000nm)	N-BAF10	#47-852	₹5,060 Qty 10+ ₹4,554	Contact Us
4.00	10.00	8.96	NIR II (750-1550nm)	N-BK7	#67-449	₹4,671 Qty 10+ ₹4,204	10 to 12 days
4.00	12.00	11	NIR II (750-1550nm)	N-BK7	#67-450	₹4,671 Qty 10+ ₹4,204	10 to 12 days
4.00	4.00	3.06	NIR II (750-1550nm)	N-LASF44	#67-446	₹4,982 Qty 10+ ₹4,476	10 to 12 days
4.00	4.00	3.06	VIS-EXT (350-700nm)	N-LASF44	#88-622	₹5,372 Qty 10+ ₹4,827	10 to 12 days
4.00	4.00	3.06	YAG-BBAR (500-1100nm)	N-LASF44	#88-781	₹5,372 Qty 10+ ₹4,827	10 to 12 days

4.00	6.00	4.51	NIR II (750-1550nm)	N-BK7	#67-447	₹4,982 Qty 10+ ₹4,476	10 to 12 days
4.00	8.00	7.17	NIR II (750-1550nm)	N-BAF10	#67-448	₹4,671 Qty 10+ ₹4,204	Contact Us
4.50	4.50	3.05	MgF ₂ (400-700nm)	N-LASF44	#45-144	₹4,204 Qty 10+ ₹3,776	10 to 12 days
4.50	4.50	3.05	NIR I (600-1050nm)	N-LASF44	#48-707	₹4,982 Qty 10+ ₹4,476	10 to 12 days
4.50	4.50	3.05	NIR II (750-1550nm)	N-LASF44	#67-451	₹4,982 Qty 10+ ₹4,476	10 to 12 days
4.50	4.50	3.05	Uncoated	N-LASF44	#45-143	₹3,737 Qty 10+ ₹3,367	10 to 12 days
4.50	4.50	3.05	VIS 0° (425-675nm)	N-LASF44	#47-866	₹4,982 Qty 10+ ₹4,476	10 to 12 days
4.50	4.50	3.05	VIS-EXT (350-700nm)	N-LASF44	#88-627	₹5,372 Qty 10+ ₹4,827	10 to 12 days
4.50	4.50	3.05	VIS-NIR (400-1000nm)	N-LASF44	#47-855	₹5,372 Qty 10+ ₹4,827	10 to 12 days
4.50	4.50	3.05	YAG-BBAR (500-1100nm)	N-LASF44	#88-786	₹5,372 Qty 10+ ₹4,827	10 to 12 days
4.50	9.00	7.41	MgF ₂ (400-700nm)	N-BK7	#45-148	₹3,873 Qty 10+ ₹3,484	10 to 12 days
4.50	9.00	7.41	NIR I (600-1050nm)	N-BK7	#48-708	₹4,671 Qty 10+ ₹4,204	10 to 12 days
4.50	9.00	7.41	Uncoated	N-BK7	#45-147	₹3,406 Qty 10+ ₹3,075	10 to 12 days
4.50	9.00	7.41	VIS 0° (425-675nm)	N-BK7	#47-867	₹4,671 Qty 10+ ₹4,204	10 to 12 days
4.50	9.00	7.41	VIS-EXT (350-700nm)	N-BK7	#88-628	₹5,060 Qty 10+ ₹4,554	Contact Us
4.50	9.00	7.41	VIS-NIR (400-1000nm)	N-BK7	#47-856	₹5,060 Qty 10+ ₹4,554	10 to 12 days
4.50	9.00	7.41	YAG-BBAR (500-1100nm)	N-BK7	#88-787	₹5,060 Qty 10+ ₹4,554	10 to 12 days
4.50	9.00	7.41	NIR II (750-1550nm)	N-BK7	#67-452	₹4,671 Qty 10+ ₹4,204	10 to 12 days



Copyright 2023, Edmund Optics India Private Limited, #267, Greystone Building, Second Floor, 6th Cross Rd, Binnamangala, Stage 1, Indiranagar, Bengaluru, Karnataka, India 560038

Phone: 1-800-363-1992 :

www.edmundoptics.com