


[All Products](#) / [Laser Optics](#) / [Laser Mirrors](#) / [Laser Line Mirrors](#)

TECHSPEC® Nd:YAG Laser Output Couplers

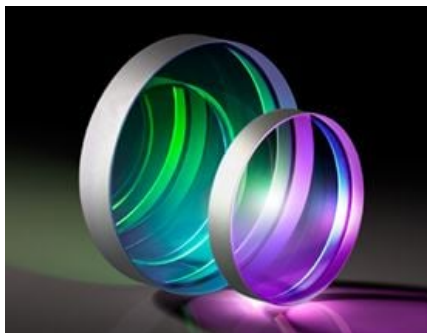

- Designs for 532nm and 1064nm Nd:YAG Lasers
- 80% Reflectivity at Nd:YAG DWL
- UV Fused Silica Substrates

Common Specifications

General

Note:

Arrow on edge points towards S1

Optical Properties

Coating Type:

Dielectric


Angle of Incidence (°):

0

Substrate:

[Fused Silica](#) (Corning 7980)

Technical Information

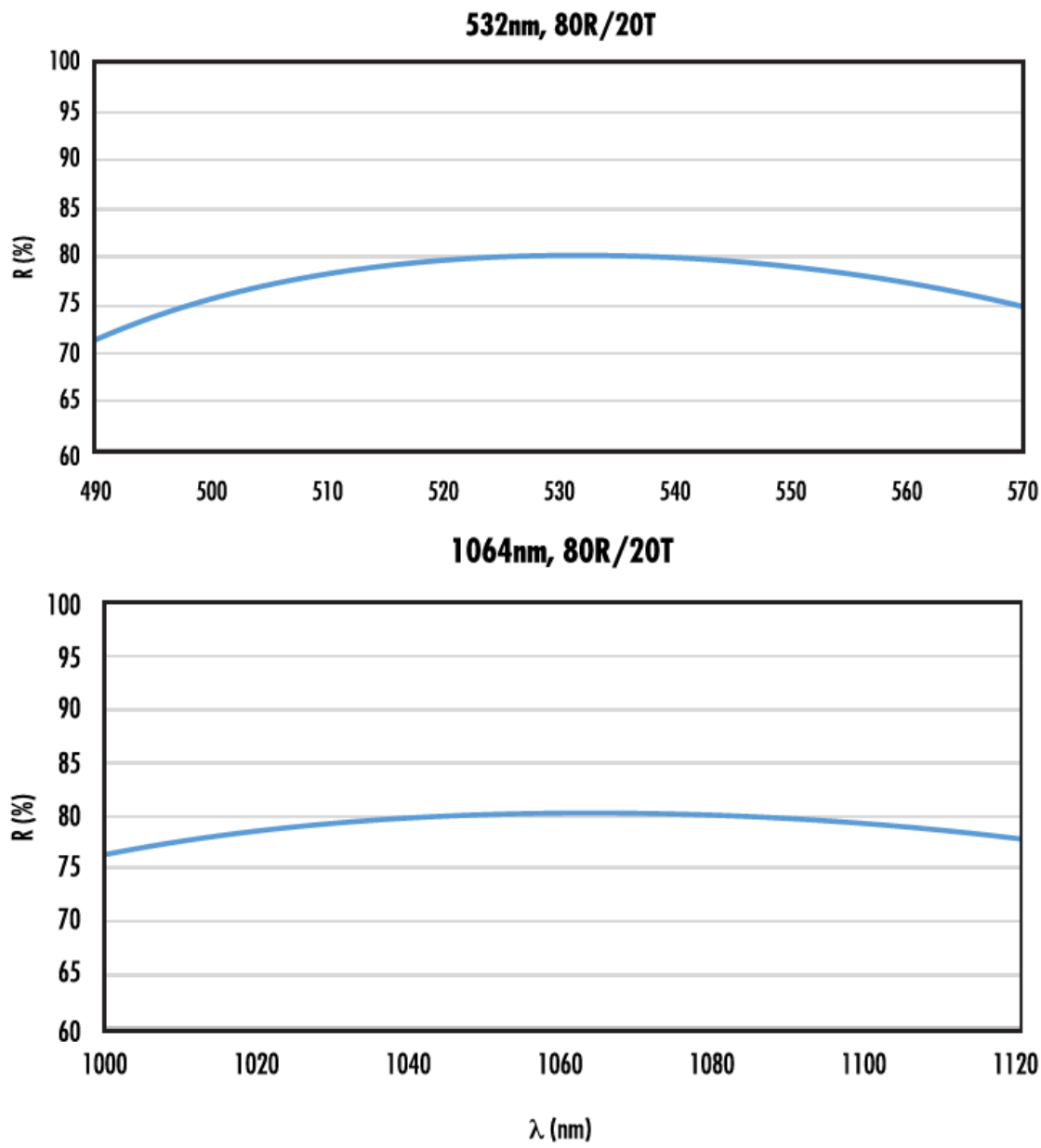

Products

Reflection/Transmission Ratio (R/T)	DWL (nm)	Dia. (mm)	Thickness (mm)	AOI (°)	Stock Number	Price	Buy
90/10	1064	19.05	9.53	0	#17-622	₹12,145 Volume Pricing	Contact Us
80/20	1064	12.70	6.35	0	#14-740	₹10,198 Volume Pricing	10 In Stock
80/20	1064	19.05	9.53	0	#17-623	₹12,145 Volume Pricing	20+ In Stock
80/20	1064	25.40	6.35	0	#14-739	₹12,923 Volume Pricing	20+ In Stock
80/20	532	12.70	6.35	0	#14-742	₹10,198 Volume Pricing	17 In Stock
80/20	532	25.40	6.35	0	#14-741	₹12,923 Volume Pricing	15 In Stock



Copyright 2023, Edmund Optics India Private Limited, #267, Greystone Building, Second Floor, 6th Cross Rd, Binnamangala, Stage 1, Indiranagar, Bengaluru, Karnataka, India 560038
Phone: 1-800-363-1992 :
www.edmundoptics.com