


[All Products](#) / [Optics](#) / [Windows and Diffusers](#) / [UV and IR Windows](#)

ISP Optics Zinc Selenide (ZnSe) Wedged Windows See More by [ISP Optics](#)

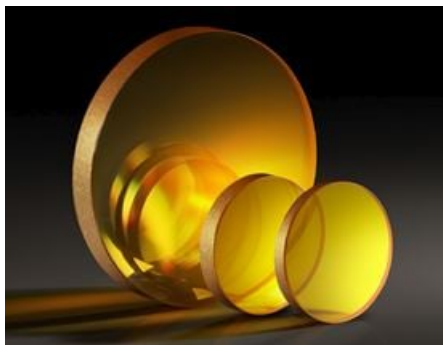

- 30 Arcmin and 3° Wedge Versions Available
- Low Dispersion
- Eliminate Etalon Effect and Cavity Feedback
- [Precision Flat Zinc Selenide Windows](#) Also Available

Common Specifications

Physical & Mechanical Properties

Bevel:	Protective as needed	Clear Aperture (%):	85
Edges:	Fine Ground	Knoop Hardness (kg/mm²):	120
Poisson's Ratio:	0.28	Young's Modulus (GPa):	67.2


Optical Properties

Coating:	Uncoated	Substrate:	Zinc Selenide (ZnSe)
Surface Quality:	60-40	Wavelength Range (nm):	600 - 18000

Material Properties

Density (g/cm³):	5.27
------------------------------------	------

Technical Information

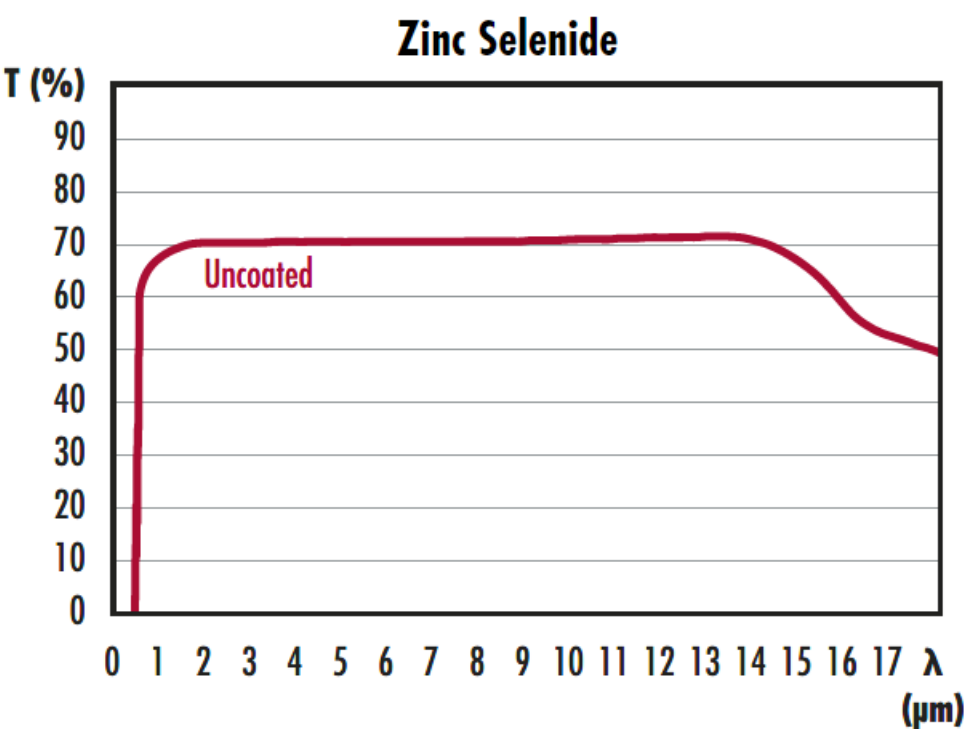

Products

Dia. (mm)	Thickness (mm)	Coating	Wedge Angle (°)	Stock Number	Price	Buy
#16-814 Clearance						
<div><div></div><div>×</div></div>						
Clearance						
Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.						
25.40	3.00	Uncoated	3°		₹60,300	10 to 12 days
#16-812 Clearance						
<div><div></div><div>×</div></div>						
Clearance						
Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.						
25.40	4.00	Uncoated	-		₹35,318	10 to 12 days

[#24-686 Clearance](#)



Clearance

Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.

38.10 3.00 Uncoated 3° ±0.5

₹50,850

[Contact Us](#)

50.80 6.00 Uncoated -

[#16-813](#)

₹67,335

10 to 12 days



Copyright 2023, Edmund Optics India Private Limited, #267, Greystone Building, Second Floor, 6th Cross Rd, Binnamangala, Stage 1, Indiranagar, Bengaluru, Karnataka, India 560038

Phone: 1-800-363-1992 :

www.edmundoptics.com