


[All Products](#) / [Optics](#) / [Optical Lenses](#) / [Plano-Convex \(PCX\) Lenses](#) / [UV and IR Plano-Convex \(PCX\) Lenses](#)

ISP Optics Zinc Selenide (ZnSe) Plano-Convex (PCX) Lenses

See More by [ISP Optics](#)

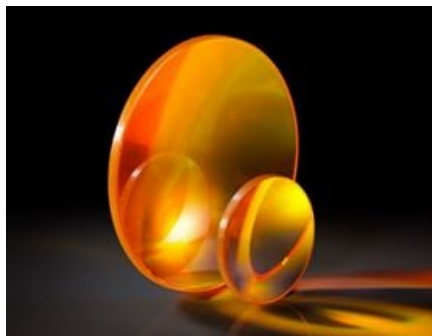

- Low Dispersion and Absorption from 0.6 – 18 μ m
- High Resistance to Thermal Shock
- Uncoated or BBAR Coated for 8 – 12 μ m

Common Specifications

Physical & Mechanical Properties



Bevel:	Protective as needed	Centering (arcmin):	<3
---------------	----------------------	----------------------------	----

Optical Properties

Substrate:	Zinc Selenide (ZnSe), CVD Grade	Focal Length Tolerance (%):	± 2
Surface Quality:	60-40	Irregularity (P-V) @ 10.6μm:	$\lambda/20$

Technical Information

Products

Dia. (mm)	EFL (mm)	BFL (mm)	Coating	Model Number	Stock Number	Price	Buy
#24-947 Clearance							
							
Clearance							
Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.							
25.40	200.00	199.52	Uncoated	ZC-PX-25-200		₹31,142	10 to 12 days
#24-948 Clearance							
							
Clearance							
Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.							
25.40	254.00	253.25	Uncoated	ZC-PX-25-254		₹15,917	10 to 12 days

[#24-949 Clearance](#)



Clearance

Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.

25.40	500.00	496.87	Uncoated	ZC-PX-25-500	₹15,917	10 to 12 days
-------	--------	--------	----------	--------------	---------	---------------

[#24-952 Clearance](#)



Clearance

Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.

38.10	75.00	74.14	Uncoated	ZC-PX-38-76	₹26,009	10 to 12 days
-------	-------	-------	----------	-------------	---------	---------------

[#24-953 Clearance](#)



Clearance

Availability
is limited,
so buy
before
these
products
disappear.
Sorry, we
cannot
accept
returns.
Receive
up to 80%
off select
products.

38.10

100.00

98.41

Uncoated

ZC-PX-
38-100

₹26,009

10 to 12 days

[#24-956 Clearance](#)



Clearance

Availability
is limited,
so buy
before
these
products
disappear.
Sorry, we
cannot
accept
returns.
Receive
up to 80%
off select
products.

38.10

200.00

199.39

Uncoated

ZC-PX-
38-200

₹26,009

10 to 12 days

[#24-957 Clearance](#)



Clearance

Availability
is limited,
so buy
before
these
products
disappear.
Sorry, we
cannot
accept
returns.
Receive
up to 80%
off select
products.

38.10

254.00

253.13

Uncoated

ZC-PX-
38-254

₹26,009

10 to 12 days

[#24-958 Clearance](#)



Clearance

Availability
is limited,
so buy
before
these
products
disappear.
Sorry, we
cannot
accept
returns.
Receive
up to 80%
off select
products.

38.10

500.00

496.79

Uncoated

ZC-PX-
38-500

₹26,009

10 to 12 days

[#24-959 Clearance](#)



Clearance

Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.

38.10	1,000.00	1000.08	Uncoated	ZC-PX-38-1000	₹26,009	10 to 12 days
-------	----------	---------	----------	---------------	---------	---------------

[#24-961 Clearance](#)



Clearance

Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.

50.80	100.00	97.78	Uncoated	ZC-PX-50-100	₹42,452	10 to 12 days
-------	--------	-------	----------	--------------	---------	---------------

[#24-982 Clearance](#)



Clearance

Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.

12.70	25.40	24.56	BBAR (8000-12000nm)	AR812-ZC-PX-12-25	₹10,784	10 to 12 days
-------	-------	-------	---------------------	-------------------	---------	---------------

[#24-992 Clearance](#)



Clearance

Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.

25.40	500.00	496.87	BBAR (8000-12000nm)	AR812-ZC-PX-25-500	₹18,092	10 to 12 days
-------	--------	--------	---------------------	--------------------	---------	---------------

[#24-994 Clearance](#)



Clearance

Availability
is limited,
so buy
before
these
products
disappear.
Sorry, we
cannot
accept
returns.
Receive
up to 80%
off select
products.

38.10	63.50	61.84	BBAR (8000- 12000nm)	AR812- ZC-PX- 38-63	₹29,054	10 to 12 days
-------	-------	-------	----------------------------	---------------------------	---------	---------------

[#24-997 Clearance](#)



Clearance

Availability
is limited,
so buy
before
these
products
disappear.
Sorry, we
cannot
accept
returns.
Receive
up to 80%
off select
products.

38.10	127.00	127.31	BBAR (8000- 12000nm)	AR812- ZC-PX- 38-127	₹29,054	10 to 12 days
-------	--------	--------	----------------------------	----------------------------	---------	---------------

[#24-999 Clearance](#)



Clearance

Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.

38.10	200.00	199.39	BBAR (8000-12000nm)	AR812-ZC-PX-38-200	₹29,054	10 to 12 days
-------	--------	--------	---------------------	--------------------	---------	---------------

[#25-010 Clearance](#)



Clearance

Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.

50.80	1,000.00	999.83	BBAR (8000-12000nm)	AR812-ZC-PX-50-1000	₹47,324	10 to 12 days
-------	----------	--------	---------------------	---------------------	---------	---------------



Copyright 2023, Edmund Optics India Private Limited, #267, Graystone Building, Second Floor, 6th Cross Rd, Binnamangala, Stage 1, Indiranagar, Bengaluru, Karnataka, India 560038
Phone: 1-800-363-1992 : www.edmundoptics.com