

[All Products](#) / [Lights and Illumination](#) / [Microscopy Lighting](#) / [Fiber Optic Illuminators](#)

SCHOTT KL Fiber Optic Light Sources See More by [SCHOTT Optical Components](#)



- Maximum Light Intensity of 1100 Lumens
- Continuous Dimming from 0 - 100%
- Various Light Guide Options Available
- Ideal for Use with Stereo Microscopes

Common Specifications

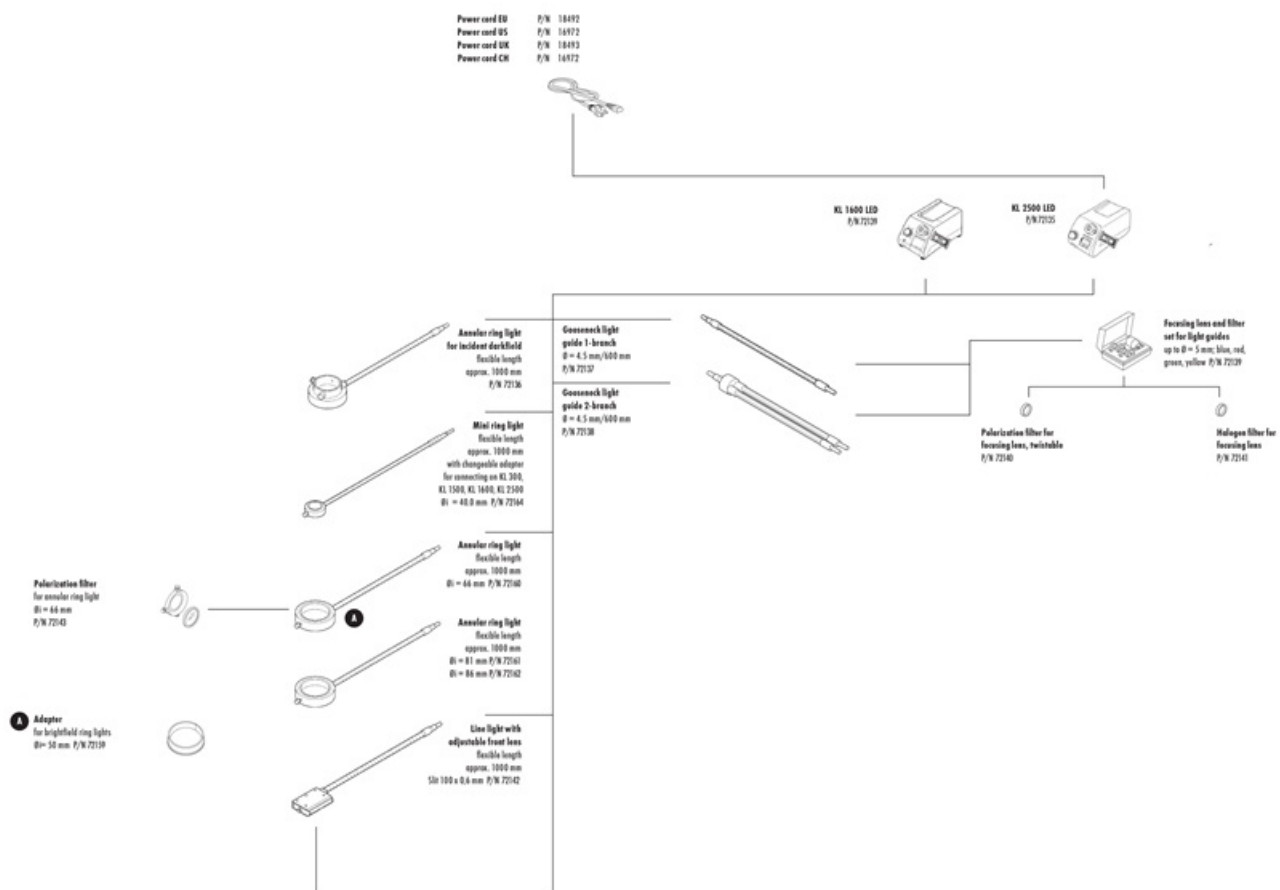
General			
Operating Lifetime (hours):	>50,000	Intensity Control Option:	Yes
Type of Illumination:	LED Illuminator	Manufacturer:	SCHOTT
Illumination Mode:	Constant		

Physical & Mechanical Properties	
Dimensions (mm):	114L x 231W x 137H
Optical Properties	
Color:	White

Hardware & Interface Connectivity			
Input Voltage (V):	24 DC		
Power Supply:	Power Cord Required and Sold Separately: USA: #16-792 Europe: #18-492 Japan: #78-580 Korea: #16-792 China: #16-792 UK: #18-493 Switzerland: #18-494		



Environmental & Durability Factors			
Color Temperature (K):	5600		

Technical Information



SCHOTT
glass made of ideas

Products

Title	Stock Number	Price	Buy
#72-134 New			
Schott KL 1600 LED Light Source	 New Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!	₹87,840	10 to 12 days
#72-135 New			
Schott KL 2500 LED Light Source	 New Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!	₹1,30,950	10 to 12 days



Copyright 2023, Edmund Optics India Private Limited, #267, Greystone Building, Second Floor, 6th Cross Rd, Binnamangala, Stage 1, Indiranagar, Bengaluru, Karnataka, India 560038
Phone: 1-800-363-1992 :
www.edmundoptics.com