


0.5 OD, 50mm Dia., VIS 0° Coated, Absorptive ND Filter

See More by [Hoya](#)

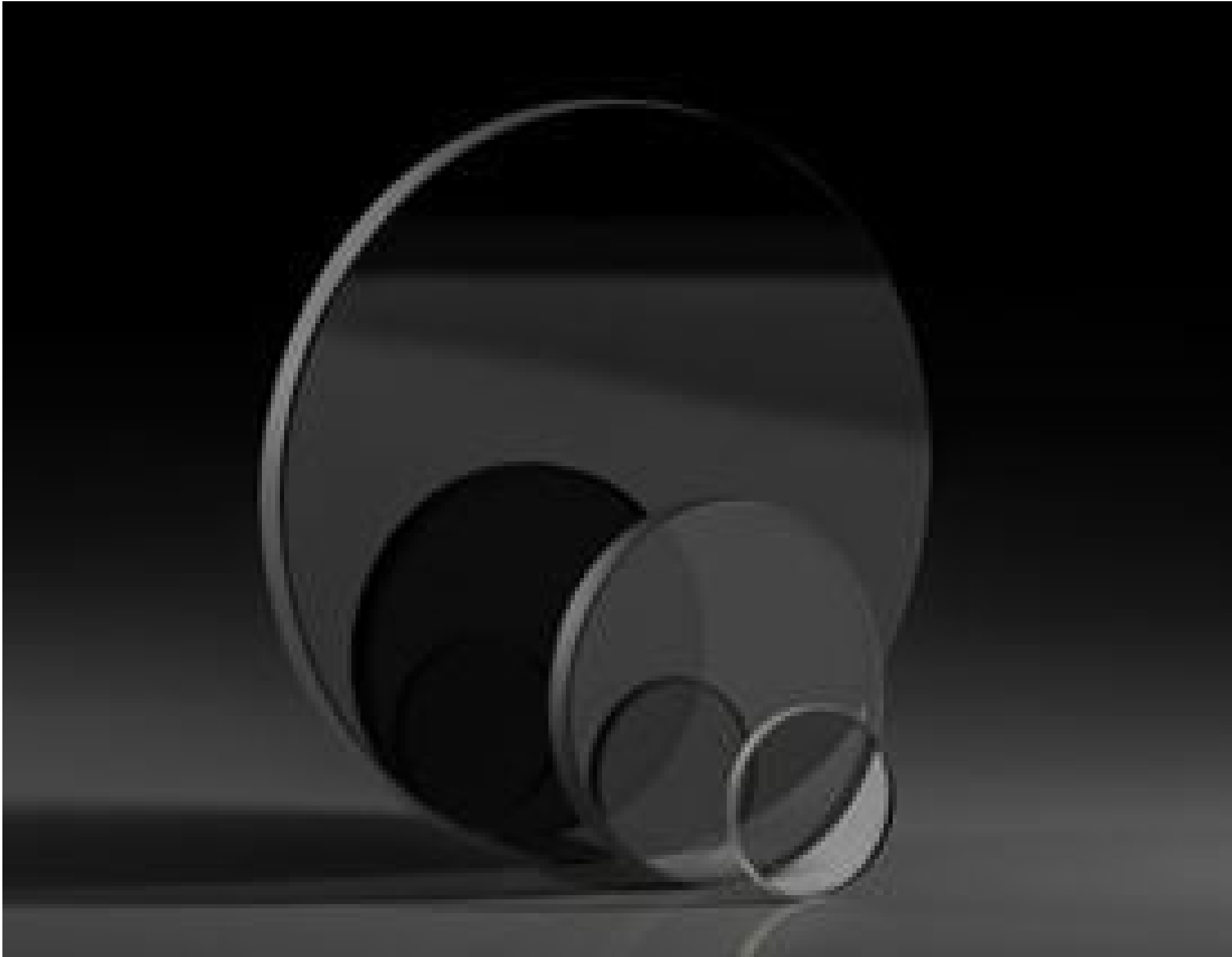

Anti-Reflection (AR) Coated HOYA Absorptive Neutral Density (ND) Filters

Stock **#13-117** 10 TO 12 DAYS

⊖ 1 ⊕

₹13,572.00

ADD TO CART

Qty 1-10
₹13,572.00
Qty 11+
₹11,919.00
Volume Pricing
Request Quote

Get Product Downloads



Diameter (mm):
50.00

Optical Density OD (Average):
0.5 ±0.05 @ 400-700nm (Uncoated Filter)

Nominal Optical Density @ Center of Coating:
0.43 @ 550nm

Glass/Filter Number: Hoya ND-25
Substrate: ☐ ND Filter Glass
Coating: VS 0° (425-675nm)
Index of Refraction n_d: 1.507
Surface Quality: 80-50
Transformation Temperature (°C): 535
Thickness (mm): 2.00
Thickness Tolerance (mm): ±0.5
Transmission (%): 32.0 (average) @ 400 - 700nm
Type: Neutral Density Filter
Blocking Wavelength Range (nm): 400 - 700
Dimensional Tolerance (mm): ±0.1
Parallelism (mm): <0.02
Coating Specification: R_{avg} ≤0.4% @ 425 - 675nm
Wavelength Range (nm): 425 - 675
Stock No. of Uncoated Filter: #65-813

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 233: Compliant