


TECHSPEC® 25mm Dia. 0.5° Nom. Fused Silica Wedge Prism Uncoated

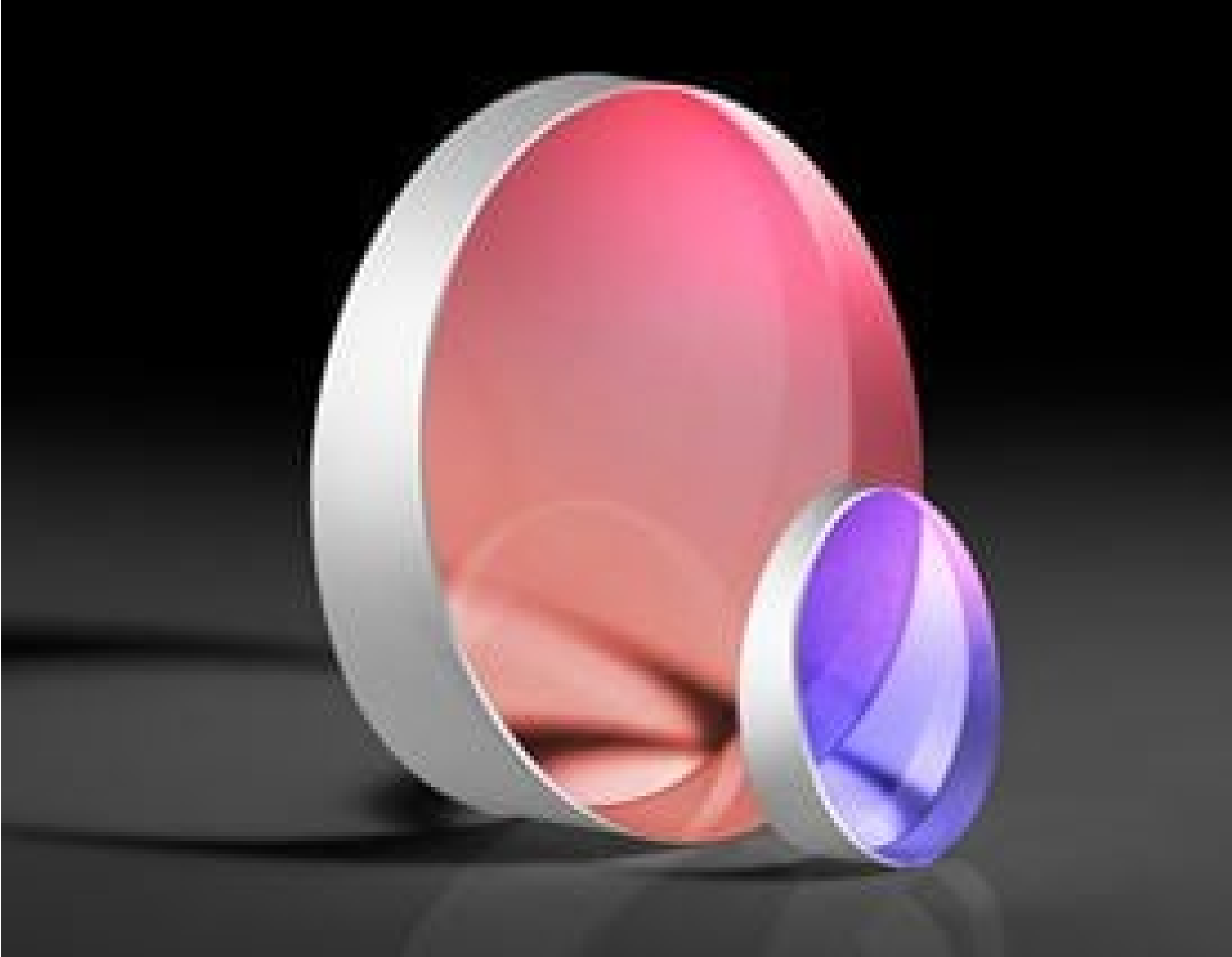

TECHSPEC Fused Silica Wedge Prisms

Stock **#84-859** 10 TO 12 DAYS

- 1 + **₹10,658.00**

ADD TO CART

Qty 1-5
₹10,658.00
Qty 6+
₹8,526.00
Volume Pricing
Request Quote

Get Product Downloads



Coating:
Uncoated

Angle Tolerance (arcsec):
15

Bevel:
Protective bevel as needed

Coefficient of Thermal Expansion CTE (10⁻⁶/°C): 0.52
Design Wavelength DWL (nm): 355
Diameter (mm): 25.00 +0.00/-0.10
Image Orientation: Beam Deviation
Power (diopters): 0.87
Ray Deviation @ 355nm (°): 0.50
Substrate: ☐ Fused Silica (Corning 7980)
Surface Flatness (P-V): λ/10
Surface Quality: 20-10
Thickness (mm): 3.00
Type: Wedge Prism
Wavelength Range (nm): 200 - 2200
Wedge Angle: 1° 3'0"

Regulatory Compliance

RoHS 2015: Compliant
Reach 219: Compliant
Certificate of Conformance: View