


0.9 OD, 12.5mm Dia., NIR I Coated, Absorptive ND Filter

See More by [Hoya](#)

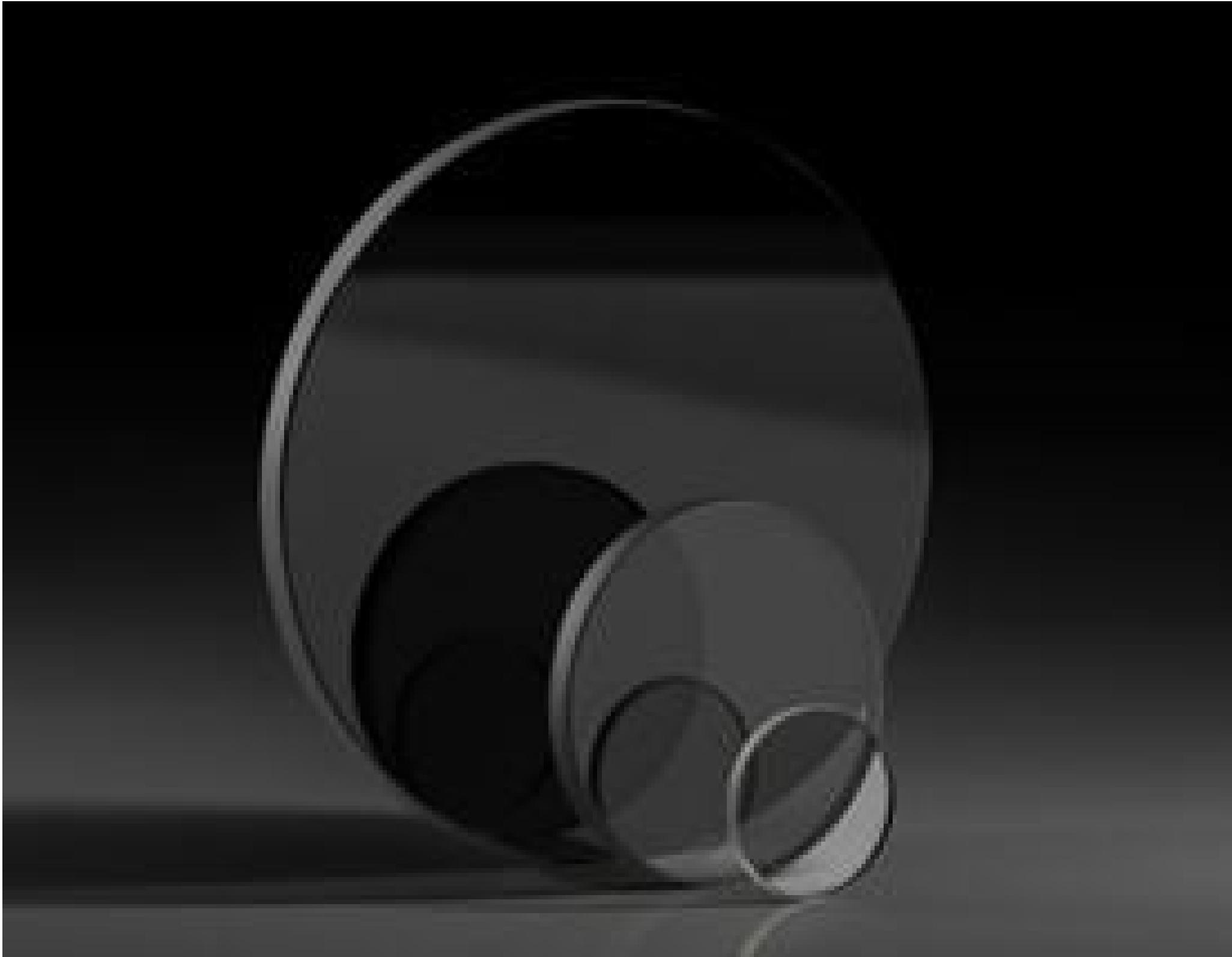

Anti-Reflection (AR) Coated HOYA Absorptive Neutral Density (ND) Filters

Stock **#13-154** 10 TO 12 DAYS

- 1 + **₹4,611.00**

ADD TO CART

Qty 1-10
₹4,611.00
Qty 11+
₹4,002.00
Volume Pricing
Request Quote

Get Product Downloads



Diameter (mm): 12.50
Optical Density OD (Average): 0.9 ±0.1 @ 400-700nm (Uncoated Filter)
Nominal Optical Density @ Center of Coating: 1.02 @ 900nm

Glass/Filter Number: Hoya ND-13
Substrate: ☐ ND Filter Glass
Coating: NIR I (600-1050nm)
Index of Refraction n_d: 1.51
Surface Quality: 80-50
Transformation Temperature (°C): 535
Thickness (mm): 2.50
Thickness Tolerance (mm): ±0.5
Transmission (%): 12.5 (average) @ 400 - 700nm
Type: Neutral Density Filter
Blocking Wavelength Range (nm): 400 - 700
Dimensional Tolerance (mm): ±0.1
Parallelism (mm): <0.02
Coating Specification: R_{avg} ≤0.5% @ 600 - 1050nm
Wavelength Range (nm): 600 - 1050
Stock No. of Uncoated Filter: #48-528

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 233: Compliant