


TECHSPEC® 0° AOI, 25.0mm Square, Cold Mirror

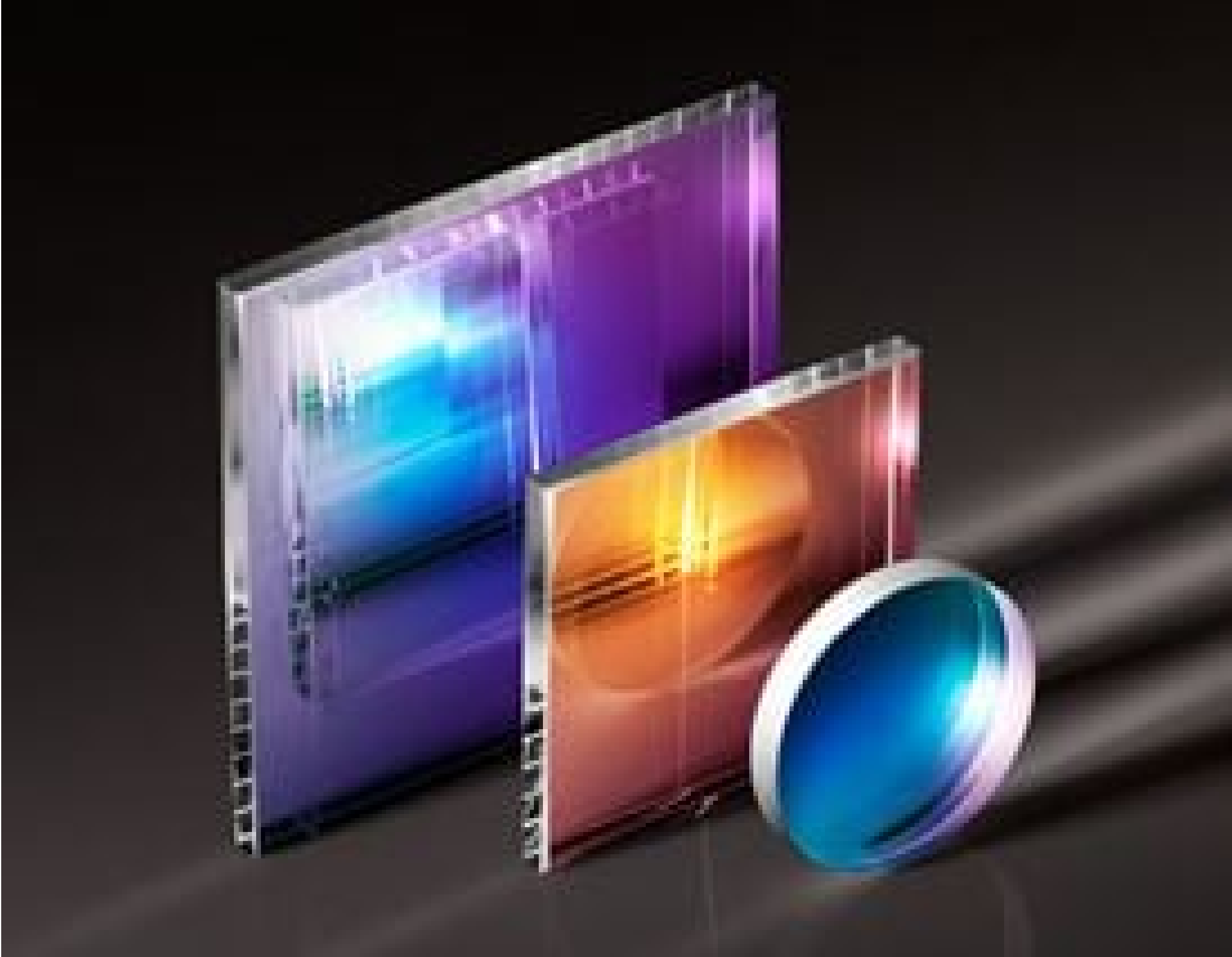

TECHSPEC High Performance Cold Mirrors

Stock **#64-438** 10 TO 12 DAYS

- 1 + **₹4,568.00**

ADD TO CART

Qty 1-9

₹4,568.00

Qty 10+

₹4,028.00

Volume Pricing

[Request Quote](#)

Get Product Downloads

Angle of Incidence (°):

0

Coating:

Cold Mirror, 0°

Substrate: ☐

[BOROFLOAT®](#)

Dimensions (mm):

25.0 x 25.0
Surface Quality: 80-50
Thickness (mm): 3.30
Thickness Tolerance (mm): ±0.2
Transmission (%): Longpass Filter
Type: Cold Mirror
Dimensional Tolerance (mm): +0.0/-0.2
Coating Specification: R _{avg} ≥95% @400 - 690nm and T _{avg} ≥90% @ 750 - 1200nm AR Coating: R _{avg} <1% @ 700 - 1150nm
Wavelength Range (nm): 400 - 1150
Surface Flatness (P-V): 4 - 6λ
Coating Type: Dielectric

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 233: Compliant