


100 x 100mm, 1.000mm Spacing, White Ivory Distortion Target

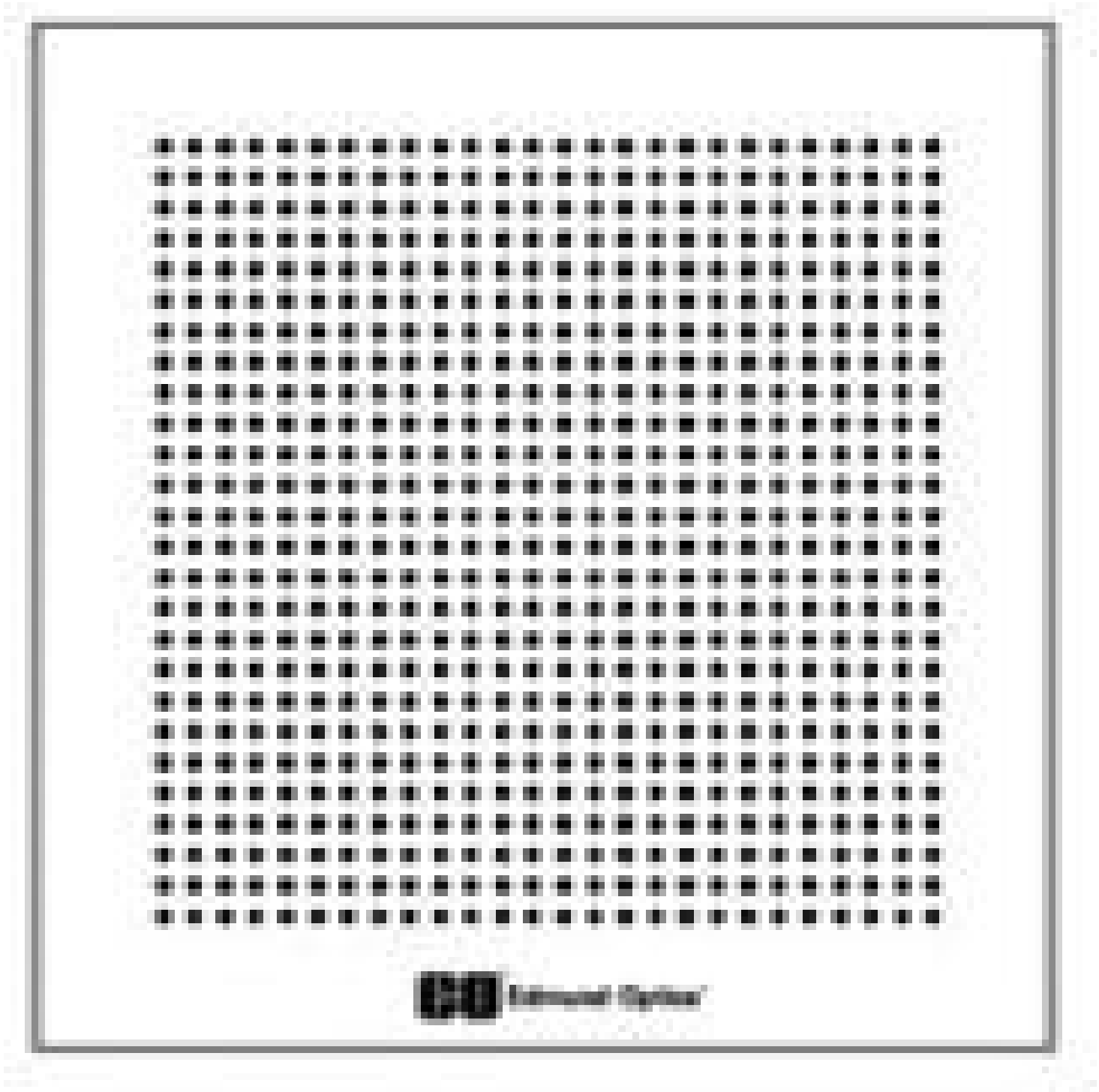

Stock #63-990 10 TO 12 DAYS

-

1

+

₹146,421.00

ADD TO CART

Qty 1-4
₹146,421.00
Qty 5+
₹139,148.00
Volume Pricing
Request Quote

Get Product Downloads

Coating:
Reflective First Surface Chromium
R_{abs} = 50% ±5% @ 550nm

Dot Diameter (mm):
0.500

Dot Spacing (mm):

1.000
Substrate: White Ivory Soda Lime Glass
Optical Density OD (Average): >3.0
Overall Accuracy (mm): ±0.002
Pattern Size (mm): 100 x 100
Dimensions (inches): 5 x 5
Surface Quality: 40-20
Thickness (mm): 3.20
Type: Chrome on White Ivory Glass
Dot Diameter Tolerance (mm): ± 0.002
Dot Spacing Tolerance (mm): ± 0.002 Center to Center
NIST Certification: Serialized NIST Traceable Certificate Included
Flatness (inches): 0.001

Regulatory Compliance

RoHS 2015: Compliant
Reach 209: Compliant
Certificate of Conformance: View
