

[See all 44 Products in Family](#)

100 x 100mm 120 Grit Ground Glass Diffuser



Stock **#83-384** **9 In Stock**

-

1

+

₹3,392

ADD TO CART

Volume Pricing	
Qty 1-10	₹3,392 each
Qty 11+	₹3,136 each
Need More?	Request Quote

Product Downloads

General	
Ground Glass Diffuser	Type:
Sandblasted on first surface	Note:
Physical & Mechanical Properties	
±0.25	Dimensional Tolerance (mm):
100.00 x 100.00	Dimensions (mm):

Cut	Edges:
120	Grit: ☐
1.60	Thickness (mm):
100.00	Width (mm):
100.00	Length (mm):

Optical Properties

Uncoated	Coating:
Float Glass	Substrate: ☐
350 - 2000	Wavelength Range (nm):

Regulatory Compliance

Compliant	RoHS 2015:
View	Certificate of Conformance:
Compliant	Reach 247:
United States	Country of Origin:
Edmund Optics India Private Limited	Imported By:

Product Details

• Available in Sizes Ranging from 5mm Diameter to 250mm Square

• Low Scatter Loss


• Evenly Ground Surface for Even Diffusion

• **Fused Silica Substrates** Available

Ground Glass Diffusers are comprised of high tolerance, quality ground glass making them ideal for a variety of industrial applications. The float glass substrate has excellent visible transmission and is ideal for general diffusing applications. A 120-grit, 220-grit or 600-grit (as noted) sandblast is used to create a diffuse surface on the glass. Ground Glass Diffusers have even diffusion across the entire surface from undergoing two orthogonal passes during this sandblast process. The scattering is a compromise of low scatter loss and medium diffusion. Typical applications include use in screens, illuminator diffusion, and targets.

Can't find what you need? Get a quick [custom quote](#).

Technical Information

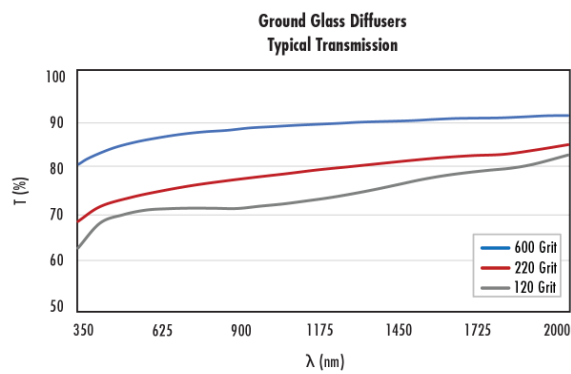

Quote Your Size

Compatible Mounts