


1064nm, 15mm Dia., Round Output, Diffractive Diffuser

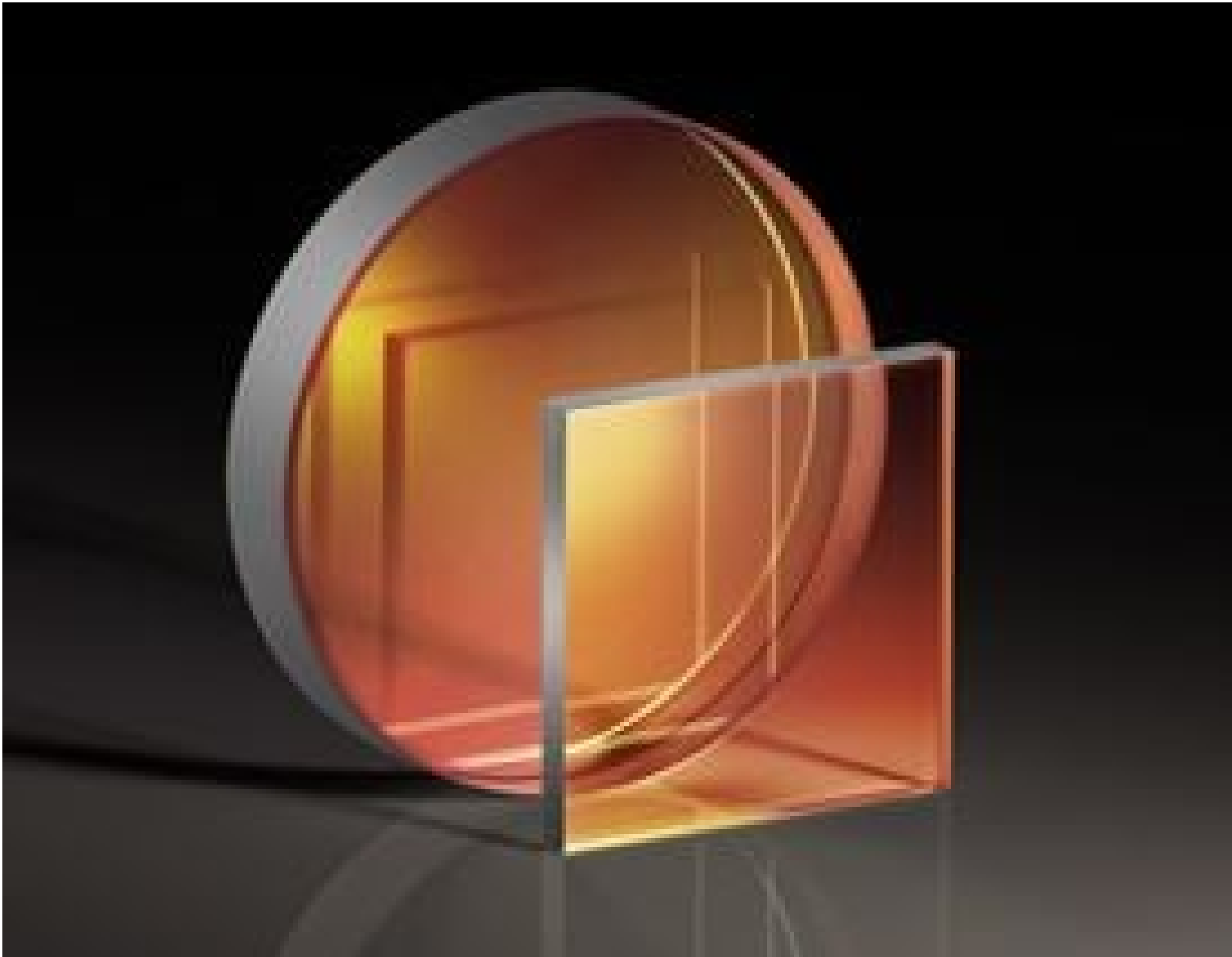

HOLO/OR Diffractive Diffusers

Stock **#14-682** 10 TO 12 DAYS

- 1 + **₹113,100.00**

ADD TO CART

Qty 1+
₹113,100.00
Volume Pricing
Request Quote

Get Product Downloads



Clear Aperture CA (mm):
13.00

Coating:
Laser V-Coat (1064nm)

Design Wavelength DWL (nm):
1064

Diameter (mm):
15.00 +0.05/-0.15

Substrate:

Fused Silica (Coming 7980)	
Thickness (mm):	3.00 ±0.1
Input Beam Mode:	SMor MM
Minimum Beam Diameter (mm):	5
Output Shape:	Round
Overall Efficiency (%):	77
Full Angle (°) :	5.27
Damage Threshold, Reference:  See Link for More Details	

Regulatory Compliance

RoHS 2015:	Compliant
Certificate of Conformance:	View
Reach 233:	Compliant